

Euro-conn




 
product specification

SPECIFICATION

- Current Rate: 3 AMP
- Insulation Resistance: 1000M Ω Min.
- Contact Resistance: 20m Ω Max.
- Dielectric Voltage: 1000V AC for one minute
- Operation Temperature: -40°C to +105 °C
- Soldering Temperature: 200°C / 5 Sec

MATERIAL

- Insulator Material: Polyester, UL 94V-0
- Standard: P.B.T
- Contact Material: Brass
- Finish: Gold plated
- Standard: Gold flash all over

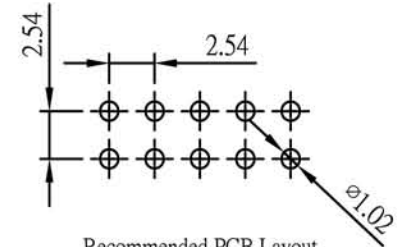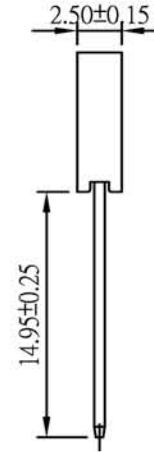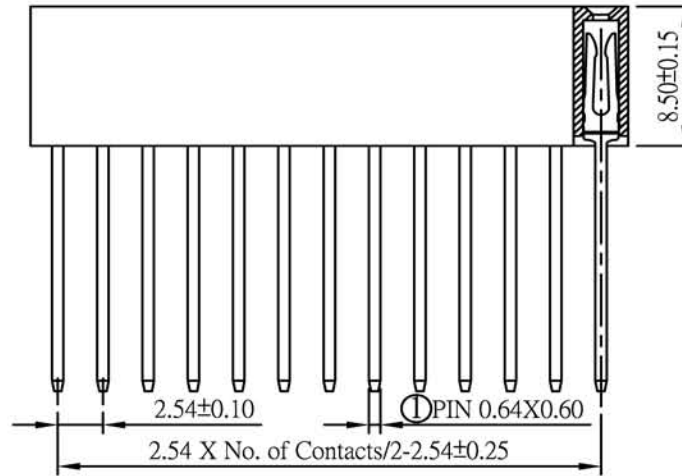

Recommended PCB Layout
(PCB TOLERANCE ± 0.05)

ORDER INFORMATION: **FH254** - ^{N.ro Pin} **1** **XX** **DF085T** **149V**

UNITS	mm	SIZE	A4	SCALE	FIRST ANGLE PROJECTION
Euro-conn					
					HEADER