

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.


Jameco Part Number 228435

RCA Audio Patch Cords

Shielded RCA Patch Cords
 Black 2.8mm OD PVC Jacket
 Fully Molded Construction
 Nickel or Gold-Plated High-Retention RCA Plugs
 Color-Coded Red-White/Red-White or Black-Black
 AWG26 Stranded Copper Center Conductor
 Low-Loss 95% Spiral-Wound Copper Shield
 99.99% Pure Oxygen-Free Copper Wire


- 255-100** 6' RCA Jack to RCA Plug
- 255-105** 10' RCA Jack to RCA Plug
- 255-110** 6' RCA Plug to RCA Plug
- 255-115** 10' RCA Plug to RCA Plug
- 255-117** 25' RCA Plug to RCA Plug
- 255-118** 25' RCA Plug to Plug – AWG24
- 255-120** 3' 2-RCA Plugs to 2-RCA Plugs
- 255-121** 3' 2-RCA Plug-Plug Gold Plated
- 255-125** 6' 2-RCA Plugs to 2-RCA Plugs
- 255-126** 6' 2-RCA Plug-Plug Gold Plated
- 255-127** 9' 2-RCA Plugs to 2-RCA Plugs
- 255-128** 9' 2-RCA Plug-Plug Gold Plated
- 255-130** 12' 2-RCA Plugs to 2-RCA Plugs
- 255-131** 12' 2-RCA Plug-Plug Gold Plated
- 255-132** 15' 2-RCA Plugs to 2-RCA Plugs
- 255-133** 15' 2-RCA Plug-Plug Gold Plated
- 255-134** 20' 2-RCA Plugs to 2-RCA Plugs
- 255-135** 25' 2-RCA Plugs to 2-RCA Plugs
- 255-136** 25' 2-RCA Plug-Plug Gold Plated
- 255-138** 50' 2-RCA Plug-Plug Nickel Plated **◀ NEW**
- 255-140** 6' 2-RCA Plugs – RCA Piggyback
- 255-145** 12' 2-RCA Plugs – RCA Piggyback
- 255-150** 6' 4-RCA Plug-Plug – Color Coded
- 255-175** 6' 2-RCA Jacks to 2-RCA Plugs
- 255-244** 3' 2-RCA Plugs to 2-RCA Angle Plugs
- 255-246** 6' 2-RCA Plugs to 2-RCA Angle Plugs

Black

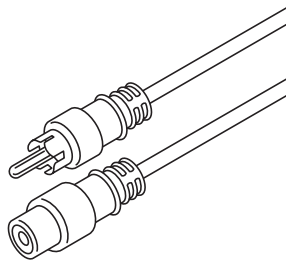


- 255-100** 6' Nickel
- 255-105** 10' Nickel

Black

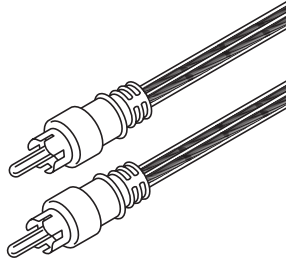


- 255-118** 25' AWG24 Nickel


Red

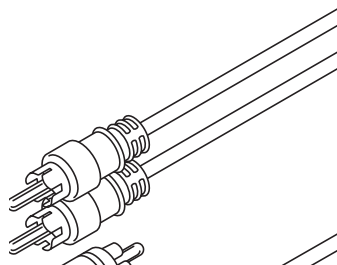

White

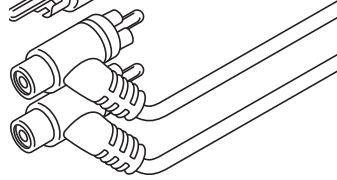


Red

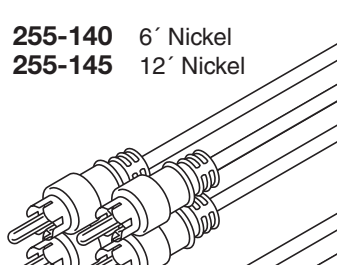

White

- 255-140** 6' Nickel
- 255-145** 12' Nickel

Red

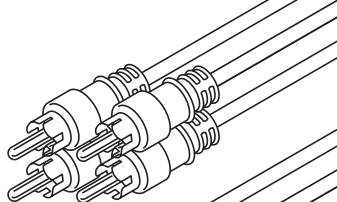


White

Yellow

Black

Red

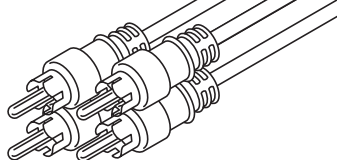


White

Yellow

Black

- 255-150** 6' Nickel

Red

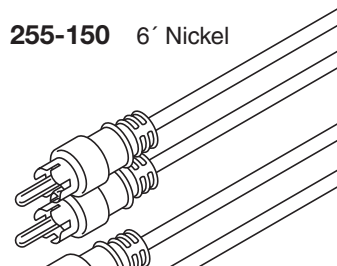

White


Red



White

- 255-175** 6' Nickel


Black

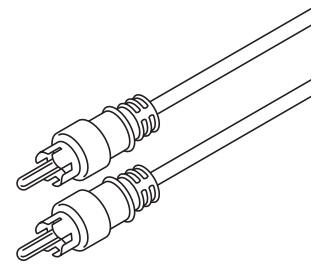


- 255-110** 6' Nickel
- 255-115** 10' Nickel
- 255-117** 25' Nickel



Red

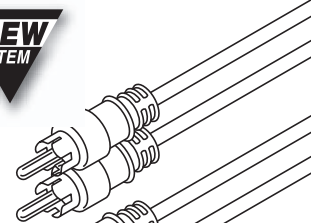

White

 

Red




White




- 255-120** 3' Nickel
- 255-121** 3' Gold
- 255-125** 6' Nickel
- 255-126** 6' Gold
- 255-127** 9' Nickel
- 255-128** 9' Gold
- 255-130** 12' Nickel
- 255-131** 12' Gold
- 255-132** 15' Nickel
- 255-133** 15' Gold
- 255-134** 20' Nickel
- 255-135** 25' Nickel
- 255-136** 25' Gold
- 255-138** 50' Nickel

Red

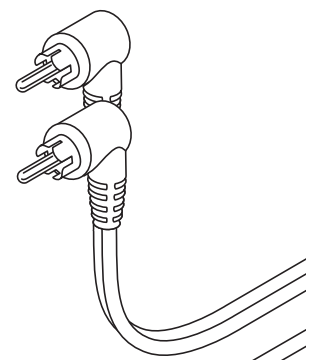

White

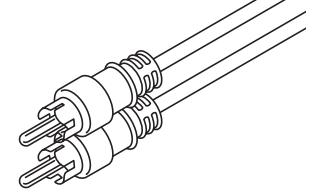

- 255-244** 3' Nickel
- 255-246** 6' Nickel