

Piezo Buzzers (Annunciators)

NEW
MARKED IN PINK

★ Web Code: JPB

Part No.	Manufacturer	Product No.	Fig.	Tone	Oper. Volt. (V/mA)	Volt. Range	Sound (dB)	Freq. (Hz)	Dimensions (H x Dia.)	Pricing		
										1	10	100
2081246	Shogyo	SEP-2202A5	6	Single	3/11	1.5 - 6	85	3000	16mm x 24mm	\$2.49	\$2.25	\$1.95
335557	ValuePro	MSR3400	13	Single	3-20/3-16	3 - 20	80	3400	.39" x .91"	2.75	2.55	2.29
337535	ValuePro	SNP428	15	Single	4-28/3-16	4 - 28	76	2900	.85" x 1.64"	2.49	2.25	1.95
1956696	Velleman	SV4/5-S	8	Single	5/25	3 - 6	87	3200	.30" x .47"	3.65	3.45	3.29
2081959	Floyd Bell	UC-05-515-P	17	Single	5/30	5 - 15	96	2100	1.08" x 1.40"	3.95	3.59	3.19
2098611	Kobitone	15210-ROX-R	6	Single	6/6	3 - 15	90	4000	0.335" x 0.543"	3.49	3.15	2.85
336989	ValuePro	SC616N	2	Single	6-16/6-22	6 - 16	95	2900	1.28" x 1.69"	1.95	1.75	1.55
1956741	Velleman	SVM06	5	Single	6/20	3 - 7	75	300-500	.91"L x .63"W x .59"H	1.95	1.75	1.55
337210	ValuePro	SC628D	2	Single	6-28/5-18	6 - 28	75	1900	1.25" x 1.69"	2.95	2.65	2.35
2098654	Kobitone	35C5-ROX-R	20	Single	6/40	3 - 15	110	2800	1.02" x 1.65"	4.75	4.25	3.75
2098638	Kobitone	27C0-ROX-R	21	Single	9/8	3 - 20	97	3500	0.552" x 1.22"	3.69	3.25	2.89
196357	Various	AL-175	14	Single	12/5.8	3 - 16	86	4000	.30" x .54"	1.75	1.49	1.25
1956725	Velleman	SV8	6	Single	12/6	3 - 16	85	4000	.30" x .55"	2.45	2.25	1.95
138713	ValuePro	32S4120-PN-R	14	Single	12/7	3 - 16	80	4000	.30" x .54"	2.45	2.25	1.95
673900	ValuePro	SEP-1172	18	— †	12/7	3 - 28	81	3300	16mm x 31.4mm	1.25	.95	.79
209690	Kobitone	256-PB313	16	Continuous	12/7	3 - 28	82	3600	.413" x 1.18"	1.95	1.75	1.49
336639	ValuePro	SBM616PU	19	— †	12/8	3 - 28	90	2900	16mm x 42mm	1.95	1.69	1.49
673926	ValuePro	SEP-2202A	6	Single	12/11	3 - 20	85	3000	16mm x 24.2mm	1.49	1.25	.95
1956688	Velleman	SV4	9	Single	12/12	4 - 15	90	2800	.79" x 1.10"	1.85	1.65	1.55
1956750	Velleman	SVM12	5	Single	12/15	7 - 17	75	300-500	.91"L x .63"W x .59"H	1.95	1.75	1.65
1956670	Velleman	SV2	10	Single	12/15	4 - 15	85	2800	.57" x 1.10"	2.19	2.09	1.95
1956709	Velleman	SV4/12-S	8	Single	12/15	8 - 16	85	3200	.30" x .47"	3.65	3.45	3.25
335927	ValuePro	PK-20A38P	6	Single**	12/15	3 - 24	95	3800	18mm x 23mm	2.95	2.59	2.29
335505	ValuePro	MAS800	12	Single	12/50	9 - 12	103	2800	15.2mm x 26mm	1.95	1.75	1.49
32602	ValuePro	11S3240-R	1	Single	24/15	1 - 27	95	2900	1.4" x 1.7"	4.95	4.45	4.29
1956768	Velleman	SVM24	5	Single	24/20	16 - 30	75	300-500	.91"L x .63"W x .59"H	2.45	2.35	2.19
76021	ValuePro	7S3240-LA	1	Single	24/20	1.5 - 28	95	3200	1.0" x 1.1"	3.95	3.49	2.95
1956733	Velleman	SV10	4	Dual	12/8	3 - 28	90	2900	.79" x 1.10"	8.95	8.59	8.15
1956717	Velleman	SV5	7	Dual	12/8	3 - 28	90	3500	.77" x 1.28"	6.39	6.15	5.79
249498	ValuePro	1103120-LF-TA	1	Dual*	12/25	4 - 16	95	2900	34.5mm x 43.5mm	2.95	2.65	2.39
1956661	Velleman	SV1	11	Dual	12/30	1 - 13	105	2900	1.02" x 1.77"	5.95	5.75	5.45
123538	ValuePro	11D3240	1	Dual*	24/20	4 - 28	80	2900	1.4" x 1.7"	4.19	3.79	3.39
336997	ValuePro	SC616NJ	1	Pulse	6-16/6-22	6 - 16	95	2900	1.28" x 1.69"	4.95	4.49	3.95
337383	ValuePro	SC628P	1	Single	6-28/4-16	6 - 28	80	2900	1.84" x 1.69"	4.95	4.49	3.95
335855	ValuePro	PK-12N40P	6	Pulse	12/10	3 - 15	83	4100	8mm x 14mm	2.95	2.59	2.29
336049	ValuePro	PK-27N36W	2	Pulse	12/15	3 - 28	90	3500	10mm x 30mm	2.55	2.19	1.95
335695	ValuePro	PF-20A35EW	3	Fast pulse	12/10	3 - 28	95	3500	.98" x 1.10"	3.55	3.19	2.49
336664	ValuePro	SC105	2	Single	1-5/3-16	1 - 5	75	2900	1.28"H x 1.69"Dia.	1.95	1.75	1.55

* Continuous or Fast Pulse ** Press fit: Panel hole - 27mm (1.06") † Requires driver circuit



Electromech

Mechanical/Electromechanical Buzzers

★ Web Code: MEB


Part No.	Manufacturer	Product No.	Fig.	Oper. Volt. (V/mA)	Voltage Range	Frequency (Hz)	Sound (dB)	Dimensions	Pricing		
									1	10	100
335370	ValuePro	AST200	1	3/80	2 - 5	2731	85	8.7"sq. x 4.2"H	\$1.49	\$1.29	\$1.09
335441	ValuePro	AST800	1	3	2 - 4.5	3200	87	11 W x 14 D x 3.5 H (mm)	1.95	1.59	1.29
140695	ValuePro	63S1120-LA	2	12/25	9 - 15	400	75	1.3"L x 0.7"W x 0.6"H	1.95	1.59	1.29
335345	ValuePro	ASI301	1	5/30	4 - 7	2400	90	.5"L x .5"W x .4"H	.95	.85	.69
335353	ValuePro	ASI401	1	12/30	8 - 15	2400	90	.5"L x .5"W x .4"H	.95	.85	.69
335388	ValuePro	AST500	1	1.5	1.2 - 3	2400	85	.5"L x .5"W x .4"H	.95	.85	.69
76065	ValuePro	TDB05-PN-R	3	5/30	4 - 7	2300	85	.35"H x .46"Dia.	2.95	2.75	2.55
24872	ValuePro	63S109LA	2	9/30	6 - 12	400	75	1.3"L x 0.7"W x 0.6"H	1.49	1.35	1.19



Piezo Sirens

★ Web Code: POS

Part No.	Manufacturer	Product No.	Fig.	Oper. Volt. (V/mA)	Voltage Range	Frequency (Hz)	Sound (dB)	Dimensions	Pricing		
									1	10	100
336225	ValuePro	PS-562	1	12/40	5 - 15	2500/3500	100	16mm x 42mm Dia.	\$4.95	\$4.49	\$3.95
207993	ValuePro	SL15R3120LA	2	12/250	6 - 16	3500	105	2.3"L X 1.8"W X 1.6"H	4.95	4.49	3.95
207889	ValuePro	18R3120	3	12/120	9 - 15	1500/3100	105	3.4"L x 2.2"W x 1.3"H	6.95	6.29	5.49
148152	Various	YC-321-1	4	12/300	2 - 12	3000	108	2.5"L x 2.8"Dia	7.95	6.95	5.95

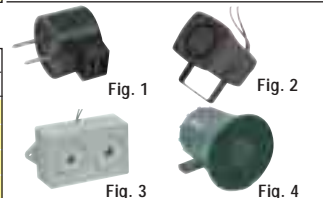

30mm PCB Mountable Speakers

NEW
MARKED IN PINK

- Ideal for PC board mounting
- Mylar diaphragm
- Power (nominal/max.): 0.15W/0.2W
- Solder leads

Part No.	Size (H x Dia.)	Impedance	Pin Spacing	Freq. Range	SPL (dB)	1	10	100
2095234	0.57" x 1.24	8Ω	0.69"	700-4kHz	82	\$1.75	\$1.49	\$1.25
135722	0.50" x 1.17"	8Ω	0.59"	700-5kHz	82	1.95	1.75	1.49
2099817	0.47" x 1.16"	100Ω	0.58"	1.1kHz ±20%	95	1.95	1.75	1.49

135722



Helping You Find What You Need
Can't find the product you're looking for?
Call us at 1-800-831-4242.

★ For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above