

AC-to-DC Regulated Switching Table-Top Power Supplies (Continued)

We are happy to change the power plug on any listed table-top power supply to a connector of your choice (see below) for just \$2.50 each. A 100 pc. minimum order applies.

Part Number	Manufacturer	Manufacturer Part No.	Output Volts (VDC)/ Current (A)	Output Connector ID x OD mm Female/Male; Polarity	Input VAC@Hz	Output Pwr (W)	LED Ind.	Size (L" x W" x H")	Cords (DC/AC)	Wt. (lbs.)	Agency Approvals	Pricing			
												1	10	50	100
3-Wire AC Input – Regulated Switching Table-Top – Triple Output															
190960	Mean Well	P25A13D-R1U	+5/2.5, +12/0.8, -12/0.3	5-pin DIN M	100-240@50-60	26	Yes	4.1 x 2.6 x 1.4	6'/6'	1.1	CUL/TUV/CE	\$39.95	\$35.95	\$32.95	\$29.95
221702	Mean Well	P50A13D-R1BU	+5/4.0, +12/2.0, -12/0.5	5-pin DIN M	100-240@50-60	50	Yes	5.7 x 3.0 x 1.7	4'/6'	1.5	UL/CUL/TUV/CE	49.95	44.95	39.95	35.95
237367	Mean Well	P50A14E-R1BU	+5/3.5, +15/1.2, -15/0.3	5-pin DIN M	100-240@47-63	42	Yes	5.8 x 3.0 x 1.7	4'/6'	1.2	UL/CUL/TUV/CE	49.95	44.95	39.95	35.95

DC Power Plugs & Adapters

Part No.	Manufacturer	Product No.	Fig.	Description (Barrel) Plug ID x OD x L (mm)	Strain Relief ID x L (mm)	Pricing		
						1	10	100
Female Plugs								
71192	ValuePro	PP137	1	1.3 x 3.45 x 9.5	4.1 x 12 (black)	\$.79	\$.69	\$.65
1537395	ValuePro	PL-005	2	1.3 x 3.5 x 9.4 (rt. angle)	2.8 x 11	.95	.85	.75
2098013	ValuePro	DCP-111	1	1.7 x 5.5 x 9.8	4.6 x 12 (black)	.95	.85	.75
191484	ValuePro	PP049W	1	2.1 x 5.5 x 9.0	4.6 x 12.5 (white)	.69	.59	.55
2004890	ValuePro	PP049S	1	2.1 x 5.5 x 9.5	4.5 x 12.5 (black)	.79	.69	.65
297617	Switchcraft	S760	3	2.1 x 5.5 x 9.5	5.5 x 25 (black)	2.95	2.49	2.25
28760	ValuePro	PP049	1	2.1 x 5.5 x 10 (P205)	4.1 x 12 (black)	.79	.69	.55
138587	ValuePro	PJ021R	2	2.1 x 5.5 x 12 (rt. angle)	2.8 x 11 (black)	.89	.79	.65
147329	ValuePro	PP049L	1	2.1 x 5.5 x 14 (P205L)	4.3 x 12 (black)	.89	.79	.65
190538	ValuePro	PP109S	1	2.5 x 5.5 x 9.5	5.0 x 13 (black)	.59	.55	.49
281877	Switchcraft	760	3	2.5 x 5.5 x 9.5	5.5 x 25 (black)	2.95	2.49	2.19
28768	ValuePro	PP109	1	2.5 x 5.5 x 10 (P206)	4.2 x 12 (black)	.79	.69	.59
147336	ValuePro	PP109L+	1	2.5 x 5.5 x 14 (P206L)	4.2 x 12 (black)	.79	.69	.59
168242	ValuePro	PP109N	3	2.5 x 5.5 x 14	3.9 x 22 (black)	.69	.59	.55
2099163	ValuePro	PL-008	2	2.5 x 5.5 x 9.5 (rt. angle)	2.8 x 11	.95	.85	.75
Male Plugs								
101135	ValuePro	PJ1025	4	— x 2.5 x 11 (P201)	4.3 x 13 (black)	\$.79	\$.69	\$.55
231176	ValuePro	AP-340	4	— x 3.5 x 14 (stereo)	4.3 x 13.5 (black)	.79	.69	.55
231167	ValuePro	AP-343	5	— x 3.5 x 14 (stereo)	4.4 x 13 (metal)	1.49	1.25	.99
231160	ValuePro	PJ1035	5	— x 3.5 x 14 (mono)	4.8 x 13.5 (metal)	1.49	1.25	.99
101152	ValuePro	PJ1035	4	— x 3.5 x 14.5 (P202)	4.0 x 13 (black)	.69	.59	.49

Female Power Plug Adapters								
1953604	ValuePro	DCP2.1-DCJ2.5	6	2.1mm M to 2.5mm F (1.4"L)	—	\$1.49	\$1.25	\$.99
1953591	ValuePro	DCP2.5-DCJ2.1	6	2.5mm M to 2.1mm F (1.4"L)	—	1.49	1.25	.99

DC Cords with Pigtail								
Part No.	Manufacturer	Product No.	Fig.	Description (Barrel) Plug ID x OD x L (mm)	AWG	1	10	100
2096763	ValuePro	DCCORD2.1	7	2.1 x 5.5 x 6' cable	24 (black)	\$1.59	\$1.39	\$1.15
2096771	ValuePro	DCCORD2.5	7	2.5 x 5.5 x 6' cable	24 (black)	1.59	1.39	1.15


DC Extension Power Cables								
2099121	ValuePro	DCEXTCORD2.1-6FT	8	2.1F x 2.1M x 6' cable	18 (black)	\$2.49	\$2.25	\$1.95
2099147	ValuePro	DCEXTCORD2.1-3FT	8	2.1F x 2.1M x 3' cable	18 (black)	2.25	1.95	1.75
2099139	ValuePro	DCEXTCORD2.5-6FT	8	2.5F x 2.5M x 6' cable	18 (black)	2.49	2.25	1.95
2099155	ValuePro	DCEXTCORD2.5-3FT	8	2.5F x 2.5M x 3' cable	18 (black)	2.25	1.95	1.75

Male & Female Power Jacks

Part No.	Manufacturer	Product No.	Dimensions H x W x D (mm)	Type/ Mount	Circuit/ Terminal	Mating Plug (above)	Pricing		
							1	10	100
1.3 mm Male Jack									
101194	Various	PP024	6.0 x 6.0 x 9.0	1/D	1/B	1.3 mm F	\$.59	\$.55	\$.45
2.1 mm Male Jacks									
101178	Various	PP014+	10.9 x 9.0 x 14.5	2/D	1/A	2.1 mm F	\$.39	\$.35	\$.29
137673	Various	PP013	10.9 x 9.0 x 14.5	3/D	4/A	2.1 mm F	.45	.39	.35
151590	Various	DPJ-021A	18.0 x 12.6 Dia.	4/C†	1/A	2.1 mm F	.89	.79	.69
151555	ValuePro	DPJ-026	21.0 x 8.0 Dia.	5/E	1/A	2.1 mm F	1.49	1.35	1.19
159611	Various	PJ1014A	57.5 x 12.6 Dia.	6/F	3/A	2.1 mm F	1.75	1.59	1.39
281851	Switchcraft	722A	15.1 x 7.5 Dia.	7/C	1/A	2.1 mm F	2.75	2.49	2.25

† Center offset

Continued on next page

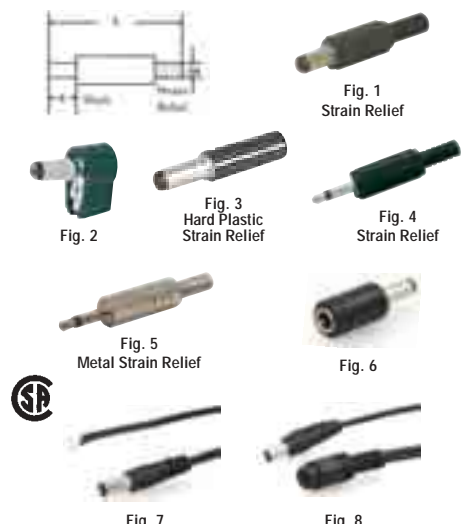

Need special orders or pricing?
Call us at 1-800-831-4242

Automobile Fused Power Plugs with Cords

Part No.	Mfr.	Fuse	1	10	100
115002	ValuePro	5A/250VAC	\$2.25	\$1.99	\$1.79
124760	ValuePro	3A/250VAC	2.49	2.25	1.99
105064	Various	2A/250VAC	1.95	1.75	1.39

Terminals	Code
Solder eyelet	A
PC board	B
Mounting	Code
Panel	C
PCB	D
Panel & PCB	E
Cable	F

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 190.