

JAMECO ReliaPro


Battery Holders

*Web Code: UAB

Eliminate battery mounting problems in portable DC power applications and products. These holders are made from special materials that maintain retention properties longer than conventional holders. They can come with leads, or attached to battery holders. * Order in multiples of 10

Part No.	Cross Ref. No.	*Mfr.	Fig.	No. of Cells	Connector	Sides	Features	1	10	100	500
216283	BH-421-1A	JRP	1	2-AAA	Wires	Single		\$.59	\$.55	\$.49	\$.39
216303	BH-431-1A	JRP	2	3-AAA	Wires	Single		.79	.69	.65	.59
216312	SBH-431-1AS	JRP	2	3-AAA	Wires	Single	w/ cover & switch	.95	.85	.75	.69
216339	SBH-441-AS	JRP	3	4-AAA	Wires	Single	w/ cover & switch	1.45	1.29	1.19	.89
216072	BH-311-2A	JRP	4	1-AA	Wires	Single	Aluminum	1.05	.95	.85	.75
643954	139	KEY	5	1-AA	Tabs	Single		.75	.69	.59	.55
216081	BH-321-2A	JRP	1	2-AA	Wires	Single		.75	.69	.59	.55
216099	BH-321-4A	JRP	1	2-AA	Wires	Single	w/ mounting tabs	.75	.69	.59	.55
216102	SBH-321-2AS	JRP	6	2-AA	Wires	Single	w/ cover, no switch	.75	.69	.59	.55
216120	SBH-321-1AS	JRP	6	2-AA	Wires	Single	w/ cover & switch	.89	.79	.72	.65
216136	BH-331-A	JRP	2	3-AA	Wires	Single		.85	.77	.69	.62
216144	SBH-331-AS	JRP	7	3-AA	Wires	Single	w/ cover & switch	.79	.69	.65	.59
216152	BH-341-2A	JRP	8	4-AA	Wires	Single		1.15	1.05	.95	.85
105858	BH-PCS	JRP	9	4-AA	Wires	Single	wires w/ connector	.95	.85	.79	.64
216179	BH-343-1A	JRP	10	4-AA	Wires	Dual		.79	.69	.65	.59
216187	SBH-341-1AS	JRP	3	4-AA	Wires	Single	w/ cover & switch	1.05	.95	.85	.75
216216	BH-363-A	JRP	11	6-AA	Wires	Dual		.75	.69	.59	.55
216223	BH-364-A	JRP	11	6-AA	Wires	Single		.95	.85	.79	.65
216240	BH-383-A	JRP	12	8-AA	Wires	Dual		1.09	.99	.89	.69
216267	BH-383-B	JRP	12	8-AA	Snaps	Dual		1.19	1.09	.99	.79
216259	BH-382-B	JRP	13	8-AA	Snaps	Dual		1.35	1.19	1.09	.79
216292	SBH-421-AS	JRP	1	2-AAA	Wires	Single	w/ cover & switch	.65	.59	.55	.49
216363	BH-242-1A	JRP	14	4-C	Wires	Single		1.09	.99	.89	.69
216371	BH-111-1A	JRP	4	1-D	Wires	Single		.69	.65	.59	.49
216390	BH-121-1A	JRP	1	2-D	Wires	Single		1.19	1.09	.95	.79
216401	BH-142-A	JRP	14	4-D	Wires	Single		1.35	1.19	1.09	.89
216427	BH-9V-A	JRP	15	1-9V	Wires	Single		.75	.69	.59	.55
11280	A104-R	JRP	16	1-9V	Wires	Single	3"L, 26AWG, snaps	.39	.35	.29	.25
105794	GBH-1009-R	JRP	17	1-9V	Wires	Single	Metal holder	.35	.32	.29	.25
1949488	BAT-SNAP-4	◆	18	1-9V	Wires	Single	4"L, 26AWG, snaps	.29	.26	.23	.19
109154	BC6-R	JRP	18	1-9V	Wires	Single	6"L, 26AWG, snaps	.29	.26	.23	.19
216452	SBS-IR-1-R	JRP	19	1-9V	Wires	Single	6"L, 26AWG, snaps	.35	.32	.29	.25
101470	A102-R	JRP	18	1-9V	Wires	Single	10"L, 26AWG, snaps	.35	.32	.29	.25
236996	103	KEY	20	1-CR2032	PC mount	Coin cell		1.65	1.49	1.35	1.19
355434	17002-00603	JRP	21	1-CR2032	PC mount	Coin cell		.79	.69	.65	.59
38543	2S2325	JRP	20	1-CR2354 or 2-CR2325	PC mount	Coin cell		.79	.69	.65	.59

§ Battery holder used in many personal computers

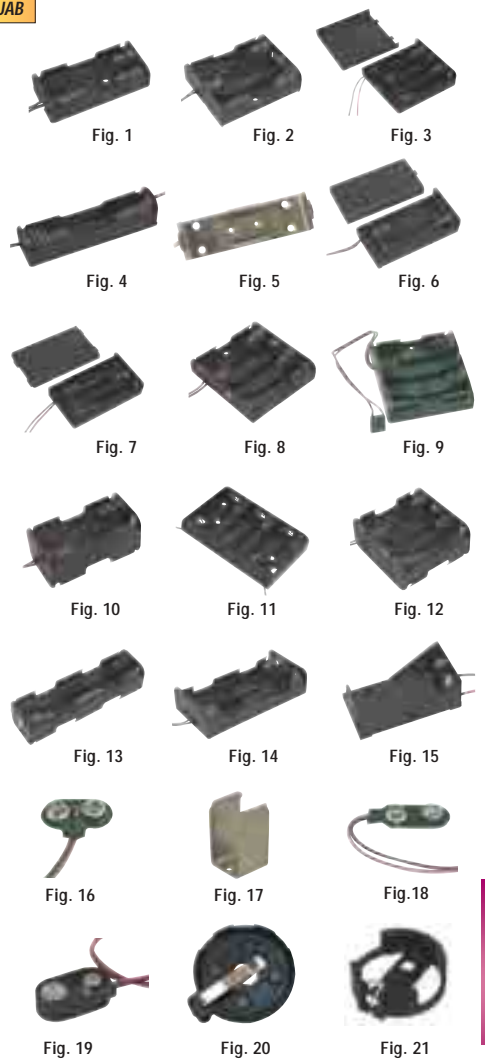


JAMECO ReliaPro

Rechargeable Battery Packs

*Web Code: LAA

Part No.	Fig.	Volt	Cell	Size (L x Dia.)	Type	mAh	Connection	1	10	25
298821	1	3.6	D Single	2.36" x 1.26" (59.9mm x 32.0mm)	NiCd	5000	Solder tab	\$19.95	\$17.95	—
298652	2	4.8	SC Single	2.36" x 1.26" (59.9mm x 32.0mm)	NiCd	2200	Solder tab	15.95	14.49	12.95
299621	3	4.8	D Single	2.36" x 1.26" (59.9mm x 32.0mm)	NiCd	5000	Lead wire	34.95	31.49	—
299680	4	6.0	D Single	2.36" x 1.26" (59.9mm x 32.0mm)	NiCd	5000	Lead wire	46.95	42.25	37.95
299495	5	9.6	SC Single	1.65" x 0.86" (41.1mm x 21.8mm)	NiCd	2200	Lead wire	24.95	22.45	—

JAMECO EXCLUSIVE

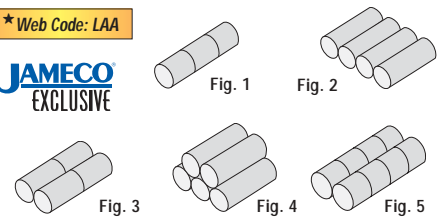

◆ Blue Part No. = Limited Quantity Available



300, 360 & 1000-Watt Single Output Lead Acid Battery Chargers

*Web Code: ABC

- Input: 115VAC/230VAC @ 47-64Hz (switch-selectable)
- 1952409/1952417/1954332/1954341/1954359: with built-in passive PFC function
- Overload, short-circuit, reverse polarity, over voltage, over temperature protection
- 1952409: Cooling by free-air convection; 1952417/1954308/1954316/1954324: Fan on/off control (depending on charging current) • Charger for lead acid batteries
- 1954316/1954324: Size: 10.0"L x 5.3"W x 1.9"H, Weight: 3.3 lbs.
- 1952409/1952417/1954308: Size: 9.3"L x 5.3"W x 1.9"H, Weight: 3.3 lbs.
- 1954332/1954341/1954359: Size: 11.8"L x 7.2"W x 2.8"H, Weight: 7.7 lbs.



1952409

Part No.	Mfr. Part No.	Watts	Boost Charge Voltage	Float Charge Voltage	Recommended Battery Capacity (AMP Hours)	Pricing	
						1	5
1952409	PB-300P-12	300	14.4	13.6	80-200	\$94.95	\$84.95
1952417	PB-360P-12	360	14.4	16.6	80-200	94.95	84.95
1954308	PB-360N-12	360	14.4	13.6	80-200	94.95	84.95
1954316	PB-360N-24	360	28.8	27.2	40-125	94.95	84.95
1954324	PB-360N-48	360	57.6	54.4	20-65	94.95	84.95
1954332	PB-1000-12	1000	14.4	13.8	200-600	349.95	314.95
1954341	PB-1000-24	1000	28.8	27.6	120-350	349.95	314.95
1954359	PB-1000-48	1000	57.6	55.2	60-175	349.95	314.95

* JRP = Jameco ReliaPro | KEY = Keystone | ◆ Manufacturer Varies

*For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above



Order by Phone 24/7 at 1-800-831-4242 or Online at www.Jameco.com