

Nibbling Tool

- Perfect for cutting, trimming, or notching sheet metal up to 18 AWG
- Time-saver when working on prototyping, chassis, and circuit boards
- Minimum .375" hole required • Size: 7.8"L



Part No.	Mfr. P/N	Description	1	10
18810	HT204	Nibbling tool	\$7.95	\$6.95
29331	HT204B	Replace. bit	3.95	3.55

Deluxe Precision Knife Set

- Three different knife handles – fine work, medium and heavy duty power grip
- Size: 6.3"L x 2.8"W x 1.4"H

 


Includes: 13 types of blades

Part No.	Description	1	10	100
72768	13 blade knife set	\$8.95	\$7.95	\$6.95

5" Steel Hemostats

- Grade 410 A.I.S.I. stainless steel
- Three locking positions



Part No.	Cross Ref. No.	Description	1	10	100
115107	HEM01	Straight	\$3.95	\$2.95	\$2.49
115115	HEM02	Curved	3.95	2.95	2.49

Metal Dial Calipers

Choose Metric or Inches

- For accurate measurements every time
- Measures outside, inside and depth
- Easy-to-read dial gauge
- Length: 6" (150mm)
- Materials: metal • Color: silver




Includes: Fitted plastic storage case

Part No.	Description (min. reading)	1	5	25
116134	Metric (.02 mm)	\$25.95	\$23.95	\$21.95
116126	Inches (.001 inch)	25.95	23.95	21.95
684449	Metric/Inches	27.95	25.95	23.95

Digital Display Caliper

Metric and Inches

- Hardened stainless steel
- Display: inches to 0.001; mm to 0.01
- Instructions for making internal, external, depth & step measurements
- Calipers measure to 6 inches/150mm

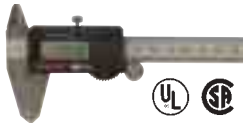

Includes: Fitted case and 1.5V silver oxide battery (replacement battery, P/N 140783, pg 146)

Part No.	Description	1	5
127482	Digital disp. caliper	\$39.95	\$36.95

*Calipers — Enter Web Code PAQ

IC Pin Straightener

Straighten bent pins safely and easily with Jameco's IC pin straightener.



- Straightens 8/14/16/18/20/24/28/40/42-pin ICs
- Materials: black plastic • Size: 3.3"L x 1.5"W x 0.4"H

Includes: Ground terminal

Part No.	Description	1	10	100
99363	IC straightener	\$7.95	\$6.95	\$5.95

T-Handle Reamer Tool


Excellent for aluminum chassis work

- For enlarging starter holes on panel mount components from 1/8" to 1/2" diameter
- T-handle for easy rotation of tool
- Handle: 3.3" long, tool: 5.3" long



Part No.	Description	1	10
151750	T-handle reamer	\$7.95	\$6.95

 4-Piece Steel Tweezer Set




- 4 styles of stainless steel tweezers, one self-locking
- Ideal for picking up small components in hard-to-reach places

Part No.	Description	1	10	100
10735	4-piece tweezer set	\$5.95	\$5.49	\$4.95

*Tweezer Sets — Enter Web Code FAA

Tweezers

- 252929: Straight round tapered, fine-point tip, stainless steel
- 253092: Curved fine-point tip
- 252938: Self-closing reverse-action tweezers; medium point tip; stainless steel
- 253113: Fine-point tip, insulated, anti-static
- 252912: Straight fine-point tip

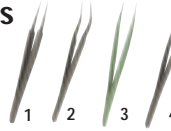

Part No.	Length	Photo	1	10	100
252929	4.75"	1	\$2.95	\$2.49	\$1.95
253092	4.6" \mathcal{R}	2	2.95	2.49	1.95
252938	4.30" \mathcal{R}	2	2.95	2.49	1.95
253113	4.75" \mathcal{R}	3	2.95	2.49	1.95
252912	4.75" \mathcal{R}	4	2.95	2.49	1.95

4-Pc. Conductive SMD Tweezer Set



- 4 types of tweezers: fine point, flat head for 4mm SMD chip device, flat head for 8mm SMD chip device, sharp angled tip
- Each is 4.5" long

Part No.	Description	1	10
172638	4-piece tweezer set	\$9.95	\$8.95

Vacuum Tweezers

Pick & place small parts of all kinds: glass slides, coins, optics, SMDs, film, etc.

- Size: 2.9"L x 0.6"W
 - One-year warranty
- Includes: 5 pads sizes 0.14" to 0.4"; 5 straight tips and 2 pieces 45° angle tips



Part No.	Description	1	5
88268	Vacuum pick & place kit	\$39.95	\$36.95

PLCC & DIP IC Extractors


- Size: 4.0"L x 2.0"W



Part No.	Mfr. Part No.	Description	1	10	100
16766	HT103B	PLCC	\$3.95	\$3.49	\$2.95
16838	HT103A	DIP	1.65	1.49	1.25

Anti-Static Heel Strap


- Discharges static without restricting your mobility
- Ground strap: 15.5"L

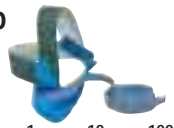

Part No.	Description	1	10	100
100328	Heel strap	\$5.95	\$5.49	\$4.95

Anti-Static Wrist Strap

- Comfortable, adjustable black Velcro wrist strap
- The coiled grounding cord has banana plug and alligator clips
- Extended cord: 9' long

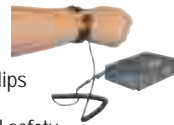

Includes: 1M Ω resistor for added safety

Part No.	Description	1	10	100
34552	Wrist strap	\$6.95	\$6.49	\$5.95

Anti-Static Work Mats

Make your work environment safe from static discharge!

These mats are made of attractive semi-conductive vinyl that provide adequate discharging, yet will not short leads or pins.




Part No.	Dimensions	Wt. (lbs.)	1	10	100
10576	11.3" x 22" \mathcal{R}	0.7	\$8.95	\$7.95	\$6.95
10584	19.5" x 23.5" \mathcal{R}	1.1	13.95	12.49	10.95
236541	23.5" x 27.5" \mathcal{R}	1.4	25.95	22.95	19.95

*Anti-Static — Enter Web Code XAA

Conductive Anti-Static Bags and Foam

Don't get zapped!

 Protect your investment with these inexpensive bags and ensure a safe work area with our conductive anti-static foam.



13864: 24.0"L x 12.0"W x 0.25"H

Part No.	Description	1	10	100
249519	4" x 6" anti-static bags	\$.25	\$.15	\$.10
249527	5" x 7" anti-static bags	.29	.19	.12
78650	8" x 10" anti-static bags	.49	.39	.29
13864	Anti-static foam	11.95	10.95	9.95

22"L Anti-Static Plastic DIP IC Storage Rails & Rubber Rail Stops

- 29516: .300" rail fits 8, 14, 16, 18, 20 and 22-pin ICs
- 29524: .600" rail fits 24, 28, 36 and 40-pin ICs
- 29583: Rubber stops used to plug plastic rail ends



* Order in multiples of 10

Part No.	Cross Ref. No.	Description	1	10	100
29516	RIC20	.300"W rail	\$.25	\$.22	\$.19
29524	RIC220	.600"W rail	.29	.25	.19
29583	RRS	Rubber stop	*.07	.07	.05

24" Joubert Bungee Cord

- Braided jacket cover
- 2.75" steel hook height
- 0.81" steel hook opening
- 0.16" thick PVC coated steel hook
- Blue cord with black coated hook
- Stretches easily to 48"



Part No.	Product No.	1	10	100
2081668	JBC24	\$.99	\$.89	\$.69

\mathcal{R} RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 190.