



16 to 30-Watt Variable Soldering Iron & Stand

116572: Length: 7.5"
36329:

- Black anodized steel base – 5.3"L x 3.3"W
- See below for replacement sponge (P/N 134631)
- Fits most soldering irons .85" dia.

Includes: Sponge

Part No.	Description	1	5	25
116572	25W VL soldering iron	\$19.95	\$17.95	\$15.95
36329	Soldering stand	4.95	4.45	3.95
134631	Sponge (for P/N 36329)	2.95	2.59	2.29



25-Watt Thermally Balanced Soldering Iron

The XY200GX is a thermally balanced soldering iron for the professional or hobbyist.

- 120VAC; 6' cord
- 25-watt power consumption
- Interchangeable tips (pg 165)
- UL listed
- Length: 8.0"
- One-year warranty

Includes: 1.6mm conical tip

Part No.	Mfr. Part No.	1	5	25
129040	200GX-25W	\$13.95	\$11.95	\$9.95



25-60-Watt High-Performance, Economical Soldering Irons

High-quality soldering irons that are suitable for both professional & do-it-yourself applications.

- Length: 9"
- 120VAC; 6' cord with 3-prong plug
- Tips for P/Ns 224611/224602: P/Ns 226018/226000
- Tip for P/N 195223: P/N 226026
- For additional tips see pg 165

Part No.	Mfr. Part No.	1	5	25
224611	200PHG-25W	\$10.95	\$9.95	\$8.95
224602	200PHG-40W	11.95	10.95	9.95
195223	200PHG-60W	12.95	11.49	10.49
226018	44-240513 conical tip	1.95	1.59	1.29
226000	44-240517 chisel tip	1.95	1.59	1.29
226026	44-240617 chisel tip	1.95	1.59	1.29



35-Watt SMD Tweezer Iron

- Max. temperature: 760°F
- Maximum efficiency ceramic heating elements insures rapid heat-up and instant heat recovery
- 120VAC
- Heater insulation exceeds 100MΩ
- Heater power consumption: 35W ea.

Includes: 0.078" tip

 
Part No.	Description	1	5	25
168410	Tweezer iron	\$54.95	\$49.95	\$44.95
168583	Tip .078"	9.95	8.95	7.95
168591	Tip .590"	11.95	10.95	9.95



50-Watt SMD Tweezer Iron

- 168401 Includes: 0.078" tip
- 236460: Replacement sponge
- 168583: 0.078" replacement tip (see above)
- 168591: 0.59" replacement tip (see above)

Part No.	Mfr. Part No.	For Use With	1	5
168401	TWZ50ESD	XY9-60A	\$49.95	\$44.95
236460	78-744615	XY9-60A	2.95	2.59



Weller® 25 & 35-Watt High-Quality Soldering Irons

- 120VAC @ 60Hz
- Interchangeable heater elements
- Lightweight handle with cushioned grip
- Quick change knurled collar
- Length: 9"

Includes: Power cord & ST3 tip (pg 163)

Part No.	Mfr. Part No.	Description	1	5
170587	WP25	25W solder iron	\$39.95	\$37.95
192102	WP35	35W solder iron	47.95	45.95
146608	ST3	Screwdriver tip 1/16"	5.95	4.95
146616	ST3	Screwdriver tip 1/8"	5.95	4.95
192145	ST6	Screwdriver tip .031"	5.95	4.95
146624	ST7	Conical tip 1/32"	5.49	4.49



Weller® 25 & 40-Watt Marksman Home Project Kits

Perfect for beginners and hobbyists. Includes stand.

- Stainless steel barrel and heat/impact resistant handle
- Ideal for kits, radios and electronics
- Indicator light shows iron is on

2094143 Includes: Knife and 2 tips
2094160 Includes: Soldering aid tool, 3 tips & solder

Part No.	Mfr. Part No.	Description	1	5
2094143	SP23LHPK	25W Iron kit	\$19.95	\$18.95
2094160	SP40LKP	40W Iron kit	24.95	23.49




Weller® 100-Watt Soldering Iron

- "Closed loop" method of controlling max. tip temperature
- Nominal heat-up time with 700°F tip is 110 seconds
- 120VAC @ 60Hz input
- Length: 6"
- Weight: 0.7 lbs.

Includes: CT6F7 (0.375" screwdriver tip; 700°F)

Part No.	Mfr. Part No.	Description	1	5
192081	W100PG	Solder iron	\$64.95	\$59.95
192090	CT6F7	.375" screwdriver tip	6.95	6.29

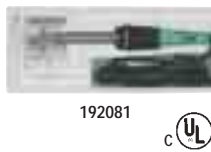

Weller® 25 to 125-Watt Cordless Soldering Iron Kit

- Self-igniting & instant heat
- Adjustable temperature (25W to 125W)
- Auto switch off
- Visible gas level
- Additional tips can be special ordered
- 2 hours of heat on average tank setting

Includes: Soldering tool, hot blower tip, hot knife tip, 2.4mm and 4.8mm double flat tip, cleaning sponge, storage case and instruction manual

Part No.	Mfr. Part No.	1	5
152207	PSI-100K	\$89.95	\$79.95



*Soldering Irons — Enter Web Code QAS

Need Solder?

See page 166 for All Your Soldering Accessories.



Weller® 8/11-Watt Battery Powered Soldering Iron

- Heats to working temperature in less than 15 seconds
- White LED light illuminates working surface
- Dual heat settings: 8 watts on low setting (850°F) or 11 watts on high setting (950°F)
- Co-molded grip for comfort grip and protective safety cap turns off power when placed on tool
- Over 150 intermittent solder joints with fresh batteries

Includes: Iron, tip, 4 "AA" batteries, lead free solder, and tip/wrench stand

Part No.	Mfr. Part No.	1	5
1943060	BP860MP	\$23.95	\$19.95



Weller® Coldheat Pro Cordless Soldering Iron

Using the patented Coldheat™ system, the Weller Pro Cordless melts solder instantly and is cool to the touch in just seconds. The Weller Pro has the power industrial professionals need to tin wire as large as 12AWG or join wires from 18-25AWG, with an average yield of 700 solder joints per 5 AA Alkaline batteries.

- Polycarbonate body
- High/low/off power switch
- Bright white LED light
- Red "in use" indicator light
- Includes carrying case and CHT3 61° angle chisel tip

Requires: 5 AA Alkaline batteries (recommend 198707, pg 146, not included)

Part No.	Mfr. Part No.	1	5
684705	CHT100	\$39.95	\$35.95

Blue Part No. = Limited Quantity Available



WAHL® 25-Watt Cordless Soldering Iron

IsoTip® Power Pro Model #7904

- 900°F tip temperature
- LED indicator light
- Solders 200+ joints or up to 30 minutes of continuous soldering
- Iron performance equivalent to 25-watt iron
- Weight: 1.1 lbs.

Includes: Iron, charging stand, battery pack and tips

Part No.	Description	1	5
132783	Power Pro cordless iron	\$69.95	\$64.95



20 to 80-Watt Butane Soldering Iron Tool Kit

- Slide switch ignition system
- Adjustable temperature up to 1200°F
- 1.3 hrs of use per refill

Includes: Solder tip, heat tip, hot knife tip, shrink attachment, cap sponge, stand & case

Part No.	Description	1	5
2076615	Flameless heat soldering	\$84.95	\$78.95



30 to 100-Watt Soldering Kit

- Includes: 100W soldering gun with extra tip, 30W soldering iron, manual desoldering pump, mini third-hand board/ component holder, lead solder, and soldering aid tool
- Size: 13.8"L x 11"W x 3"H

Part No.	Description	Weight	1	5
684596	GSR-600A	4.0 lbs.	\$35.95	\$29.95

