

## Interface, Graphic & Sound Cards

\* Web Code: VBB



### Serial Interface Cards

Part No.	Manufacturer	Product No.	Bus Type	Ports	Connectors	Description	1	10
171362	Various	4025A	PCI	1	DB9	32-byte FIFO, 921kb/sec transfer rate, supports IRQ sharing, single 16C550	\$24.95	\$19.95
172006	Dolphin	99467	PCI	2	DB9	32-byte FIFO, 921kb/sec transfer rate, supports IRQ sharing, dual 16C650 DB9 male	34.95	30.95
171548	Various	99468	PCI	4	DB25	32-byte FIFO, standard RS-232 interface, 921kb/sec transfer rate, supports IRQ sharing 16C550	69.95	59.95
171661	Various	99469	PCI	8	DB25	32-byte FIFO, standard RS-232 interface, 921kb/sec transfer rate, supports IRQ sharing 16C650	119.95	109.95
344903	SYBA	SD-PCI-1S	PCI	2	DB9	32-bit PCI bus, dual DB-9 male, Nm9835CV chipset.	27.95	24.95

### Parallel Interface Card

Blue Part No. = Limited Quantity Available

171927	Dolphin	4008A	PCI	1	DB25	32-byte FIFO, 2MB/sec transfer rate, supports ECP and EPP, supports IRQ sharing, DB25 female	\$39.95	\$34.95
--------	---------	-------	-----	---	------	--	---------	---------

### Network Interface Card

155221	3-COM	3CR990B-FX-97	PCI	1	FDD1	100BASE-FX Secure fiber network interface card	\$24.95	\$19.95
--------	-------	---------------	-----	---	------	--	---------	---------

### Video Graphics Card

364111	ATI	109-54100-00	PCI	2	HDDDB15	8MB graphics accelerator, Rage LT PRO AGP chipset, 7-pin TV-out and DFB connectors, Windows® 98 and NT4.0 compatible.	\$24.95	\$22.45
--------	-----	--------------	-----	---	---------	---	---------	---------

### SCSI Cards

Blue Part No. = Limited Quantity Available

149294	Various	CI-2020	ISA	—	50-pin F	DOS, Windows® NT/95, OS2 Netware, SCO UNIX compatible, internal and external SCSI-II connectors, fast SCSI II	\$29.95	\$24.95
191513	Adaptec	AHA-2940U2B	PCI	2	68-pin F	AIC-7890AB chipset, Windows® 95/NT, Netware, OS/2 compatible, Ultra II SCSI internal/external Ultra II SCSI 68-pin connectors, ultra SCSI II	49.95	44.95

### I/O Controller Cards


291901	—	MCT-IDEFH-2	ISA	—	Multiple	16-bit interface, supports 2 IDE hard drives up to 528MB and 2 floppy drives from 360kb to 1.44Mb, jumper selectable for enabling and disabling ports	\$5.95	\$5.49
--------	---	-------------	-----	---	----------	---	--------	--------

### Sound Card

249404	Creative Labs	CT4830	PCI	—	Multiple	2-audio line-out (mini stereo 3.5mm F), 1 microphone input (mini phono 3.5mm F) 1-audio line-in (mini stereo 3.5mm F) and 1 game port (DB15F)	\$24.95	\$22.45
--------	---------------	--------	-----	---	----------	---	---------	---------

\* Web Code: LBU

## Keyboards & Keypads

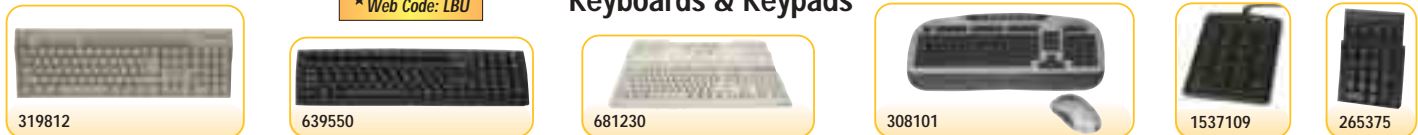

Part No.	Mfr.	Product No.	Interface	Description	Size (L"xW"xH")	Wt. (lbs.)	1	10	25
455603	Powmax	KM-2501	PS/2	104-key soft touch w/ multimedia & 12 function keys.	17.5 x 6.0 x 1.2	1.8	\$8.95	\$7.95	\$6.95
319812	PC Concepts	iCIA	PS/2	107-key soft touch keyboard w/ programmable function keys, software included	17.5 x 5.7 x 0.8	1.8	7.95	6.95	6.25
354950	Compaq	KB-9965	PS/2	107-key soft-touch keyboard w/ 12 function keys	18.5 x 6.5 x 1.4	1.3	4.95	4.49	3.95
639550	IOne	Scorpius-2KB	PS/2	103-key soft touch keyboard, Windows® 98SE/2000/ME/XP compatible (black)	15.9 x 6.5 x 1.3	2.1	39.95	35.95	31.95
681230	NMB	RT915CTW	PS/2	104-key tactile keyboard w/ 12 function keys w/ built-in speakers	18.5 x 10.0 x 3.2	2.5	12.95	11.49	9.95
454483	Powmax	HB5103	PS/2	Black 3-in-1 internet kit 104-key optical mouse, speakers	17.1 x 6.12 x 1.0	2.24	14.95	13.49	11.95
319661	IOne	Gemini-M1	PS/2	104-key soft touch wireless keyboard w/ 12 multimedia function keys and 2-butt optical mouse, batteries included	17.6 x 7.5 x 1.6	2.2	14.95	13.49	12.95
308101	Labtech	967360-0403	PS/2	104-key wireless RF keyboard and 3-button optical scroll-mouse multimedia hot-keys	18.0 x 8.7 x 1.6	4.5	29.95	26.95	23.95
1537109	Arctic	25551	USB	18-key tactile keypad	4.3 x 3.0 x 0.5	0.2	12.95	11.49	9.95
265375	IOne	Scorpius-22RB	Serial	22-key tactile keypad w/ 2-key rollover and auto repeat function	6.2 x 4.2 x 1.3	0.8	39.95	35.95	31.95

## Replacement Switches for AT-Style Computer Cases

### PC Pushbutton Switch

- Contacts rated at 250VAC • Current: 8A
- Alternate action double pole switch
- UL/CSA/VDE approved • Size: 0.9"L x 0.7"W x 0.9"D



Part No.	Product No.	1	10	100
174238	PSD-1-2S8	\$1.49	\$1.25	\$ .95

### PC Rocker Switch

- For mini-tower cases
- Current: 10A
- Contacts rated at 250VAC
- DPST
- UL/CSA approved
- Size: 0.9"L x 1.2"W x 1.4"D



Part No.	Product No.	1	10	100
127028	GRK-618A	\$1.49	\$1.25	\$ .95

## Business Card CD-R Kit

Differentiate yourself or your business from others. This kit includes 12 50MB capacity CD-R and sleeves, 16 labels and label design software. A great way to promote your business in trade shows and exhibits. Easy to carry and cost-effective.



Part No.	Description	1	10
249308	Do-It-Yourself Business Card CD-R kit	\$2.49	\$2.25

## The Best Warranty in the Industry

All Jameco purchases are guaranteed for a full 90 days and even longer for Jameco House Brands.

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 190.