

## JAMECO ValuePro USB-A Cable w/ Bracket

- Supports data transfer rates of 12Mbps
- Allows connection of two devices
- Dual USB-A female connectors • 8" long



Part No.	Description	1	10	25
144813	Female panel mount	\$4.25	\$3.75	\$3.25
319652	Male panel mount	1.49	1.35	1.19

## JAMECO ValuePro USB-to-DB9 Serial Adapter

- USB-A to DB9 male
- Length: 13"
- Supports automatic handshake mode
- Over 230kpbs data transfer rate
- 96 byte buffer each for upstream and downstream data flow
- Works with cellphones, PDA, digital cameras, modems and ISDN terminal adapters



\* Web Code: NAV

Part No.	Description	1	5
387954	USB-A to DB9	\$18.95	\$16.95

## Audio/Video Adapter

- Converts impedance of video/audio signals to 100Ω for transmission over CAT 5 UTP cable
- Support both NTSC or PAL video signals
- Signal pairs: video (BNC), CAT pairs 4(RJ45); audio 1 (RCA); CAT pair 3 (RJ45); audio 2 (RCA), CAT pair 2 (RJ45)



Includes: Mounting hardware

Part No.	Description	1	5
220881	BNC/RJ45	\$24.95	\$22.45

Blue Part No. = Limited Quantity Available

## 3.5" Color LCD Video Monitor

The display monitor operates on a standard composite video signal from VCR, video camera, video game, or navigation system: ideal for mounting in seat backs & custom enclosures.



- Thin film technology color LCD
- High resolution (480H x 234V) flat screen
- Back light cold cathode fluorescent lamp
- Video color system: NTSC/PAL auto switch
- Power consumption: 3-watt • Weight: 5.3 ounces
- Input signal: 1.0Vp-p; 75
- Power supply: 12V ±10%
- Active area: 3.2"W x 2.4"H
- Dimensions: 3.9"L x 2.8"H x 0.8"D

\* Web Code: VBF

Part No.	Product No.	1	5
1928257	15-MC04	\$149.95	\$134.95



## Quick and Easy Search

Our enhanced website offers thousands of datasheets and photos to assist you in finding the products you need.

## 2.4GHz Wireless Audio/Video Transmitter & Receiver

- Frequency range: 2413MHz to 2470MHz
- Video input: 1Vp-p • Audio input: 2Vp-p
- Impedance: 50Ω
- Output power: 1 watt


Includes: 12VDC @ 1A wall adapter, RCA patch cable, antenna and mounting hardware

179864:

- For use with 2.4GHz cameras, transmitters and receivers
- Gain: 3dB; unidirectional

2081633:

- Frequency range: 2.4GHz - 2.5GHz
- Reverse polarity SMA plug • Gain: 2dBi
- Polarization: linear, vertical • Impedance: 50Ω
- Power handling: 2 watt • VSWR: 2.0:1 max.

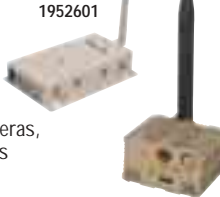

Part No.	Description	1	5
289852	Wireless audio/video tran.	\$159.95	\$143.95
1952601	Wireless audio/video recv.	79.95	71.95
179864	2.4GHz SMA RF antenna	5.95	5.35
2081633	2.4GHz SMA antenna	1.95	1.75

Blue Part No. = Limited Quantity Available

## Dual Page Color Quad Processor

- Signal format: NTSC/PAL color
- Alarm input: 8
- 7-character titles
- Display rate: 60fps/50fps • 4-channels with loop
- Video outputs selectable: 1Vp-p 75Ω
- Video inputs: 1Vp-p, 75Ω • BNC video connectors
- Memory 1024 x 512 • Date time generator
- Switching interval: 1 to 99 seconds



Part No.	Product No.	1	5
638240	15-OC43	\$189.95	\$169.95

## Color Camera with 8mm Lens

- 1/3" CCD image sensor
- Horizontal res: 420 lines
- Min. illumination: 0.5 lux
- Electronic shutter: 1/120,000 sec.
- 510(H) x 492(V) EIA signal format
- Auto iris lens: DC drive/AES/video drive
- Video output: 1Vp-p, 75Ω • Vertical freq.: 60Hz
- Audio output: 2Vp-p max., 50Ω
- Backlight, auto-gain, and mirror reverse picture switch selectable • S/N ratio: 52dB
- Auto-tracing white balance • 2X digital zoom

Power Requirements: 12VDC @ 150mA

Part No.	Product No.	1	5
395461	15-CC25	\$119.95	\$107.95

## CMU Camera

- Tracks the position and size of a colorful or bright object
- Measures the RGB or YUV statistics of an image region
- Dumps a bitmap showing the shape of the tracked object
- Automatically acquire and tracks the first object it sees
- Dumps a complete image over the serial port
- Physically tracks using a directly connected servo
- Supports multiple CPU boards on one camera for parallel processing



Part No.	Description	1	5
358467	3.5" color LCD monitor	\$139.95	\$124.95

Blue Part No. = Limited Quantity Available

## SONY Color CCD Camera

### Sony Chipset

- 1/4" Sony super HAD CCD sensor
- NTSC system w/510(H) x 492(V)
- Furnished mini lens: 3.6mm
- Minimum illumination: 0.5 lux @ F2.0
- Supports these functions: auto electronic shutter (AES), auto iris control (AIC), auto gain control (AGC), auto white balance (AWB), back light compensation (BLC) and flicker less (FL)
- Video drive iris control: high/low switchable auto gain control; on/off backlight compensation
- Video output: 1Vp-p; 75Ω

Requires: 12VDC @ 120mA

power supply (recommend P/N 100095, pg 120)

Includes: Power/signal cable & mounting hardware

Part No.	Description	1	5
213436	Enclosed color camera	\$154.95	\$139.95

## Color Dome Cameras

- 1/4" CCD image sensor
- 512H x 492V
- Video output: 1Vp-p, 75Ω
- NTSC format
- 3.6mm lens with F2.0
- Horizontal line resolution: 319855 - 380 lines; 171037 - 330 lines
- Lux: 171037 - 2



Part No.	Product No.	Description	Price
319855	15-2400CTD	2.4GHz wireless	\$149.95
171037	15-CD25-1	Mini	99.95

## Black & White Camera with Lens

### EIA Format

- 1/3" CCD image sensor
- 510(H) x 492(V)
- Horizontal res.: >350 lines
- Sensitivity: 0.7 lux/F2.0
- Power supply: 12VDC (recommend P/N 162996, pg 122)
- Video output: 1Vp-p, composite video 75Ω
- Power consumption: 110mA • FOV: 92°
- Electronic shutter: 1/125,000 sec. (linear)
- S/N ratio: 46dB • Size: 1.3"L x 1.3"W x 1.2"H



Part No.	Product No.	1	5
171029	15-BB13L-1	\$44.95	\$39.95

## Mini Wireless Color Camera

This super-small (1" x 3/4" by 7/8") 1/4 ounce, 3 Lux

wireless camera and receiver combo delivers sharp, full-motion video images at 380 lines of resolution. With its 150' (unobstructed) range and 9-volt battery power.



Part No.	Product No.	1	5
249025	203CA	\$54.95	\$49.45

## Mounting Brackets for Enclosed Camera

- Material: white plastic
- Swivel angle: 360°
- Tilt angle: 90°
- For use with enclosed cameras



Part No.	Max Load	Height	1	5
170982	6.6 lbs.	2.0"	\$3.95	\$3.49

\* Outdoor Camera Enclosures— Enter Web Code LBB

\* Video Accessories — Enter Web Code YBE