

Buzzers, Sirens & Speakers

3 LEVELS OF SAVINGS
NAME BRANDS HOUSE BRANDS FACTORY OVERRUN

JAMECO ValuePro

Mechanical/Electromechanical Buzzers

*Web Code: MEB

Part No.	Manufacturer	Cross Ref. No.	Fig.	Oper. Volt. (V/mA)	Voltage Range	Frequency (Hz)	Sound (dB)	Dimensions	Pricing		
									1	10	100
335370	ValuePro	AST200	1	3/80	2 - 5	2731	85	8.7"sq. x 4.2"H	\$1.49	\$1.29	\$1.09
140695	ValuePro	63S1120-LA	2	12/25	9 - 15	400	75	1.3"L x 0.7"W x 0.6"H	1.95	1.59	1.29
335345	ValuePro	ASI301	1	5/30	4 - 7	2400	90	.5"L x .5"W x .4"H	.89	.79	.65
335353	ValuePro	ASI401	1	12/30	8 - 15	2400	90	.5"L x .5"W x .4"H	.89	.79	.65
335388	ValuePro	AST500	1	1.5	1.2 - 3	2400	85	.5"L x .5"W x .4"H	.85	.75	.59
76065	ValuePro	TDB05-PN	3	5/30	4 - 7	2300	85	.35"H x .46"Dia.	2.95	2.75	2.55
24872	ValuePro	63S109LA	2	9/30	6 - 12	400	75	1.3"L x 0.7"W x 0.6"H	1.49	1.35	1.19




JAMECO ValuePro

Piezo Sirens

*Web Code: POS

Part No.	Manufacturer	Product No.	Fig.	Oper. Volt. (V/mA)	Voltage Range	Frequency (Hz)	Sound (dB)	Dimensions	Pricing		
									1	10	100
336225	ValuePro	PS-562	1	12/40	5 - 15	2500/3500	100	16mm x 42mm Dia.	\$4.95	\$4.49	\$3.95
207993	ValuePro	SL15R3120LA	2	12/250	6 - 16	3500	105	2.3"L X 1.8"W X 1.6"H	4.95	4.49	3.95
207889	ValuePro	18R3120	3	12/120	9 - 15	1500/3100	105	3.4"L x 2.2"W x 1.3"H	5.95	5.49	4.95
148152	Various	YC-321-1	4	12/300	2 - 12	3000	108	2.5"L x 2.8"Dia	7.95	6.95	5.95

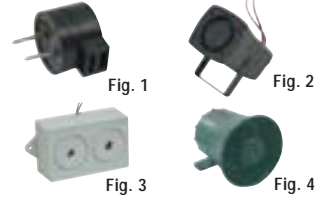

Flat Element, Square Speakers

- Excellent for alarms or other voice uses
- Stainless steel diaphragm

*Web Code: XAE

Part No.	Product No.	Dimensions (Dia." x D")	Input		Impedance (Ω)	Output SPL (dB)	Frequency Range (Hz)	Element Size (Dia." x H")	Pricing		
			Nom (W)	Max (W)					1	10	100
34025	GSP02-R	1.2 x 0.2	0.4	0.8	8	70	1300 - 8000	1.2 x 0.1	\$2.25	\$1.95	\$1.49
76030	AZ40S	1.6 x 0.2	0.4	0.8	8	70	600 - 6000	1.6 x 0.1	1.95	1.69	1.49
673766	AZ50S	1.9 x 0.2	0.4	0.8	8	70	500 - 6000	1.9 x 0.1	1.75	1.49	1.19



Alnico Round, Square and Rectangular Speakers

*Web Code: EAL

Part No.	Product No.	Fig.	Dimensions (Dia." x D")	Input		Impedance (Ω)	Output SPL (dB)	Frequency Range (Hz)	Magnet Size (Dia." x H")	Pricing		
				Nom (W)	Max (W)					1	10	100
2099614	31204	1	4.05 x 1.6	1.0	2.0	4	95	300 - 1200	0.9 x 0.6	\$2.95	\$2.49	\$1.95
135765	RA2425	2	2.2 x 0.8	0.25	0.5	8	87	400 - 4000	0.5 x 0.4	1.59	1.45	1.09
88411	A0200	2	2.0 x 0.8	0.2	0.4	8	87	430 - 4500	0.5 x 0.4	2.29	1.95	1.75
111588	B0102	1	1.7 x 0.6	0.1	0.3	8	83	500 - 5500	0.5 x 0.4	2.39	2.19	1.95
2115442	K7048202	3	1.6Lx2.8Wx0.9H	3.0	3.0	8	82	310 - 12000	0.87 x 0.29	3.95	3.59	3.19
135812	A1527C02	3	1.6Lx2.8Wx1.2H	2.0	5.0	8	82	450 - 20000	0.5 x 0.5	4.49	3.95	3.59
2077301	2559024	2	2.25 x 0.77	0.2	0.2	8	90	450 - 4000	0.9 x 0.8	1.95	1.69	1.49
1954834	NMB-0030	2	1.8 x 0.5	0.5	1.0	8	87	550 - 6000	0.9 x 0.2	2.49	2.25	1.95
2081676	FMO09A	**	4.0 x 1.6	15.0	30.0	8	102	900 - 6000	2.8 x 7.3	3.95	3.59	3.19
1950972	I-826-219	*	8.2Lx2.2Wx2.0H	1.0	13.0	8	95	30 - 20000	1.5 x 2.8	6.95	6.29	5.49
2081220	TP-252	†	2.6 x 0.875	0.5	1.0	16	89	400 - 4000	0.9 x 0.5	2.49	2.25	1.95
1954826	R11-49	†	2.9 x 1.2	0.5	1.0	16	89	300 - 7500	0.9 x 0.4	2.49	2.25	1.95
1954842	609-0033	†	3.6Lx2.0Wx1.5H	1.0	3.0	16	89	200 - 3000	0.9 x 0.7	2.95	2.59	2.39
1954851	R-A162	†	4.0 x 1.5	1.0	2.0	16	89	200 - 3500	0.9 x 0.6	2.95	2.59	2.39
307820	UF1082		1.73 x 0.275	0.5	1.0	40	80	200 - 6000	0.8 x 0.1	2.49	2.19	1.95

- For computer case use
- Paper diaphragm
- Large magnet
- Wide frequency response
- Pre-tinned solder lugs



*Sony LCD plasma replacement speaker (actual size: 6"H x 2.15"W x 1.94"D) **Indoor/outdoor mylar diaphragm (closed back) † With wire leads †† Pair of wire leads (2) 11"/10"

Micro Round and Rectangular Speakers

*Web Code: TBX

Part No.	Product No.	Dimensions (Dia." x D")	Input (W)		Impedance (Ω)	Magnet Size (Dia." x H")	Output SPL (dB)	Frequency Range (Hz)	Pricing		
			Nom.	Max.					1	10	100
2099825	H73	0.80 x .115	0.1	0.2	8	0.47 x 0.03	78	800 - 7000	\$1.59	\$1.45	\$1.09
2099606	SP801W	1.05 x 0.35	0.1	0.2	8	0.67 x 0.17	78	320 - 7500	1.75	1.49	1.25
2095242	35CS088-M75NA	1.4Lx1.3Wx0.2H	0.2	0.3	8	0.44 x 0.10	80	550 - 6700	1.95	1.75	1.49
307871	GC0401M	1.57 x 0.67	0.2	0.3	8	0.71 x 0.43	80	600 - 8000	1.49	1.29	1.09
2081191	5000375-00	2.00 x 0.34	0.2	1.5	8	0.63 x 1.14	85	600 - 3000	1.49	1.25	.95
1956590	TR-050F-R	2.00 x 0.70	0.5	1.0	16	1.25 x 0.34	85	500 - 5000	1.49	1.29	1.09
138861	GC0201	0.80 x 0.169	0.1	0.2	32	0.26 x 0.06	78	800 - 7000	.99	.89	.75
2099593	SP452W	2.25 x 0.5	0.1	0.2	45	0.68 x 0.17	86	150 - 9000	1.95	1.79	1.59
355514	YGD40A-50	1.57 x 0.40	0.5	1.0	50	0.72 x 0.43	89	600 - 5200	1.95	1.69	1.49



30mm PCB Mountable Speakers

- Ideal for PC board mounting
- Mylar diaphragm
- Power (nominal/max.): 0.15W/0.2W
- Solder leads

Part No.	Size (H x Dia.)	Impedance	Pin Spacing	Freq. Range	SPL (dB)	1	10	100
2095234	0.57" x 1.24"	8Ω	0.69"	700-4kHz	82	\$1.75	\$1.49	\$1.25
135722	0.50" x 1.17"	8Ω	0.59"	700-5kHz	82	1.75	1.49	.99
2099817	0.47" x 1.16"	100Ω	0.58"	1.1kHz ±20%	95	1.95	1.75	1.49



The Best Warranty in the Industry

All Jameco purchases are guaranteed for a full 90 days and even longer for Jameco House Brands.

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 197.