




Threaded Standoffs

3 LEVELS OF SAVINGS
NAME BRANDS HOUSE BRANDS FACTORY OVERRUN

.187"/.250" Aluminum, Brass & Steel Hex Threaded Standoffs

*Web Code: TBO

- Finish:
- 1 Brass (plain)
- 2 Aluminum iridite (clear)
- 3 Brass bright tin plate
- 4 Stainless steel
- 5 Brass zinc clear chromate

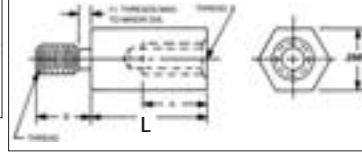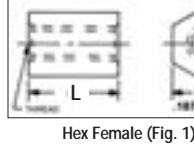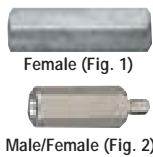

Hex Female Standoffs

* Order in multiples of 10

.187" Hex 4-40 Thread (Fig. 1)

Part No.	*Mfr.	Product No.	Length of L	Pricing		
				1	10	100
175636	◆	2052-440S0 ¹	.187"	\$.25	\$.22	\$.15
133613	RAF	2053-440AL7 ²	.250"	.29	.25	.19
102796	JVP	14-552 ³	.250"	.35	.29	.25
133640	RAF	2057-440AL7 ²	.500"	.39	.35	.25
139792	RAF	2058-440AL7 ²	.563"	.29	.25	.19
133648	RAF	2059-440AL7 ²	.625"	.29	.25	.19
133656	RAF	2061-440AL7 ²	.750"	.39	.35	.29
139185	RAF	2065-440AL7 ²	1.00"	.55	.49	.35

.250" Hex 6-32 Thread (Fig. 1) (Continued)

Part No.	*Mfr.	Mfr Part No.	Length of L	Pricing		
				1	10	100
143441	RAF	2124-632AL7 ²	1.75"	\$.79	\$.69	\$.55
387495	RAF	2140-632A7 ²	4.00"	1.95	1.75	1.49
387508	RAF	2144-632A7 ²	5.00"	1.95	1.75	1.49
387516	RAF	2148-632A7 ²	6.00"	2.95	2.49	2.25
387524	RAF	2152-632A7 ²	7.00"	2.95	2.49	2.25
387532	RAF	2156-632A7 ²	8.00"	2.95	2.49	2.25
387541	RAF	2160-632A7 ²	9.00"	2.95	2.49	2.25
387559	RAF	2164-632A7 ²	10.0"	2.95	2.49	2.25

Hex Male/Female Standoffs

.187" Hex 4-40 (Fig. 2) (A: .250"; B: .187")

Part No.	*Mfr.	Mfr Part No.	Length of L	Pricing		
				1	10	100
393458	RAF	4501-440AL7 ²	.250"	\$.45	\$.39	\$.35
393466	RAF	4503-440AL7 ²	.375"	.35	.29	.25
393474	RAF	4505-440AL7 ²	.500"	.45	.39	.35
393491	RAF	4509-440AL7 ²	.750"	.39	.35	.29
393503	RAF	4513-440AL7 ²	1.00"	.49	.45	.35

.187" Hex 6-32 Thread (Fig. 2) (A: .375"; B: .250")

Part No.	*Mfr.	Mfr Part No.	Length of L	Pricing		
				1	10	100
393546	RAF	4503-632AL7 ²	.375"	\$.35	\$.29	\$.25
393554	RAF	4505-632AL7 ²	.500"	.39	.35	.29
393571	RAF	4509-632AL7 ²	.750"	.35	.29	.25
393588	RAF	4513-632AL7 ²	1.00"	.45	.39	.29

.250" Hex 4-40 Thread (Fig. 2) (A: .250"; B: .187")

Part No.	*Mfr.	Product No.	Length of L	Pricing		
				1	10	100
77586	RAF	4530-440AL7 ²	.250"	\$.35	\$.29	\$.25
1582330	KEY	8713 ⁵	.250"	.55	.49	.35
77594	RAF	4532-440AL7 ²	.375"	.45	.35	.19
393845	RAF	4532-440-B-12L ⁵	.375"	.35	.29	.25
111756	RAF	4534-440AL7 ²	.500"	.45	.39	.29
393852	RAF	4534-440B12 ⁵	.500"	.35	.29	.25
139214	RAF	4536-440AL7 ²	.625"	.45	.39	.29
139222	RAF	4538-440AL7 ²	.750"	.49	.45	.35
139231	RAF	4542-440AL7 ²	1.00"	.55	.49	.45
128566	RAF	4546-440AL7 ²	1.25"	.49	.45	.39
393895	RAF	4546-440B12 ⁵	1.25"	.75	.69	.59
166546	RAF	4550-440AL7 ²	1.50"	.75	.69	.59
393909	RAF	4550-440B12 ⁵	1.50"	.55	.49	.39
618020	◆	S440MF1.5 ²	1.50"	.25	.22	.15

.250" Hex 8-32 Thread (Fig. 1)

Part No.	*Mfr.	Mfr Part No.	Length of L	Pricing		
				1	10	100
387567	RAF	2100-832A7 ²	.250"	* \$1.19	* \$1.15	
387575	RAF	2102-832A7 ²	.375"	* .19	* .15	
387639	RAF	2124-832A7 ²	1.75"	1.49	1.35	1.19
387663	RAF	2140-832A7 ²	4.00"	1.95	1.75	1.49
387671	RAF	2144-832A7 ²	5.00"	1.95	1.75	1.49
387680	RAF	2148-832A7 ²	6.00"	2.95	2.49	2.25
387698	RAF	2152-832A7 ²	7.00"	2.95	2.49	2.25
387701	RAF	2156-832A7 ²	8.00"	2.95	2.49	2.25
387719	RAF	2160-832A7 ²	9.00"	2.95	2.49	2.25
387727	RAF	2164-832A7 ²	10.0"	2.95	2.49	2.25

.250" Hex 10-32 Thread (Fig. 1)

Part No.	*Mfr.	Mfr Part No.	Length of L	Pricing		
				1	10	100
387735	RAF	2100-1032A7 ²	.250"	\$.95	\$.85	\$.75
387743	RAF	2102-1032A7 ²	.375"	.95	.85	.75
387807	RAF	2124-1032A7 ²	1.75"	1.49	1.35	1.19
387840	RAF	2144-1032A7 ²	5.00"	1.95	1.75	1.49
387858	RAF	2148-1032A7 ²	6.00"	2.49	2.25	1.95
387866	RAF	2152-1032A7 ²	7.00"	2.49	2.25	1.95
387874	RAF	2156-1032A7 ²	8.00"	2.95	2.49	2.25
387882	RAF	2160-1032A7 ²	9.00"	2.95	2.49	2.25
387891	RAF	2164-1032A7 ²	10.0"	2.95	2.49	2.25

.250" Hex 6-32 Thread (Fig. 2) (A: .375"; B: .250")

Part No.	*Mfr.	Product No.	Length of L	Pricing		
				1	10	100
133542	RAF	4530-632AL7 ²	.250"	\$.45	\$.39	\$.25
2095103	◆	4530-632-BR7 ³	.250"	.39	.29	.19
133568	RAF	4532-632AL7 ²	.375"	.45	.39	.25
77607	RAF	4534-632AL7 ²	.500"	.45	.39	.25
77623	RAF	4538-632AL7 ²	.750"	.55	.49	.39
77650	RAF	4542-632AL7 ²	1.00"	.65	.59	.49
393959	RAF	4542-632B12 ⁵	1.00"	.55	.49	.45
206623	◆	SP14SS125 ⁴	1.25"	1.39	1.25	.95
393968	RAF	4546-632B12 ⁵	1.25"	.85	.75	.65

.250" Hex 4-40 Thread (Fig. 1)

Part No.	*Mfr.	Product No.	Length of L	Pricing		
				1	10	100
139193	RAF	2100-440A7 ²	.250"	\$.25	\$.22	\$.15
1944353	◆	4-40BHEX ¹	.250"	* .08	* .07	
77501	RAF	2102-440AL7 ²	.375"	.29	.25	.19
393693	RAF	2102-440B12 ⁵	.375"	.59	.55	.35
134763	RAF	2103-440AL7 ²	.437"	.39	.35	.19
393705	RAF	2103-440B12 ⁵	.437"	* .19	* .15	
108371	RAF	2104-440AL7 ²	.500"	.45	.39	.25
393713	RAF	2104-440B1 ⁵	.500"	.35	.29	.25
77519	RAF	2106-440AL7 ²	.625"	.49	.45	.25
393721	RAF	2106-440B12 ⁵	.625"	.35	.29	.25
133605	RAF	2108-440AL7 ²	.750"	.45	.39	.25
393731	RAF	2108-440B12 ⁵	.750"	.49	.45	.39
1944370	◆	.2504-40BHEX1	.750"	* .08	* .07	
139205	RAF	2112-440A7 ²	1.00"	.29	.25	.19
393749	RAF	2112-440B12 ⁵	1.00"	.49	.45	.39
387401	RAF	2148-440A7 ²	6.00"	1.95	1.75	1.49
387428	RAF	2152-440A7 ²	7.00"	2.95	2.49	2.25
387444	RAF	2156-440A7 ²	8.00"	2.95	2.49	2.25
387452	RAF	2160-440A7 ²	9.00"	2.95	2.49	2.25
387461	RAF	2164-440-A7 ²	10.0"	2.95	2.49	2.25

.250" Hex 6-32 Thread (Fig. 1)

Part No.	*Mfr.	Product No.	Length of L	Pricing		
				1	10	100
77535	RAF	2100-632AL7 ²	.250"	\$.29	\$.25	\$.19
1582398	◆	6-32BHEX ¹	.250"	* .08	* .07	
133591	RAF	2102-632A7 ²	.375"	.29	.25	.19
1582400	◆	6-32BHEXF ¹	.375"	* .08	* .07	
77543	RAF	2104-632AL7 ²	.500"	.29	.25	.19
393772	RAF	2104-632B12 ⁵	.500"	.35	.29	.25
77552	RAF	2106-632AL7 ²	.625"	.45	.39	.25
77570	RAF	2108-632AL7 ²	.750"	.45	.39	.25
77578	RAF	2112-632AL7 ²	1.00"	.49	.45	.29
1944388	◆	.250.6-32BHEX ¹	1.00"	* .08	* .07	
143407	RAF	2120-632A7 ²	1.50"	.59	.55	.39
393811	RAF	2120-632B12 ⁵	1.50"	.75	.69	.65

Ceramic Donut Magnet

- For science, fridge or projects
- Size: 1.23" Dia. x 0.19" Thick • Center hole: .375" Dia.

Part No.	Product No.	1	10	100
109031	CDM	\$.49	\$.39	\$.25

.250" Round Threaded Standoffs

*Web Code: TBO

- Aluminum or Brass
- † Finish: Iridite (clear); ¹ per MIL-C-5541-D; ² brass (plain)

.250" Round 4-40 Thread Female

* Order in multiples of 10

Part No.	*Mfr.	Metal†	Length	Pricing		
				1	10	100
1945102	◆	Alum ¹	.250"	\$.45	\$.39	\$.25
1944468	◆	Brass ²	.250"	* .08	* .07	
1944564	◆	Alum ¹	.500"	.35	.29	.25
1944476	◆	Brass ²	.500"	* .08	* .07	
1945129	◆	Alum ¹	.750"	* .08	* .07	
1944484	◆	Brass ²	.750"	* .08	* .07	
1944599	◆	Alum ¹	1.00"	.55	.49	.39

.250" Round 6-32 Thread Female

* Order in multiples of 10

Part No.	*Mfr.	Metal†
----------	-------	--------