

AC-to-DC Unregulated Linear Wall Adapters

3 LEVELS OF SAVINGS
NAME BRANDS **HOUSE BRANDS** **FACTORY OVERRUN**

 



AC-to-DC Unregulated Linear Wall Adapters

120VAC @ 60Hz

We specialize in Wall Adapters - Call for additional OEM PRICING.

*Web Code: UAP

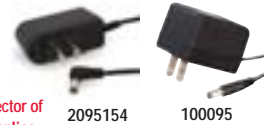

We are happy to change any listed DC wall adapter power plug to a connector of your choice (see pg 130) for just \$2.50 each. A 100 pc. minimum order applies.

Part No.	Manufacturer	Product No.	Output Rating		Output Connector ID x OD mm Female/Male; Polarity ◆	Size (H" x W" x D")	Case Color	Output Cord Length	Wt. (lbs.)	Agency Approvals	Pricing			
			Voltage (VDC)	Curr. (mA)							1	10	50	100
112070	ReliaPro	DBU050022Z5480	5	225	2.5mm x 5.5mm F 2	1.9 x 2.2 x 2.0	Black	7'	0.3	UL/CSA	\$4.95	\$4.49	\$3.95	\$3.59
155601	ReliaPro	DCU050100B3582	5	1000	2.1mm x 5.5mm F 2	2.6 x 2.0 x 1.7	Black	6'	0.7	UL/CSA	9.95	8.95	7.95	6.95
1918657	ReliaPro	DDU050100	5	1000	2.5mm x 5.5mm F 2	3.2 x 2.2 x 1.9	Black	6'	0.7	UL/CUL	9.95	8.95	7.95	6.95
237251	Freeplay	DPX350817	6	100	2.1mm x 5.5mm F 2	2.4 x 1.7 x 1.4	Black	6'	0.4	UL/CSA	3.95	3.59	3.19	2.89
302439	Dynage	LF06300D-08	6	300	2.1mm x 5.5mm F 2	2.2 x 1.7 x 1.5	Black	6'	0.4	UL/CSA	4.95	4.49	3.95	3.59
2099551	Fuhua	UE-3560300D	6	300	2.5mm x 5.5mm F 2	2.2 x 1.7 x 1.7	Black	6'	0.4	UL/CUL	4.95	4.49	3.95	3.59
119255	ReliaPro	DBU060050Z2251	6	500	2.1mm x 5.5mm F 1	2.3 x 1.8 x 1.8	Black	6'	0.6	UL/CUL	6.95	6.25	5.59	4.95
101266	ReliaPro	DBU060050E3860	6	500	2.1mm x 5.5mm F 2	2.4 x 1.9 x 1.6	Black	6'	0.4	UL/CSA	6.95	6.25	5.59	4.95
15544	ReliaPro	DBU060050Z8371	6	500	3.5mm M 2	2.4 x 1.9 x 1.6	Black	6'	0.4	UL/CSA	6.95	6.25	5.59	4.95
2081431	PEI	DV-0670-B14	6	700	2.1mm x 5.5mm F 2	2.4 x 2.0 x 1.6	Black	6'	0.5	UL/CUL	5.95	5.39	4.79	4.29
147707	ReliaPro	DBU060080C6962	6	800	2.1mm x 5.5mm F 2	2.3 x 2.0 x 1.6	Black	6'	0.6	UL/CSA	7.95	6.95	5.95	4.95
220943	ReliaPro	DCU060120G2401	6	1200	2.1mm x 5.5mm F 1	2.5 x 2.0 x 1.7	Black	6'	0.7	UL/CUL	8.95	7.95	6.95	5.95
2095154	Thomson	5-2760	7.5	500	2.1mm x 5.5mm right angle F 2	2.5 x .96 x 1.4	Black	6'	0.4	UL/CUL	4.95	4.49	3.95	3.59
220951	ReliaPro	DCU075100G2291	7.5	1000	2.1mm x 5.5mm F 1	2.5 x 2.0 x 1.7	Black	6'	0.6	UL/CUL	8.95	7.95	6.95	5.95
248751	Uniq	AD-071A	7.5	1000	2.5mm x 5.5mm F 2	2.3 x 2.3 x 1.9	Black	6'	0.9	UL/CSA	4.95	4.49	3.95	3.59
280250	ReliaPro	DDU075110G9521	7.5	1100	2.1mm x 5.5mm F 2	2.9 x 2.3 x 1.9	Black	6'	0.9	UL/CUL	8.95	7.95	6.95	5.95
127511	ReliaPro	DDU080100E2281	8	1000	2.1mm x 5.5mm F 2	3.1 x 2.5 x 2.1	Black	6'	1.3	UL	9.95	8.95	7.95	6.95
355936	ReliaPro	DBU090020	9	200	1.3mm x 3.5mm F 2	2.2 x 1.7 x 1.5	Black	6'	0.4	UL/CUL	5.95	5.35	4.79	4.39
134025	ReliaPro	DBU090020Z6100	9	200	2.1mm x 5.5mm F 1	2.1 x 1.7 x 1.6	Black	6'	0.4	UL/CSA	5.95	5.35	4.79	4.39
2100152	TONT	AP2911	9	200	2.1mm x 5.5mm F 2	2.6 x 1.8 x 1.5	Black	6'	0.4	UL/CUL	4.95	4.49	3.95	3.59
100845	ReliaPro	DBU090020E0850	9	200	2.1mm x 5.5mm F 2	2.1 x 1.7 x 1.5	Black	6'	0.4	UL/CSA	5.95	5.35	4.79	4.39
2082556	Thomson	5-2616	9	200	2.1mm x 5.5mm right angle F 2	2.2 x 1.4 x 1.4	Black	6'	0.5	UL/CUL	4.95	4.49	3.95	3.59
2082548	Atlinks	5-2617	9	200	2.1mm x 5.5mm right angle F 2	2.2 x 1.4 x 1.4	Gray	6'	0.5	UL/CUL	4.95	4.49	3.95	3.59
100837	ReliaPro	DBU090020Z5490	9	200	3.5mm M 2	2.6 x 1.8 x 1.6	Black	6'	0.4	UL/CSA	5.95	5.35	4.79	4.39
2082572	Atlinks	5-2677	9	210	2.1mm x 5.5mm right angle F 2	2.2 x 1.4 x 1.4	Black	6'	0.5	UL/CUL	4.95	4.49	3.95	3.59
133891	ReliaPro	DBU090030C112	9	300	2.1mm x 5.5mm F 2	2.0 x 1.5 x 1.5	Black	6'	0.4	UL/CSA	5.95	5.35	4.79	4.39
318676	ReliaPro	DBU090030H5790	9	300	2.5mm x 5.5mm F 1	2.2 x 1.7 x 1.5	Black	6'	0.4	UL/CUL	5.95	5.39	4.79	4.39
1949120	Various	AD35-0900300DU	9	300	2.5mm x 5.5mm F 2	2.2 x 1.7 x 1.5	Black	6'	0.4	UL	4.95	4.49	3.95	3.59
189238	ReliaPro	DBU090030H4540	9	300	2.5mm x 5.5mm F 2	2.2 x 1.7 x 1.5	Black	6'	0.4	UL/CUL	5.95	5.35	4.79	4.39
202155	ReliaPro	DBU090035F1982	9	350	2.1mm x 5.5mm F 2	2.2 x 1.7 x 1.5	Black	6'	0.3	UL/CUL	5.95	5.39	4.79	4.29
1954615	Mei Int.	MADA-2131	9	350	2.5mm M 1	2.2 x 1.7 x 1.5	Black	6'	0.3	UL/CUL	4.95	4.49	3.95	2.95
140636	ReliaPro	DCU090040C6351	9	400	2.5mm x 5.5mm F 2	2.6 x 2.0 x 2.0	Black	6'	0.6	UL/CSA	5.95	5.35	4.79	4.25
163628	ReliaPro	DCU090050Z7484	9	500	2.1mm x 5.5mm F 1	2.5 x 1.9 x 1.7	Black	6'	0.6	UL/CSA	6.95	6.25	5.59	4.95
100853	ReliaPro	DCU090050E2961	9	500	2.1mm x 5.5mm F 2	2.5 x 1.9 x 1.7	Black	6'	0.6	UL/CSA	6.95	6.25	5.59	4.95
147732	ReliaPro	OH-41036DT	9	500	2.1mm x 5.5mm F 2	2.6 x 2.0 x 1.7	Beige	6'	0.6	UL/CSA	6.95	6.25	5.59	4.95
236937	ReliaPro	DCU090050G6440	9	500	2.5mm x 5.5mm right angle F 2	2.5 x 2.0 x 1.7	Black	6'	0.4	UL/CSA	6.95	6.25	5.59	4.95
1586162	CUI Inc	DPD090050	9	500	3.5mm M 2	2.3 x 1.9 x 1.6	Black	6'	0.6	UL/CSA	5.95	4.95	4.29	3.69
155611	ReliaPro	DCU090050A2011	9	500	3.5mm M 2	2.5 x 2.0 x 1.6	Black	6'	0.5	UL/CSA	6.95	6.25	5.59	4.95
202180	ReliaPro	DCU090060F2091	9	600	2.1mm x 5.5mm F 2	3.3 x 2.9 x 2.3	Black	6'	0.6	UL/CUL	6.95	6.25	5.59	4.95
100175	ReliaPro	DCU090060Z6652	9	600	2.5mm x 5.5mm F 2	2.7 x 2.0 x 1.7	Black	6'	0.6	UL/CSA	6.95	6.25	5.59	4.95
202198	ReliaPro	DCU090080F2221	9	800	2.1mm x 5.5mm F 2	3.3 x 2.9 x 2.3	Black	6'	0.6	UL/CUL	8.95	7.95	6.95	5.95
421577	Powerline	0900-12	9	850	2.5mm x 5.5mm F 2	2.7 x 2.1 x 1.7	Black	6'	0.8	UL/CSA	6.95	6.25	5.59	3.95
164929	ReliaPro	DDU090100C2550	9	900	2.1mm x 5.5mm F 1	2.7 x 2.3 x 1.8	Black	6'	0.9	UL/CUL	6.95	6.25	5.59	4.95
421690	Fisher Price	SA48-29A	9	1000	2.1mm x 5.5mm F 2	3.1 x 2.2 x 1.8	Black	6'	1.1	UL/CSA	6.95	5.95	4.95	3.95
364576	ReliaPro	DDU090100J0490	9	1000	2.1mm x 5.5mm F 2	2.9 x 2.3 x 1.9	Black	6'	0.9	UL/CUL	9.95	8.95	7.95	6.95
227774	GTE	ADP2108GT	9	1000	2.1mm x 5.5mm right angle F 2	2.5 x 2.2 x 1.9	Black	6'	0.9	UL/CUL	7.95	6.95	5.95	4.95
2099905	Golden Regent	W48D-H1000	9	1000	2.5mm x 5.5mm F 1 (US plug)	3.2 x 2.3 x 1.9	Black	6'	0.9	UL/CUL	9.95	8.95	7.95	6.95
2099913	ENG *	T48-9-1000D3	9	1000	2.5mm x 5.5mm F 1 (Euro plug)	3.2 x 2.3 x 1.9	Black	6'	0.9	CE/TUV	8.95	7.95	6.95	6.25
2099921	ENG *	T48-9-1000D4	9	1000	2.5mm x 5.5mm F 1 (UK plug)	3.2 x 2.3 x 1.9	Black	6'	0.9	CE/TUV	8.95	7.95	6.95	6.25
127505	ReliaPro	DDU090100	9	1000	2.5mm x 5.5mm F 2	2.6 x 2.4 x 2.0	Black	6'	0.9	UL/CSA	9.95	8.95	7.95	6.95
1586082	GTE	ADP2108GT (2.5)	9	1000	2.5mm M 2	2.6 x 2.2 x 1.9	Black	6'	0.9	UL/CSA	7.95	6.95	5.95	4.95
15587	ReliaPro	DDU090100Z9081	9	1000	3.5mm M 2	2.6 x 2.4 x 2.0	Black	6'	0.9	UL/CSA	9.95	8.95	7.95	6.95
130526	ReliaPro	DDE090120F3621	9	1200	2.1mm x 5.5mm F 1	2.4 x 2.0 x 1.8	Black	6'	1.0	UL/CSA	10.95	9.95	8.95	7.95
143693	ReliaPro	DFU0901500A3040	9	1500	2.1mm x 5.5mm F 2	3.3 x 2.5 x 2.3	Black	6'	1.3	UL/CSA	12.95	11.49	9.95	8.95
2082193	Phillips	SPA-3545-81	12	100	2.1mm x 5.5mm F 2	2.5 x 1.8 x 1.5	Black	6'	0.5	UL/CSA	7.95	6.95	6.25	4.95
163993	ReliaPro	DBU120020E2291	12	200	2.1mm x 5.5mm right angle F 1	2.4 x 1.7 x 1.6	Black	6'	0.4	UL/CSA	5.49	4.95	4.75	4.29
100095	ReliaPro	DBU120020G0610	12	200	2.1mm x 5.5mm F 2	2.1 x 1.8 x 1.5	Black	6'	0.4	UL/CSA	5.49	4.95	4.75	4.29
158043	ReliaPro	DBU120020E2261	12	200	2.1mm x 5.5mm right angle F 2	2.2 x 1.7 x 1.5	Black	6'	0.4	UL/CSA	5.95	5.39	4.59	3.95
127976	ReliaPro	DCU120030D7161	12	300	2.1mm x 5.5mm F 2	2.6 x 1.8 x 1.6	Black	6'	0.7	UL/CSA	6.95	6.25	5.59	4.95
2082046	Videx	U/090/9	12	300	2.1mm x 5.5mm right angle F 2	2.5 x 1.9 x 1.7	Black	6'6"	0.6	UL/CSA	6.95	6.25	5.59	4.95
249236	ReliaPro	DBU120030G8970	12	300	2.5mm x 5.5mm right angle F 2	2.2 x 1.7 x 1.5	Black	6'	0.5	UL/CUL	6.95	6.25	5.59	4.95

* 240VAC 50Hz ⚡ Blue Part No. = Limited Quantity Available

More AC-to-DC Wall Adapters listed on pages 121-123 & 125

♻️ RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 197.

