

 

AC-to-DC Regulated & Unregulated Table-Top Power Supplies

3 LEVELS OF SAVINGS
 NAME BRANDS HOUSE BRANDS FACTORY OVERRUN

Jameco carries the full line of Mean Well Power products. For additional products visit www.Jameco.com/meanwellproducts

AC-to-DC Regulated & Unregulated Linear & Switching Table-Top Power Supplies

We are happy to change the power plug on any listed table-top power supply to a connector of your choice (see pg 130) for just \$2.50 each. A 100 pc. minimum order applies.

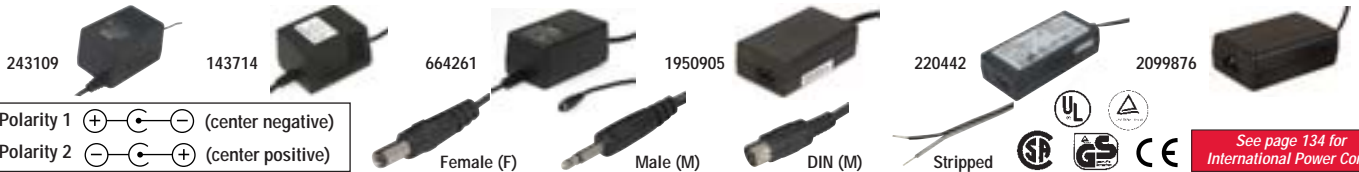

See page 134 for International Power Cords

Part No.	Manufacturer	Product No.	Output Volts (VDC)/ Current (A)	Output Connector ID x OD/F = female; M = male; Polarity ◆	Input VAC@Hz	Output Power (W)	LED Ind.	Size (L" x W" x H")	Cords* (DC/AC)	Wt. (lbs.)	Agency Approvals	Pricing			
												1	10	50	100
2-Wire AC Input – Unregulated Linear Table-Top												*Web Code: TBE			
190051	APS	APS48EA114	+7/1.5	2.5mm x 5.5mm F 2	120@60	10	No	3.4 x 2.3 x 1.9	6'/6'	1.9	UL/CUL	\$6.95	\$6.25	\$4.95	\$3.95
243109	Regal	JK-91001-N	+9/1.0	Stripped & Tinned	120@60	9	No	3.3 x 2.2 x 1.9	6'/6'	1.2	UL/CSA	6.95	6.25	4.95	3.95
2081941	Toshiba	AD-121ADT	+12/1.0	2.1mm x 5.5mm F 2	120@60	12	No	3.2 x 2.2 x 1.9	6'/6'	1.3	UL/CUL	7.95	6.95	6.25	5.59
140880	ReliaPro	DC1215ST	+12/1.5	Stripped & Tinned	120@60	18	No	3.1 x 2.1 x 1.9	6'/6'	1.5	UL	11.95	10.95	9.95	8.95
143714	Horizon+	DC1220F1	+12/2.0	2.1mm x 5.5mm F 2	120@60	24	No	3.8 x 2.8 x 2.3	6'/6'	2.2	CUL	13.95	12.49	10.95	9.95
143722	ReliaPro	DC1220F5	+12/2.0	2.5mm x 5.5mm F 2	120@60	24	No	3.8 x 2.8 x 2.3	6'/6'	2.2	UL/CUL	14.95	13.49	11.95	10.95
143731	ReliaPro	DC1220M3	+12/2.0	3.5mm M 2	120@60	24	No	3.8 x 2.8 x 2.3	6'/6'	1.9	UL/CUL	14.95	13.49	11.95	10.95
139096	ReliaPro	DC2412F1	+24/1.2	2.1mm x 5.5mm F 2	120@60	29	No	4.4 x 3.1 x 2.6	6'/6'	2.5	—	14.95	13.49	11.95	10.95
1953815	SR Components	DC24-1.2	+24/1.2	2.1mm x 5.5mm F 2	120@60	29	No	4.5 x 3.4 x 2.6	5'/6"	0.7	UL	12.95	11.95	10.49	8.95
173665	Skynet	DND-3005	+30/0.5	2.5mm x 5.5mm F 2	120@60	15	No	3.0 x 2.5 x 2.2	5'9"/3'2"	1.4	UL/CUL	6.95	6.25	5.95	4.95
2-Wire AC Input – Regulated Linear Table-Top												*Web Code: CEM			
664261	Intermec	062035	+5/0.75	4-pin DIN M	120@60	3.75	No	4.4 x 2.5 x 2.0	6'/6'	1.6	UL/CSA	\$8.95	\$7.95	\$6.95	\$6.25
2099569	JEC	57-1607-U4D	+16/0.7	2.5mm x 5.5mm F 2	120@60	19	No	3.6 x 2.7 x 3.6	6'/6'	1.3	UL	8.95	7.95	6.95	6.25
174845	ReliaPro	DCR2410F12	+24/1	2.1mm x 5.5mm F 2	120@60	24	No	4.4 x 3.0 x 2.5	6'/6'	2.6	UL	17.95	15.95	14.49	12.95
2-Wire AC Input – Regulated Switching Table-Top – Single Output												*Web Code: DDZ			
153752	Cisco	34-0912-02	+5/2.5	2.5mm x 5.5mm F 2	100-240@50-60	13	No	3.5 x 2.2 x 1.2	6' ¹	0.5	UL/CUL/TUV/CE	\$11.95	\$10.49	\$8.95	\$7.95
1586242	Phihong	PSAA15W-050-R	+5/3.0	2.1mm x 5.5mm F 2	100-240@50-60	15	No	3.2 x 2.0 x 1.2	6' ¹	—	UL/CUL/TUV/CE	15.95	14.49	12.95	11.49
1940299	Mean Well	GS18B05-P1J	+5/3.0	2.1mm x 5.5mm F 2	100-240@50-60	18	Yes	3.1 x 2.1 x 1.3	4' ¹	0.5	UL/CSA/TUV/CEC	15.95	14.49	13.49	12.49
1552505	ITE Power	SYS1102-2005	+5/4.0	2.1mm x 5.5mm F 2	100-240@50-60	20	Yes	4.0 x 2.0 x 1.3	3'6' ¹	0.7	UL/CUL/TUV/CE	13.95	11.95	9.95	8.95
1940483	Mean Well	GS25B05-P1J	+5/4.0	2.1mm x 5.5mm F 2	100-240@50-60	20	Yes	3.1 x 2.1 x 1.3	4' ¹	0.5	UL/CSA/TUV/CEC	16.49	14.95	13.95	12.95
377925	Mean Well	P30B-1P2JU	+5/4.0	2.1mm x 5.5mm F 2	90-264@47-63	20	Yes	4.3 x 2.6 x 1.4	6'/6'	0.7	UL/CSA/TUV/CE	21.95	19.95	18.95	17.95
380621	Mean Well	ES25B05-P1MU	+5/4.0	2.5mm x 5.5mm F 2	90-264@47-63	20	Yes	3.1 x 2.1 x 1.3	6'/6'	0.5	UL/CSA/TUV/CE	18.95	16.95	15.49	14.49
1940301	Mean Well	GS18B07-P1J	+7.5/2.0	2.1mm x 5.5mm F 2	100-240@50-60	18	Yes	3.1 x 2.1 x 1.3	6' ¹	0.5	UL/CSA/TUV/CEC	15.95	14.49	13.49	12.49
1707067	Mean Well	ES25B07-P1J	+7.5/2.93	2.1mm x 5.5mm F 2	100-240@50-60	22	Yes	3.1 x 2.1 x 1.3	6' ¹	0.4	UL/CUL/TUV/CE	10.95	9.49	8.49	7.49
195806	ReliaPro	DCR920F12	+9/2.0	2.1mm x 5.5mm F 2	100-240@50-60	18	Yes	4.2 x 2.6 x 1.4	6'/6'	0.9	UL/CUL/TUV/CE	21.95	19.95	18.95	17.95
1940310	Mean Well	GS18B09-P1J	+9/2.0	2.1mm x 5.5mm F 2	90-264@47-63	18	Yes	3.1 x 2.1 x 1.3	6' ¹	0.5	UL/CUL/TUV/CE	15.95	14.49	13.49	12.49
195768	ReliaPro	DCR920F52	+9/2.0	2.5mm x 5.5mm F 2	100-240@50-60	18	Yes	4.3 x 2.6 x 1.4	6'/6'	0.9	UL/CUL/TUV/CE	21.95	19.95	18.95	17.95
380681	Mean Well	ES25B09-P1MU	+9/2.78	2.5mm x 5.5mm F 2	90-264@47-63	25	Yes	3.1 x 2.1 x 1.3	6'/6'	0.5	UL/CSA/TUV/CE	18.95	16.95	15.49	14.49
379787	Mean Well	P30B-2P2MU	+9/2.89	2.5mm x 5.5mm F 2	90-264@47-63	26	Yes	4.3 x 2.6 x 1.4	6'/6'	0.7	UL/CSA/TUV/CE	19.95	18.95	17.95	16.95
1940213	EDAC, Inc.	EA10302	+9/3.3	2.1mm x 5.5mm F 2	100-240@50-60	30	Yes	3.9 x 1.8 x 1.2	4' ¹	0.5	UL/CUL/TUV/CE	14.95	13.49	11.95	10.95
1950905	APS	AD715U-1121	+12/1.2	2.5mm x 5.5mm F 2	100-240@50-60	15	No	3.7 x 2.1 x 1.3	6' ¹	0.5	UL/CUL/TUV/CE	11.95	10.95	9.95	8.95
191353	Delta	ADP-15FB	+12/1.25	2.1mm x 5.5mm F 2	100-240@50-60	15	No	3.5 x 2.3 x 1.2	6' ¹	0.5	UL/CE	12.95	11.49	9.95	8.95
1940328	Mean Well	GS18B12-P1J	+12/1.5	2.1mm x 5.5mm F 2	100-240@50-60	18	No	3.1 x 2.1 x 1.3	6'/6'	0.5	UL/CSA/TUV/CEC	15.95	14.49	13.49	12.49
2099868	DVE	DSA-0421S	+12/2.0	2.1mm x 5.5mm F 2	100-240@50-60	24	Yes	3.7 x 2.2 x 1.3	6'/6'	0.4	UL/CUL/TUV/CE	19.95	17.95	15.95	13.95
1537555	APD	DA-24B12	+12/2.0	2.5mm x 5.5mm F 2	100-240@47-63	24	No	3.6 x 2.2 x 1.3	6' ¹	0.4	UL/CUL/TUV/CE	19.95	17.95	15.95	13.95
1942155	Jentec	JTA0210P	+12/3.0	2.1mm x 5.5mm F 2	100-240@50-60	36	Yes	4.3 x 2.0 x 1.2	4' ¹	0.6	UL/CUL/TUV/CE	15.95	13.95	11.95	10.95
401042	ReliaPro	ADPV16	+12/3.0	2.1mm x 5.5mm F 2	100-240@50-60	36	No	3.9 x 1.8 x 1.2	4' ¹	0.5	UL/CUL/TUV/CE	22.95	20.49	18.95	16.95
220442	ReliaPro	SL120300RT	+12/3.0	2.5mm x 5.5mm F 2 ¹	100-240@50-60	36	Yes	4.3 x 2.0 x 1.2	6' ¹	0.6	UL/CUL/TUV/CE	24.95	22.49	19.95	17.95
2099876	Lishin Int.	LSE9802A 1240	+12/3.33	2.1mm x 5.5mm F 2	100-240@50-60	40	Yes	3.7 x 2.2 x 1.3	5'/6"	0.4	UL/CSA/TUV/CE	22.95	20.49	18.95	16.95
1940336	Mean Well	GS18B15-P1JT	+15V/1.2	2.1mm x 5.5mm F 2	100-240@50-60	18	No	3.1 x 2.1 x 1.3	6'/6'	0.5	UL/CSA/CEC	15.95	14.49	13.49	12.49
1537070	Phihong	PSA15W-150R	+15/1.25	2.5mm x 5.5mm F 2	100-240@47-63	15	No	4.3 x 2.6 x 1.0	6' ¹	0.8	UL/CUL/TUV/CE	17.95	16.49	14.95	13.49
1940521	Mean Well	GS25B15-P1JT	+15/1.66	2.1mm x 5.5mm F 2	100-240@50-60	25	No	3.1 x 2.1 x 1.3	6'/6'	0.5	UL/CSA/CEC	18.95	16.95	14.95	13.49
1940539	Mean Well	GS25B18-P1J	+18/1.38	2.1mm x 5.5mm F 2	100-240@50-60	25	Yes	3.1 x 2.1 x 1.3	6' ¹	0.5	UL/CSA/TUV/CEC	18.95	16.95	14.95	13.49
1940352	Mean Well	GS18B24-P1J	+24/0.75	2.1mm x 5.5mm F 2	100-240@50-60	18	Yes	3.1 x 2.1 x 1.3	6' ¹	0.5	UL/CSA/TUV/CEC	15.95	14.49	13.49	12.49
1940547	Mean Well	GS25B24-P1JT	+24/1.04	2.1mm x 5.5mm F 2	100-240@50-60	25	Yes	3.1 x 2.1 x 1.3	6' ¹	0.5	UL/CSA/TUV/CEC	16.49	14.95	13.49	12.49
221613	Mean Well	P30B-6P2JT	+24/1.12	2.1mm x 5.5mm F 2	100-240@50-60	27	Yes	4.3 x 2.6 x 1.4	6'/6'	0.8	UL/CUL/TUV/CE	26.95	24.95	22.95	20.49
1940230	EDAC, Inc.	EA1030D2	+24/1.25	2.1mm x 5.5mm F 2	100-240@50-60	30	Yes	3.9 x 1.8 x 1.2	4' ¹	0.5	UL/CUL/TUV/CE	19.95	17.95	15.95	13.95
229843	Phihong	PSAA60W-240	+24/2.5	2.1mm x 5.5mm F 2	100-240@47-63	60	No	5.1 x 2.4 x 1.3	4' ¹	0.5	UL/CSA/CEC	36.95	33.95	31.95	28.95
1707075	Mean Well	ES18B28-P1J	+28/0.64	2.1mm x 5.5mm F 2	100-240@50-60	18	Yes	3.1 x 2.1 x 1.3	6' ¹	0.5	UL/CUL/TUV/CE	8.95	7.95	6.95	5.95
205911	Delta	ADP-25HB	+30/0.83	2.1mm x 5.5mm F 2	100-125@50-60	25	No	3.5 x 2.4 x 1.2	6'/7'	1.1	UL/CUL	12.95	11.49	9.95	8.95

* See accessory table-top power cord chart on page 129 when AC cord needed; refer to 1, 2 or 3 in "Cord (DC/AC)" column above for correct power cord. † Right Angle
 ✓ CEC Equivalent available. Add a "C" before part number for CEC version. 🌿 CEC

3-Wire Regulated Table-Top Power Supplies on Next Page

🌿 RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 197.