



## DC Power Plugs & Adapters



\*Web Code: MFP

Part No.	Mfr.	Product No.	Fig.	Description (Barrel) Plug ID x OD x L (mm)	Strain Relief ID x L (mm)	Price		
						1	10	100
71192	ValuePro	PP137R	1	F plug, 1.3 x 3.5 x 9.5	4.1 x 12 (black)	\$.79	\$.69	\$.65
1537395	ValuePro	PL-005R	2	F plug, 1.3 x 3.5 x 9.4 (rt. angle)	2.8 x 11	.95	.85	.75
2098013	ValuePro	DCP-111R	1	F plug, 1.7 x 5.5 x 9.8	4.6 x 12 (black)	.95	.85	.75
191484	ValuePro	PP049W	1	F plug, 2.1 x 5.5 x 9.0	4.6 x 12.5 (white)	.69	.59	.55
2004890	ValuePro	PP049S	1	F plug, 2.1 x 5.5 x 9.5	4.5 x 12.5 (black)	.79	.69	.65
297617	Switchcraft	S760R	3	F plug, 2.1 x 5.5 x 9.5	5.5 x 25 (black)	3.95	3.49	2.95
28760	ValuePro	PP049R	1	F plug, 2.1 x 5.5 x 10 (P205)	4.1 x 12 (black)	.79	.69	.55
138587	ValuePro	PJ021R	2	F plug, 2.1 x 5.5 x 12 (rt. angle)	2.8 x 11 (black)	.89	.79	.65
147329	ValuePro	PP049LR	1	F plug, 2.1 x 5.5 x 14 (P205L)	4.3 x 12 (black)	.89	.79	.65
190538	ValuePro	PP109SR	1	F plug, 2.5 x 5.5 x 9.5	5.0 x 13 (black)	.59	.55	.49
281877	Switchcraft	760R	3	F plug, 2.5 x 5.5 x 9.5	5.5 x 25 (black)	2.95	2.49	2.19
28768	ValuePro	PP109R	1	F plug, 2.5 x 5.5 x 10 (P206)	4.2 x 12 (black)	.79	.69	.59
147336	ValuePro	PP109L+	1	F plug, 2.5 x 5.5 x 14 (P206L)	4.2 x 12 (black)	.79	.69	.59
168242	ValuePro	PP109NR	3	F plug, 2.5 x 5.5 x 14	3.9 x 22 (black)	.69	.59	.55
2099163	ValuePro	PL-008R	2	F plug, 2.5 x 5.5 x 9.5 (rt. angle)	2.8 x 11	.95	.85	.75
101135	ValuePro	PJ1025	4	M plug, — x 2.5 x 11 (P201)	4.3 x 13 (black)	.79	.69	.55
231176	ValuePro	AP-340R	4	M plug, — x 3.5 x 14 (stereo)	4.3 x 13.5 (black)	.79	.69	.55
231167	ValuePro	AP-343	5	M plug, — x 3.5 x 14 (stereo)	4.4 x 13 (metal)	1.49	1.25	.99
231160	ValuePro	PJ1035R	5	M plug, — x 3.5 x 14 (mono)	4.8 x 13.5 (metal)	1.49	1.25	.99
101152	ValuePro	PJ1035R	4	M plug, — x 3.5 x 14.5 (P202)	4.0 x 13 (black)	.69	.59	.49
2113703	ValuePro	JR1826R	6	Adapter, 1.7mm M to 2.1mm F (1.7" L)	—	1.49	1.25	.99
2112989	ValuePro	JP1828CR	6	Adapter, 2.1mm M to 1.3mm F (1.3" L)	—	1.49	1.25	.99
1953591	ValuePro	DCJ2.1-DCP2.5R	6	Adapter, 2.1mm M to 2.5mm F (1.4" L)	—	1.49	1.25	.99
2113009	ValuePro	JP1829R	6	Adapter, 2.5mm M to 1.3mm F (1.3" L)	—	1.49	1.25	.99
2113711	ValuePro	Jr1827R	6	Adapter, 2.5mm M to 1.7mm F (1.7" L)	—	1.49	1.25	.99
1953604	ValuePro	DCJ2.5-DCP2.1R	6	Adapter, 2.5mm M to 2.1mm F (1.4" L)	—	1.49	1.25	.99

### DC Cords with Pigtail – 6' length

Part No.	Mfr.	Cross Ref. No.	Fig.	Description (Barrel) ID x OD x L (mm)	AWG	Price		
						1	10	100
2113674	ValuePro	DCCORD1.3R	7	Jack, 1.3 x 3.5 x 12	24 (black)	\$1.59	\$1.39	\$1.15
2114693	ValuePro	DCCORD1.7R	8	Plug, 1.7 x 2.5 x 12	24 (black)	1.59	1.39	1.15
2114706	ValuePro	6FT#245.5X1.7R	7	Jack, 1.7 x 2.5 x 12	24 (black)	1.59	1.39	1.15
2096763	ValuePro	DCCORD2.1R	7	Jack, 2.1 x 5.5 x 12	24 (black)	1.59	1.39	1.15
2114600	ValuePro	6FT#245.5X2.1R	8	Plug, 2.1 x 5.5 x 12	24 (black)	1.59	1.39	1.15
2096771	ValuePro	DCCORD2.5R	7	Jack, 2.5 x 5.5 x 12	24 (black)	1.59	1.39	1.15
2114597	ValuePro	6FT#245.5X2.5R	8	Plug, 2.5 x 5.5 x 12	24 (black)	1.59	1.39	1.15

### DC Extension Power Cables


Part No.	Mfr.	Product No.	Description	Dimensions	AWG	Price
2099147	ValuePro	DCEXTCORD2.1-3FTR	9	2.1F x 2.1M x 3' cable	18 (black)	\$1.75 \$1.49 \$1.25
2099121	ValuePro	DCEXTCORD2.1-6FTR	9	2.1F x 2.1M x 6' cable	18 (black)	1.95 1.75 1.49
2099155	ValuePro	DCEXTCORD2.5-3FTR	9	2.5F x 2.5M x 3' cable	18 (black)	1.75 1.49 1.25
2099139	ValuePro	DCEXTCORD2.5-6FTR	9	2.5F x 2.5M x 6' cable	18 (black)	1.95 1.75 1.49

## Male & Female Power Jacks

Part No.	Mfr.	Product No.	Description	Dimensions H x W x D (mm)	Type/ Mount	Circuit/ Terminal	Mating Plug (see right)	Price		
								1	10	100
								Terminals	Code	
101194	Various	PP024	1.3mm male	6.0 x 6.0 x 9.0	1/D	1/B	1.3 mm F	\$.59	\$.55	\$.45
101178	Various	PP014+	2.1mm male	10.9 x 9.0 x 14.5	2/D	1/A	2.1 mm F	.39	.35	.29
137673	Various	PP013R	2.1mm male	10.9 x 9.0 x 14.5	3/D	4/A	2.1 mm F	.45	.39	.35
151590	Various	DPJ-021AR	2.1mm male	18.0 x 12.6 Dia.	4/C†	1/A	2.1 mm F	.89	.79	.69
151555	ValuePro	DPJ-026R	2.1mm male	21.0 x 8.0 Dia.	5/E	1/A	2.1 mm F	1.49	1.35	1.19
159611	Various	PJ1014AR	2.1mm male	57.5 x 12.6 Dia.	6/F	3/A	2.1 mm F	1.75	1.59	1.39
281851	Switchcraft	722AR	2.1mm male	15.1 x 7.5 Dia.	7/C	1/A	2.1 mm F	2.75	2.49	2.25
207714	Various	HEC0470	2.5 mm male	11.0 x 9.0 x 14.5	2/D	1/B	2.5 mm F	.55	.49	.39
101186	Various	PP014+	2.5 mm male	11.0 x 9.0 x 14.5	2/D	1/A	2.5 mm F	.49	.45	.29
151563	Various	DPJ-026AR	2.5 mm male	15.1 x 8.0 Dia.	5/E	1/A	2.5 mm F	1.49	1.35	1.19
159506	Various	PJ1015AR	2.5 mm male	57.5 x 12.6 Dia.	6/F	3/A	2.5 mm F	1.49	1.35	1.19
202358	Various	HD2388	2.5 mm male	12.4 x 7.7 Dia.	8/C*	3/A	2.5 mm F	1.19	.99	.89
2100355	Switchcraft	HE2388M	2.5 mm male	17.1 x 10.9 Dia.	8/C**	4/A	2.5 mm F	1.49	1.35	1.19
281842	Switchcraft	712AR	2.5 mm male	15.8 x 7.5 Dia.	7/C	1/A	2.5 mm F	3.95	3.39	2.95
297553	Switchcraft	PC712AR	2.5 mm male	23.3 x 11.0 Dia.	9/D	1/A	2.5 mm F	3.95	3.39	2.95
297529	Switchcraft	L712AR	2.5 mm male	23.3 x 11.0 Dia.	10/C	1/A	2.5 mm F	3.95	3.39	2.95
101143	ValuePro	PJ0352R	3.5 mm female	10.0 x 10.0 x 18.5	11/E	2/A	3.5 mm M	.39	.35	.29
109496	ValuePro	PJ035PMR	3.5 mm female	10.5 x 9.0 x 20.0	12/C	2/A	3.5 mm M	.49	.45	.39
165730	ValuePro	PJ035AR	3.5 mm female	15.5 x 5.9 Dia.	13/C	3/A	3.5 mm M	.79	.69	.59

† Center offset \*Plastic \*\*Metal

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 197.

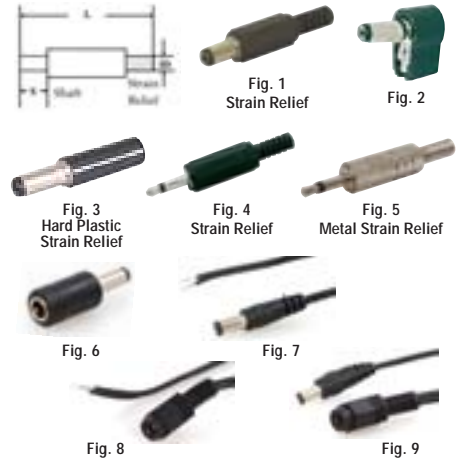

## Wagan Cell Phone/ PDA Travel Adapter

Provides Both DC & USB Power

Converts any car charger into a wall adapter by simply plugging the adapter into the wall and car charger into the DC port. It's universal for all cell phone brands when used with your car charger. It's also suitable for any PDA or MP3 player by utilizing the USB port.

- DC: 12V @ 500mA • USB: 5V @ 500mA
- Fuse protected • Space saving folding design

Part No.	Description	1	10
2096051	AC to DC power adapter	\$14.95	\$13.49

## Automobile Fused Power Plugs with Cords

- Accepts .25" x 1.25" fuse
- 115002: Screw assembly w/ strain relief (no cord)
- 124760: 3' cord w/ pigtail
- 105064: 12' cord w/ pigtail

Part No.	Mfr.	Fuse	1	10	100
115002	ValuePro	5A/250VACR	\$2.25	\$1.99	\$1.79
124760	ValuePro	3A/250VACR	2.49	2.25	1.99
105064	Various	2A/250VAC	1.95	1.75	1.39

