


Evergreen, Energizer®, Duracell® & Lexcell® Alkaline Batteries

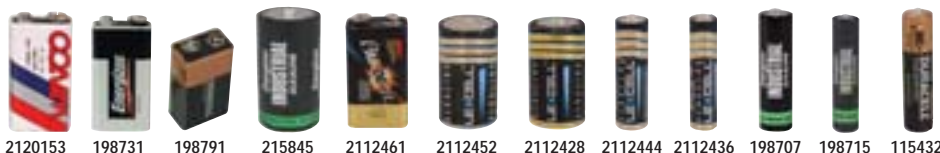

Part No.	Size	Min	Ea. Price
2112461	9V, Super Alkaline Lexcell®††	2	\$.98
2112452	1.5V, D-cell Lexcell®††	2	.87
2112428	1.5V, C-cell Lexcell®††	2	.81
2112444	1.5V, AA Lexcell®†	4	.20
2112436	1.5V, AAA Lexcell®†	4	.20



*Web Code: NBF

Blowout Prices

Part No.	Size	1	10
2120153	9-volt Winco	\$1.79	\$1.59
198731	9-volt Energizer®	2.05	1.85
198791	9-volt Duracell®	2.95	2.65
215845	1.5V D-cell Energizer®	1.15	1.05

Part No.	Size	Min	1	40	100
198707	AA Energizer®†	4	\$.79	\$.69	\$.65
198715	AAA Energizer®†	4	.69	.59	.55
115432	AAA Duracell®††	2	.69	.59	.49

† Sold in multiples of 4 †† Sold in multiples of 2

Silver Oxide and Zinc Chloride Batteries

*Web Code: XAB

Applications: personal computers, workstations, test equipment, feature telephones, copiers, fax machines, video scramblers/descramblers and remotes.

Part No.	Cross Ref.	Description	1	10
140783	357	Silver oxide, button, 175mAh	\$1.55	\$1.39
2119831	S736S	Silver oxide, button, 34mAh	1.25	1.09
2119849	S1131S	Silver oxide, button, 73mAh	1.35	1.19
2119857	S1142S	Silver oxide, button, 116mAh	1.45	1.29
2119890	ER6MSG	Zinc chloride, AA	.59	.55
2119822	ER03MSG	Zinc chloride, AAA	.69	.59
151095	GF6F22	Zinc chloride, 9V	1.35	1.19

NEW
MARKED IN PINK



Automatic Lead Acid Battery Chargers

- Safely charge and maintain lead acid batteries without supervision
- Safe for gel cell batteries
- Multi-stage charging circuit prevents batteries from overcharging
- High frequency MOSFET switching design
- Input voltage: 98 to 132VAC @ 50/60Hz
- Short-circuit, overload, and reverse polarity protection
- Analog amp meter
- Extends battery life
- Output banks: 3

*Web Code: ABC



Part No.	Mfr. Part No.	Output Volt.	Size (L"xW"xH")	Wt. (lbs.)	1	10
673416	SEC-1215A	13.5VDC @ 15A	8.5 x 8.4 x 3.3	4.8	\$145.95	\$131.95
673432	SEC-2415A	27.0VDC @ 15A	10.8 x 8.4 x 3.3	6.4	239.95	215.95

Panel Meters

0.6" High 3½ & 4½-Digit LCD Digital Panel Meters



- Input ranges: 200mV, 20V, 200V, 500V
- Accuracy: ±0.5%
- Supply voltage: 8-12VDC (recommend 9V battery P/N 151095, above left)
- Automatic polarity indication
- Input impedance: >100MΩ
- Size: 2.7"W x 1.7"H

*Web Code: WBU

Part No.	Cross Ref. No.	Description	1	10	25
108388	PM-428	3½-digit (no bezel, snap mount)	\$10.95	\$9.95	\$8.95
175951	PM-128	3½-digit (bezel, screw mount)	12.95	11.65	10.49
146835	PM-188BL	3½-digit (with backlight display)	14.95	13.45	11.95
123140	PM-328	4½-digit (bezel, screw mount)	29.95	26.95	24.25

Can not use in common ground applications

Analog Panel Meters

- Includes mounting hardware
- 316507: Includes current shunt

Part No.	Mfr. P/N	Range	Size (W"xH"xD")	1	10
316603	AVM6015	0 - 15VDC	2.4 x 1.8 x 1.3	\$9.95	\$8.95
316671	AVM7015	0 - 15VDC	2.8 x 2.4 x 1.4	9.95	8.95
316638	AVM6030	0 - 30VDC	2.4 x 1.8 x 1.3	9.95	8.95
316654	AVM7030	0 - 30VDC	2.8 x 2.4 x 1.4	9.95	8.95
316718	AVM60150	0 - 150VAC	2.4 x 1.8 x 1.3	9.95	8.95
316785	AVM60300	0 - 300VAC	2.4 x 1.8 x 1.3	9.95	8.95
315301	AIM60005	0 - 50µA	2.4 x 1.8 x 1.3	9.95	8.95
316523	AIM6050	0 - 50mA	2.4 x 1.8 x 1.3	9.95	8.95
316486	AIM60100	0 - 100mA	2.4 x 1.8 x 1.3	9.95	8.95
316558	AIM60500	0 - 500mA	2.4 x 1.8 x 1.3	9.95	8.95
316566	AIM60500	0 - 5A	2.4 x 1.8 x 1.3	9.95	8.95
316582	AIM705000	0 - 5A	2.8 x 2.4 x 1.4	9.95	8.95
316494	AIM6010A	0 - 10A	2.4 x 1.8 x 1.3	9.95	8.95
316507	AIM6030A	0 - 30A	2.4 x 1.8 x 1.3	12.95	11.65

*Web Code: YBQ



316603



316523

Drill Mountable Panel Meters

- Mount by simply drilling a single hole (7/32") and insert the threaded section of the panel meter
- Module size: 1.71"L x 0.84"W

Part No.	Mfr. Part No.	Description	Digit Ht.	Supply Volt.	Measurement Range	1	5	25
2113201	EMV-1125	4-digit, LCD volt/current meter	.50"	7.5-15VDC	200mV-20V/200µA-200mA	\$32.95	\$29.95	\$26.95
2095040	EMV 1200	3-digit, signal pwr'd, LCD voltmeter	.50"	3-50VDC	4-25VDC	33.95	30.95	27.95
2095058	EMT 1900	3½-digit, LCD thermometer	.50"	4-28VDC	14-122°F	33.95	30.95	27.95
2095074	EMC 1500	5-digit, LCD hour meter	.35"	5-27VDC	99999 hours	33.95	30.95	27.95
2095082	EMA 1710	Analog-style LCD panel meter	—	5-12VDC	0-1VDC	33.95	30.95	27.95

Multi-Function Graphics Display

Customize the SGD 24-M 2.4" color TFT graphics meter with a simple click of the mouse. Using Lascar's Panel Pilot Windows-based software downloadable from www.panelpilot.com select from a number of available meter styles previously provided by a traditional panel meter, choose colors, text labels, voltage input scaling and even display your company logo on power-up. Save all selections to the meter and computer, detach the unit and mount to your panel.

- Operating voltage: 4-30VDC
- Adjustable 0 to 40VDC input
- Screw terminal connections
- Programmable via USB interface
- Free Windows-based configuration software



PanelPilot

Part No.	Mfr. Part No.	Description	1	5	25
2115354	SGD-24-M	3½-digit, bargraph & analog style meter	\$94.95	\$86.95	\$79.95

*For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above

