

JAMECO BenchPro 100-Piece Professional Electronics Tool Kit

- Kit includes:
 - Soldering iron
 - 12 screwdrivers
 - 7-piece hex key set
 - Extractor
 - 4 Pliers
 - Adjustable wrench
 - Crimper/Stripper
 - 6-piece screwdriver set
 - 3-piece soldering aid kit
 - Desoldering pump
 - Multimeter
 - Tweezers
 - 5-piece file set
 - 10-piece wrench set
 - Voltage tester
 - 2 bottles cleaning liquid
 - Blade cutters
 - Cordless screwdriver kit (bits included)
- Aluminum case features removable pallets, surface-type locks, and black plastic handle
- Size: 18.0"L x 14.0"W x 6.0"H • Weight: 15.5 lbs.



Part No.	Description	1	5
242851	100-piece tool kit	\$199.95	\$159.95

Cabling Technician's Tool Belt Kit

Kit Includes:

- 66/110 blade punch down tool
- Probe pick and spudger
- Cable stripper
- Electrician's scissors
- Splicer's knife
- Mini screwdriver
- High quality nylon belt pouch



Part No.	Mfr. Part No.	1	5	25
2112250	TTK-5200	\$49.95	\$44.95	\$39.95

JAMECO BenchPro Automatic Wire Strippers

- Spring loaded handle
- Size: 7.0"L x 2.5"W
- Weight: 0.8 oz.
- Provide a clean strip without damaging conductor



Includes: Wire stopper for desired strip length

Part No.	Mfr. Description	1	5	25
2112284	BenchPro 10-24 AWG	\$8.95	\$7.95	\$6.95
175098	Various 8-22 AWG	16.95	15.49	13.95

JAMECO BenchPro Flat Cable Cutter

- Spring loaded handle
- Blade lock for safe storage
- Provides clean cut
- Size: 6.5" L x 2.0"W
- Weight: 5.6 oz.



Part No.	Description	1	5	25
2112241	Flat cable cutter	\$5.95	\$5.49	\$4.95

JAMECO BenchPro Heavy Duty Scissors

- Spring loaded handle
- Blade lock for safe storage
- Ergonomic handle
- Stainless steel tongs
- Suitable for fiber optic cable



Part No.	Description	1	5	25
2112313	Heavy duty scissors	\$5.95	\$5.49	\$4.95

JAMECO BenchPro UTP/STP Wire Stripper

- Quickly strips insulation without damaging wire
- Strips shielded and unshielded
- Strip 24 to 3 AWG (.5 - 6.2mm)
- Twisted pair cable
- Size: 3.5"L x 1.25"W



Part No.	Description	1	5	25
2112292	UTP/STP stripper	\$2.95	\$2.49	\$1.95

Hand Tools for Mini-Fit™ Jr.



304928: Accepts wire range from 14-24 AWG

Part No.	Mfr. Part No.	Description	1	5
304928	63811-1000	Crimp tool	\$49.95	\$44.95
304936	11-03-0044	Extraction tool	19.95	18.95

For all Your Wire and Cable needs see pages 58-61

5" Wire Cutter/Strippers

- Insulated handles
- Spring return
- Tempered steel cutting edge
- Size: 5.0"L x 3.0"W
- One-year warranty



78992: 10-30 AWG (screw adjustable)
 215889: 10-24 AWG (dial to adjust for wire gauge)

Part No.	Product No.	1	5	25	100
78992	HT108	\$4.49	\$3.95	\$3.49	\$2.95
215889	JE-2022C	3.95	3.69	3.29	2.95

*Cutters/Strippers — Enter Web Code BAK

H 5" Wire Cutter/Stripper

- Strips and cuts 20-24 AWG wires
- Spring loaded for easy use
- Cutter angled at 45° for use in tight places
- Insulated grips
- Size: 5.0"L x 3.0"W



Part No.	Mfr. Part No.	1	5	25	100
159274	HT1091	\$4.95	\$4.49	\$3.95	\$3.49

6" Wire Cutter/Strippers

- Plier nose
- Wire size markings, in AWG and mm
- Size: 6.0"L x 2.0"W



161226: Premium
 12-20 AWG stranded; 10-18 AWG solid
 161234: Premium
 16-26 AWG stranded; 14-24 AWG solid
 161218: Standard
 16-26 AWG stranded; 14-24 AWG solid
 Color: red

Part No.	Mfr. Part No.	Description	1	5
161226	ID45-215	Cushioned grips	\$15.95	\$14.95
161234	ID45-216	Cushioned grips	15.95	14.95
161218	ID45-121	Non-cushioned grips	14.49	12.95

H 6.6" Wire Stripper

- Wire stripper, cutter, steel wire cutter, and wire loop
- Scale: AWG and mm
- Strips and cuts wires from 20-30 AWG
- Size: 6.6"L x 2.0"W




Part No.	Mfr. Part No.	1	5	25
159291	HT5023	\$9.95	\$8.95	\$7.95

*Wire Strippers — Enter Web Code HAY

H 7-in-1 Wire-Handling Tools

- Wire stripper, wire cutter, steel wire cutter, pliers and wire loop
- Solderless crimping tool
- Scale: mm and inch
- Size: 6.6"L x 3.0"W

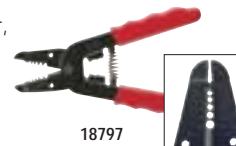

Part No.	Mfr. Part No.	Description	1	5	25
18797	HT1041	10-18AWG	\$4.95	\$4.49	\$3.95
127862	HT1042	16-26AWG	5.95	5.49	4.95
127871	HT1043	22-30AWG	5.95	5.49	4.95

Test/Tools

R² RapidRench Adjustable Ratcheting Socket Wrench

- Fits hundreds of SAE and metric fasteners
- Tighten or loosen with a flip of a switch
- Dial adjusts jaws to the exact size of the fastener
- Jaw capacity: 1/4" to 7/8" (6.35mm to 22.2mm)
- Rubberized comfort grip for extra control



Part No.	Mfr. Part No.	1	5
1943131	FR28SWMP	\$29.95	\$26.95

*Wrenches — Enter Web Code WEL

RapidSlide Adjustable Wrench

- Slide/control button on handle for fast, easy and accurate jaw adjustment
- SAE/metric adjustment markings on head
- 1" maximum jaw opening allows each tool to work with more fastener sizes



Part No.	Mfr. Part No.	1	5
1943123	AC8NKWMP	\$19.95	\$17.95

H Rotary Coax Cable Strippers

2 and 3 Blade

- 159119 (3 Blade):
 2 settings RG58/59/62
 • For cable sizes 4-10mm
 • Size: 4.2"L x 1.3"W
 • Color: black



- 159185 (2 Blades):
 4 settings RG58/59/62/174
 • For cable sizes 4-12mm
 • Size: 3.9"L x 0.7"W • Color: gray



Includes: Hex key wrench for adjusting blade

Part No.	Mfr. Part No.	1	5	25
159119	HT312B (3 blade)	\$9.95	\$9.45	\$8.95
159185	HT332D (2 blade)	12.95	11.95	10.95

For Electronic Starter Kit see page 153