

## T-Handle Reamer Tool

Excellent for aluminum chassis work

- For enlarging starter holes on panel mount components from 1/8" to 1/2" diameter
- T-handle for easy rotation of tool
- Handle: 3.3" long, tool: 5.3" long



Part No.	Description	1	10
151750	T-handle reamer	\$7.95	\$6.95

## 4-Piece Steel Tweezer Set




- 4 styles of stainless steel tweezers, one self-locking
- Ideal for picking up small components in hard-to-reach places

Part No.	Description	1	10	100
10735	4-piece tweezer set	\$5.95	\$5.49	\$4.95

\* Tweezer Sets — Enter Web Code FAA

## Tweezers

- 252929: Straight round tapered, fine-point tip, stainless steel
- 253092: Curved fine-point tip
- 252938: Self-closing reverse-action tweezers; medium point tip; stainless steel
- 253113: Fine-point tip, insulated, anti-static
- 252912: Straight fine-point tip

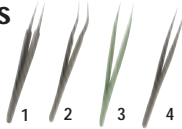

Part No.	Length	Photo	Price	10	100
252929	4.75"	1	\$2.95	\$2.49	\$1.95
253092	4.6"	2	\$2.95	2.49	1.95
252938	4.30"	2	\$2.95	2.49	1.95
253113	4.75"	3	\$2.95	2.49	1.95
252912	4.75"	4	\$2.95	2.49	1.95

## 4-Pc. Conductive SMD Tweezer Set



- 4 types of tweezers: fine point, flat head for 4mm SMD chip device, flat head for 8mm SMD chip device, sharp angled tip
- Each is 4.5" long

Part No.	Description	1	10
172638	4-piece tweezer set	\$9.95	\$8.95

## Vacuum Tweezers

Pick & place small parts of all kinds: glass slides, coins, optics, SMDs, film, etc.

- Size: 2.9"L x 0.6"W
- One-year warranty
- Includes: 5 pads sizes 0.14" to 0.4"; 5 straight tips and 2 pieces 45° angle tips



Part No.	Description	1	5
88268	Vacuum pick & place kit	\$39.95	\$36.95

## PLCC & DIP IC Extractors

\* Web Code: MAB

- Size: 4.0"L x 2.0"W



Part No.	Mfr. Part No.	Description	1	10	100
16766	HT103B	PLCC	\$3.95	\$3.49	\$2.95
16838	HT103A	DIP	1.65	1.49	1.25

## Anti-Static Heel Strap

- Discharges static without restricting your mobility
- Ground strap: 15.5"L



Part No.	Description	1	10	100
100328	Heel strap	\$5.95	\$5.49	\$4.95

## Anti-Static Wrist Strap

- Comfortable, adjustable black Velcro wrist strap
  - The coiled grounding cord has banana plug and alligator clips
  - Extended cord: 9' long
- Includes: 1MΩ resistor for added safety



Part No.	Description	1	10	100
34552	Wrist strap	\$6.95	\$6.49	\$5.95

## Anti-Static Work Mats

Make your work environment safe from static discharge! These mats are made of attractive semi-conductive vinyl that provide adequate discharging, yet will not short leads or pins.



Part No.	Dimensions	Wt. (lbs.)	1	10	100
10576	11.3" x 22"	0.7	\$8.95	\$7.95	\$6.95
10584	19.5" x 23.5"	1.1	13.95	12.49	10.95
236541	23.5" x 27.5"	1.4	25.95	22.95	19.95

\* Anti-Static — Enter Web Code XAA

## Field Service Static Kit

This mat folds easily to fit into a field service bag.

- 4 pocket for ESD safe storage
- 10' ground strap and 6' wrist strap share on one ground point
- Size: 2' x 3'



Part No.	Mfr. Part No.	1	5	25
2113720	8PK-AS07-1	\$17.95	\$16.49	\$14.95

## Conductive Anti-Static Bags and Foam

Don't get zapped!

Protect your investment with these inexpensive bags and ensure a safe work area with our conductive anti-static foam.

Part No.	Description	1	10	100
13864	24.0"L x 12.0"W x 0.25"H	*		
249519	4" x 6" anti-static bags	*	\$0.15	\$0.10
249527	5" x 7" anti-static bags	*	.19	.12
78650	8" x 10" anti-static bags	.49	.39	.29
13864	Anti-static foam	11.95	10.95	9.95

## 22"L Anti-Static Plastic DIP IC Storage Rails & Rubber Rail Stops

- 29516: .300" rail fits 8, 14, 16, 18, 20 and 22-pin ICs
- 29524: .600" rail fits 24, 28, 36 and 40-pin ICs
- 29583: Rubber stops used to plug plastic rail ends

Part No.	Cross Ref. No.	Description	1	10	100
29516	RIC20	.300"W rail	.. \$0.25	.. \$0.22	.. \$0.19
29524	RIC220	.600"W rail	.... \$0.29	.... \$0.25	.... \$0.19
29583	RRS	Rubber stop	.... *	.... \$0.07	.... \$0.05

## Standard Adjustable 3X Magnifying Lamp


- 4" Diameter lens
- Maneuverable 30" arm extension
- Lamp tilts & turns in any direction
- Uses 60W incandescent bulb (not included)
- Power requirement: 110VAC/60Hz
- 3-diopter lens • Weight: 2.9 lbs.



Part No.	Description	1	5
22710	Magnifying lamp	\$26.95	\$23.59

## 3X, 3-Bulb Magnifying Lamp

- Three 9-watt fluorescent compact bulbs
- Adjustable 3-diopter lens
- 7" x 4.5" rectangular lens
- 47" long arm
- 2 on/off buttons • UL listed
- Color: beige • Weight: 8.15 lbs.

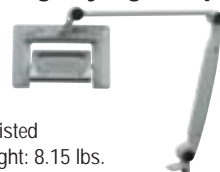

Part No.	Description	1	5
217517	Adj. magnifying lamp	\$89.95	\$84.95

## KLIP-ON Deluxe 3X Magnifying Lamps

Ideal for limited workspaces in home or office.

- High quality 3.5" Dia. glass lens w/ dust cover
- Heavy duty 2" spring loaded clamp
- Super bright 13 watt fluorescent bulb (6400 Kelvin) included
- 16" gooseneck-directs light in any directions
- Weight: 2.0 lbs.



Part No.	Cross Ref. No.	Color	1	5
1955044	LUX250W	White	\$34.95	\$31.49
1955052	LUX250B	Black	34.95	31.49

## Precision 5 Diopter Magnifying Lamp

- 40" arm extension
- 5 diopter lens
- 5" diameter lens
- Weight: 7.1 lbs.
- Power requirement: 110VAC/60Hz



Includes: 22W circuline fluorescent bulb

Part No.	Description	1	5
197456	Magnifying lamp	\$99.95	\$89.95

\* Magnifying Lamps — Enter Web Code DAW

## 3X Magnifying Lamps

- 5" Dia. lens • 45" extension arm
- Supplied w/ 22-watt circuline tube
- Extra strong, all-metal mounting base with electrical outlet
- New wire clip design permits easy installation
- Metal bulb holder for extra protection
- 3-diopter lens • Weight: 7.3 lbs.
- Power requirement: 110VAC/60Hz



Part No.	Description	1	5
100829	Black lamp	\$59.95	\$54.95
149981	White lamp	59.95	54.95

Large Volume Orders Require Special Pricing  
 Call us at 1-800-831-4242