


Weller® 25 & 40-Watt Marksman Home Project Kits

Perfect for beginners and hobbyists. Includes stand.


- Stainless steel barrel and heat/impact resistant handle
- Ideal for kits, radios and electronics
- Indicator light shows iron is on

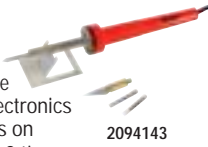

Part No.	Mfr. Part No.	Description	1	5
2094143	SP23LHPK	25W Iron kit	\$19.95	\$18.95
2094160	SP40LK	40W Iron kit	24.95	23.49

Weller® 100-Watt Soldering Iron

- "Closed loop" method of controlling max. tip temperature
- Nominal heat-up time with 700°F tip is 110 seconds
- 120VAC @ 60Hz input
- Length: 6" • Weight: 0.7 lbs.

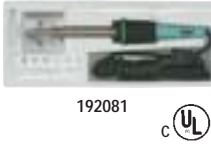

Includes: CT6F7 (0.375" screwdriver tip; 700°F)

Part No.	Mfr. Part No.	Description	1	5
192081	W100PG	Solder iron	\$64.95	\$59.95
192090	CT6F7	.375" screwdriver tip	6.95	6.29

Weller® 25 to 125-Watt Cordless Soldering Iron Kit

- Self-igniting & instant heat
- Adjustable temperature (25W to 125W)
- Auto switch off
- Visible gas level
- Additional tips can be special ordered
- 2 hours of heat on average tank setting



Includes: Soldering tool, hot blower tip, hot knife tip, 2.4mm and 4.8mm double flat tip, cleaning sponge, storage case and instruction manual

Part No.	Mfr. Part No.	Description	1	5
152207	PSI-100K		\$89.95	\$79.95

Weller® 8/11-Watt Battery Powered Soldering Iron

- Heats to working temperature in less than 15 seconds
- White LED light illuminates working surface
- Dual heat settings: 8 watts on low setting (850°F) or 11 watts on high setting (950°F)
- Co-molded grip for comfort grip and protective safety cap turns off power when placed on tool
- Over 150 intermittent solder joints with fresh batteries



Includes: Iron, tip, 4 "AA" batteries, lead free solder, and tip/wrench stand

Part No.	Mfr. Part No.	Description	1	5
1943060	BP860MP		\$23.95	\$19.95

30 to 100-Watt Soldering Kit

- Includes:
- 30W soldering iron
 - 100W soldering gun w/ extra tip
 - Manual desoldering pump
 - Mini third-hand board/component holder
 - Soldering aid tool
 - Lead solder
 - Size: 13.8"L x 11"W x 3"H



Part No.	Product No.	Weight	1	5
684596	GSR-600A	4.0 lbs.	\$35.95	\$29.95

WAHL® 25-Watt Cordless Soldering Iron

IsoTip® Power Pro Model #7904

- 900°F tip temperature
- LED indicator light
- Solders 200+ joints or up to 30 minutes of continuous soldering
- Iron performance equivalent to 25-watt iron • Weight: 1.1 lbs.



Includes: Iron, charging stand, battery pack and tips

Part No.	Description	1	5
132783	Power Pro cordless iron	\$69.95	\$64.95

*Soldering Irons — Enter Web Code QAS

MASTER 20 to 80-Watt Butane Soldering Iron Tool Kit

- Slide switch ignition system
- Adjustable temperature up to 1200°F
- 1.3 hrs of use per refill




Includes: Solder tip, heat tip, hot knife tip, shrink attachment, cap sponge, stand & case

Part No.	Description	1	5
2076615	Flameless heat soldering	\$84.95	\$78.95

Electric & Manual Desolder Pumps

- Easily disassembled for cleaning
 - Replacement tips available
- 19255: • UL listed
- One-hand operation
 - Size: 10.5"L x 1.0"Dia.
- 19166: Size: 7.8"L x 0.8"Dia.
- 1942139: Size: 13.3"L x 1.0"Dia.

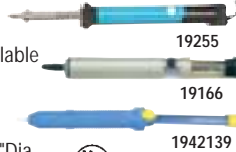

*Web Code: GAS

Part No.	Description	1	5
19255	Electric desolder pump	\$26.95	\$23.95
19166	Manual desolder pump	4.95	4.49
1942139	Manual desolder pump	8.95	7.95
19262	1 tip for 19255	3.95	3.49
22091	2 tips for 19166	4.49	3.95
307782	1 tip for DP100	2.49	1.95

Weller® 40-Watt Soldering Station

- Lighted on/off switch
- Adjustable power from 5 watts to 40 watts
- 120V @ 60Hz
- Temp. is electronically controlled from 350° to 850°F
- Size: 5.5"L x 4.5"W x 3.5"H • Weight: 1.9 lbs.




Includes: ST3 1/8" screwdriver tip and manual

Part No.	Mfr. Part No.	Description	1	5
146595	WLC100		\$59.95	\$54.95

Weller® Soldering Tips

 Replacement Tips for WLC100, WP25 & WP23




*Web Code: NAB

Part No.	Mfr. P/N	Description	1	5
146608	ST1	Screwdriver tip 1/16" ...	\$5.95	\$4.95
146616	ST3	Screwdriver tip 1/8" ...	5.95	4.95
192145	ST6	Screwdriver tip .031" ...	5.95	4.95
146624	ST7	Conical tip 1/32" ...	5.49	4.49

Weller® 42-Watt Controlled-Output Soldering Station

- Complete with macro style, low voltage, temp. controlled soldering iron
- Closed loop method of controlling maximum tip temperature for protection of temperature sensitive components
- 120VAC @ 60Hz input
- Power unit housing features impact resistant plastic for durability • Uses PT series tips
- Quick disconnect plug for soldering iron and lighted on/off switch • Weight: 4.0 lbs.
- Separate conductor grounds iron tip and terminates third pin of power cord • Size: 5.9"L x 4.5"W x 3.6"H

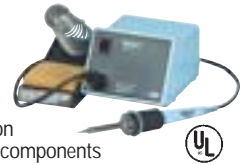

Includes: Soldering iron and PTA7 tip (below)

• Tips all .062"

Part No.	Mfr. P/N	Description	1	5
170552	WTCP	Solder station	\$144.95	\$136.95
192161	TC201T	Replacement iron	79.95	72.95
192170	PTA6	Screwdriver tip 600°F ...	3.95	3.49
192188	PTA7	Screwdriver tip 700°F ...	3.95	3.49
192196	PTA8	Screwdriver tip 800°F ...	3.95	3.49

*Soldering/Desoldering Stations — Enter Web Code GEJ

45-Watt Analog Display Soldering Station

Grounded Soldering Tip

- 150°C to 480°C (302°F to 896°F)
 - Fully grounded
 - Insulated ceramic heating element for rapid heat-up and heat recovery
 - Heater insulation exceeds 100MΩ
 - Zero voltage circuitry eliminating high voltage spike and magnetic field generation
 - Size: 4.1"L x 3.5"W x 3.5"H • Weight: 2.5 lbs.
- Includes: Manual, soldering iron w/ 1/32" tip, stand, tip cleaner and sponge



156814: Sharp conical chisel tip

156822: Conical chisel tip

NEW MARKED IN PINK

Part No.	Mfr. Part No.	Description	1	5
2114685	LF369D	45W station	\$59.95	\$54.95
156814	XYB01	1/32" tip	3.95	3.49
156822	XYB04	1/16" tip	3.95	3.49
134631	SP715	Sponge	2.95	2.59

Weller® 50-Watt Analog & Digital Display Soldering Stations

Innovative heater and sensor combination for quick heat-up and rapid temperature recovery.

- Tip temperature offset capability allows user to reset temperature readings to match tip size and style
- Wireless temp. lockout
- Auto power-down after 90 minutes of inactivity • Temp. accuracy: ±9.0°F
- Temperature range: 350°F to 850°F • ESD safe
- Size: 5.9"L x 4.5"W x 3.6"H • Weight: 4.0 lbs.



Includes: PES51 50W soldering iron with ETA tip, PH50 stand and sponge, and adjustment tool

Part No.	Mfr. Part No.	Description	1	5
217461	WES51	Analog	\$124.95	\$121.95
233533	WESD51	Digital	169.95	159.95
2082847	PES51	Soldering iron	38.95	37.95