

Powered Project Breadboards

- Solderless breadboard with 2420 tie points
- Power switch with light
- Outputs are short-circuit protected

Includes: Power cord

136259:

- Fixed power: +5V @ 1A; variable power: 0 to ±15VDC @ 500mA
- Edge plate for non-DIP size components
- Input power: 120/220VAC @ 50-60Hz (switchable)
- Replacement fuse: P/N 103908, pg 41
- One-year warranty
- Breadboard size: 7.4"L x 6.8"W
- Back panel has ground terminal

1942163:

- Input power: 110VAC or 220VAC @ 50-60Hz (switch selectable)
- Triple output power supply: fixed 5VDC @ 1A; 0 to +16VDC @ 500mA (adjustable); 0 to -16VDC @ 500mA (adjustable)
- Grounded case
- Overload protection
- Fuse protection
- Lighted power switch

Part No.	Description	Overall Size	Wt. (lbs.)	1	5
136259	15VDC @ 500mA	9.8"L x 8.0"W x 2.6"H	6.8	\$175.95	\$159.95
1942163	5VDC @ 1A & 16VDC @ 500mA	10.3"L x 8.8"W x 3.3"H	6.0	99.95	89.95

*Web Code: XAT



136259



1942163



Resistance & Capacitance Decade Substitution Boxes

Wide-range decade substitution boxes for product design or calibration checks.

- Light durable construction
- Case may be grounded separately
- Three binding posts permit isolated substitutions
- Size: 4.7"W x 5.7"H x 1.4"D • Wt: 0.7 lbs.
- 211668: 1% resistance substitution from 1Ω to 11.111110MΩ
- 7 decade ranges of resistance
- Values can be changed in 1Ω increments • @ 3 watts
- 211676: 5% capacitance substitution from 100pF to 11.111μF
- 5 decade ranges of capacitance • @ 50VDC



Part No.	Description	1	5
211668	Resistance	\$99.95	\$89.95
211676	Capacitance	129.95	119.95



Bug Boxes

- Box size: 4.9"L x 3.3"W x 0.6"H
- Anti-static plastic • 3 compartments
- Fits in bug cage (P/N 11332, below)
- Designed to store all types of components

2115661/2115670: 30 molded compartments

Part No.	Description	1	10	100
11375	3 ver. & 3 horiz. dividers	\$6.95	\$6.49	\$5.95
2115661	3 ver. & 3 horiz. (clear)	4.95	4.49	3.95
2115670	3 ver. & 3 horiz. (white)	4.95	4.49	3.95



11375

 
NEW MARKED IN PINK



Bug Tray

- 10 compartments
- 3.2"L x 0.4"W x 0.4"H ea.
- Tray size: 4.8"L x 3.6"W x 0.5"H
- Fits in bug cage (P/N 11332, below)

Part No.	Description	1	10	100
11800	Divided bug tray	\$4.95	\$4.49	\$3.95



Blue P/N = Limited Quantity




Bug Cage

- Holds bug boxes or trays
- Modular and interlocking
- Case size: 5.0"L x 3.9"W x 5.1"H

Blue Part No. = Limited Quantity Available

Part No.	Description	Color	1	10	100
11332	Bug cage	Blue	\$8.95	\$7.95	\$6.95

 

Boxes/Trays not included



Plastic Fliptop Case for SMDs

- 128 compartments
- 8 rows x 16 columns grid
- Fliptop openings on each bin
- Padded cover locks bins closed
- Perfect match to store P/N 156882 SMD resistor assortment, pg 53

Includes: Labels for each bin

Part No.	Size (L" x W" x H")	1	10
164267	11.0 x 8.3 x 1.7	\$49.95	\$44.95



JAMECO EXCLUSIVE

Plastic Fliptop Boxes

- Clear plastic box with a clear plastic lid and removable dividers
- 100256: Size: 8.4"L x 4.5"W x 1.4"H
- 148902: Size: 10.2"L x 4.7"W x 1.6"H
- 2095955: Size: 7.7"L x 5.3"W x 1.4"H
- 11 individual rounded compartments

Part No.	Compartment	1	10	100
100256	18 (1.4" x 1.5" each)	\$2.29	\$1.95	\$1.79
148902	12 (1.7" x 2.3" each)	3.95	3.49	2.95
2095955	11 (10-1.75"x1.5", 1-3.5"x1.5")	2.49	2.29	1.95




100256



Component Cabinets



319600

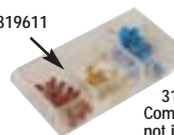

Drawer (319601) Divider (319611)

- 319600:
 - Drawer can be divided into 3 sections (clear)
 - Wall mountable cabinet (ABS black)
 - Cabinet size: 6.0"D x 14.7"W x 7.4"H
- Includes: 20 clear plastic drawers, 20 dividers and 30 adhesive I.D. labels
- 319601: 5.5"L x 2.7"W x 1.5"H; 319611: 2.5"W x 1.2"H
- 2108605:
 - Counter-top design (ABS blue)
 - Cabinet size: 7.0"D x 17.625"W x 9.75"H
- Includes: 14 clear plastic drawers in 3 sizes: 10 ea. 6.375"L x 3.375"W x 1.5"H, 3 ea. 6.375"L x 8.75"W x 1.5"H, 1 ea. 6.375"L x 8.75"W x 3.25"H and 20 adhesive I.D. labels

319601 Components not included



2108605

Part No.	Description	1	10	100
319600	20-drawer cabinet	\$16.95	\$15.49	\$13.95
2108605	14-drawer cabinet	24.95	22.95	19.95
319601	Drawer for cabinet	.49	.45	.39
319611	Divider for cabinet	*	.12	.10

* Order in multiples of 10



Aluminum and Black Phenolic Boxes with Cover



Die Cast Aluminum Phenolic Boxes w/ Cover (BBE)

*Web Code: PDC

Part No.	Mfr. Part No.	Type	Size (L" x W" x H")	Connector Types (A - B)	1	5	25
2113797	3751	Mini	1.13 x 1.50 x 0.88	BNC(F) - BNC(F)	\$29.95	\$28.95	\$27.95
2113800	2391	A	1.13 x 2.25 x 0.88	BNC(M) - BNC(F)	27.95	26.95	25.95
2113834	3230	B	1.38 x 2.25 x 1.13	BNC(F) - BNC(F)	24.95	23.95	22.95
2113826	3231	B	1.38 x 2.25 x 1.13	BNC(F) - BNC(M)	29.95	28.95	27.95
2114280	2902	C	4.25 x 2.64 x 1.71	BNC(F) - BNC(F)	39.95	38.49	36.95
2113842	3603	D	3.00 x 2.63 x 1.65	BNC(F) - BNC(M)	37.95	36.95	35.95

Black Phenolic Box w/ Cover

Part No.	Mfr. Part No.	Size (L" x W" x H")	Connector Type	1	5	25
2113851	2259	1.44 x 1.75 x 0.69	Post, double binding	\$27.95	\$26.95	\$25.95

*For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above