

Enclosures & ShapeLock Prototyping Compound

3 LEVELS OF SAVINGS
NAME BRANDS **HOUSE BRANDS** **FACTORY OVERRUN**

JAMECO ValuePro

Enclosures


The prototype builder boards on pg 175 are designed to fit into our ABS plastic and aluminum enclosures, metal cabinets and heavy-duty instrument cases. The pre-cut boards have 2 or 4 mounting holes compatible with the PC board mounting hardware listed on pg 175 (P/N 106551).

Board description: Laminated glass epoxy 1/16" thick fire retardant per FR-4 specs. Copper-clad and solder mask one side. Drilled holes: .035" diameter on .080" square pad. Pads spaced on .10" x .10" grid.

See page 55 for Knobs and 108 Hardware

JAMECO EXCLUSIVE

*Web Code: UAL

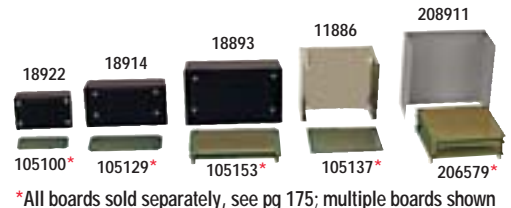

*All boards sold separately, see pg 175; multiple boards shown

ABS Plastic Enclosures

Lid for precision fit (adds 0.4" height). Complete with four screws and lid. All sizes below are interior dimensions.

Part No.	Cross Ref. No.	Size (L x W x D)	1	10	50	100
18922	H2855	3.1" x 2.0" x 0.9"	\$3.49	\$3.19	\$2.89	\$2.49
18914	H2853	4.9" x 2.5" x 1.5"	3.95	3.59	3.19	2.75
18893	H2851	6.0" x 3.5" x 1.9"	4.95	4.49	3.95	3.49
18906	H2852	7.5" x 4.3" x 2.3"	7.49	6.79	5.95	5.49

Die-Cast Aluminum Enclosures

Made from aluminum, an excellent heat-sink, these cases are great for high temp circuits (up to 600°C). Includes screws.

Part No.	Cross Ref. No.	Size (L x W x D)	1	10	50	100
11957	B5002	3.9" x 2.0" x 1.0"	\$5.95	\$5.49	\$4.95	\$4.49
11965	B5004	4.7" x 2.4" x 1.6"	8.95	8.29	7.49	6.59
11973	B5006	7.5" x 4.3" x 2.4"	15.95	14.49	12.95	11.49

Aluminum Enclosures

The enclosure comes in two pieces which slide together.

Part No.	Cross Ref. No.	Size (L x W x D)	1	10	50	100
11870	H2300	4.0" x 2.0" x 2.8"	\$5.95	\$5.49	\$4.95	\$3.95
11886	H2320	5.0" x 4.0" x 3.0"	8.95	7.95	6.95	5.95
11894	H2335	7.0" x 6.2" x 4.6"	10.95	9.95	8.95	7.95

Metal Enclosures

- Mounting screws and rubber feet included
- Glossy black textured steel top cover and ivory aluminum base

Part No.	Cross Ref. No.	Size (L x W x D)	1	10	50	100
208901	B2741A	4.0" x 3.3" x 2.2"	\$5.95	\$5.49	\$4.95	\$4.49
208911	B2743A	5.9" x 5.3" x 3.0"	8.95	7.95	6.95	6.25
209350	B2746A	6.3" x 7.8" x 2.5"	9.95	8.95	7.95	6.95
208929	B2744A	7.3" x 6.3" x 2.8"	9.95	8.95	7.95	6.95
209358	B2747A	7.5" x 9.8" x 3.2"	14.95	13.49	11.95	10.95

ABS Heavy-Duty Instrument Cases

P/N 18877 includes ventilation and speaker sound slots.

Part No.	Cross Ref. No.	Size (L x W x D)	1	10	50	100
18869	H2505	7.9" x 6.3" x 2.5"	\$7.95	\$7.29	\$6.59	\$5.95
18877	H2507	10.0" x 7.5" x 3.1"	8.95	7.95	7.49	6.95

ABS Enclosures w/ Clear Tops

Includes screws for mounting boards, rubber gasket for a tight seal on your equipment & drilled holes for mounting.

Part No.	Cross Ref. No.	Size (L x W x D)	1	10	50	100
141832	203C1	4.9" x 3.4" x 2.4"	\$8.95	\$7.95	\$7.49	\$6.95
141841	203D1	6.5" x 3.4" x 2.2"	9.95	8.95	8.49	7.95
141859	203F1	7.3" x 5.7" x 3.0"	11.95	10.95	9.95	8.95

SERPAC

Specialty Enclosures

*Web Code: TBY

A Series — with PCB Boss Mounts

- 4-piece design
- Interchangeable end panel
- 4-insert areas for customized I-plates

Part No.	Mfr. Part No.	Color	Batt. Holder	Size (L" x W" x H")	1	10	100
373456	A-42-BK	Black	None	7.12 x 5.00 x 1.62	\$14.49	\$12.95	\$11.49
373608	A-42-9V-BK	Black	1-9V	7.12 x 5.00 x 1.62	12.95	11.95	10.95

C Series — with Pinch-Fit for PCBs

- Simple 2-piece design
- 2-insert areas for customized I-plates

Part No.	Mfr. Part No.	Color	Size (L" x W" x H")	1	10	100
675331	C-4-BK	Black	2.13 x 1.38 x 0.58	\$2.95	\$2.69	\$2.39
694567	C-8-TR-RD	Red	2.40 x 1.85 x 0.93	3.95	3.49	2.95

H Series — Handheld with Built-in Battery Holder

- Ergonomic handheld design
- 5-insert areas for customized I-plates

Part No.	Mfr. Part No.	Color	Batt. Holder	Size (L" x W" x H")	1	10	100
374635	H-65-9V-BK	Black	1-9V	4.94 x 2.75 x 0.94	\$9.95	\$8.95	\$7.95
374942	H-67-9V-BK	Black	1-9V	4.94 x 2.75 x 1.28	8.95	7.95	6.95
374601	H-75-4AA-BK	Black	4-4A	7.20 x 3.65 x 1.20	13.95	12.49	11.95

S Series — Two-piece Standard Enclosures

- 2-piece design
- 2-insert areas for customized I-plates

Part No.	Mfr. Part No.	Color	Batt. Holder	Size (L" x W" x H")	1	10	100
675454	110-I-BK	Black	None	3.61 x 2.27 x 1.01	\$3.95	\$3.49	\$2.95
675462	111-BK	Black	None	3.61 x 2.27 x 1.51	4.49	3.95	3.49
675569	211-BK	Black	1-9V	4.10 x 2.60 x 1.51	4.49	3.95	3.49
675489	131-BK	Black	None	4.38 x 3.25 x 1.51	5.95	5.49	4.95
675577	231-BK	Black	1-9V	4.38 x 3.25 x 1.51	4.95	4.75	4.49
675500	151-BK	Black	None	5.63 x 3.25 x 1.51	6.95	6.29	5.59
675593	251-BK	Black	1-9V	5.63 x 3.25 x 1.51	7.95	7.29	6.49
675518	153-BK	Black	None	5.63 x 3.25 x 2.51	6.95	6.29	5.59
675526	171-BK	Black	None	6.88 x 4.88 x 1.51	9.95	8.95	7.95
675534	172-BK	Black	None	6.88 x 4.88 x 2.01	7.95	7.49	6.95
675542	173-BK	Black	None	6.88 x 4.88 x 2.51	10.95	9.95	8.95
675551	193-BK	Black	None	9.50 x 6.34 x 2.51	15.95	13.49	11.95

† Insert on top is recessed 0.015" on all models designated with an "I"

⊕ Blue Part No. = Limited Quantity Available

Ⓡ RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 197.



Please Note: Images used are representative. Color and shapes may vary by model.

M Series — Handheld with Built-in Battery Holder

* Translucent

- Streamlined handheld design
- 5-insert areas for customized I-plates

Part No.	Mfr. Part No.	Color	Size (L" x W" x H")	1	10	100
694815	M-6-TR-GY	Gray*	4.15 x 2.40 x 0.85	\$9.95	\$8.95	\$8.49
694807	M-6-TR-GR	Green*	4.15 x 2.40 x 0.85	11.95	10.95	9.95

R Series — Waterproof Cases to 30 Feet

- Dustproof, corrosion proof, airtight and UV protected with lifetime guarantee
- Auto pressure purge valve, secure lock holes, nut & bolt security & foam-filled

Part No.	Mfr. Part No.	Color	Size (L" x W" x H")	1	10	100
675614	R-120F	Black	7.6 x 5.0 x 2.2	\$19.95	\$17.95	\$15.95
675622	R-300F	Black	9.59 x 7.42 x 3.98	44.95	39.95	35.95

SHAPELOCK Re-Usable Prototyping Compound

"Shape-then-lock" Design Plastic

Build your invention now – without machine tools. Create super-strong custom parts, prototypes, molds, servo brackets, robot housings, sculptures, science projects, and more.

- Melts at 160°F
- Safely hand moldable
- Becomes rigid at room temperature
- Non-toxic, light weight and paintable



Part No.	Mfr. Part No.	Description	1	5
2112495	01-250	250 gram bag	\$14.95	\$13.49
2112508	01-500	500 gram bag	24.95	22.95