

Mice & Mouse Pads


*Web Code: MCM



Part No.	Manufacturer	Mfr. Part No.	Type	Interface	Description	Size (L" x W" x H")	1	10	25
685943	Dell	OW7751	Mech. Ball	USB	3-button with scroll, black	4.8 x 2.5 x 1.5	\$7.95	\$6.95	\$6.25
687746	Cherry	M-5000	Optical	USB-PS/2	3-button with scroll with PS/2 to USB adapter, black	4.6 x 2.6 x 1.5	7.95	6.95	6.25
265471	—	—	Optical	USB	Mini optical mouse	3.7 x 2.2 x 1.3	9.95	8.95	7.95
305082	IOne	Libra-90	Trackball	PS/2	PS/2 trackball with USB adapter, black	5.6 x 4.7 x 1.9	24.95	22.95	19.95
2006650	IOne	MSM9UP-BLK	Optical	USB-PS/2	3-button with scroll, black	4.5 x 2.3 x 1.5	8.95	7.95	6.95
2006668	IOne	MSM9UP-WHT	Optical	USB-PS/2	3-button with scroll, white	4.5 x 2.3 x 1.5	8.95	7.95	6.95
265447	BenchPro	32022378	Optical	PS/2	Wireless, 5 button optical scrollpro w/ PS/2 to USB adapter	4.9 x 3.0 x 1.6	16.95	15.95	14.95
121363	—	KP-01	Mouse pad	—	Mini mouse pad, blue	7.0 x 5.5 x 1.0	.69	.59	.49
1951001	—	MP-ATT	Mouse pad	—	Mouse pad (2" x 3.5"; 2.75" x 5" window slots)	9.5 x 7.5 x 1.2	.69	.59	.49

*Web Code: LBU

Keyboards & Keypads

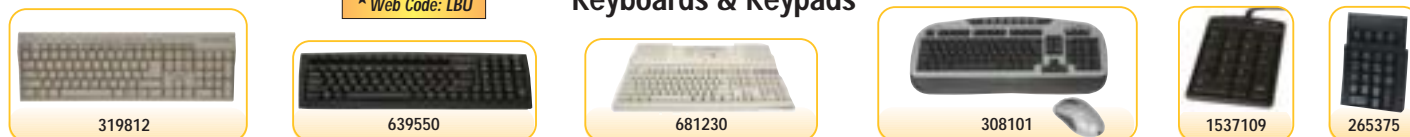

Part No.	Mfr.	Mfr. Part No.	Interface	Description	Size (L" x W" x H")	Wt. (lbs.)	1	10	25
455603	Powmax	KM-2501	PS/2	104-key soft touch w/ multimedia & 12 function keys.	17.5 x 6.0 x 1.2	1.8	\$7.95	\$6.95	\$5.95
319812	PC Concepts	iCIA	PS/2	107-key soft touch keyboard w/ programmable function keys, software included	17.5 x 5.7 x 0.8	1.8	7.95	6.95	6.25
354950	Compaq	KB-9965	PS/2	107-key soft-touch keyboard w/ 12 function keys	18.5 x 6.5 x 1.4	1.3	4.95	4.49	3.95
639550	IOne	Scorpius-2KB	PS/2	103-key soft touch keyboard, Windows® 98SE/2000/ME/XP compatible (black)	15.9 x 6.5 x 1.3	2.1	39.95	35.95	31.95
681230	NMB	RT915CTW	PS/2	104-key tactile keyboard w/ 12 function keys w/ built-in speakers	18.5 x 10.0 x 3.2	2.5	9.95	8.95	7.95
454483	Powmax	HB5103	PS/2	Black 3-in-1 internet kit 104-key optical mouse, speakers	17.1 x 6.12 x 1.0	2.24	12.95	11.49	10.95
319661	IOne	Gemini-M1	PS/2	104-key soft touch wireless keyboard w/ 12 multimedia function keys and 2-butt optical mouse, batteries included	17.6 x 7.5 x 1.6	2.2	12.95	11.49	9.95
308101	Labtech	967360-0403	PS/2	104-key wireless RF keyboard and 3-button optical scroll-mouse multimedia hot-keys	18.0 x 8.7 x 1.6	4.5	26.95	24.95	22.95
1537109	Arctic	25551	USB	18-key tactile keypad	4.3 x 3.0 x 0.5	0.2	12.95	11.49	9.95
265375	IOne	Scorpius-22RB	Serial	22-key tactile keypad w/ 2-key rollover and auto repeat function	6.2 x 4.2 x 1.3	0.8	39.95	35.95	31.95

Blue Part No. = Limited Quantity Available

CPU Heat Sinks with Fan

*Web Code: MBG

Part No.	Description	Size (H" x W" x D")	1	10
684748	Heat sink w/ fan, socket 7 Pentium®	1.02 x 2.60 x 2.30	\$2.95	\$2.65
319185	Heat sink w/ fan, socket 7 PIII	1.40 x 2.62 x 2.30	3.75	3.49
1945313	Heat sink w/ fan, Pentium® 75-133MHz	2.07 x 2.05 x 1.43	4.95	4.49
206244	Heat sink w/ dual fan, SECC II Pentium®	1.24 x 1.96 x 5.25	7.95	6.95
319951	Heat sink w/ dual fan, for PIII slot 1	2.00 x 4.90 x 8.50	5.95	5.49
661087	Heat sink w/ fan, socket 370 PIII	2.36 x 2.19 x 1.54	5.95	5.49
645482	Heat sink w/ fan, socket 370 PIII	1.30 x 2.05 x 1.97	11.95	10.95
190545	Heat sink w/ fan, socket 370 PIII	2.00 x 2.32 x 2.37	10.95	9.95

Legacy 3.5" Hard Disk Drives

*Web Code: SAW

Part No.	Capacity	Description	Warranty	1	10
151036	3.2GB★	EIDE/Ultra DMA33	1 year	\$34.95	\$31.45
151044	4.3GB★	EIDE/Ultra DMA33	1 year	49.95	44.95
146333	2.5GB★	EIDE/FAST ATA-2	1 year	29.95	26.95
124978	1.27GB★	IDE	1 year	29.95	26.95

★ Pull = Extra Savings

Disk Drive Mounting Rails

- AT and compatibles
- 8 mounting holes
- Includes all necessary mounting hardware

Part No.	Description	Wt. (lbs.)	1	10
34323	Mounting rails (2)	0.04	\$1.95	\$1.49

3.5" Hard Drive Bracket Short

Part No.	Product No.	Color	*Web Code: SDW	1	10
1950745	G/S435	Silver		\$4.95	\$4.49

*Video Text Modules Available Online — Enter Web Code RAJ

Monitor/Mouse/Keyboard Cable

HDDDB15 male/female for monitor, 5-pin DIN male/female for keyboard and DB9 male/female for mouse.

Part No.	Product No.	Length	1	5
141284	G/S(KVM062)	6'	\$9.95	\$8.95

Replacement Switches for AT-Style Computer Cases

PC Pushbutton Switch

- Contacts rated at 250VAC • Current: 8A
- Alternate action double pole switch
- UL/CSA/VDE approved • Size: 0.9"L x 0.7"W x 0.9"D

Part No.	Product No.	1	10	100
174238	PSD-1-2S8	\$1.49	\$1.25	\$0.95

PC Rocker Switch

- For mini-tower cases
- Contacts rated at 250VAC
- UL/CSA approved
- Current: 10A
- DPST
- Size: 0.9"L x 1.2"W x 1.4"D

Part No.	Product No.	1	10	100
127028	GRK-618A	\$1.49	\$1.25	\$0.95

Business Card CD-R Kit

Differentiate yourself or your business from others. This kit includes 12 50MB capacity CD-R and sleeves, 16 labels and label design software. A great way to promote your business in trade shows and exhibits. Easy to carry and cost-effective.

Part No.	Description	1	10
249308	Do-It-Yourself Business Card CD-R kit	\$2.49	\$2.25

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 197.