

# HDMI Cables, Adapters, Audio Plugs & Jacks


3 LEVELS OF SAVINGS  
**NAME BRANDS** **HOUSE BRANDS** **FACTORY OVERRUN**

JAMECO ValuePro

## HDMI Cables & Adapters

\*Web Code: DEM

High Definition Multimedia Interface (HDMI) is the industry supported, uncompressed, all digital audio/video interface. HDMI provides an interface between any audio/video source, such as set-top box, DVD players, A/V receivers, audio/video monitors, DTV, HDTV, and plasma monitor.

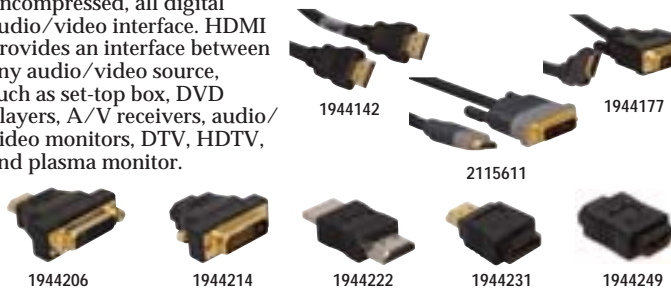

Part No.	Product No.	Description	1	5	25
1944142	10HM-01128-01	Male to male, 1 meter	\$10.95	\$9.95	\$8.95
1944151	10HM-01128-02	Male to male, 2 meters	12.95	11.49	9.95
1944169	10HM-01128-05	Male to male, 5 meters	17.95	15.95	14.49
2115611	AV22400B-12	HDMI M to DVI M 12 feet	14.95	13.49	11.95
1944177	10HM-15128-01	Male to DVI-D single link, 1 meter	9.95	8.95	7.95
1944185	10HM-15128-02	Male to DVI-D single link, 2 meters	11.95	10.95	9.95
1944193	10HM-15128-05	Male to DVI-D single link, 5 meters	16.95	15.25	13.75
1944206	30HM-15228-MO	HDMI M to DVI F video adapter	8.95	7.95	6.95
1944214	30HM-15328-MO	HDMI F to DVI M video adapter	8.95	7.95	6.95
1944222	30HM-01100	M to M HDMI gender changer	7.49	6.95	6.49
1944231	30HM-01200	F to M HDMI gender changer	7.49	6.95	6.49
1944249	30HM-01400	F to F HDMI gender changer/coupler	7.95	7.25	6.49

## Stereo, Phone, Audio Plugs & Jacks

\*Web Code: AJS

Interconnects

Part No.	Manufacturer	Product No.	Fig.	Description	Dimensions (mm)	1	10	100
297297	Switchcraft	850X	1	2.5mm mono phone, audio plug, black plastic	25.8L x 6.35 Dia.	\$3.49	\$3.15	\$2.79
281869	Switchcraft	750	2	3.5mm mono audio plug, plastic	41.5L x 5.7 ID	2.95	2.65	2.39
297060	Switchcraft	170	3	1/4" commercial phone plug, metal	69.7L x 17.46 Dia.	5.95	5.49	4.95
281754	Switchcraft	250	4	1/4" mono phone audio plug, plastic	73.7L x 7.6 ID	3.45	3.09	2.79
281762	Switchcraft	267	5	1/4" commercial phone plug, black plastic	73.7L x 7.6 ID	4.95	4.49	3.95
281789	Switchcraft	297	6	1/4" stereo phone audio plug, metal	73.7L x 7.6 ID	4.95	4.49	3.95
297123	Switchcraft	236	7	1/4" stereo phone audio plug, rt. angle, cable mnt.	46.4 x 15.9 ID	6.95	6.25	5.65
281771	Switchcraft	280	8	1/4" mono phone audio plug, metal	73.7L x 7.6 ID	3.85	3.49	3.15
229876	ValuePro	JR0101BLK	9	RCA plug, metal (black stripes)	61.7L x 7.0 ID	1.95	1.75	1.49
229868	ValuePro	JR0101R	9	RCA plug, metal (red stripes)	61.7L x 7.0 ID	2.25	1.95	1.75
230287	ValuePro	JR0101Y	10	RCA plug, yellow housing, gold plated	61.7L x 7.0 ID	1.49	1.25	1.09
229921	ValuePro	JR1625BLK	11	RCA plug, plastic, black (5 pk)	51.5L x 5.0 ID	1.45	1.29	1.15
229930	ValuePro	JR1625R	12	RCA plug, plastic, red (5 pk)	51.5L x 5.0 ID	1.45	1.29	1.15
281800	Switchcraft	3502	13	RCA phone plug, metal	33.8L x 5.0 ID	1.95	1.75	1.59
281818	Switchcraft	3502A	14	RCA phono audio plug, nickel	42.4 x 7.3 ID	2.25	1.95	1.75
281834	Switchcraft	41	15	3.5mm audio jack	7.8L x 5.9 Dia.	1.85	1.69	1.49
2114562	Adam Tech	ASJ-40-4A	16	3.5mm stereo jack, PCB mount, open	9.0H x 11.6W x 37.0L	1.15	1.05	.95
2114571	Adam Tech	ASJ-41-5	17	3.5mm stereo jack, PCB mount, closed	38.5H x 12.6L	1.59	1.45	1.35
568392	Switchcraft	35R4PC4BH3	18	3.5mm stereo jack, rt. angle horz., threaded	6.0H x 11.0W x 8.0L	1.49	1.35	1.19
1766180	Switchcraft	35R4PC4BHN2	18	3.5mm stereo jack, rt. angle horz., non-threaded	5.0H x 12.0W x 15.0L	1.69	1.49	1.35
2081334	Shogyo	354-3PY	18	3.5mm mono jack, rt. angle horz., non-threaded	6.1H x 11.9W x 12.0L	1.09	.89	.69
2100291	Shogyo	354-PY (CT)	19	3.5mm mono jack, rt. angle horz., threaded	6.45H x 11.7W x 14.3L	1.19	.99	.79
2081772	Kycon	ST3120-3-WHT	20	3.5mm stereo jack, rt. angle horz., non-threaded	10.45H x 12.0W x 6.8L	.49	.45	.39
1766198	Switchcraft	35R4PC4BV4	21	3.5mm stereo jack, rt. angle ver., threaded	12.3H x 8.1W x 14.0L	1.75	1.59	1.45
2095373	Various	HTJ-035-22D	22	3.5mm mono jack, rt. angle horz., non-threaded, blk.	10.45H x 10.0W x 14.0L	.99	.89	.79
2095437	ValuePro	J355W	23	3.5mm mono audio jack	10.1H x 8.4W x 17.6L	1.19	.99	.79
2081238	Shogyo	SCJ330	23	3.5mm mono audio jack	10.6H x 9.0W x 21.7L	1.95	1.75	1.49
281738	Switchcraft	11	24	1/4" mono phone audio jack	12.8L x 9.1 Dia.	1.85	1.69	1.49
296892	Switchcraft	12A	25	1/4" mono phone audio jack, metal	31.7L x 9.4 Dia.	1.79	1.59	1.45
296905	Switchcraft	13B	25	1/4" mono phone audio jack, metal	30.6L x 9.4 Dia.	2.95	2.79	2.65
281746	Switchcraft	12B	25	1/4" stereo phone audio jack	14.7L x 9.1 Dia.	1.95	1.79	1.59
2120209	ValuePro	STJ-.25	26	1/4" stereo phone audio jack, shielded, threaded	20.8L x 16.7W x 16.5H	1.69	1.49	1.35
1581564	Keystone	901	27	RCA jack, PCB mount, right angle, black	11.8H x 10.6W x 6.8L	.49	.45	.39
220581	ValuePro	KY-006-1(W)	27	RCA jack, PCB mount, white	11.2H x 14.2W x 12.2L	.65	.59	.55
220556	ValuePro	KY-006-1(R)	27	RCA jack, PCB mount, red	11.2H x 14.2W x 12.2L	.65	.59	.55
220572	ValuePro	KY-006-1(B)	27	RCA jack, PCB mount, black	11.2H x 14.2W x 12.2L	.39	.35	.25
220564	ValuePro	KY-006-1(Y)	27	RCA jack, PCB mount, yellow	11.2H x 14.2W x 12.2L	.39	.35	.29
2076359	Various	AJ842G3	28	RCA jack, PCB mount, rt. angle, red/white/yellow (3)	40.6H x 22.9W x 21.6L	.59	.55	.49
2076332	Various	SCJ-0358-YLW	29	RCA jack, PCB mount, yellow	9.9H x 19.1W x 13.0L	.45	.35	.25
169502	Various	SCJ-0358-BLK-R	29	RCA jack, PCB mount, black	10.2H x 21.6W x 12.7L	.55	.49	.45
319249	Velleman	CA066	30	RCA jack, 2 pair stereo, panel mount, red/white	73.7H x 12.2W x 24.9L	.95	.85	.75
159485	Various	CS7021-DN-BLK-R	31	RCA jack, panel mount, black	21.3W x 9.7H	.95	.85	.75
172340	Various	CS7021-DN-RD-R	31	RCA jack, panel mount, red	21.3W x 9.7H	.85	.75	.69



† Closed circuit

**JAMECO ELECTRONICS** Product Search:

### Quick and Easy Search

Our enhanced website offers thousands of datasheets and photos to assist you in finding the products you need.

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 197.