

Solderless Terminals

3 LEVELS OF SAVINGS
 NAME BRANDS | HOUSE BRANDS | FACTORY OVERRUN



Terminal Blocks

NEW
 MARKED IN PINK


For detailed specifications, please see our website at www.Jameco.com



*Web Code: XBD

Part No.	Mfr.	Mfr. Part No.	Fig.	Term.	Terminal Spacing	Description	1	10	100
2094506	OST	OSTTE020161R	1	2	0.138"/3.5mm	Top screw	\$.29	\$.25	\$.19
2094522	OST	OSTTF020161R	2	2	0.138"/3.5mm	Side screw	.35	.29	.25
2120680	OST	OSTEH022160R	3	2	0.138"/3.5mm	Top screw	.49	.45	.39
2094514	OST	OSTTE030161R	1	3	0.138"/3.5mm	Top screw	.39	.35	.29
2094531	OST	OSTTF030161R	2	3	0.138"/3.5mm	Side screw	.49	.45	.39
2120698	OST	OSTEH032160R	3	3	0.138"/3.5mm	Top screw	.75	.69	.65
2094565	OST	OSTTJ0231530R	4	2	0.150"/3.81mm	R/A screw	.65	.59	.55
2094602	OST	OSTTS02315A	5	2	0.150"/3.81mm	Top screw	.65	.59	.55
2094629	OST	OSTTS02315B	6	2	0.150"/3.81mm	Top screw	.65	.59	.55
2094645	OST	OSTTOQ023250R	7	2	0.150"/3.81mm	Vertical header	.25	.22	.15
2094661	OST	OSTTOQ023251R	8	2	0.150"/3.81mm	R/A header	.25	.22	.15
2094573	OST	OSTTJ0331530R	4	3	0.150"/3.81mm	R/A screw	.95	.85	.75
2094611	OST	OSTTS03315A	5	3	0.150"/3.81mm	Top screw	.95	.85	.75
2094637	OST	OSTTS03315B	6	3	0.150"/3.81mm	Top screw	.95	.85	.75
2094653	OST	OSTTOQ033250R	7	3	0.150"/3.81mm	Vertical header	.35	.29	.25
2094670	OST	OSTTOQ033251R	8	3	0.150"/3.81mm	R/A header	.35	.29	.25
2120621	OST	OSTTB020161R	2	2	0.197"/5mm	Side screw	.35	.29	.25
2094485	OST	OSTTA020161R	9	2	0.197"/5mm	Top screw	.29	.25	.19
2094549	OST	OSTTG0201600R	10	2	0.197"/5mm	45° angle screw	.39	.35	.29
160785	Dinkle	EK500V-02P	11	2	0.197"/5mm	Top screw	.59	.55	.45
164794	OST	OSTTH020160R	3	2	0.197"/5mm	Top screw	.65	.59	.49
99427	Dinkle	128V2P-R	12	2	0.197"/5mm	Top screw	.79	.59	.49
189676	OST	OSTTC020162R	13	2	0.197"/5mm	Top screw	.79	.59	.49
161067	Dinkle	EK500A-02P	14	2	0.197"/5mm	45° angle screw	.85	.75	.55
2120735	OST	OSTHT020080R	15	2	0.197"/5mm	45° angle screw	.69	.65	.59
2120639	OST	OSTTB030161R	2	3	0.197"/5mm	Side screw	.49	.45	.39
2094493	OST	OSTTA030161R	9	3	0.197"/5mm	Top screw	.39	.35	.29
2094557	OST	OSTTG0301600R	10	3	0.197"/5mm	45° angle screw	.59	.55	.49
2081203	Dinkle	ED500V-3P	16	3	0.197"/5mm	Top screw	.69	.59	.45
189668	OST	OSTTC030162R	13	3	0.197"/5mm	Top screw	.89	.79	.69
99398	Dinkle	DT128V3P	12	3	0.197"/5mm	Top screw	.95	.89	.79
160793	Dinkle	EK500V-03P	11	3	0.197"/5mm	Top screw	.95	.89	.79
164806	OST	OSTTH030160	3	3	0.197"/5mm	Top screw	.95	.89	.79
161059	Dinkle	EK500A-03P	14	3	0.197"/5mm	45° angle screw	1.15	.95	.85
2120743	OST	OSTHT030080R	15	3	0.197"/5mm	45° angle screw	.95	.85	.75
2094477	OST	OSTOP240200R	23	24	0.197"/5mm	1.3 x 1.0mm	1.19	1.09	.95
164815	OST	OSTOP240000R	23	24	0.197"/5mm	1.3 x 1.3mm	1.59	1.39	1.19
2120567	OST	OSTYC022150R	11	2	0.200"/5.08mm	Top screw	.45	.39	.35
2094688	OST	OSTOQ025450R	17	2	0.200"/5.08mm	Vertical header	.25	.22	.15
2094709	OST	OSTOQ025451R	18	2	0.200"/5.08mm	Vertical header	.25	.22	.15
2120647	OST	OSTTC022162R	1	2	0.200"/5.08mm	Top screw	.29	.25	.19
2094581	OST	OSTTJ025153R	19	2	0.200"/5.08mm	Top screw	.65	.59	.55
152347	OST	OSTTA024163R	20	2	0.200"/5.08mm	Top screw	.65	.55	.45
2094696	OST	OSTOQ035450R	17	3	0.200"/5.08mm	Vertical header	.29	.25	.19
2094717	OST	OSTOQ035451R	18	3	0.200"/5.08mm	Vertical header	.29	.25	.19
2120575	OST	OSTYC032150R	11	3	0.200"/5.08mm	Top screw	.55	.49	.45
2120655	OST	OSTTC032162R	1	3	0.200"/5.08mm	Top screw	.39	.35	.29
152355	OST	OSTTA034163R	20	3	0.200"/5.08mm	Top screw	.49	.45	.39
2094590	OST	OSTTJ035153R	19	3	0.200"/5.08mm	Top screw	.89	.79	.69
249084	OST	EDZA750/30	21	3	0.200"/5.08mm	Top screw	2.19	1.95	1.75
276672	Buchanan	6PCV-05-006	22	6	0.375"/9.53mm	Top screw	1.49	1.29	1.15

Blue Part No. = Limited Quantity Available

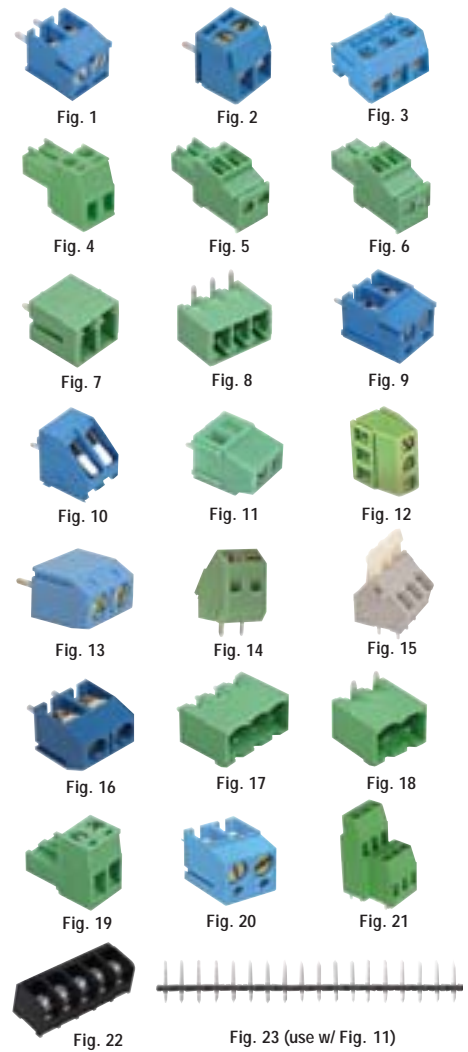

3M Electrical Connector Kit

• 79 pieces

Part No.	1	10
651954 R	\$9.95	\$8.95

171-Pc. Solderless Terminal Kit

170 Terminals and Connectors!

- Clear, hinged plastic box
- Use crimping tool P/N 72996, pg 91



Qty.	Description	Wire Gauge	Blade Size	Qty.	Description	Wire Gauge	Blade Size
10	Male spade	22-16	1/4"	10	Ring term.	16-14	#10
10	Male spade	16-14	1/4"	5	Ring term.	12-10	#10
10	Fem. spade	22-16	1/4"	5	Ring term.	12-10	#14
10	Fem. spade	16-14	1/4"	10	Spade term.	16-22	#6
10	Ring term.	22-16	#6	10	Spade term.	16-22	#8
10	Ring term.	22-16	#8	10	Spade term.	16-14	#10
10	Ring term.	16-14	#10	10	Butt conn.	16-22	—
15	Ring term.	16-14	#6	10	Butt conn.	16-14	—
10	Ring term.	16-14	#8	5	Butt conn.	12-10	—

Part No.	Product No.	1	10	25
10990	G1C175-R	\$14.95	\$13.49	\$11.95

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 197.

