




## Pushbutton Switches

\* Web Code: UBU

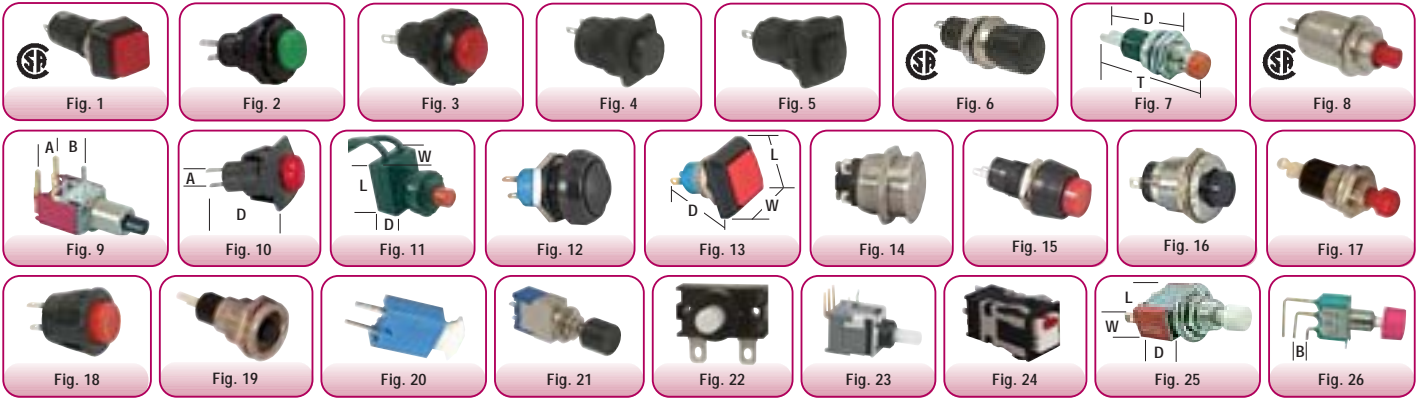

Part No.	Manufacturer	Product No.	Fig.	Pins	Mounting Hole Dia.	Contact Form ( ) Momentary	Contact Rating	Dimensions (L" x W" x D")	Lead Spacing		Terminal Type	Button Color	Pricing		
									A*	B*			1	10	100
315521	ValuePro	R13-23B-Y	1	1	.480"	SPST off-on	3A @ 125VAC	1.38 (D) x 1.53 (T)	.18	—	Solder	Yellow	\$ .95	\$ .85	\$ .69
164523	Mountain Switch	1DS466R	1	2	.406"	SPST off-(on)	3A @ 125VAC	.50 x .50 x .60	.16	—	Solder	Red	2.95	2.59	2.09
315484	ValuePro	R13-23B-R	1	2	.480"	SPST off-on	3A @ 125VAC	1.13 (D) x 1.53 (T)	.20	—	Solder	Red	.95	.85	.75
315492	ValuePro	R13-23B-B	1	2	.480"	SPST off-on	3A @ 125VAC	1.13 (D) x 1.53 (T)	.20	—	Solder	Black	.95	.85	.75
315432	ValuePro	R13-23A-R	1	2	.480"	SPST off-(on)	3A @ 125VAC	1.13 (D) x 1.53 (T)	.20	—	Solder	Red	.95	.85	.75
315651	ValuePro	R13-502A-05-BB	1	2	.500"	SPST off-(on)	3A @ 125VAC	.82 (D) x 1.02 (T)	.23	—	Solder	Black	1.75	1.49	1.25
315442	ValuePro	R13-511A-05-BB	1	2*	.480"	SPST off-(on)	3A @ 125VAC	1.13 (D) x 1.53 (T)	.20	—	Solder	Black	.95	.85	.75
315678	ValuePro	R13-502A-05-BG	2	2	.500"	SPST off-(on)	3A @ 125VAC	.82 (D) x 1.02 (T)	.20	—	Solder	Green	1.75	1.49	1.25
315660	ValuePro	R13-502A-05-BR	3	2	.500"	SPST off-(on)	3A @ 125VAC	.82 (D) x 1.02 (T)	.22	—	3Solder	Red	1.75	1.49	1.25
315791	ValuePro	R13-508A-05-BB	4	2	.630"	SPST off-(on)	3A @ 125VAC	.94 (D) x 1.16 (T)	.24	—	Solder	Black	1.95	1.69	1.49
315820	ValuePro	R13-508AL-05-BRR	4	4	.630"	SPST off-(on)	3A @ 125VAC	.93 (D) x 1.14 (T)	.21	.25	Solder w/ LED	Red	1.95	1.69	1.49
315897	ValuePro	R13-511A-05-BB	5	2	.500"	SPST off-(on)	3A @ 125VAC	.93 (D) x 1.14 (T)	.23	—	Solder	Black	1.95	1.69	1.49
315900	ValuePro	R13-511A-05-BR	5	2	.500"	SPST off-(on)	3A @ 125VAC	.93 (D) x 1.14 (T)	.24	—	Solder	Red	1.95	1.69	1.49
315599	ValuePro	R13-40A-R	6	2	.480"	SPST off-(on)	3A @ 125VAC	.98 (D) x 1.56 (T)	.20	—	Solder	Red	1.19	1.05	.95
315580	ValuePro	R13-40B-B	6	2	.480"	SPST off-(on)	3A @ 125VAC	.87 (D) x 1.4 (T)	.20	—	Solder	Black	1.39	1.25	1.15
26623	ValuePro	MS102	7	2	.250"	SPST off-(on)	3A @ 125VAC	.65 (D) x 1.10 (T)	—	.14	Solder lugs	Red	.59	.49	.45
164566	Mountain Switch	MS402R	8	2	.172"	SPST off-(on)	.5A @ 125VAC	.60 (D) x .80 (T)	.08	—	Solder	Red	1.95	1.69	1.49
315643	ValuePro	R13-81-R	8	2	.203"	SPST off-(on)	.5A @ 125VAC	.44 (D) x .78 (T)	.08	—	PC terminal	Red	.95	.85	.75
71643	ValuePro	SWB210	9	2	.219"	SPST off-(on)	1A @ 120VAC	.36 x .20 x .33	.20	.20	PC right angle	Black	2.79	2.45	2.29
174414	ValuePro	R13-510A	10	2	.500"	SPST off-(on)	3A @ 125VAC	.82 (D) x 1.0 (T)	—	.167	Solder lugs	Red	.95	.85	.75
22218	Judco	J1882	11	2*	.375"	SPST off-(on)	2A @ 14VDC	.65 x .52 x .40	.25	—	5" Pigtail	Red	1.09	.95	.85
171758	Apem	IPR3SAD2	12	2	.500"	SPST off-(on)	2A @ 250VAC	.76 (D) x 1.0 (T)	.19	—	Solder	Black	14.95	13.49	11.95
171766	Apem	IPC3SAD6	13	2	.500"	SPST off-(on)	2A @ 250VAC	.82 x .69 x .46	.19	—	Solder	Red	14.95	13.49	11.95
171774	Apem	AV191003C900	14	2	.750"	SPST off-(on)	2A @ 48VDC	.87 (D) x 1.2 (T)	.37	—	Screw	Silver	13.95	12.95	11.49
164494	Mountain Switch	DS450R	15	2	.406"	SPST off-on	3A @ 125VAC	.59 (D) x 1.2 (T)	.175	—	Solder	Red	3.95	3.49	3.19
164488	Mountain Switch	DS463R	15	2	.406"	SPST off-(on)	3A @ 125VAC	.59 (D) x 1.2 (T)	.175	—	Solder	Red	2.95	2.59	2.09
164582	Mountain Switch	DS016B	16	2	.469"	SPST off-(on)	1A @ 125VAC	.46 (D) x .88 (T)	.22	—	Solder	Black	2.19	2.09	1.99
164639	Mountain Switch	MS3120R	17	2	.295"	SPST off-(on)	.5A @ 125VAC	.31 (D) x 1.1 (T)	.175	—	Solder	Red	1.75	1.49	1.25
106112	Mountain Switch	DS412R	18	2	.734"	SPST off-(on)	3A @ 110VAC	.66 (D) x .63 (T)	.275	—	Solder lugs	Red	1.75	1.49	1.25
164671	Mountain Switch	NS801M0	19	2	.492"	SPST off-(on)	1A @ 125VAC	1.0 (D) x 1.1 (T)	.213	—	Solder terminal	Black	3.95	3.49	3.19
26649	ValuePro	MS103	7	2	.250"	SPST on-(off)	3A @ 125VAC	.65 (D) x 1.10 (T)	—	.17	Solder lugs	Black	.59	.49	.45
22200	Judco	J1881	11	2*	.375"	SPST on-off, Alt <sup>1</sup>	2A @ 14VDC	.65 x .52 x .40	.25	—	5" Pigtail	White	1.29	1.15	1.05
172700	Arctic	MPS1SPSTBLWH	20	2	—	SPST (on/off)	.05A @ 24VDC	.38 x .20 x .10	.10	—	Solder terminal	White	.35	.29	.25
315380	ValuePro	PA102A1-B	21	2	.250"	SPST on-(off)	6A @ 125VAC	1.2 (D) x 1.7 (T)	.185	—	Solder	Black	1.95	1.69	1.49
315388	ValuePro	PA101A1-R/BL	21	2	.250"	SPST on-off	6A @ 125VAC	1.2 (D) x 1.7 (T)	.185	—	Solder	Red	1.75	1.59	1.39
355451	ValuePro	J1881	22	2*	.375"	SPST on-off, Alt <sup>1</sup>	2A @ 14VAC	.65 x .52 x .40	.25	—	5" Pigtail	White	.75	.69	.65
447072	Apem	TP32Y0030050	21	3	.250"	SPST on-on	4A @ 20VAC	0.7 (D) x 0.8 (T)	.11	—	Solder	Black	.59	.55	.49
200774	C&K Switch	TP125H8AQE	23	3	.219"	SPDT off-(on)	1A @ 120VAC	.32 x .20 x .33	.20	.10	PC right angle	Black	2.95	2.59	2.09
72645	AlcoSwitch	TPC11FGRA2	9	3	.203"	SPDT off-(on)	1A @ 125VAC	.32 x .26 x .37	.20	.20	PC right angle	Red	1.49	1.29	1.09
1839705	Honeywell†	AML22CBC2AA	24	5	.750"	SPDT (on)-off	3A @ 125VAC	.80 x .80 x 1.8	.228	.177	Solder	††	24.95	21.95	19.95
202999	Various	BB16	23	3	.250"	SPDT on-on	.1A @ 28VAC	.39 x .35 x .35	.18	.10	Solder right angle	White	.79	.69	.59
596799	C&K Switch	U811SHZGE	25	3	.250"	SPDT on-(on)	1A @ 120VAC	.50 x .27 x .41	.185	—	Solder	††	1.95	1.69	1.49
121305	ValuePro	GPB006-WH	25	3	.250"	SPDT on-(on)	1A @ 120VAC	.52 x .27 x .38	—	.185	Solder lugs	White	3.49	3.15	2.79
28063	ValuePro	PB126	25	3	.250"	SPDT on-(on)	5A @ 120VAC	.52 x .28 x .38	—	.185	Solder lugs	Red	3.49	3.15	2.79
154878	Eaton Corp.	PS11-123	26	3	.250"	SPDT on-(on)	5A @ 125VAC	.50 x .27 x .37	—	.14	Solder right angle	Red	1.49	1.29	1.09

\* Lead wires    † Alt = alternate action    ‡ Subminiature    † With red neon lamp (5V)    †† Cap is not included

\* For Complete Specs & Additional Product Listings Search [www.Jameco.com/More](http://www.Jameco.com/More) and Enter Web Code Listed Above



Order by Phone 24/7 at 1-800-831-4242 or Online at [www.Jameco.com](http://www.Jameco.com)