

## EGE Rotary DIP Switches


- Gold plated contacts to ensure reliable, low resistance connection
- Fully sealed construction
- Terminals: PC pin leads
- Life: 10,000 cycles min.
- Op. force: 500g-cm max.
- Lead spacing: A = 0.1"; B = 0.3"
- Material: UL94V-0 grade
- Max. switching load rating: 25mA @ 24VDC
- Size: .39"W x .39"D x .20"H • Top adjustment



139636  
\*Web Code: UAX

Part No.	Mfr. Part No.	Type	Pos.	1	10
139636	ERD110RSZ	BCD	10	..... \$2.89	\$2.59
139652	ERD116RSZ	HEX	16	..... 2.95	2.65

## Standard, Low Profile, Piano & Right Angle DIP Switches

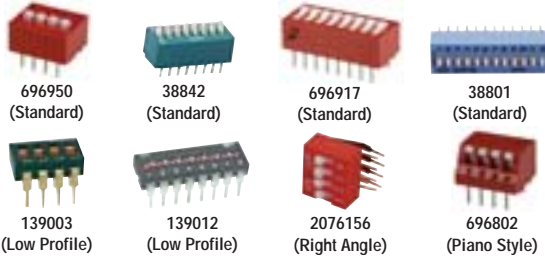

Compatible Socket Chart, see page 18 for Sockets

Switch	Socket	Switch	Socket
2-position	112193	7-position	112214
3-position	112193	8-position	112222
4-position	112206	9-position	112231
5-position	112214	10-position	38608
6-position	112214	12-position	112282

\*Web Code: UCY

- Switch contacts: SPST
- Piano switches have raised lever
- Low profile switches have either raised or slide levers

## 94H Series Rotary DIP Switches

- Make & break rating: 30mA @ 30VDC for 10,000 cycles
- Contact res.: 50mΩ max.
- Type: BCD 10-position
- Carrying current rating: 100mA @ 50VDC
- Insulation resistance: 5,000MΩ min.
- Contact material: 30µ" gold over 50µ" nickel



Part No.	Mfr. Part No.	Actuator	1	10
697071	94HAB10RAT	Flush right angle	.. \$1.95	\$1.75
788555	94HBB10T	0.270", straight	..... 2.49	2.25

## JAMECO ValuePro Rotary Switches

- Contact rating: 30VDC @ 0.3A; except P/N 2099631: 125VAC @ 0.3A
- Insulation resistance: 10MΩ min.
- Mounting hole diameter: 3/8"; except P/N 2099631: 0.348"
- Contact resistance: 30mΩ
- Material: solid brass bushings, slotted aluminum shafts (except for P/N 2099631: D-type and P/N 622352); round, plated frame, plastic contact wafer (except for P/N 622352/2099631 – phenolic casing)
- Make before break; except P/N 2099631: break before make
- Solder eyelet lugs
- Shaft size: 0.46"L x 0.25" Dia.; except P/N 622352: 1.5"L x 0.25" Dia. and P/N 2099631: 0.34"L x 0.25" Dia.



101574  
\*Web Code: DAM

Includes: Washer and nut

Part No.	Product No.	Poles	Pos.	1	10	100
101532	G3SR026	1	12	..... \$ .95	\$ .85	\$ .75
622352	35-376	1	12	..... 2.95	2.65	2.39
2099631	SR2511-0205	2	5	..... .95	.85	.75
101574	G3SR022	2	6	..... .95	.85	.75
101566	G3SR023	3	4	..... .95	.85	.75
101558	G3SR024	4	3	..... .95	.85	.75

† Solder eyelet style

## C&K A Series Rotary Switches

- 1.5"H flatted actuator
- 3/8-32 threaded mounting style
- Solder lug terminals
- Dielectric strength: 1000Vrms
- 15,000 make & break cycles
- Contacts and terminals: brass, silver plated
- Contact resistance: 20mΩ typical @ 2-4VDC
- Contact rating: 2.5A @ 125VAC; 250mA @ 250VDC
- Housing/actuator: glass filled 6/6 nylon (UL94V-0)



Part No.	Mfr. Part No.	Type	Pos.	1	10
576501	A11215RNZQ	SP, 300 index	12	\$6.95	\$6.25
576421	A20615RNZQ	DP, 300 index	6	6.95	6.25

Part No.	Product No.	*Mfr.	*Type	Pos.	Pricing		
					1	10	100
109057	206-2	◆	1,5	2	\$.69	\$.59	\$.49
1951385	206-2LP	◆	2,6	2	.69	.59	.45
2076156	SDAX-2RX-X	BNS	3,5	2	.59	.45	.39
109059	206-2-VP-R	JVP	3,5	2	.79	.69	.59
206359	206-3	◆	1,5	3	.65	.55	.45
202472	ADF03	ALC	2,6	3	.59	.49	.45
696802	DP-04B	JVP	1,4	4	.95	.85	.75
38818	206-4	◆	1,5	4	.59	.55	.49
38820	DT-04VP	JVP	1,5	4	.75	.65	.59
696950	78B04ST	GRY	1,5	4	1.15	1.05	.85
2082231	3-4356405	AMP	1,7	4	.79	.69	.59
696888	76SB04ST	GRY	1,7	4	.95	.89	.79
206499	DPS804	FJT	2,4	4	.69	.59	.49
139003	206-4LP	JVP	2,5	4	.75	.65	.55
778251	209-4LPST	CTS	2,6	4	.49	.45	.39
2076164	SDAX-4RX-X	BNS	3,5	4	.59	.45	.39
2076181	SDAX-4RX-T	BNS	3,5	4	.69	.59	.49
2082249	JS8805	◆	1,6	5	.59	.49	.39
2082505	206-517	JVP	1,7	5	.59	.49	.45
2082513	206-518	JVP	1,8	5	.59	.49	.45
2076674	DPL-06KT	JVP	1,4	6	.69	.59	.49
38826	206-6	JVP	1,5	6	.89	.79	.69
2076201	A6D-6100LP	OMN	2,6	6	.69	.59	.45
38834	206-7	◆	1,5	7	.95	.89	.79

\*1. Standard; 2. Low Profile; 3. Right Angle; 4. Piano Style; 5. Slide Raised; 6. Slide Flush; 7. Rocker Raised; 8. Rocker Flush

## JAMECO ValuePro Tri-State DIP Switch

- Pre-tinned leads
- Two isolated buses
- Switch contacts: bused, tri-state
- Labeled tri-state positions (+, 0, -)
- Compatible socket, use P/N 37373, pg 18

 


Part No.	Cross Ref. No.	Positions	Contact Rating	1	10	100	500
138992	ETA108E	8	24VDC @ 25mA	..... \$1.95	\$1.75	\$1.49	\$1.25

## SMT Low Profile DIP Switches

\*Web Code: SDS


- Insulation resistance: 1000MΩ (min.) across open switch & between adjacent closed switch
- Contact resistance: 100mΩ initial
- Dielectric strength: 300VAC for 1 min.
- Gold plated beryllium copper contacts, gold flash coated terminals
- Bottom seal/top tape seal
- Non-switching rating: 100mA or 50VDC max.
- Length: 0.246"



Part No.	Manufacturer	Product No.	Positions	Type	1	10	100
2076199	Grayhill	90HB104SR	4	SPST	..... \$ .35	\$.25	\$.19
546759	Various	3-435668	5	SPST	..... .39	.29	.25
1945022	Various	SMT-6PDS	6	SPST	..... .49	.35	.29

## JAMECO ValuePro SPST Round Keylock Switches

- Used in computer and other security systems
- Mounting hole = 0.75" (except P/N 106650 = 0.5")
- Key removable from 2 positions
- 105832: All keys are different; 196649: All keys are alike
- Includes: Mounting nut

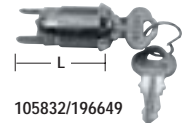

Part No.	Cross Ref. No.	No. Flat, Dia.	Length	Terminal	Voltage/Current	1	10	100
106650	KS4B	2, 0.21"	0.55"	Barrel	125VAC/3A	\$4.55	\$4.09	\$3.55
105832	KS3B	2, 0.66"	1.48"	0.25" quick connect	125VAC/6A	4.95	4.49	3.95
196649	3313E-M	2, 0.66"	1.48"	0.25" quick connect	125VAC/6A	4.95	4.49	3.95

\* ALC = Alcoswitch | AMP = AMP/Type | BNS = Bourns | C&K = C&K Switches | CTS = CTS | FJT = Fujitsu | GRY = Grayhill | JVP = Jameco ValuePro | OMN = Omron | ◆ Manufacturer Varies

\*For Complete Specs & Additional Product Listings Search [www.Jameco.com/More](http://www.Jameco.com/More) and Enter Web Code Listed Above