

DC Brushless Tubeaxial Fans

3 LEVELS OF SAVINGS
NAME BRANDS **HOUSE BRANDS** **SPECIAL BUY**



Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers

* 5V Web Code: TAS

* 12V Web Code: LBZ

NEW
 MARKED IN PINK



695050



2134125



2131944

mm to Inches Conversion Chart

mm	6	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	70	75	76	80	92	94	95	97	120	125	126	127	150	172
Inches	0.24	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.76	2.95	2.99	3.15	3.63	3.70	3.74	3.82	4.72	4.92	4.96	5.00	5.90	6.77

Fans

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2134088	Adda	AD2005LX-K70	5	20 x 20 x 6	0.6	Hypro	60	0.3	TUV/CE	12	5.5"	\$10.95	\$9.95	\$8.95	\$7.95
2131872	Adda	AD0205MX-K53-LF	5	25 x 25 x 6	2.4	Hypro	120	0.6	CE	29	6" ¹	8.95	7.95	6.95	5.95
1312247	Adda	AD0205LX-G50-LF	5	25 x 25 x 10	1.8	Hypro	100	0.5	UL/CSA/CE	15.6	5.5"	7.95	6.95	6.25	5.95
2132197	Adda	AD0205MB-G50GL	5	25 x 25 x 10	2.2	Ball	120	0.6	UL/CUL/TUV/CE	23	5.5"	8.95	7.95	6.95	6.25
695050	Sunon	GM0502PFV2-8	5	25 x 25 x 10	3.0	Vapo	80	0.4	UL/CUL	16	5.5"	9.95	8.95	7.95	6.95
2188924	Adda	AD0305HX-K70(TX)	5	30 x 30 x 6	3.5	Hypro	180	0.9	UL/CUL/TUV/CE	32	5.5"	6.95	5.95	5.49	4.95
2208905	Sunon	KDE0503PEB1-8	5	30 x 30 x 6	4.9	Ball	180	0.9	UL/CUL/TUV/CE	28	5.5"	4.95	4.49	3.95	3.49
2203354	Adda	AB3505LB-QB0 [†]	5	35 x 35 x 7	0.09	Ball	100	0.5	UL/CUL/TUV/CE	19	12"	6.95	5.95	4.95	3.95
2134096	Adda	AD3505MX-G53	5	35 x 35 x 10	6.0	Hypro	130	0.65	UL/CUL/TUV/CE	30	12" ¹	4.95	4.49	3.95	3.49
1708457	Sunon	KDE0504PEB3-8 (MS)	5	40 x 40 x 6.8	3.5	Ball	90	0.45	UL/CUL/TUV	20	6"	4.95	4.49	3.95	3.59
2167242	Adda	AD0405LB-K90(S)-LF	5	40 x 40 x 6.8	4.5	Ball/Sleeve	50	0.25	UL/CUL/TUV/CE	19.9	5.4"	7.95	6.95	6.25	5.95
2220200	Adda	AD0405MB-K90	5	40 x 40 x 6.8	5.2	Ball	90	0.45	UL/CUL/TUV/CE	23.8	5.5"	7.95	6.95	6.25	5.59
2133886	Adda	AD0405LX-G70	5	40 x 40 x 10	4.7	Hypro	80	0.40	UL/CUL/TUV/CE	21	11"	5.95	5.39	4.79	4.39
2258814	Adda	AD0405MB-G76	5	40 x 40 x 10	5.0	Ball	110	0.55	UL/CUL/TUV/CE	22	4" w/ conn ¹	4.95	4.49	3.95	3.49
2138628	Adda	AD0405MB-G70-LF	5	40 x 40 x 10	5.7	Ball	110	0.55	UL/CUL/TUV/CE	22	12"	7.95	6.95	5.95	5.49
2220091	Adda	AD0405MK-G70	5	40 x 40 x 10	5.7	Hypro	110	0.55	UL/CUL/TUV/CE	15.9	4"	5.95	5.39	4.79	4.29
2131928	Adda	AD0405MX-G76-LF	5	40 x 40 x 10	5.7	Hypro	110	0.55	UL/CUL/TUV/CE	15.9	11" ¹	4.95	4.49	3.95	3.49
1928353	Adda	AD0405HX-G70	5	40 x 40 x 10	6.7	Hypro	190	0.95	UL/CUL/TUV/CE	30	11"	5.95	5.39	4.79	4.29
2229933	Sunon	EE40100S1-0000-999	5	40 x 40 x 10	8.0	Sleeve	271	1.36	UL/CUL/TUV	32	12"	7.95	6.95	6.25	5.95
2132189	Adda	AD0405HB-G70	5	40 x 40 x 10	8.7	Ball	100	0.8	UL/CUL/TUV/CE	25	12" w/ conn	4.95	4.49	3.95	3.49
2230993	Delta	FBK04F05L	5	40 x 40 x 20	3.9	Ball	120	0.6	UL/UR	24	10"	6.95	6.25	5.59	4.95
2131910	Adda	AD0405MX-C50-LF	5	40 x 40 x 20	8.1	Hypro	160	0.8	UL/CUL/TUV/CE	27	13"	6.95	6.25	5.59	4.95
2134133	Adda	AP.505HB-J90	5	45 x 45 x 8	6.0	Hypro	120	0.6	UL/CUL/TUV/CE	31	5"	9.95	8.95	7.95	6.95
2134125	Adda	AP0505HB-J90 [§]	5	50 x 50 x 8	6.0	Ball	140	0.60	UL/CUL/CE	30	5"	3.95	3.49	2.95	2.49
136494	Delta	AFB0505LA	5	50 x 50 x 10	7.4	Ball	120	0.4	UL/CE/CSA/VDE	26	11"	5.95	4.95	3.95	3.49
2150774	Adda	AD0505MB-G70-LF	5	50 x 50 x 10	10.5	Ball	180	0.9	UL/CUL/TUV/CE	24	12"	9.95	8.95	8.49	7.95
2121324	Adda	AD0505MB-G76LF	5	50 x 50 x 10	10.5	Ball	180	0.9	UL/CUL/TUV/CE	24	11" ¹	7.95	6.95	5.95	4.95
2186241	Sunon	KDE0505PPV1.11.MS.A.GN	5	50 x 50 x 10	13	Vapo	270	1.4	UL/CUL/VDE	30	16" w/ conn	8.95	7.95	6.95	5.95
2132120	Adda	AD0605LB-A72GL	5	60 x 60 x 25	13.8	Ball	150	0.75	UL/CUL/TUV/CE	20.3	12" ¹	5.95	5.39	4.79	4.29
2131944	Adda	AD0605HB-A71-LF	5	60 x 60 x 25	23.2	Ball	450	2.25	UL/CUL/TUV/CE	32	11"	6.95	6.25	5.59	4.95
2131952	Adda	AD0605HB-A72GL	5	60 x 60 x 25	24.3	Ball	450	2.25	UL/CUL/TUV/CE	36	12" ⁵	6.95	6.25	5.59	4.95
2258671	Adda	AD0805HB-D71	5	80 x 80 x 15	29.9	Ball	430	2.1	UL/CUL/TUV/CE	33	12"	10.95	9.95	8.95	7.95
2095269	Adda	AD2012LX-G70(X)	12	20 x 20 x 10	0.6	Hypro	60	0.84	UL/CUL/CE	20	5.5"	7.95	6.95	5.95	4.95
2227655	Adda	AD0212MX-K50	12	25 x 25 x 6	2.4	Hypro	60	0.72	UL/CUL/TUV/CE	29	5.5"	11.95	10.95	9.95	8.95
2179454	Jamicon	KF0210S1H	12	25 x 25 x 10	2.57	Sleeve	120	1.44	UL/TUV/CE	27.4	12"	3.95	3.49	2.95	2.49
2121316	Adda	AD0212HB-G50GL	12	25 x 25 x 10	2.8	Ball	90	1.08	UL/CUL/CE	29	5.5"	5.95	5.39	4.79	4.29
2133958	Adda	AD0312DB-G50	12	30 x 30 x 10	2.18	Ball	50	0.6	UL/CUL/CE	17	12"	5.95	5.39	4.79	4.29
212741	Sunon	KDE1235PFB2-8	12	35 x 35 x 10	4.5	Ball	60	0.8	UL/CUL/TUV/CE/VDE	21	3" w/ conn	6.95	6.25	5.59	4.95
2179411	Sunon	MF35101V1-10000-A99	12	35 x 35 x 10	7.2	Vapo	60	0.72	UL/CUR/TUV/CE	28	5.5"	11.95	10.95	9.95	8.95
2186224	Delta	FFB03812VHN-F00	12	38 x 38 x 28	20.2	Ball	650	7.8	UL/CSA/VDE/CE	58.5	13" ¹	5.95	4.95	4.49	3.95
2215435	Adda	AD0412HX-K96 (X)	12	40 x 40 x 6	5.4	Hypro	140	0.96	UL/CUL/TUV/CE	30.5	5.5" ¹	8.95	7.95	6.95	6.25
2132162	Adda	AD0412LS-G70(T)	12	40 x 40 x 10	4.7	Sleeve	70	0.84	UL/CUL/TUV/CE	14	12"	4.95	4.49	3.95	3.49
2095314	Adda	AD0412LX-G70	12	40 x 40 x 10	4.7	Hypro	70	0.84	UL/CUL/TUV	14	11"	5.95	5.39	4.79	4.39
2224180	Adda	AD0412LX-G76	12	40 x 40 x 10	4.7	Hypro	70	0.84	UL/CUL/TUV	14	12" ¹	5.95	5.49	4.95	4.49
2167630	Sunon	HA40101V4-0000-999	12	40 x 40 x 10	5.3	Vapo	65	0.8	UL/TUV/CE	18.2	12"	6.95	6.25	5.59	4.95
2133915	Adda	AD0412MX-G70	12	40 x 40 x 10	5.7	Hypro	80	0.96	UL/CUL/TUV/CE	20	11.5"	4.95	4.49	3.95	3.49
2197530	JMC	4010-12-HBHA	12	40 x 40 x 10	6.4	Dual Ball	80	0.96	UL/CUL/TUV	25	8" w/ conn ¹	7.95	6.95	6.25	5.59
2205384	Adda	AD0412HB-G70(T)	12	40 x 40 x 10	6.7	Ball	100	1.2	UL/CUL/TUV/CE	25	12"	6.49	5.49	4.95	4.49
2167234	Sunon	ME40101V1-0000-A99	12	40 x 40 x 10	8.0	Vapo	90	1.08	UL/CUL/TUV	32	12"	4.95	4.49	3.95	3.49
1708473	Sunon	KDE1204PPVX11.MS.A	12	40 x 40 x 10	9.5	Vapo	150	1.8	UL/CUL/TUV	39	12"	5.95	4.95	4.49	3.95
2228181	Delta	AFB0412LD	12	40 x 40 x 20	3.88	Ball	50	0.6	UL/CE/CSA/TUV	25	13"	3.95	3.59	3.29	2.95
2133835	Adda	AD0412DX-C50	12	40 x 40 x 20	4.9	Hypro	50	0.6	UL/CUL/TUV/CE	10	11"	4.95	4.49	3.95	3.59

¹ 3 leads; speed sensor ⁵ 3 leads; alarm (All fans operate to their specs with or without the additional optional wire functions) [§] DC chip cooler [†] Blower

For case mounting screws, P/Ns 2188481 or 2188490, page 78

DC Brushless Tubeaxial Fans



Call for additional OEM PRICING – we carry major manufacturers.

DC Brushless Tubeaxial Fans & Blowers (Continued)



* 12V Web Code: LBZ

NEW MARKED IN PINK



2205499



2210909



2099446

mm to Inches Conversion Chart

mm	6	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	70	75	76	80	92	94	95	97	120	125	126	127	150	172
Inches	0.24	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.76	2.95	2.99	3.15	3.63	3.70	3.74	3.82	4.72	4.92	4.96	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
195899	Sunon	KDE1204PKS2	12	40 x 40 x 20	6.5	Sleeve	70	0.9	UL/CSA/TUV	25.5	12"	\$4.95	\$4.49	\$3.95	\$3.59
2134176	Adda	AD0412LB-C50	12	40 x 40 x 20	7.0	Ball	70	0.84	UL/CUL/TUV/CE	25	11"	5.95	5.39	4.79	4.29
207052	Adda	AD0412LB-C53	12	40 x 40 x 20	7.0	Ball	110	1.32	UL/CUL/TUV/CE	30	11" (1)	5.95	5.39	4.79	4.29
2151021	Sanyo Denki	109P0412H601	12	40 x 40 x 20	8.0	Ball	110	1.3	UL/CSA	33	7" w/ conn ¹	4.95	4.49	3.95	3.59
2133907	Adda	AD0412MB-C50	12	40 x 40 x 20	8.5	Ball	80	0.96	UL/CUL/TUV/CE	28.5	11"	4.95	4.49	3.95	3.49
2220218	Adda	AD0412HB-C50(G)	12	40 x 40 x 20	8.8	Ball	100	1.2	UL/CUL/TUV/CE	36	10" w/conn	6.95	6.25	5.59	4.95
249375	Adda	AD0412HB-C71GD	12	40 x 40 x 20	8.97	Ball	160	1.1	UL/CUL/TUV/CE	39.3	12"	6.95	6.25	5.59	4.95
2230969	Delta	EFB0412HHD	12	40 x 40 x 20	9.5	Ball	100	1.2	UL/CUL/CSA/TUV	30.5	12"	5.95	4.95	4.49	3.95
1928118	Adda	AD0412HB-C50	12	40 x 40 x 20	10.5	Ball	110	1.2	UL/CUL/TUV/CE	31.9	12"	8.95	7.95	6.95	6.25
2135380	Adda	AD0412UB-C72GP(P)	12	40 x 40 x 20	10.6	Ball	200	2.4	UL/CUL/TUV/CE	34	12" ²	9.95	8.95	7.95	6.95
2227330	Elina	HDF4020L-12HBB-4	12	40 x 40 x 20	10.9	Ball	165	1.98	UL/CUL/TUV	34	18" w/ conn	7.95	6.95	5.95	4.95
2186232	Delta	FFB0412HN-ST20	12	40 x 40 x 28	10.6	Ball	110	0.84	UL/CSA/TUV	36	3.5" w/ conn ¹	3.95	3.49	2.95	2.49
2082089	Sanyo Denki	109P0412H302	12	40 x 40 x 28	11.3	Ball	195	2.3	UL/CSA/TUV	37	3.75"	5.95	4.95	4.49	3.95
2228800	Delta	GFBO412EMS-D	12	40 x 40 x 56	31.2	Ball	135	16.2	UL/CUL/VDE	64	3" w/ conn	11.95	10.95	9.95	8.95
2095322	Adda	AD4512MX-G76	12	45 x 45 x 10	6.7	Hypro	70	0.84	UL/CUL/TUV/CE	22	11" ¹	9.95	8.95	7.95	6.95
2095349	Adda	AD0512MB-G76	12	50 x 50 x 10	10.5	Ball	120	1.4	UL/CUL/TUV/CE	24	11" ¹	9.95	8.95	7.95	6.95
2202992	Sunon	ME50101V1-000U-A99	12	50 x 50 x 10	13.8	Vapo	110	1.3	UL/CUL/TUV	31	12"	7.95	6.95	6.25	5.95
2099534	Adda	AD0512HB-D70	12	50 x 50 x 15	14.2	Ball	100	1.3	UL/CUL/TUV/CE	29	5.5"	6.95	6.25	5.59	4.95
2258451	Sunon	KDE1205PHYV1	12	50 x 50 x 15	17	Vapo	87	1.0	UL/CUL/TUV/CE	33	12" ¹	6.95	6.25	5.59	4.95
2203004	Sunon	MB50151V1-000U-A99	12	50 x 50 x 15	17	Vapo	87	1.05	UL/CE/TUV/CUL	33	12"	8.95	7.95	6.95	6.25
2228261	NMB	2106KL-04W-B39	12	52 x 52 x 15	9.9	Ball	70	0.84	UL/CSA/CE/TUV	21	12" (1)	6.95	6.25	5.59	4.95
139601	Adda	AD0512HS-D71	12	52 x 52 x 15	12	Sleeve	100	1.2	UL/CSA/CE	29	5"	3.95	3.49	2.95	2.49
139602	Adda	AD0512HS-D71-LF	12	52 x 52 x 15	12	Sleeve	100	1.2	UL/CSA/CE	29	6"	8.95	7.95	6.95	6.25
2133991	Adda	AD0612LX-G70	12	60 x 60 x 10	10	Hypro	120	1.44	UL/CUL/TUV/CE	26	11"	6.95	6.25	5.59	4.95
2121332	Adda	AD0612LX-G76(T)	12	60 x 60 x 10	10	Hypro	110	1.32	UL/CUL/TUV/CE	26	11" ¹	6.95	6.25	5.59	4.95
2205499	Adda	AD0612HB-G90	12	60 x 60 x 10	14.06	Ball	140	1.6	UL/TUV/CE	32.8	4.5" w/ conn	4.95	4.49	3.95	3.49
2095357	Adda	AD0612HB-G70	12	60 x 60 x 10	14.5	Ball	150	1.8	UL/CUL/TUV/CE	32	11"	7.95	6.95	6.25	5.95
1946025	Evercool	EC6010M12CA	12	60 x 60 x 10	15.5	Ball	160	1.9	UL/CE/TUV	30	9" ¹	8.95	7.95	6.95	6.25
2217959	Thermactive	RDM6010B1	12	60 x 60 x 10	15.9	Ball	170	2.04	UL/CUL/TUV/CE	31	12"	6.95	5.95	5.49	4.49
2210909	Delta	AFB0612LB-TXNS	12	60 x 60 x 15	11.55	Ball	100	0.84	UL/CSA/CE	24	6" w/ conn ²	5.95	4.95	4.49	3.95
1928046	Adda	AD0612MS-D70GL	12	60 x 60 x 15	14	Sleeve	110	1.32	UL/CUL/TUV/CE	29	5"	5.95	5.39	4.79	4.29
2167568	Sunon	ME60151V1-000U-A99	12	60 x 60 x 15	25.2	Vapo	160	1.92	UL/TUV/CE	36.2	12"	6.95	5.95	5.49	4.95
144161	Adda	AD0612LB-C70GL	12	60 x 60 x 20	12.6	Ball	80	1.0	UL/CSA/TUV	22.7	12"	5.95	4.95	4.49	3.95
2134011	Adda	AD0612MX-C70GL	12	60 x 60 x 20	14.5	Hypro	130	1.56	UL/CUL/TUV/CE	25.7	12"	4.95	4.49	3.95	3.49
2227276	YS Tech	NYW060250125BL	12	60 x 60 x 25	15.8	Ball	80	0.96	UL/CUL/TUV	23.5	7" w/ conn	4.95	4.49	3.95	3.59
2155292	Comair Rotron	GDA6025-12BB	12	60 x 60 x 25	18	Ball	140	1.7	UL/CUL/TUV	26.1	12"	3.95	3.59	2.95	2.59
2162847	NMB	2410ML-04W-B30	12	60 x 60 x 25	19	Ball	117	1.4	UL/CSA/VDE/CE	29	12"	8.95	7.95	6.95	6.25
2205149	Sunon	MB60251V2-000U-G99	12	60 x 60 x 25	19.3	Vapo	74	0.8	UL/CUL/CE/TUV	29	12" ¹	9.95	8.95	7.95	6.95
2217941	Thermactive	RDH6025B-FG	12	60 x 60 x 25	20.3	Ball	140	1.68	UL/CUL/TUV/CE	29	12" ¹	6.95	6.25	5.95	5.49
2230766	Thermactive	RDH6025B	12	60 x 60 x 25	20.3	Ball	140	1.68	UL/CUL/TUV/CE	29	12" ⁴	7.95	6.95	5.95	5.49
2228818	Mitsubishi	MMF-06D12DL	12	60 x 60 x 25	21.6	Ball	70	0.84	UL/CSA	23	8" w/ conn	6.95	6.25	5.59	4.95
2150766	Adda	AD0612HB-A72GL	12	60 x 60 x 25	23.2	Ball	230	2.7	UL/CUL/TUV/CE	32.3	12" ²	7.95	6.95	5.95	4.95
2227719	Adda	AD0612HB-A70GL	12	60 x 60 x 25	23.2	Ball	230	2.76	UL/CUL/TUV/CE	32.3	12"	9.95	8.95	7.95	6.95
2158311	Delta	AFB0612EH-BF00	12	60 x 60 x 25	38.35	Ball	480	5.76	UL/CSA/CE	46.5	8" w/ conn ¹	11.95	10.95	9.95	8.95
2125561	AVC	DE07015R12U	12	70 x 70 x 15	43	Hydraulic	700	8.4	UL/CE/TUV	46	8" w/ conn	5.95	4.95	3.95	2.95
2227647	JMC	7025-12LS	12	70 x 70 x 25	22	Sleeve	100	1.2	UL/CUL/TUV	24.3	6" w/ conn.	6.95	6.25	5.59	4.95
2099446	Adda	AD7512LB (2A)†	12	76 x 76 x 30	6.9	Ball	110	1.32	UL/CUL/TUV/CE	29	15" w/ conn ²	6.95	6.25	5.59	4.95
2192561	Adda	AD0812LB-D70(T)	12	80 x 80 x 15	20	Ball	90	1.08	UL/CSA/TUV/CE	19.6	12"	7.95	6.95	5.95	5.49
2132007	Adda	AD0812HS-D70-LF	12	80 x 80 x 15	38.6	Sleeve	250	3.0	UL/CSA/TUV/CE	33	12"	5.95	5.49	4.95	4.49
2095365	Adda	AD0812XX-D71	12	80 x 80 x 15	39.4	Hypro	350	4.2	UL/CSA/TUV/CE	42	11"	8.95	7.95	6.95	5.95

¹ 3 leads; speed sensor ² 3 leads; locked rotor protection ⁴ 4 leads with speed sensor, PWM control (All fans operate to their specs with or without the additional optional wire functions) † Blower
For case mounting screws, P/Ns 2188481 or 2188490, page 78

Continued on next page

* For additional products, availability and specifications visit Jameco.com and enter the Web Code in the product search box



Order by Phone at 1-800-831-4242 or Online at www.Jameco.com

DC Brushless Tubeaxial Fans

3 LEVELS OF SAVINGS
NAME BRANDS **HOUSE BRANDS** **SPECIAL BUY**



Call for additional OEM PRICING – we carry major manufacturers.

NEW
 MARKED IN PINK

DC Brushless Tubeaxial Fans & Blowers (Continued)



* 12V Web Code: LBJ

* 24V Web Code: QEF



2211012



2228172



2203346

mm to Inches Conversion Chart

mm	6	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	70	75	76	80	92	94	95	97	120	125	126	127	150	172
Inches	0.24	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.76	2.95	2.99	3.15	3.63	3.70	3.74	3.82	4.72	4.92	4.96	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
2230985	Delta	EFC0812DF	12	80 x 80 x 15	49	Ball	330	3.9	UL/CSA/TUV/CE	45	12 ³	\$9.95	\$8.95	\$7.95	\$6.95
141921	Adda	AD0812HB-C70	12	80 x 80 x 20	27.3	Ball	240	2.9	UL/CSA/CE	34	12"	10.95	9.95	8.95	7.95
2228121	NMB	3110GL-B4W-B14	12	80 x 80 x 25	24.7	Ball	100	1.2	UL/CSA/VDE/CE	22	10"	6.95	6.25	5.59	4.95
2228148	Mechatronics	F8025S12B	12	80 x 80 x 25	26	Ball	75	1.2	UL/CSA/TUV	22	10"	6.95	6.25	5.59	4.95
2228113	Nidec	D08A-12TL	12	80 x 80 x 25	27.7	Ball	120	0.7	UL	19	8" w/ conn	6.95	6.25	5.59	4.95
688597	NMB	3110GL-B4W-B19-PA1	12	80 x 80 x 25	30	Ball	120	1.2	UL/CSA/TUV/CE	22	12" w/ conn ¹	5.95	5.35	4.79	4.29
2205181	Delta	AFB0812M-F00	12	80 x 80 x 25	30.8	Ball	180	1.8	UL/CSA/CE	29.5	12 ¹	5.95	5.35	4.79	4.29
123530	Adda	AD0812MS-A70GL	12	80 x 80 x 25	32	Sleeve	150	1.8	UL/CSA/TUV	28.3	12"	6.95	5.95	4.95	4.59
1955010	NMB	3110KL-04W-B40	12	80 x 80 x 25	35.3	Ball	200	2.40	UL/CSA/TUV/CE	31	13"	6.95	6.25	5.59	4.95
2135697	Panaflo	FBM-08A12H	12	80 x 80 x 25	39.6	Sleeve	220	2.1	UL/CSA	32	12" w/ conn	3.95	3.49	2.95	2.49
2210984	Sunon	EE80251B1-0000-A99	12	80 x 80 x 25	41	Ball	145	1.7	UL/CUL/TUV/CE	33	12"	7.95	7.49	6.95	6.25
2081078	Jamicon	JF0825B1UR	12	80 x 80 x 25	52	Dual Ball	370	4.4	UL/CUL/TUV/CE	40	12"	9.95	8.95	7.95	7.49
2210933	Sunon	PF80251V1-0000-A99	12	80 x 80 x 25	60	Vapo	341	4.1	UL/CUL/TUV	46.5	12"	12.95	11.95	10.95	9.95
2209001	Sanyo Denki	9GV0812P4K03	12	80 x 80 x 25	74.8	Ball	870	10.4	UL/CUL/TUV	52	12 ⁴	7.95	6.95	6.25	5.95
2228164	EBM Papst	8312	12	80 x 80 x 32	31.8	Ball	220	2.2	UL/CSA/TUV	36	12"	12.95	11.49	9.95	8.95
107406	EBM Papst	8312GHL	12	80 x 80 x 32	39.4	Sleeve	330	4.0	UL/CE/CSA/VDE	43	12"	6.95	5.95	4.95	4.49
2230758	Thermactive	RGM8038B1	12	80 x 80 x 38	83.4	Ball	850	11.7	UL/CUL/TUV/CE	57	12 ⁴	10.95	9.95	8.95	7.95
1928100	Adda	AD0812XB-F71DS	12	80 x 80 x 38	99	Ball	1500	18.0	UL/CSA/TUV/CE	57	12"	9.95	8.95	7.95	6.95
1952783	Nidec	TA350DC-M34138-34	12	92 x 92 x 25	35	Ball	160	1.92	UL/CSA	26.4	10" w/ conn ³	3.95	3.49	2.95	2.49
1952257	AVC	C9025S12L	12	92 x 92 x 25	37.2	Sleeve	150	1.8	UL/CUL/TUV/CE	26.2	5.5 ¹	2.95	2.59	2.29	1.95
154641	Nidec	TA350DC-M33422-16	12	92 x 92 x 25	48	Ball	290	3.5	UL/CSA	35	12"	9.95	8.95	7.95	6.95
2228236	Sunon	1209PTB1-6	12	92 x 92 x 25	49	Ball	170	2.8	UL/CUL/CE/TUV	35	12"	9.95	8.95	7.95	6.95
2193942	Orion	DPF92B012	12	92 x 92 x 25	50	Ball	290	3.48	UL/CUL	33	12"	7.95	6.95	6.25	5.59
2228201	Mechatronics	E9225H12B2	12	92 x 92 x 25	51	Ball	360	4.3	UL/CUL/TUV	36	14"	9.95	8.95	7.95	6.95
2172711	Mechatronics	MC9238X12B-FS	12	92 x 92 x 38	80.5	Ball	720	8.6	UL/CUL/TUV	47.5	12"	6.95	5.95	5.49	4.95
174140	Common Wealth	FP108MS3	12	120 x 120 x 25	62	Sleeve	140	1.7	UL/CSA/TUV/CE	25	12"	8.95	7.95	7.25	6.49
2228156	NMB	4710KL-04W-B19	12	120 x 120 x 25	63.5	Ball	120	1.44	UL/CE/CSA/TUV	27	8 ²	9.95	8.95	7.95	6.95
2228172	AVC	F1225B12L	12	120 x 120 x 25	75.2	Ball	270	3.24	UL/CSA/CUL	39.5	8" w/conn ²	9.95	8.95	7.95	6.95
2228130	Delta	WFB1212H-BF05	12	120 x 120 x 25	86.5	Ball	360	4.32	UL/CSA/TUV/CE	37.6	13 ¹	9.95	8.95	7.95	6.95
2227866	YSTech	FD121225MB	12	120 x 120 x 25	87.8	Ball	290	3.48	UL/CUL/TUV	40.5	12"	12.95	11.95	10.95	9.95
2170927	Adda	AD1212US-A71GL-LF	12	120 x 120 x 25	98.6	Sleeve	500	6.0	UL/CUL/TUV/CE	43.3	11"	8.95	7.95	7.25	6.49
2203346	Adda	AB1212MS-Y01†	12	120 x 120 x 32	28	Sleeve	560	100	UL/CUL/CE/TUV	49	12"	9.95	8.95	7.95	6.95
1928020	Adda	AD1212MB-Y51	12	120 x 120 x 32	99	Ball	260	3.1	UL/CUL/TUV/CE	41	11"	10.95	9.95	8.95	7.95
2211012	EBM Papst	4112GX	12	120 x 120 x 38	94	Sleeve	290	3.5	UL/CSA/CE	44	Terminals	9.95	8.95	7.95	6.95
2173079	Sunon	EEC0381B2-0000-A99	12	120 x 120 x 38	116	Ball	425	5.1	UL/CUL/TUV/CE	44	12"	14.95	13.95	12.95	11.95
2138679	Mechatronics	F1238E12B2	12	120 x 120 x 38	126	Ball	700	8.5	UL/CUL/TUV	43	12 ²	11.95	10.95	9.95	8.95
2228252	Orion	OD1238-12HHB	12	120 x 120 x 38	154	Sleeve	1300	15.6	UL/CUL/CE/TUV	52	12" w/conn	14.95	13.49	11.95	10.95
2203426	Adda	AD1312UB-F51(CU)	12	127 x 127 x 38	193	Ball	1220	14.6	UL/CUL/CE	56	12"	9.95	8.95	7.95	6.95
2228295	Sanyo	109E1712K502	12	172 x 51	300	Ball	2900	34.8	CSA/UL/TUV	55	12"	39.95	35.95	32.95	29.95
2167605	Adda	AD0424HB-G70-LF	24	40 x 40 x 10	6.2	Ball	90	2.16	UL/CUL/TUV/CE	26	12"	9.95	8.95	7.95	6.95
2133931	Adda	AD0424HB-G73	24	40 x 40 x 10	6.7	Ball	90	2.16	UL/CUL/TUV/CE	25	12 ¹	10.95	9.95	8.95	7.95
2217924	Thermactive	RDH4010B2	24	40 x 40 x 10	7.6	Ball	90	2.16	UL/CUL/TUV/CE	33	12"	7.95	6.95	5.95	4.95
2158514	Sunon	MB40202V2-0000-A99	24	40 x 40 x 20	7.7	Vapo	33	2.16	UL/CUL/TUV/CE	21	12"	9.95	8.95	7.95	6.95
2217932	Thermactive	RDH4020B2	24	40 x 40 x 20	8.1	Ball	70	1.68	UL/CUL/TUV/CE	31	12"	10.95	9.95	8.95	7.95
2133940	Adda	AD0424UB-C56	24	40 x 40 x 20	9.6	Ball	90	2.16	CE	37	11 ²	7.95	6.95	5.95	4.95
1708422	Sunon	KDE2406PHS3	24	60 x 60 x 15	15	Sleeve	50	1.2	UL/CUL/TUV/CE	31	12"	7.95	6.95	6.25	5.59
2188588	Sunon	ME60152V2-0000-A99	24	60 x 60 x 15	21.9	Vapo	85	2.04	UL/CUL/TUV	32.5	12"	8.95	7.95	6.95	6.25
2134029	Adda	AD0624MB-C70GL	24	60 x 60 x 20	14.5	Ball	80	1.92	UL/CUL/CE	28	12"	8.95	7.95	6.95	6.25
2224219	Adda	AD0624MS-A70GL	24	60 x 60 x 25	18	Sleeve	80	1.92	UL/CUL/TUV	27	12"	6.95	6.25	5.59	4.95
189861	Jamicon	JF0625B2M-005-065R	24	60 x 60 x 25	19	Ball	130	3.1	UL/TUV/CE	31.3	10"	8.95	7.95	6.95	6.25
2228244	Frilec	2406PTB1	24	60 x 60 x 25	23.5	Ball	60	1.4	UL/CSA/CE	33	12"	8.95	7.95	6.95	6.25
1928071	Adda	AD0624HB-A70GL	24	60 x 60 x 25	25	Ball	150	3.6	UL/CSA/TUV/CE	36.9	12"	8.95	7.95	6.95	6.25

¹ 3 leads; speed sensor ² 3 leads; locked rotor protection ³ 4 leads; wired for Dell proprietary PWM circuit control w/ tach (blue), lock rotor (yellow) & fan guard
⁴ 4 leads with speed sensor, PWM control (All fans operate to their specs with or without the additional optional wire functions) † Blower

For case mounting screws, P/Ns 2188481 or 2188490, page 78

DC Brushless Tubeaxial Fans, Fan Guards & Filters

Call for additional OEM PRICING – we carry major manufacturers.

NEW
MARKED IN PINK



212628



2155065



2218046



DC Brushless Tubeaxial Fans & Blowers (Continued)

* 24V Web Code: QEF * 48V Web Code: MAJ

mm to Inches Conversion Chart

mm	6	6.8	10	15	20	25	28	30	32	35	38	40	45	51	60	70	75	76	80	92	94	95	97	120	125	126	127	150	172
Inches	0.24	0.27	0.40	0.60	0.80	1.00	1.10	1.18	1.26	1.40	1.50	1.60	1.80	2.00	2.36	2.76	2.95	2.99	3.15	3.63	3.70	3.74	3.82	4.72	4.92	4.96	5.00	5.90	6.77

Part No.	Manufacturer	Mfr. Part No.	Voltage (VDC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection (Leads)	Pricing			
												1	10	50	100
212628	Adda	AD0624UB-A71GL	24	60 x 60 x 25	26.9	Ball	160	3.84	UL/CUL/CE	37.9	13"	\$8.95	\$7.95	\$6.95	\$6.25
2224227	Adda	AD0824MX-A70GL	24	80 x 80 x 25	31	Hypro	100	2.4	UL/CUL/TUV	28	12"	8.95	7.95	6.95	5.95
290029	Jamicon	JF0825B2M	24	80 x 80 x 25	32.52	Dual Ball	130	3.1	UL/CSA/TUV/CE	27.8	10"	9.95	8.95	7.95	6.95
136161	Jamicon	JF0825B2H	24	80 x 80 x 25	38.74	Dual Ball	150	3.6	UL/CSA/TUV	31	10"	9.95	8.95	7.95	6.95
2158565	Sunon	EE80252B1-0000-A99	24	80 x 80 x 25	41	Ball	75	1.8	UL/CUL/TUV/CE	33	12"	9.95	8.95	7.95	6.95
1928388	Adda	AD0824UB-A72GL	24	80 x 80 x 25	50	Ball	260	6.24	UL/CUL/CE/TUV	41	12" 2	10.95	9.95	8.95	7.95
2134150	Adda	AQ0824UB-A71GL *	24	80 x 80 x 25	50	Ball	260	6.24	CE	41	12"	11.95	10.95	9.95	8.95
2211160	IMC Boxer	3113PL05WB30	24	80 x 80 x 32	28	Ball	130	3.1	UL/CUL	31	12"	5.95	5.49	4.95	4.49
2220171	Adda	AD0824UB-Y51	24	80 x 80 x 32	55.3	Ball	180	4.3	UL/CUL/TUV/CE	43.8	12"	9.95	8.95	7.95	6.95
1951051	Mechatronics	E9225L24B1-FS	24	92 x 92 x 25	35	Ball	85	2.04	UL/CUL	27	12" 1	4.95	3.95	2.95	2.49
2203071	NMB	3610PL05W-B30	24	92 x 92 x 25	41	Ball	87	2.1	UL	33	11"	5.95	4.95	4.49	3.95
2203080	Nidec	TA350DC-A31394-55	24	92 x 92 x 25	42	Ball	140	3.12	UL/CSA	40	3" w/ conn	2.95	2.75	2.49	1.95
2215751	NMB/IMC	3610PL-05W-B20-100	24	92 x 92 x 25	43	Ball	90	2.2	UL/CUL/TUV	39	12"	4.95	4.49	3.95	3.49
2155065	Delta	AFB0924H-R00	24	92 x 92 x 25	51.2	Ball	200	4.8	UL/CSA/CE	34	12" 2	8.95	7.95	6.95	5.95
2158303	Sunon	EE92252B1-0000-A99	24	92 x 92 x 25	51.5	Dual Ball	87	2.1	UL/TUV/CE	34	12"	10.95	9.95	8.95	7.95
1928329	Adda	AD0924XB-A71GL	24	92 x 92 x 25	67	Ball	250	6.0	UL/CUL/TUV/CE	42	12"	9.95	8.95	7.95	6.95
2230977	Delta	AFB0924VH	24	92 x 92 x 25	68	Ball	220	5.2	UL/CSA/VDE/CE	45	12"	9.95	8.95	7.95	6.95
2228199	Sunon	KDE2412PTB2-6A	24	120 x 120 x 25	80	Ball	230	5.5	UL/CUL/CE/TUV	36.5	12"	11.95	10.95	9.95	8.95
2121527	Adda	AD1224MB-A71GL	24	120 x 120 x 25	80.5	Ball	170	4.08	UL/CUL/TUV/CE	38	12"	11.95	10.95	9.95	8.95
2218046	Adda	AD1224UB-A70GL	24	120 x 120 x 25	99	Ball	250	6.0	UL/CUL/TUV/CE	43.3	11"	12.95	11.95	10.95	9.95
2197556	Coolmax	1225M24B-ZD1	24	120 x 120 x 25	103.8	Dual Ball	300	7.2	UL/TUV	42.5	6" w/ conn	8.95	7.95	6.95	6.25
2211021	EBM Papst	4124GX	24	120 x 120 x 38	87	Sleeve	138	3.3	UL/CSA/CE	43	Terminals	9.95	8.95	7.95	6.95
694524	Jamicon	JF1238B2MR-R	24	120 x 120 x 38	101.3	Ball	230	5.28	UL/CSA/TUV/CE	39.1	9"	15.95	14.95	13.95	12.49
2215478	Conair Rotron	MD24B2	24	120 x 120 x 38	110	Ball	250	6.0	UL/CSA/TUV/CE	50	Terminals	10.95	9.95	8.95	7.95
1809910	Sunon	KD2412PMSX-6A	24	120 x 120 x 38	119	Sleeve	300	7.2	UL/CUL/TUV/CE	45	12"	7.95	6.95	6.25	5.59
2197433	EBM Pabst	4214NHRH	24	120 x 120 x 38	120.7	Ball	313	7.5	UL/CSA/CE	49	12"	9.95	8.95	7.95	6.95
2144761	Mechatronics	F1238X24B-FS	24	120 x 120 x 38	140	Dual Ball	500	12	UL/CUL/TUV	45	12"	10.95	9.95	8.95	7.95
2121341	Adda	AD0848UB-Y51	48	80 x 80 x 32	55.3	Ball	140	6.72	UL/CUL/TUV/CE	44	12"	7.95	6.95	5.95	5.49
2135371	Adda	AD0948MB-F91DS(M)	48	92 x 92 x 38	93.5	Dual Ball	160	7.6	CE	48.5	12"	9.95	8.95	7.95	6.95
2203400	Adda	AD1248HB-A71GL	48	120 x 120 x 25	87.8	Ball	100	4.8	UL/CUL/CE/TUV	39.1	12"	10.95	9.95	8.95	7.95
2134192	Adda	AD1248UB-Y51	48	120 x 120 x 32	131	Ball	210	10.08	UL/CUL/TUV/CE	48.4	11"	10.95	9.95	8.95	7.95
2134352	Adda	AD1348HB-F53	48	127 x 127 x 38	161	Ball	230	11	UL/CUL/TUV/CE	53	11" 1	17.95	15.95	14.49	12.95
1954711	Delta	EFB1348HVE-SV06	48	127 x 127 x 38	168	Ball	360	20	UL/CSA/VDE/CE	52	26" 1	19.95	17.95	15.95	14.49

¹ 3 leads; speed sensor ² 3 leads; locked rotor protection (All fans operate to their specs with or without the additional optional wire functions) * Waterproof
For case mounting screws, P/Ns 2188481 or 2188490, page 78

Fan Guards, Screws & Aluminum Washable Filters

* Web Code: UAR

• Guards and filters fit all fans. Please match by size dimension.
Example: P/N 300557 fan (80mm) matches P/N 31924 metal guard (80mm).

2188481



Fig. 1



Fig. 2



Fig. 3



Fig. 4



Fig. 5



Fig. 6



Part No.	mm	Description	Fig.	1	10	50	100
2188481	5x10	Fan frame screw, chrome	—	\$.15	\$.09	\$.07	\$.049
123502	40	Metal (chrome) guard	1	.59	.55	.49	.45
120038	60	Metal (chrome) guard	1	.65	.59	.55	.49
687666	60	Metal (black anodized) guard	2	.85	.79	.75	.69
31924	80	Metal (chrome) guard	1	.69	.65	.59	.55
1928433	80	Metal (black anodized) guard	2	.79	.69	.65	.59
2172869	80	Metal (gold plated) guard	2	.55	.49	.45	.39
123511	92	Metal (chrome) guard	1	.75	.69	.65	.59
2135689	92	Metal (black anodized) guard	2	.89	.79	.69	.59
2172877	92	Metal (gold plated) guard	2	.65	.55	.45	.39
25735	120	Metal (chrome) guard	1	.79	.75	.69	.65
695068	120	Metal (black anodized) guard	2	1.09	.99	.89	.79
Part No.	mm	Description	Fig.	1	10	50	100
695076	127	Metal (chrome) guard	1	\$.79	\$.69	\$.59	\$.49
1811198	172	Metal (chrome) guard	1	.89	.79	.69	.59
1952290	80	Plastic guard only	3	.49	.45	.39	.35
1952661	92	Plastic guard only	3	.59	.55	.49	.45
1952695	40	Plastic guard w/ mesh	4	1.59	1.49	1.35	1.25
1952708	60	Plastic guard w/ mesh	5	1.65	1.49	1.39	1.29
2158135	80	Plastic guard w/ mesh	4	1.65	1.49	1.39	1.29
138562	80	Plastic guard w/ mesh (clip)	5	1.79	1.69	1.59	1.45
229665	92	Plastic guard w/ mesh	4	1.39	1.29	1.19	1.05
196817	120	Plastic guard w/ mesh	4	2.19	2.09	1.95	1.79
138580	80	Alum. washable filter	6	2.25	1.95	1.79	1.59
130105	120	Alum. washable filter	6	3.49	3.15	2.75	2.49

* For additional products, availability and specifications visit Jameco.com and enter the Web Code in the product search box



Order by Phone at 1-800-831-4242 or Online at www.Jameco.com

AC Tubeaxial Fans & Power Cords

3 LEVELS OF SAVINGS
NAME BRANDS **HOUSE BRANDS** **SPECIAL BUY**



Call for additional OEM PRICING – we carry major manufacturers.

120 & 220VAC Tubeaxial Fans

NEW
 MARKED IN PINK

COMMONWEALTH™



* Web Code: ABJ



2126096

2228287

2205624

102892

Part No.	Manufacturer	Mfr. Part No.	Voltage (VAC)	Size mm (W x H x D)	Air Flow (CFM)	Bearing	Current (mA)	Power (Watts)	Agency Approvals	Noise (dBA)	Connection	Pricing			
												1	10	50	100
213867	Fulltech	UF60D11BWH	120	60 x 60 x 30	10.2	Ball	35	4	UL/CUL/VDE/CE	28	12" leads	\$17.95	\$16.49	\$15.95	\$14.49
2230660	Thermocool	G8025HAS	120	80 x 80 x 25	23	Sleeve	130	13	UL/CUL/TUV/CE	30	12" leads	10.95	9.95	8.95	7.95
146078	Common Wealth	FP108AX-S1-B	120	80 x 80 x 25	23	Ball	180	14	UL/CE	29	12" leads	15.95	14.49	12.95	11.95
300557	Fulltech	UF80B11SWH	120	80 x 80 x 25	24	Sleeve	140	14	UL/CUL/TUV/CE	35	12" leads	13.95	12.95	11.95	10.95
2228279	Mechatronics	UF80A12BWL	120	80 x 80 x 38	25	Ball	110	9	UL/CSA	32	11" leads	14.95	13.49	11.95	10.95
300600	Fulltech	UF80A11BWH	120	80 x 80 x 38	29	Ball	120	12	UL/CUL/TUV/CE	36	12" leads	15.95	14.49	12.95	11.49
300389	Fulltech	UF80A11BTH	120	80 x 80 x 38	30	Ball	120	12	UL/CUL/TUV/CE	36	Terminals	15.95	14.49	12.95	11.49
2126096	Common Wealth	FP-108B**	120	92 x 92 x 25	22	Ball	60	8	UL/CSA	24	15" leads	9.95	8.95	7.95	6.95
2230678	Thermocool	G9225HAS	120	92 x 92 x 25	34	Sleeve	140	13	UL/CUL/TUV/CE	40	Terminals	10.95	9.95	8.95	7.95
303467	Sunon	SF11592A-1092HBL.GN	120	92 x 92 x 25	37	Ball	110	12	UL/CSA/TUV/CE	40	12" leads	12.95	11.95	10.95	9.95
2135275	Common Wealth	FP-108JC	120	92 x 92 x 38	45	Sleeve	150	10	UL/CSA/CE	37	12" leads	13.95	12.49	10.95	9.95
1810048	Sunon	SP101AT-1122HBL.GN	120	120 x 120 x 25	78	Ball	180	18	UL/CUL/TUV/CE	46	12" leads	16.95	15.49	13.95	12.49
124063	Sunon	SP101AT-1122HBT.GN	120	120 x 120 x 25	78	Ball	180	18	CSA/TUV/CE	46	Terminals	16.95	15.49	13.95	12.49
2230379	EBM PABST	4800N	120	120 x 120 x 38	57.1	Sleeve	78	9	UL/CSA/CE	32	Terminals	14.95	13.49	11.95	10.95
303361	Fulltech	UF12A11BTL1	120	120 x 120 x 38	64	Ball	80	15	UL/CUL/TUV/CE	37	Terminals	14.95	13.49	11.95	10.95
2230694	Thermocool	G12038MAB	120	120 x 120 x 38	85	Ball	220	19	UL/CUL/TUV/CE	44	Terminals	12.95	11.95	10.95	9.95
2230686	Thermocool	G12038HAS	120	120 x 120 x 38	95	Sleeve	280	21	UL/CUL/TUV/CE	48	Terminals	11.95	10.95	9.95	8.95
106586	Common Wealth	FP108-1-S1/T	120	120 x 120 x 38	105	Sleeve	180	12	UL/CSA/CE	47	Terminals	12.95	11.95	10.95	9.95
16935	Common Wealth	FP108-1-S1-B/T	120	120 x 120 x 38	105	Ball	200	17	UL/CSA/TUV/CE	47	Terminals	13.95	12.49	11.95	10.49
1707163	Sunon	SP101A-1123HBL-GN	120	120 x 120 x 38	107	Ball	180	18	UL/CSA/TUV	50	12" leads	15.95	14.49	12.95	11.49
2125931	Common Wealth	FP108-1	120	120 x 120 x 38	112	Ball	250	19	UL/CUL/TUV/CE	45	Terminals	13.95	12.49	11.49	9.95
102884	Sunon	SP100A-1123XBT.GN	120	120 x 120 x 38	117	Ball	240	20	UL/CUL/TUV/CE	50	Terminals	14.95	13.95	12.95	11.95
2230141	Fulltech	UF13A11BTH	120	127 x 127 x 38	120	Ball	160	12	UL/CUL/TUV/CE	50	Terminals	19.95	17.95	15.95	14.49
2230707	Thermocool	G13538HAS	120	135 x 135 x 38	122	Sleeve	340	25	UL/CUL/TUV/CE	53	12" leads	13.95	12.49	11.25	10.49
2230715	Thermocool	G15050HAS	120	150 x 150 x 50	198	Sleeve	400	38	UL/CUL/TUV/CE	59	12" leads	20.95	18.95	16.95	15.49
2227701	ETRI	148VE0282030	120	172 x 150 x 38	122	Ball	100	11	UL/CSA/CE	36	Terminals	29.95	26.95	24.95	21.95
2230723	Thermocool	G17050HASB	120	172 x 172 x 51	198	Ball	400	38	UL/CUL/TUV/CE	59	Terminals	20.95	18.95	16.95	15.49
189684	Fulltech	UF15PC11BTH	120	172 x 150 x 51	226	Ball	250	30	UL/CUL/TUV/CE	58	Terminals	36.95	34.95	32.95	29.95
212582	Fulltech	UF15PC11BWH	120	172 x 150 x 51	226	Ball	250	30	UL/CUL/TUV/CE	58	12" leads	36.95	34.95	32.95	29.95
2230117	ADDA	AA8252HB-AT	220	80 x 80 x 25	21	Ball	60	13.8	UL/CUL/TUV/CE	27.8	Terminals	12.95	11.95	10.95	9.95
100918	Sunon	SF23080A/2083HSL.GN	220	80 x 80 x 38	30	Sleeve	60	13.5	UL/CSA/TUV/CE	35	12" leads	15.95	13.95	12.49	10.95
355630	Fulltech	UF-80A23-BTH-R	220	80 x 80 x 38	30	Ball	60	12	UL/CSA/VDE/CE	36	Terminals	12.95	11.49	10.25	9.49
2210837	EG&G Rotron	SU3G1	220	80 x 80 x 38	32	Sleeve	70	10	UL/CSA	39	12" leads	8.95	7.95	6.95	6.25
303459	Sunon	DP200A-2123XBL.GN	220	120 x 120 x 38	117	Ball	120	21	UL/CSA/TUV/CE	50	12" leads	15.95	14.95	13.95	12.95
102892	Sunon	DP200A-2123XBT.GN	220	120 x 120 x 38	117	Ball	120	21	UL/CSA/TUV/CE	50	Terminals	17.95	15.95	14.49	12.95
2258419	Fulltech	UF12A1223BWH*	115/230	120 x 120 x 38	92/106	Ball	260/120	23	UL/CUL/TUV/CE	42/46	12" leads	15.95	14.49	12.95	11.59
2228287	Papst	RER125-19/56	230	138 x 40	61.2	Ball	120	19	UL/CSA/TUV/CE	65	15" leads	39.95	35.95	32.95	29.95
2230424	Commonwealth	FP-108EX (S-1)	220	172 x 150 x 51	210	Ball	220	32	UL/CSA/TUV/CE	50	Terminals	34.95	31.49	27.95	24.95
2205624	Adda	AK1752HB-LF(AT)	220	172 x 150 x 51	210	Ball	160	36.8	UL/CUL/TUV/CE	65	Terminals	39.95	37.95	34.95	32.49

* 4 wire leads, dual voltage

** 24 AWG quick disconnect terminals

 
 
 

For case mounting screws, P/Ns 2188481 or 2188490, page 78



DC & AC Plug Fan Power Cords

* Web Code: GAE

For Fans with Terminal Connection

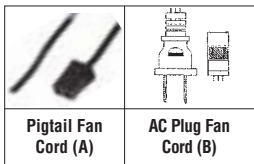

Part No.	Description	Fig.	Length	1	10	100	250
28564	Straight pigtail fan cord	1A	24"	\$1.49	\$1.25	\$.99	\$.89
2076658	Straight pigtail fan cord	1A	36"	1.59	1.45	1.29	1.15
1952548	45° pigtail fan cord	2A	24"	1.59	1.35	1.09	.99
104192	90° pigtail fan cord	3A	24"	1.59	1.35	1.09	.99
1952572	Straight AC plug fan cord	1B	72"	3.95	3.59	3.19	2.49
1952581	45° AC plug fan cord	2B	72"	4.95	4.59	3.95	3.49

REGULATED SWITCHING TABLE-TOP POWER SUPPLIES — BEST SELLERS

Part No.	Voltage	Current	Page	Price
2227807	5VDC	5A	95	\$15.95
2229482	12VDC	1.5A	95	11.95
2197927	12VDC	3A	95	13.95
2079357	12VDC	3.34A	95	16.95
2218151	12VDC	5A	96	16.95
2230230	12VDC	6A	96	17.95



2218151



1950913

Part No.	Voltage	Current	Page	Price
2229950	12VDC	10A	88	\$49.95
1940619	15VDC	3.33A	96	12.49
1950913	24VDC	2.5A	96	19.95
2078338	24VDC	3.75A	96	28.95
2228931	48VDC	0.52A	96	11.95
2218100	48VDC	1.45A	96	16.95