


## LED Panel-Mount Indicators

- Easy panel installation
  - Panel/status/instrument indicators
- 141111CJ/141129CJ/141137CJ: Chrome housing  
236427CJ/236419CJ: Black nylon housing

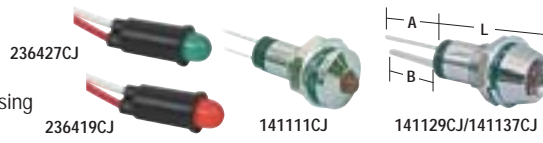

Part No.	Mfr. Cross Ref. No.	LED Size	Color	Dimensions (in.)			Mounting Hole	Vf @ If	Pricing			
				L	A	B			1	10	100	1000
236427CJ	5102H5-12V	T1 $\frac{3}{4}$	Green	.53	6.0	6.0	.25"	12V @ 15mA	\$1.25	\$1.12	\$0.90	\$0.68
236419CJ	5102H1-12V	T1 $\frac{3}{4}$	Red	.53	6.0	6.0	.25"	12V @ 15mA	1.19	1.07	.86	.64
141111CJ	L922SRD	T1	Red	.56	.34	.25	.23"	12V @ 20mA	.79	.60	.52	.45
141129CJ	L913RD	T1	Red	.56	.39	.32	.24"	12V @ 20mA	1.09	.81	.69	.61
141137CJ	L917RD	T1 $\frac{3}{4}$	Red	.70	.55	.47	.31"	12V @ 20mA	.89	.79	.71	.55

## Neon Panel Mount Lamps

- Input voltage: 120V
- Mounting hole diameter: 5/8" (16mm)
- Solder terminals: 0.196" (5mm)



215802CJ: Red  
215811CJ: Yellow  
215829CJ: Green

Part No.	Mfr. Cross Ref. No.	1	10	100
215802CJ	R9-71N-05-120V-R ..	\$1.79	\$1.59	\$1.35
215811CJ	R9-71N-05-120V-Y ....	1.79	1.59	1.35
215829CJ	R9-71N-05-120V-G ....	1.79	1.59	1.35

## Incandescent Panel Mount Lamps

Quantity SAVE

- 215781CJ/215790CJ/215773CJ: wire length - 3.9" (100mm)
- 215749CJ/215757CJ/215765CJ: wire length - 4.9" (125mm)
- 215714CJ/215722CJ/215731CJ: solder terminals - 0.196" (5mm)



Part No.	Mfr. Cross Ref. No.	Fig.	Voltage	Color	Mounting Hole	Pricing		
						1	10	100
215773CJ	R9-46B-W100-12V-R	1	12	Red	1/2" (13mm)	\$1.79	\$1.61	\$1.20
215781CJ	R9-46B-W100-12V-Y	1	12	Yellow	1/2" (13mm)	1.65	1.45	1.19
215790CJ	R9-46B-W100-12V-G	1	12	Green	1/2" (13mm)	1.79	1.61	1.20
215749CJ	R9-55B-W130-12V-R	2	12	Red	9/32" (7mm)	1.79	1.59	1.35
215757CJ	R9-55B-W130-12V-Y	2	12	Yellow	9/32" (7mm)	1.65	1.45	1.19
215765CJ	R9-55B-W130-12V-G	2	12	Green	9/32" (7mm)	1.79	1.59	1.35
215714CJ	R9-71B-05-12V-R	3	12	Red	5/8" (16mm)	1.79	1.61	1.20
215722CJ	R9-71B-05-12V-Y	3	12	Yellow	5/8" (16mm)	1.65	1.45	1.19
215731CJ	R9-71B-05-12V-G	3	12	Green	5/8" (16mm)	1.79	1.61	1.20

## Miniature Fluorescent Lamps

Add fluorescent color to your projects, computer case, car and other displays with these economical lights. Now you can easily and affordably mount these 4" light tubes to add cool cold-cathode effects and give your display a richer look and feel. Optional power supply below converts 12VDC input into 180V - 800V output needed by lights.



Part No.	Prod. No.	Description	1	10	25
239610CJ	FLW1	White light ....	\$9.95	\$8.95	\$7.95
239572CJ	FLB1	Blue light .....	9.95	8.95	7.95
239581CJ	FLBL1	Black light .....	9.95	8.95	7.95
239628CJ	FLY1	Yellow light .....	9.95	8.95	7.95
239601CJ	FLP1	Pink light .....	9.95	8.95	7.95
239599CJ	FLG1	Green light .....	9.95	8.95	7.95
239636CJ	FLPS1	12VDC PS .....	9.95	8.95	7.95

## Cluster-Type T1 $\frac{3}{4}$ LED Lamps

- Cluster-type red/green T1 $\frac{3}{4}$  LEDs
- Lens: water clear
- Common anode
- 660nm for red/570nm for green
- 3 lead wires

150914CJ: 50 Cluster (30 green/20 red)    150922CJ: 14 Cluster (8 green/6 red)



Part No.	Product No.	Vf @ If	mcd @ mA	Lead Wire	Mounting Hole Dia.	Dimensions (Dia. x L)	Pricing		
							1	10	100
150914CJ	LCR5250A-79	20.5V @ 40mA	12,000 @ 40	16"	M4	2.07 x 1.98	\$13.19	\$11.99	\$11.35
150922CJ	LCR2614B-79	10V @ 20mA	1950 @ 20	7"	M3	1.02 x 1.51	4.95	4.21	3.16

## CdS Photocells

- Applications include: auto-focus lenses, exposure meters, contrast controls for TVs, dimmer or light switches, flame detectors, electronic toys, street lamp switches, optocouplers
- Generate variable signal based on detection of light levels
- Soldering: 230°C for 3 seconds
- Operating temperature: -30°C to +70°C
- Cadmium Sulfide (CdS)

SALE

Part No.	Mfr. Cross Ref. No.	Rating		Resistance ( $\Omega$ )		Size (inches)		Lead Spacing (inches)	Lead Length (inches)	Pricing				
		Vp	mW	Dark	Light	A	B			1	10	100	1000	
120299CJ	136055CJ	CDST08	50	200	100k	10k	0.40	0.44	0.30	1.50	\$0.89	\$0.80	\$0.69	\$0.52
	202366CJ	CDS0029001	150	90	300k	4k	0.14	0.17	0.10	1.02	1.69	1.52	1.22	.91
	120310CJ	CDS0029004	150	90	2M	27k	0.14	0.17	0.10	1.44	1.45	1.20	1.09	.99
	202374CJ	CDS0029006	150	90	5M	80k	0.14	0.17	0.10	1.02	1.65	1.45	1.16	.87
202438CJ	202391CJ	CDS0029203	150	90	10M	5k	0.14	0.17	0.10	1.02	1.49	1.35	1.19	1.09
	202382CJ	CDS0029008	150	90	20M	10k	0.14	0.17	0.10	1.02	1.49	1.34	1.21	.99
	202420CJ	CDS0018003	150	100	500k	16k	0.17	0.20	0.13	1.02	1.55	1.35	1.25	1.05
	202403CJ	CDS0018001	150	100	200k	3k	0.17	0.20	0.13	1.02	1.49	1.35	1.19	1.09
	202411CJ	CDS0018006	150	100	5M	80k	0.17	0.20	0.13	1.02	.69	.65	.59	.55
	202438CJ	CDS0037004	200	150	500k	15k	0.25	0.29	0.20	1.02	1.49	1.34	1.07	.80
	120301CJ	CDS0037001	200	150	300k	3k	0.25	0.29	0.20	1.02	1.79	1.59	1.45	1.29
	120299CJ	CDS0045001	350	400	300k	8k	0.37	0.43	0.30	1.44	1.79	1.59	1.45	1.29
	202454CJ	CDS0045003	350	400	1M	12k	0.37	0.43	0.30	1.44	1.69	1.55	1.35	1.15

Committed to You

We are committed to providing you with the best service in the industry.