

Pocket Trimmer Potentiometer Adjustment Tool

- Glass-filled body
- Stainless steel blade
- Size: 5.2"L



Part No.	Description	1	10	100
153314CB	Trimmer tool	\$1.35	\$1.22	\$1.09

Crimp Pin Extraction Tools

 
- Easily extract 0.093" locking pins from connectors
- Heavy duty metal
- Precision design • Length: 5" 131887CB
- See crimp pins on pg 138 (42729CB and 42649CB)



Part No.	Prod. No.	Description	1	10
131887CB	HT319C	Male tool for 42729CB	\$10.95	\$9.86
131879CB	HT319B	Fem. tool for 42649CB	11.29	9.03

BNC Connector Removal Tools

- For deep chassis removal
- Allows access to hard-to-reach places



Part No.	Product No.	Length	1	10	25
159151CB	HT2206	6"	\$11.49	\$9.05	\$6.79
152047CB	HT2212	12"	14.99	14.25	13.53


D-Sub Pin Insertion/Extraction Tool

- Insertion/extraction tool: red/white plastic body; exchangeable tips



Part No.	Description	1	10	100
19094CB	Insert/extract tool	\$2.79	\$2.49	\$2.15

Molex Connector Extraction Tools

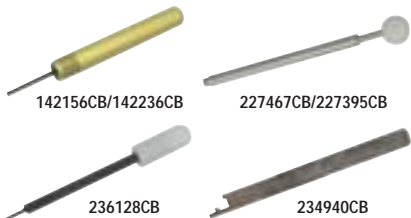

- 142156CB/227467CB: For .062" power connectors
- 142236CB/227395CB: For .093" power connectors
- 236128CB/234940CB: For .100" KK® series housing

Part No.	Product No.	AWG	1	10
142156CB	W-HT-2285	18-30	\$14.49	\$13.49
227467CB	W-HT-2023	18-30	11.99	10.99
142236CB	W-HT-2038	14-30	14.49	13.49
227395CB	W-HT-2054	14-30	11.99	10.99
236128CB	W-HT-1884	22-30	9.99	8.99
234940CB	11-03-0022	22-30	14.99	12.99

Bushing Assembly Tool

- For use with strain relief bushings, P/N 182351CB, pg 108



Part No.	Description	1	10	100
73470CB	Bushing tool	\$34.95	\$28.75	\$28.45

Committed To You

We're committed to providing you with the best service in the industry.

3X, 3-Bulb Magnifying Lamp

Adjustable rectangular 3-diopter lens allows independent movement of the lens for best lighting and viewing angles. Three 9-watt compact fluorescent bulbs located to the side and top of the lens provide superior lighting to your workspace or job at hand. The integral spring-balance arm reduces the chance of pinched hands from springs, and provides a sleek clean look.



- 47" long arm
- 2 on/off buttons
- Color: beige
- UL listed
- Weight: 8.15 lbs.

Part No.	Description	1	10	25
217517CB	Adj. magnifying lamp	\$79.95	\$74.95	\$69.95

3X Magnifying Lamps

- 45" extension arm
- Supplied with 22-watt circuline tube
- New wire clip design permits easy installation
- Extra strong, all-metal mounting base with electrical outlet
- Metal bulb holder for extra protection
- Power requirement: 110VAC/60Hz
- 3X magnification
- Weight: 7.3 lbs.



Part No.	Description	1	10	25
100829CB	Black lamp	\$59.95	\$53.95	\$49.95
149981CB	White lamp	59.95	53.95	49.95

Standard Adjustable 3X Magnifying Lamp

- 4" Diameter lens
- Maneuverable 30" arm extension
- Lamp tilts & turns in any direction
- Uses 60W incandescent bulb (not included)
- Power requirement: 110VAC/60Hz
- 3X magnification
- Weight: 2.9 lbs.



Part No.	Description	1	10	25
22710CB	Magnifying lamp	\$26.49	\$25.19	\$23.89

Precision 5X Magnifying Lamp

The arm extends to 40", is adjustable to any direction or angle, and has a 5X magnifying glass with built-in light. This is the perfect tool to help identify small electronic components and magnify a printed circuit board to help solder electronic components.



- 5" diameter lens
- Weight: 7.1 lbs.
- Power requirement: 110VAC/60Hz

Includes: 22W circuline fluorescent bulb

Part No.	Description	1	10	25
197456CB	Magnifying lamp	\$109.95	\$98.95	\$88.95

Flexible Neck Magnifier

Never squint again at small fine print or have a hard time holding a magnifying glass while holding two other tools with only two hands. Just simply clamp the magnifying lens on to a table or workbench and adjust the flexible gooseneck into position.



- 3.5" diameter & 3x diopter lens
- Arm length: 20"
- Weight: 1.8 lbs.

Part No.	Description	Price
239548CB	Flexible neck magnifier	\$11.49

Tweezers with 8X Magnifier

The perfect combination hand tool for professionals working with small objects. Magnifying glass stays in perfect focus with tweezer heads.



- Stainless steel construction
- Precision tip tweezers
- 1.2" diameter 8 diopter lens
- Length: 3.8"

Part No.	Description	1	5
217824CB	Tweezer magnifier	\$6.29	\$5.99

Super Bright, Super Reliable LED Flashlights

The perfect tool for individuals who really depend upon a flashlight that always works. Containing space-age solid-state circuitry, batteries last 14X longer than conventional flashlights. Its super bright white LEDs will last at least 11 years.



- Waterproof, designed for all weather conditions
- Shockproof, withstands a drop from 4'
- Low cost per hour of operation
- Industrial grade switch, rated for 10,000 operations

215677CB: One month continuous operation using three "D" cell batteries (not included, P/N 215845CB, pg 225)



215685CB: 25-days continuous operation using three "C" cell batteries (not included)

215693CB: 14-days continuous operation using 3 "AA" cell batteries (not included, P/N 198707CB, pg 225)

262422CB: 210 hours of continuous operation using 3 "AAAA" batteries (included)

261972CB: Headtorch delivers 330 hours of continuous operation using 3 "AA" batteries (not included, use P/N 198707CB, pg 225)

Part No.	Cross Ref. No.	LEDs	Length	1	10
215677CB	LW-4000	10	10.6"	\$63.95 \$54.95	\$49.59
215685CB	LW-3000	7	8.9"	49.95	44.96
215693CB	LW-2100	4	7.9"	31.95	29.63
262422CB	LW-TEC1000	1	—	\$21.79 19.95	18.95
261972CB	LW-HT	4	—	37.95	34.16