



RoHS Compliant Product  
RoHS Also Available

Details on Page 1

Color Code Legend  
New Sale Lower\$ QtySave

## 2-Piece Tweezer Set

 
- PVC insulated handles
- Serrated tips for parts handling
- Bent tip and straight rounded tip (wide tip)
- Length: 5.8"



**SALE**

Part No.	Description	1	10	25
253180CK	Tweezer set	\$2.29	\$2.05	\$1.85


## 4-Piece Steel Tweezer Set



- 4 styles of stainless steel tweezers, one self-locking
- Ideal for picking up small components in hard-to-reach places

Part No.	Description	1	10	50
10735CK	4-piece tweezer set	\$7.95	\$6.95	\$5.95

## Tweezers

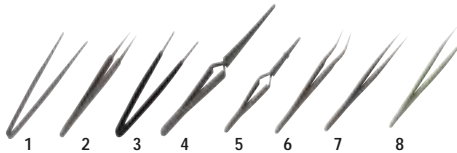

- 253163CK: Straight, round tapered, wide-point tip
- 252929CK: Straight round tapered, fine-point tip, stainless steel
- 253121CK: Wide-tip, insulated
- 252945CK: Self-closing reverse-action tweezers; wide point tip; stainless steel
- 252937CK: Self-closing reverse-action tweezers; medium point tip; stainless steel
- 253091CK: Curved fine-point tip
- 252911CK: Straight fine-point tip
- 253112CK: Fine-point tip, insulated, anti-static

**SALE**

Part No.	Length	Photo	1	10	25
253163CK	4.5"	1	\$0.79	\$0.69	\$0.63
252929CK	4.75"	2	\$2.25	1.99	1.79
253121CK	4.6"	3	\$0.99	.89	.79
252945CK	6.6"	4	\$1.99	1.79	1.65
252937CK	4.3"	5	\$2.25	1.99	1.79
253091CK	4.6"	6	\$2.25	1.99	1.79
252911CK	4.75"	7	\$2.25	1.99	1.79
253112CK	4.75"	8	\$2.25	1.99	1.79

## 12-Piece File Tool Kit

- Fine and coarse file assortment for metal and wood
- 3-piece metal flat; 2-piece metal triangle; 1 each wood round; metal round; wood half-round; metal half-round; metal/wood half-round; and 2 detachable handles



Part No.	Description	1	5
233314CK	12-piece file kit	\$8.55	\$7.75

**SALE**

## 8-Piece Steel File Set

- Strong tool steel
- 1 ea. 0.15"Dia., 0.13"Dia., 0.12"Dia., 0.11"Dia. and four 0.22"Dia. (5.65"L)



**SALE**

Part No.	Cross Ref. No.	Description	1	10
100360CK	FS108F	8-piece file set	\$7.29	\$6.62

## Strip-Wrap-Unwrap Tool

- Tool tip made of tempered steel
- Spring steel cutter
- Use with 30 AWG wire on .025" square posts
- No solder necessary, see pg 102 for wire
- Wrap 1 to 2 turns of insulated portion of wire for secure connections • 4.5" long



34585CK

Part No.	Cross Ref. No.	1	10	25
34585CK	HSM30 (Modified)	\$49.99	\$44.99	\$39.99
236785CK	HSR30 (Regular)	\$29.95	26.95	23.95

## 30 AWG Wire Wrap/Strip Tools

Recommended for use on 0.025" (0.63mm) square posts on 0.100" (2.54mm) center grids. The first 1-1/2 loop on the modified tool has wire insulation while all loops on a regular tool have bare wires.



242798CK



Regular Modified

Part No.	Description	1	10	25
242801CK	Tool (Regular)	\$17.95	\$16.15	\$14.55
242798CK	Tool (Modified)	19.95	17.95	16.15
242827CK	Replace tip for 242801CK	6.49	5.85	5.29
242819CK	Replace tip for 242798CK	7.49	6.75	5.89
242835CK	Replace stripper assembly	5.49	4.67	3.50

**SALE**

## IC Pin Straightener

Straighten bent pins safely and easily with Jameco's IC pin straightener.



- Straightens 8/14/16/18/20/24/28/40/42-pin ICs
- Materials: black plastic • Size: 3.3"L x 1.5"W x 0.4"H

Includes: Ground terminal

Part No.	Description	1	10	100
99362CK	IC straightener	\$6.95	\$6.26	\$5.63

## 33' Magnetic Tip Tape Measure

Retractable measuring tape's case has a rubber finish for easy grip and yellow contrast for easy visibility.



**SALE**

- 1" wide
- Metric and inches with 1mm and 1/16" scales
- Triple riveted magnetic end hook
- Bottom & side buttons for temporary tape lock
- Front thumb lock for permanent locking of tape measure • Belt clip and strap

Part No.	Description	1	5
261833CK	Measuring tape	\$6.99	\$6.25

## Impact Punch-Down Tool

Conforms to AT&T performance specification. Reversible clip-in blade, adjustable spring-loaded impact mechanism and spare blade storage in the handle.



124142CK

124151CK

- One-year warranty
- 124142CK: For 66-type bifurcated terminals
- Size: 7.0"L x 1.4"W x 1.1"H
- 124151CK: Blade for 110-type terminals

**SALE**

Part No.	Description	1	10
124142CK	# 3527 Tool w/ 66 blade	\$47.89	\$43.53
124151CK	110 blade	17.99	16.19

## Impact Punch-Down Tools

- Reversible clip-in blade
- Adjustable (HI-LO) spring-loaded impact mechanism
- Storage bin on handle for spare blade
- 175071CK: Tool with blade
- For 66-type terminals
- Size: 5.2"L x 1.5"W x 1.0"H
- 324013CK: Tool with blade
- For 110-type terminals
- Size: 5.8"L x 1.7"W x 1.2"H
- 175089CK: Punch-down blade 110-type terminals



175089CK 175071CK

Part No.	Description	1	10
175071CK	Tool with 66 blade	\$34.95	\$31.46
324013CK	Tool with 110 blade	37.39	33.65
324021CK	Punch-down blade 66	14.95	13.49
175089CK	Punch-down blade 110	14.95	13.49

## Digital Display Calipers

Metric and Inches

- Hardened stainless steel
- Display: inches to 0.001; mm to 0.01
- Instructions for making internal, external, depth & step measurements
- Calipers measure to 6 inches/150mm
- One-year warranty



Includes: Fitted case and 1.5V silver oxide battery (replacement battery, P/N 140783CK, pg 228)

Part No.	Description	1	10	25
127482CK	Digital disp. calipers	\$64.95	\$58.46	\$52.61

## Metal Dial Calipers

Choose Metric or Inches

- For accurate measurements every time
- Measures outside, inside and depth
- Easy-to-read dial gauge
- Length: 6" (150mm)
- Materials: metal • Color: silver



116134CK

Part No.	Description (min. reading)	1	10	25
116134CK	Metric (.02 mm)	\$29.95	\$26.96	\$24.26
116126CK	Inches (.001 inch)	29.95	26.96	24.26

We're committed to providing you with the best service in the industry.



## Free Technical Support

Our knowledgeable Tech Support department is ready to answer your questions. Just call us! 1-800-831-4242