



## Silicon Controlled Rectifiers (SCRs)

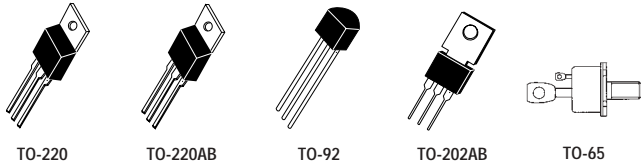

Part No.	Product No.	Mfr.	Pkg.	Rating	* Minimum order 10 pieces			
					1	10	100	1000
14859CG	C38M	+	TO-65	600 PRV, 35A (2N3899)	\$6.89	\$6.19	\$5.59	\$5.05
14736CG	C106B1*	+	TO-202	200 PRV, 4A (2N6239)†	.67	.54	.46	.40
14752CG	C122B	+	TO-220	200 PRV, 8A†	.73	.66	.63	.52
14761CG	C122M	+	TO-220	600 PRV, 8A†	1.35	1.25	1.05	.69
220484CG	EC103B	+	TO-92	200 V <sub>DRM</sub> , 0.8A	<del>.26</del> .22	.198	.178	.16
220530CG	T106B1	+	TO-202AB	200 V <sub>DRM</sub> , 4A	.36	.324	.30	.285
160119CG	T106D1	+	TO-202AB	400 V <sub>DRM</sub> , 4A	.39	.349	.319	.287
119802CG	2N5060	+	TO-92	25 PRV, 0.8A	*	.19	.15	.12
211422CG	2N5061	+	TO-92	60 PRV, 0.8A	*	.14	.13	.11
120070CG	2N5062	+	TO-92	100 PRV, 0.8A	*	.13	.12	.11
211431CG	2N5064	+	TO-92	200 PRV, 0.8A	*	.18	.16	.14
140417CG	2N6507	+	TO-220AB	400 PRV, 25A	.83	.75	.63	.56
220548CG	S4025L	TEC	TO-220AB	400 V <sub>DRM</sub> , 25A	1.49	1.42	1.34	1.30
160135CG	S6025L	TEC	TO-220AB	600 V <sub>DRM</sub> , 25A	1.42	1.28	1.15	1.04

† Isolated + Jameco Value Offering TEC = Teccor \*10 pcs. in Diode/Rectifier cabinet kit, below

 
## Rectifiers



Part No.	Product No.	Mfr.	Pkg.	Rating	* Minimum order 10 pieces			
					1	10	100	1000
177754CG	T6A05L	+	T6L	50 PIV, 6A	\$3.36	\$3.32	\$2.88	\$2.65
177762CG	T6A10L	+	T6L	100 PIV, 6A	.75	.65	.55	.45
177818CG	T6A100L	+	T6L	1000 PIV, 6A	.80	.72	.65	.49
618100CG	MBR745	+	TO-220	35 V <sub>RRM</sub> , 7.5A	.56	.49	.437	.393
301444CG	MBR1060	+	TO-220	60 V <sub>RRM</sub> , 10A	.63	.56	.48	.43
35924CG	1N1188	+	DO-5	400 PRV, 35A	4.49	4.45	4.14	3.28
645706CG	MBR1645	+	TO-220	45 V <sub>RRM</sub> , 16A	.85	.74	.63	.56
618097CG	MBR2535CR	+	TO-220	35 V <sub>RRM</sub> , 30A	.85	.78	.71	.67
35975CG	1N4001*	+	DO-41	50 PRV, 1A	*	.04	.028	.017
76961CG	1N4002	+	DO-41	100 PRV, 1A	*	.04	.028	.017
76970CG	1N4003	+	DO-41	200 PRV, 1A	*	.04	.028	.017
35991CG	1N4004**	+	DO-41	400 PRV, 1A	*	.04	.028	.017
76988CG	1N4005	+	DO-41	600 PRV, 1A	*	.04	.028	.017
76996CG	1N4006	+	DO-41	800 PRV, 1A	*	.04	.028	.017
36011CG	1N4007*	+	DO-41	1000 PRV, 1A	*	.04	.03	.021
227846CG	1N5059	+	SOD57	200 V <sub>R</sub> , 2A	* .054	.049	.044	
227854CG	1N5060	+	SOD57	400 V <sub>R</sub> , 2A	* .08	.07	.052	
227862CG	1N5061	+	SOD57	600 V <sub>R</sub> , 2A	* .09	.08	.06	
227871CG	1N5062	+	SOD57	800 V <sub>R</sub> , 2A	* .26	.24	.20	
77075CG	1N5400	+	DO-27A	50 PRV, 3A	* .10	.098	.074	
36249CG	1N5401	+	DO-27A	100 PIV, 3A	* .09	.076	.051	
77083CG	1N5402	+	DO-27A	200 PRV, 3A	* .10	.075	.059	
36265CG	1N5404*	+	DO-27A	400 PRV, 3A	* .10	.09	.057	
36273CG	1N5408*	+	DO-27A	1000 PRV, 3A	* .15	.11	.08	
177949CG	1N5817	+	DO-204AL	20 PIV, 1A	* .12	.09	.078	
177957CG	1N5818	+	DO-204AL	30 PIV, 1A	* .07	.058	.052	
177965CG	1N5819	+	DO-204AL	40 PIV, 1A	* .10	.085	.075	
177973CG	1N5820	+	DO-201AD	20 PIV, 3A	* .14	.125	.112	
177981CG	1N5821	+	DO-201AD	30 PIV, 3A	* .16	.13	.10	
177990CG	1N5822	+	DO-201AD	40 PIV, 3A	* .21	.18	.168	.134
618062CG	40CPO060	+	TO-247AC	60 V <sub>RRM</sub> , 40A (Schottky)	2.25	1.45	1.32	1.22

+ Jameco Value Offering \*10 pcs./ \*\*100 pcs. in Diode/Rectifier cabinet kit, right

## Bridge Rectifiers

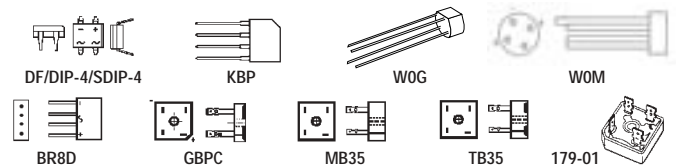

Part No.	Product No.	Mfr.	Pkg.†	Rating	1 10 100 1000			
					178001CG	DF005M	+	DF
255960CG	DF005S	+	SDIP-4	50 PIV, 1A	.25	.23	.21	.16
103000CG	DF01M	+	DF	100 PIV, 1A	.30	.26	.21	.17
103042CG	DF02M	+	DF	200 PIV, 1A	.35	.30	.22	.13
102971CG	DF04M	+	DF	400 PIV, 1A	.37	.32	.23	.17
103034CG	DF06M	+	DF	600 PIV, 1A	.40	.31	.27	.24
103026CG	DF10M	+	DF	1000 PIV, 1A	.30	.27	.23	.15
256559CG	DF10S	+	SDIP-4	1000 PIV, 1A	.32	.29	.23	.17
256604CG	DF01S	+	SDIP-4	100 PIV, 1.5A	.23	.22	.21	.20
256591CG	DF02S	+	SDIP-4	200 PIV, 1.5A	.31	.28	.22	.165
256583CG	DF04S	+	SDIP-4	400 PIV, 1.5A	.24	.22	.17	.13
256575CG	DF08M	+	DIP-4	800 PIV, 1.5A	.35	.30	.25	.18
256567CG	DF08S	+	SDIP-4	800 PIV, 1.5A	.26	.24	.22	.165
145429CG	KBPO2M	+	KBP	200 PIV, 1.5A	.40	.35	.29	.19
119562CG	KBPO4M*	+	KBP	400 PIV, 1.5A	.48	.45	.35	.25
279494CG	W005G	+	WOG	50 PIV, 1.5A	.38	.32	.27	.19
103018CG	W02G	+	WOG	200 PIV, 1.5A	.47	.39	.34	.21
102980CG	W04G	+	WOG	400 PIV, 1.5A	.44	.39	.35	.30
102998CG	W06G	+	WOG	600 PIV, 1.5A	.43	.41	.33	.245
179469CG	W08G	+	WOG	800 PIV, 1.5A	.35	.32	.26	.18
279515CG	W10G	+	WOG	1000 PIV, 1.5A	.42	.40	.33	.22
178124CG	W005M	+	WOM	50 PIV, 1.5A	.29	.24	.19	.13
178132CG	W01M	+	WOM	100 PIV, 1.5A	.36	.27	.20	.17
178141CG	W02M	+	WOM	200 PIV, 1.5A	.38	.33	.28	.19
178175CG	W08M	+	WOM	800 PIV, 1.5A	.35	.29	.257	.16
178183CG	BR805D	+	BR8D	50 PIV, 2A	.55	.49	.39	.35
178204CG	BR82D	+	BR8D	200 PIV, 2A	.85	.77	.69	.62
178247CG	BR810D	+	BR8D	1000 PIV, 2A	.59	.49	.39	.35
253260CG	2KBP06M	+	KBP	600 PIV, 2A	.48	.42	.37	.25
253286CG	2KBP10M	+	KBP	1000 PIV, 2A	.40	.35	.29	.24
179477CG	GBPC25-01	+	GBPC	100 PIV, 25A	2.29	1.86	1.53	1.22
179485CG	GBPC25-02	+	GBPC	200 PIV, 25A	3.25	2.69	2.25	1.65
178280CG	MB254	+	MB35	400 PIV, 25A	2.35	2.10	1.90	1.70
178415CG	MB354	+	MB35	400 V <sub>RRM</sub> , 12A	2.95	2.65	2.39	2.15
178335CG	TB252	+	TB35	200 PIV, 25A	2.09	1.85	1.69	1.50
25574CG	MDA990-3	+	179-01	200 PIV, 30A	3.99	3.45	2.99	1.85
25591CG	MDA990-6	+	179-01	600 PIV, 30A	4.59	4.29	3.99	3.59
299882CG	GBPC1204	+	GBPC	400 V <sub>RRM</sub> , 12A	2.99	2.67	1.89	1.15
299874CG	GBPC1206	+	GBPC	600 V <sub>RRM</sub> , 12A	3.15	2.67	1.95	1.46
299866CG	GBPC1206W	+	GBPC-W	600 V <sub>RRM</sub> , 12A	1.89	1.55	1.10	1.04
178431CG	MB358	+	MB35	800 PIV, 35A	3.59	3.29	2.75	1.85
178503CG	TB3510	+	TB35	1000 PIV, 35A	3.25	2.65	2.40	2.15

+ Jameco Value Offering \*10 pcs. in Diode/Rectifier cabinet kit, below  
† DF/KBP/WOG/WOM/179-01 - plastic case; GBPC/TB35 - plastic case, metal base; MB35 - metal case

## Diode/Rectifier Assortment Cabinet Kit

420 pcs. (15 types) Diodes, Zener Diodes, Switching and Silicon Rectifiers

Includes:

- 20 drawer component cabinet (319599CG),
- 20 clear plastic drawers (319601CG),
- 20 clear dividers (319610CG), pg 326 and
- 30 adhesive labels for drawers to identify parts in kit

10 each: 1N270, 1N751A, 1N3600, 1N4001, 1N4007, 1N4733A, 1N4735A, 1N4742A, 1N5404, 1N5408, C106B1, KBP04M  
100 each: 1N914, 1N4004, 1N4148

Part No.	Description	Wt. (lbs.)	1	10
82587CG	420 pcs. (15 types) diode kit	5.0	\$39.95	\$35.95
130366CG	Refill for 82587CG (420 pcs.)	0.3	25.95	22.30



SAVE 16%