 
 
 


- Logic control levels
- Long life with reliable operation
- Moisture resistant
- Compatible with IC sockets
- Compact design/construction
- Excellent for PCB applications



DIP Relays
 For more Major Brand DIP Relays visit www.Jameco.com



Aromat



EGE

CLARE

Part No.	Product No.	Manufacturer	Fig.	Contact Form	Coil Voltage	Coil Ohms	Contact Voltage	Contact Current	Pins	Jameco Socket	Size L x W x H (in.)	Leads A x B x C (in.)	Pricing			
													1	10	50	100
106463	201A05	Excel Cell Elect.	3A	SPST-NO	5VDC	500	100VDC	0.5A	8	37161	.78 x .25 x .20	.10 x .40 x .30	\$2.59	\$2.17	\$1.82	\$1.50
138431	2D1A05	Excel Cell Elect.	3B	SPST-NO	5VDC	500	100VDC	0.5A	8	37161	.77 x .30 x .22	.10 x .40 x .30	2.29	1.95	1.65	1.34
139977	RSB5S	Shin Mei	1C	DPDT	5VDC	125	120VAC/30VDC	1A/2A	8	37372	.79 x .39 x .37	.20 x .40 x .30	2.49	2.25	1.95	1.75
99311	DS2Y-S-DC12V	Aromat (NAIS)	1C	DPDT	12VDC	720	110VAC/30VDC	.3A/1A	8	37372	.79 x .40 x .43	.20 x .40 x .30	2.59	2.38	2.12	1.80
99901	LX200D00	Clare	1C	DPDT	12VDC	720	125VAC/100VDC	2A	8	37372	.79 x .40 x .30	.20 x .40 x .30	6.95	6.25	5.63	4.49
136549	DS4E-M-DC5V	Aromat	2D	4PDT	5VDC	62.5	125VAC/30VDC	.6A/2A	14	112299	1.40 x .40 x .36	.20 x .30 x .30	6.15	5.91	5.43	4.74
176313	DS4E-M-DC12V	Aromat	2D	4PDT	12VDC	360	125VAC/30VDC	.6A/2A	14	112299	1.40 x .40 x .36	.20 x .30 x .30	5.99	5.74	5.45	4.96

CLARE

 OptoMOS® Solid State Relays

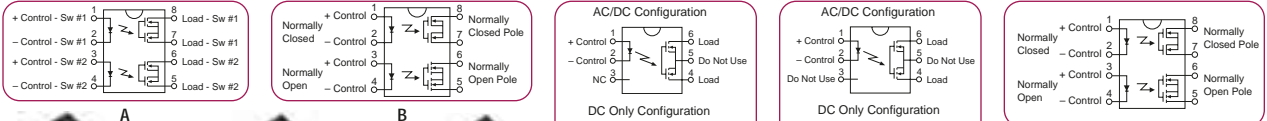

For more Clare Relays visit www.Jameco.com

Part No.	Product No.	Package	Description	Fig.	Load Voltage (V)	Current Handling (mA)	On-Resistance (ohms)	Isolation Voltage (Vrms)	Input Control Current (mA)	Off-State Leakage (µA)	Switching Speed (on/off) (ms)	Pricing		
												1	25	50
1582903	LAA110	DIP-8	Dual single pole, 1-Form-A	1A	350	120	35	3750	5	1	3/3	\$3.45	\$3.15	\$2.89
1582911	LAA110P	Flatpack-8	Dual single pole, 1-Form-A	2A	350	120	35	3750	5	1	3/3	3.95	3.65	3.42
1582920	LAA110S	SOIC-8	Dual single pole, 1-Form-A	3A	350	120	35	3750	5	1	3/3	3.95	3.65	3.42
1582938	LAA120	DIP-8	Dual pole, 2-Form-A	1A	250	170	20	3750	5	1	5/5	4.99	4.19	3.45
1582946	LAA125S	DIP-8	Dual pole, 2-Form-A	1A	350	170	16	3750	5	1	5/5	4.75	3.99	2.89
1582954	LAA127	DIP-8	Dual pole, 2-Form-A	1A	250	200	10	3750	5	1	5/5	6.19	5.39	4.89
1582962	LBA110	DIP-8	Dual pole, 1-Form-A & 1-Form-B	1B	350	120	35	3750	2	1	3/3	4.25	3.94	3.70
1582971	LBA110P	Flatpack-8	Dual pole, 1-Form-A & 1-Form-B	2B	350	120	35	3750	2	1	3/3	4.25	3.94	3.70
1582989	LBA110S	SOIC-8	Dual pole, 1-Form-A & 1-Form-B	3B	350	120	35	3750	2	1	3/3	4.25	3.94	3.70
1582997	LCA110	DIP-6	Single pole, 1-Form-A	1C	350	120	35	3750	2	1	3/3	1.75	1.59	1.49
1583009	LCA110S	SOIC-6	Single pole, 1-Form-A	3C	350	120	35	3750	2	1	3/3	1.75	1.61	1.51
1583025	LCA120L	DIP-6	Single pole, 1-Form-A	1D	250	170	20	3750	5	1	5/5	2.99	2.49	2.29
1583141	LCA710	DIP-6	Single pole, 1-Form-A	1D	60	1000	0.5	3750	10	1	2.5/0.25	4.75	4.41	4.14
1583164	PLA132S	SOIC-6	Single pole, 1-Form-A	3D	50	600	1	3750	5	1	5/2	4.49	3.99	3.75
1583050	LCB110	DIP-6	Single pole, 1-Form-B	1C	350	120	35	3750	5	1	3/3	2.45	2.24	2.10
1583068	LCB120	DIP-6	Single pole, 1-Form-B	1D	250	170	20	3750	5	1	5/5	3.05	2.80	2.63
1583084	LCC110	DIP-8	Common input, 1-Form-C	1E	350	120	35	3750	8	1	4/4	3.35	2.99	2.79
1583092	LCC120	DIP-8	Common input, 1-Form-C	1E	250	170	20	3750	10	1	5/5	4.35	3.65	3.62
1583148	PAA140A	SOIC-8	Single pole, 2-Form-A	3A	400	250	8	3750	50	1	3/1	6.55	6.07	5.69

crydom

Solid State Relays



For more Crydom Solid State Relays visit www.Jameco.com

Part No.	Product No.	Control Voltage	Type	Contact Style	Contact Voltage	Contact Current	Pins	Fig.	Terminal Type	Agency Approval	Size L" x W" x H"	Pricing		
												1	10	50
467487	A0241*	4V - 10VDC	DC/AC	SPST-NO	24V - 280V	0.025A - 1A	4	1	Solder leads	UL/CSA/CE	0.95 x 0.20 x 0.50	\$9.95	\$9.46	\$9.01
467508	ASO241**	4V - 10VDC	DC/AC	SPST-NO	24V - 280V	0.025A - 1A	4	1	Solder leads	UL/CSA/CE	0.70 x 0.20 x 0.50	10.09	9.59	9.14
468156	CX240DSR***	3V - 15VDC	DC/AC	SPST-NO	12V - 280V	0.06A - 5A	4	2	Solder leads	UL/CSA/VDE/CE	1.70 x 1.00 x 0.30	10.09	9.59	9.14
468498	D2410	3V - 32VDC	DC/AC	SPST-NO	24V - 280V	10A	4	3	Screw terminal	UL/CSA/VDE/CE	1.80 x 0.90 x 2.30	34.25	32.63	31.09
468771	D2W203F*	3V - 32VDC	DC/AC	—	24V - 280V	0.06A - 2A	4	4	Solder leads	UL/CSA/CE	1.70 x 0.47 x 1.18	10.45	9.94	9.47
468789	D2W203F-11*	3V - 32VDC	DC/AC	—	24V - 280V	0.6A - 35A	4	4	Solder leads	UL/CSA/CE	1.70 x 0.47 x 1.18	11.09	10.55	10.05
480260	MCX240D5	3V - 15VDC	DC/AC	SPST-NO	12V - 280V	0.06A - 5A	4	5	Solder leads	UL/CE	1.70 x 0.40 x 1.00	12.25	11.66	11.10
480518	PF240D25	3V - 15VDC	DC/AC	—	12V - 280V	0.06A - 25A	4	6	Solder leads	UL/VDE/CE	1.70 x 1.35 x 0.90	22.35	21.28	20.28
481027	TD2425	3V - 32VDC	DC/AC	SPST-NO	24V - 280V	25A	4	3	Screw terminal	UL/CSA/VDE/CE	1.80 x 0.90 x 2.30	34.69	32.63	31.09
467903	CMX60D10	3V - 10VDC	DC/DC	SPST-NO	0V - 60V	0A - 10A	4	7	Solder leads	UL	1.70 x 1.00 x 0.30	33.19	31.61	30.09
127790	D2W202F	3V - 32VDC	DC/AC	SPST	280VAC	2A	4	8	Solder Lead	UL/CSA	1.70 x 0.40 x 1.30	8.05	7.84	7.32
478805	DMO063	3V - 10VDC	DC/DC	SPST-NO	0V - 60V	0A - 3A	4	9	Solder leads	—	0.70 x 0.20 x 0.50	17.35	16.49	15.70

* Triac output ** Random turn-on *** SCR output Blue Part No. = Limited Quantity Available

This product ships from a separate warehouse and may require an additional day to ship. Each warehouse will accrue separate shipping charges. Sorry, we're unable to ship USPS.

RoHS compliant product This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. [Details on page 212](#)

Color Code Legend
New Sale Lower\$ QtySave