

Cutters, Strippers & Crimping Tools

Color Code Legend
New **Sale** **Lower\$** **QtySave**

Additional Cutters & Strippers are available online at www.Jameco.com/Tools

5" Wire Cutter/Strippers

- Insulated handles
- Spring return
- Tempered steel cutting edge
- Size: 5.0"L x 3.0"W
- One-year warranty

78992: 10-30 AWG (screw adjustable)


215889: 10-24 AWG (dial to adjust for wire gauge)



Part No.	Cross Ref. No.	1	10	50	100
78992	HT108	\$3.95	\$4.01	\$3.39	\$2.98
215889	JE-2022C	3.95	3.49	2.95	2.59

Ratcheted Modular Connector Crimping Tool

- Insulated grip
- Ratcheted type
- Metal • 7.5"L
- Crimps RJ45 (8P8C) and RJ11/12 (6P6C)
- Weight: 0.7 lbs.

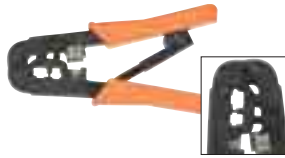

Part No.	Description	1	10	50
159312	RJ45/11/12	\$23.95	\$21.95	\$19.95

Ratcheted BNC Crimping Tool

- Crimps RG58, RG59, RG62, RG174 and fiber optic
- Hex sizes: 0.043", 0.068", 0.100", 0.137", 0.213", 0.255"
- All steel construction
- Size: 8.5"L x 2.5"W • Weight: 1.1 lbs.



Part No.	Product No.	1	10	50
114535	HT-336G	\$26.05	\$23.44	\$21.10

D-Sub Crimping Tool 20-28 AWG

- Crimps D-sub pins and sockets
- For use w/ P/Ns 43377 & 43369, pg 92 & 100766, pg 103
- Size: 7.0"L x 4.0"W



Part No.	Product No.	1	10	50
159266	HT213	\$12.95	\$10.95	\$9.89

Non-Insulated Terminal D-Sub Crimping Tool 14-26 AWG


- Heavy-duty metal tool with cutter and insulated handles
- For computer pins and sockets, D-sub 26-28 AWG wire
- For butt-insulated connectors, 22-26 AWG wire
- For telephone spade lugs, 22-26 AWG wire
- For non-insulated connectors, 20-22 AWG wire
- For non-insulated connectors, 14-18 AWG wire
- Coiled spring return • Size: 7.3"L x 1.5"W



Part No.	Product No.	1	10	50	100
99443	HT202A	\$9.49	\$8.55	\$7.69	\$6.95

Xcelite Needle Nose Pliers

- 217891 (submini needle nose): Serrated jaws
- Positive gripping of fine wire or subminiature components
- Fine point allows use in confined areas
- 217998: Smooth jaws
- General purpose for pick-up and wire forming

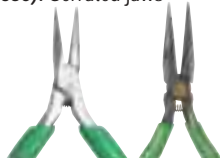

Part No.	Prod. No.	Description	1	10
217891	L4	4" mini needle nose	\$14.95	\$13.69
217998	LN54G	5" thin long nose	15.05	14.37

Half-Round Long Nose Pliers

- Drop forged steel
- Spring return action
- Length: 4.5"
- Heat treated
- Vinyl grips
- Knurled jaws



Part No.	Description	1	10	50	100
177608	Half-round pliers	\$4.95	\$4.49	\$3.95	\$3.59

4.3" Diagonal Wire Cutter

- Cuts component wire up to 1.2mm thick
- Stainless steel
- Durable rubber handles
- Jaws are designed for flush cutting
- 4.3"L x 2.1"W with 0.5" cutting blade



Part No.	Description	1	10	50	100
35482	Wire cutter	\$5.59	\$4.99	\$4.55	\$3.99

5" Diagonal Wire Cutter

- Cuts component wire up to 1.2mm thick and 0.08mm fine wire
- Insulated handles
- Jaws are designed for flush cutting
- 5.0"L x 1.8"W w/ 0.5" cutting blade



Part No.	Description	1	10	50
161411	Wire cutter	\$7.49	\$6.74	\$6.07

Xcelite Diagonal Cutters



Manufactured from the finest forged alloy steel with polished head and cushion comfort handles.

- Flush cutting edge
- Cutting edges machine ground and electronically hardened for extended life
- Forged alloy steel w/ polished head
- Handle coil springs for fast cutting action
- ESD safe cushion grips for maximum comfort

Part No.	Product No.	Description	1	10
217921	MS54J	4" oval head-flush	\$18.79	\$16.94
1536974	S475NJS	4" relieved head-flush	15.35	14.83
217904	MS549J	4" tapered head-flush	15.09	14.56
217867	MS545J	4" slim line tapered head-flush	14.59	12.99


Xcelite Cutters and Pliers



Part No.	Product No.	1	10	50	100
146712	170M	\$5.89	\$5.69	\$5.29	\$4.99
146739	MS54V	14.95	14.29	13.59	12.95
146721	MN7776V	16.95	16.39	15.29	14.25

Xcelite Shearcutter/Pliers Set

- Improved handle grip for control and comfort
- Non-glare black finish carbon steel
- Size (plier): 5.6"L
- Size (shearcutter): 5.2"L

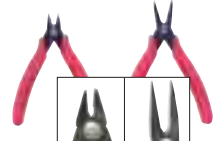

Part No.	Product No.	1	10	50
152055	S2K	\$15.99	\$14.99	\$13.99

6" Wire Cutter/Strippers

- Plier nose
- Wire size markings, in AWG and mm
- Size: 6.0"L x 2.0"W

161226: Premium

• 12-20 AWG stranded; 10-18 AWG solid

161234: Premium

• 16-26 AWG stranded; 14-24 AWG solid

161218: Standard

• 16-26 AWG stranded; 14-24 AWG solid • Color: red



Part No.	Product No.	Description	1	10
161226	ID45-215	Cushioned grips	\$18.39	\$17.50
161234	ID45-216	Cushioned grips	17.79	17.06
161218	ID45-121	Non-cushioned grips	12.39	12.25

Automatic Wire Stripper

- Spring load grip
- Size: 7.0"L x 2.5"W
- Weight: 0.8 lbs.



Includes: Wire stopper for desired strip length

Part No.	Description	1	10	50
175098	Strips 8-22 AWG	\$16.95	\$15.26	\$13.73

Rotary Coax Cable Strippers

2 and 3 Blade

159119 (3 Blade): 2 settings RG58/59/62

- For cable sizes 4-10mm
- Size: 4.2"L x 1.3"W • Color: black



159185 (2 Blades): 4 settings RG58/59/62/174

- For cable sizes 4-12mm
- Size: 3.9"L x 0.7"W
- Color: gray



Includes: Hex key wrench for adjusting blade

Part No.	Product No.	1	10	50
159119	HT312B (3 blade)	\$13.95	\$11.86	\$8.89
159185	HT332D (2 blade)	13.95	12.56	11.30

Hand Tools for Mini-Fit™ Jr.



304928: Accepts wire range from 14-24 AWG

Part No.	Product No.	Description	1	10
304928	63811-1000	Crimp tool	\$48.05	\$43.12
304936	11-03-0044	Extraction tool	19.99	18.99

RoHS compliant product This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 204.