


Multi-Turn Trimming Potentiometers

Color Code Legend
New Sale Lower\$ QtySave

Additional Potentiometers are available online at www.Jameco.com/Passives

Bourns® 1/2-Watt, 1/4" Square, Trimming Pots (±10%)

- Resistance tolerance: ±10%
- Absolute min. res.: 1% or 2Ω
- Adjustment angle: 240° nominal
- Insulation res. (500VDC): 1,000MΩ min.
- Power rating: 0.5W @ 70°C
- Temperature range: -55°C to 125°C

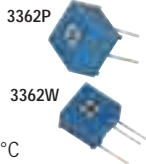

3362H Series — Top Adjustment, Y-Layout

Part No.	Product No.	Ohms	1	10	100
770371	3362H-1-103	10k \$0.82	\$0.69	\$0.64

3362P Series — Top Adjust, Y-Layout

Part No.	Product No.	Ohms	1	10	100
854663	3362P-1-102R	1k \$0.81	\$0.66	\$0.59
854698	3362P-1-202	2k82	.69	.64
770435	3362P-1-203	20k81	.68	.60
854727	3362P-1-503	50k81	.68	.57

3362R Series — Top Adjust, Rev. Y-Layout

Part No.	Product No.	Ohms	1	10	100
770451	3362R-1-103R	10k \$0.81	\$0.69	\$0.64

3362W Series — Side Adjust, Rev. Y-Layout

Part No.	Product No.	Ohms	1	10	100
770566	3362W-1-103R	10k \$0.82	\$0.69	\$0.64

1/2-Watt Trimming Pots (±10%)

3362P Series — Linear Taper

- Terminals: solderable pins
- Rotational life: 200 cycles
- Wiper positioning: 50% nominal
- Top adjustment: 240° nominal
- Insulation resistance: 500VDC 1,000MΩ min.
- Absolute minimum resistance: 1% or 2Ω max.
- Contact resistance variation: 1% or 3Ω maximum



Equivalent to:	Equivalent to:
Bourns 3362P	Murata PVC6
Copal CT-6P	Vishay 76

Qty.	1	10	100	500
Price	\$0.69	\$0.62	\$0.47	\$0.42

Part No.	Cross Ref. No.	Ohms
182810	3362P-501	500
182837	3362P-103R	10k

Pocket Trimmer Potentiometer Adjustment Tool

- Glass-filled body
- Stainless steel blade
- Size: 5.2"L



Part No.	Description	1	10	100
153315	Trimmer tool \$1.35	\$1.23	\$0.92
776108	Adjustment tool 1.49	1.37	1.26

Bourns® 1/4-Watt, 4mm Square SMD, Trimming Pots (±10%)

3314 Series

- Top adjust. straight slot
- Adjustment angle: 210°
- End resistance: 1% or 2Ω max.
- Power rating: 0.25W @ 70°C
- Insulation resistance: (500VDC) 100MΩ min.
- Contact resistance variation: 3% or 3Ω max.



Part No.	Product No.	Ohms	1	10	100
854330	3314J-1-502E	5K \$1.38	\$1.29	\$1.21
854284	3314G-1-103E	10K 1.19	1.06	1.04


Free Technical Support

Our knowledgeable Tech Support department is ready to answer your questions. Just call us!

1-800-831-4242

Bourns® 1/2-Watt, 3/8" Square, Multi-Turn Trimming Pots (±10%)

- 25 turns nominal
- Resistance tolerance: ±10%
- Power rating: 0.5W @ 70°C (300V max.)
- Temperature range: -55°C to 150°C
- Absolute min. resistance: 1% or 2Ω max.
- Insulation resistance (500VDC): 1,000MΩ min.

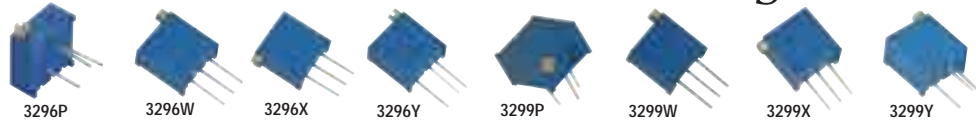

3296P — Side Adjust, Y-Layout Solder Pins

Part No.	Product No.	Ohms	1	10	100
769311	3296P-1-104R	100k	.. \$2.49	\$2.29	\$1.99

3296W — Top Adjust, In-Line Solder Pins

Part No.	Product No.	Ohms	1	10	100
853530	3296W-1-101R	100 \$2.19	\$1.73	\$1.30
853636	3296W-1-201R	200 2.15	1.72	1.55
853759	3296W-1-501R	500 2.05	1.66	1.25
769469	3296W-1-501LF	500 1.99	1.63	1.54
853556	3296W-1-102R	1k 2.05	1.89	1.73
769389	3296W-1-102LF	1k 1.99	1.63	1.54
853652	3296W-1-202R	2k 2.19	1.94	1.73
769426	3296W-1-202LF	2k 1.99	1.62	1.54
853775	3296W-1-502R	5k 2.05	1.83	1.74
769477	3296W-1-502LF	5k 2.05	1.74	1.31
853572	3296W-1-103R	10k 2.05	1.83	1.74
769397	3296W-1-103LF	10k 1.99	1.62	1.54
853679	3296W-1-203R	20k 2.05	1.66	1.25
769434	3296W-1-203LF	20k 2.05	1.65	1.24
853791	3296W-1-503R	50k 2.05	1.88	1.73
769485	3296W-1-503LF	50k 1.65	1.43	1.34
853599	3296W-1-104R	100k 2.05	1.65	1.59
769400	3296W-1-104LF	100k 1.99	1.64	1.45
853695	3296W-1-204R	200k 2.19	1.98	1.73
853812	3296W-1-504R	500k 2.05	1.89	1.73
769493	3296W-1-504LF	500k 2.05	1.89	1.73
853610	3296W-1-105R	1M 2.05	1.66	1.25

3296X — Side Adjust, In-Line Solder Pins

Part No.	Product No.	Ohms	1	10	100
853960	3296X-1-501R	500	... \$2.19	\$1.94	\$1.73
853935	3296X-1-202R	2k 2.15	1.72	1.55
769549	3296X-1-202LF	2k 1.99	1.62	1.54
853986	3296X-1-502R	5k 2.15	1.72	1.55
853871	3296X-1-103R	10k 2.19	1.93	1.73
769522	3296X-1-103LF	10k 1.99	1.62	1.54
853951	3296X-1-203R	20k 2.15	1.72	1.55
853898	3296X-1-104R	100k	... 2.15	1.72	1.55

3296Y — Top Adjust, Y-Layout Solder Pins

Part No.	Product No.	Ohms	1	10	50
240389	3296Y-1-501	500	\$2.19	\$2.03	\$1.52
240397	3296Y-1-102	1k 2.19	1.98	1.48
1156947	3296Y-1-102LF	1k 1.65	1.42	1.34
1156971	3296Y-1-202LF	2k 1.65	1.42	1.34
240418	3296Y-1-502	5k 2.39	2.22	2.00
769581	3296Y-1-502LF	5k 2.05	1.66	1.25
240426	3296Y-1-103	10k 1.99	1.85	1.66
1156955	3296Y-1-103LF	10k 2.05	1.65	1.24
240434	3296Y-1-203	20k 2.09	1.78	1.33
1156998	3296Y-1-203LF	20k 1.65	1.42	1.34
240451	3296Y-1-503	50k 2.39	2.22	2.00
1157018	3296Y-1-503LF	50k 1.65	1.42	1.34
240469	3296Y-104	100k 1.99	1.85	1.66

3299P — Side Adjust, Y-Layout Solder Pins

Part No.	Product No.	Ohms	1	10	100
854145	3299P-1-502	5k \$2.75	\$2.23	\$1.97
854102	3299P-1-103R	10k 2.79	2.25	2.16
769688	3299P-1-503	50k 2.45	2.27	2.16

3299W — Top Adjust, In-Line Solder Pins

Part No.	Product No.	Ohms	1	10	50
238553	3299W-1-100	10 \$2.39	\$2.25	\$1.99
183556	3299W-1-102	1k 2.39	2.25	1.99
1157149	3299W-1-102LF	1k 2.65	2.37	1.79
238617	3299W-1-202	2k 3.45	2.36	1.77
1157181	3299W-1-202LF	2k 2.65	2.37	1.79
238625	3299W-1-502	5k 2.89	2.64	1.98
769725	3299W-1-502LF	5k 2.59	2.08	1.83
183564	3299W-1-103	10k 2.39	2.25	1.99
769696	3299W-1-103LF	10k 2.59	2.08	1.83
238633	3299W-1-203	20k 2.39	2.25	1.99
769717	3299W-1-203LF	20k 2.59	2.08	1.83
238650	3299W-1-503	50k 2.39	2.25	1.99
1157237	3299W-1-503LF	50k 2.65	2.37	1.79
183572	3299W-1-104	100k 2.89	2.68	2.23
769709	3299W-1-104LF	100k 2.59	2.59	2.08
854161	3299W-1-204R	200k 2.59	2.07	1.83
1157190	3299W-1-204LF	200k 2.65	2.37	1.79
238676	3299W-1-504	500k 3.45	3.19	2.09
238684	3299W-1-105	1M 2.95	2.67	2.32
1157165	3299W-1-105LF	1M 2.65	2.28	2.14

3299X — Side Adjust, In-Line Solder Pins

Part No.	Product No.	Ohms	1	10	100
854188	3299X-1-102R	1k \$2.59	\$2.08	\$1.83
854225	3299X-1-202R	2k 2.59	2.08	1.83
854209	3299X-1-103R	10k 2.59	2.08	1.83

3299Y — Top Adjust, Y-Layout Solder Pins

Part No.	Product No.	Ohms	1	10	100
240590	3299Y-1-502	5k \$2.59	\$2.09	\$1.56
240602	3299Y-1-103	10k 2.89	1.96	1.47

For additional Bourns® Pots visit our website, www.Jameco.com.

▲ This product typically requires one additional day to ship. Please request "ship partial" if you prefer the other products on your order to ship immediately. A separate shipping charge would apply.

RoHS compliant product This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 204.