

D-Sub Crimping Tool

20-28 AWG

- Crimps D-sub pins and sockets
- For use w/ P/Ns 43377, 43369 & 100766, pg 64
- Size: 7.0"L x 4.0"W

*Web Code: PAL



Part No.	Mfr. Part No.	1	10	50
159266	HT213	\$12.95	\$10.95	\$9.49

Crimping/Cut/Strip Tool

For RJ11 (6P) and RJ45 (8P) Modular Plugs

- Repeatable crimp action for consistent high quality connections
- Push-down locking mechanism
- Size: 8.0"L x 2.0"W



• Weight: 0.8 lbs.

Includes: Cut and strip blade

Part No.	Product No.	1	10
174684	TTK071	\$26.95	\$24.26

Xcelite Needle Nose Pliers

217891 (submini needle nose): Serrated jaws

- Positive gripping of fine wire or subminiature components
- Fine point allows use in confined areas



- 217998: Smooth jaws
- General purpose for pick-up and wire forming

Part No.	Mfr. P/N	Description	1	10
217891	L4	4" mini needle nose ...	\$14.95	\$13.69
217998	LN54G	5" thin long nose	15.49	14.49

Half-Round Long Nose Pliers

- Drop forged steel
- Heat treated
- Spring return action
- Length: 4.5"
- Vinyl grips
- Knurled jaws



Part No.	Description	1	10	50	100
177608	Half-round pliers	\$4.95	\$4.49	\$3.95	\$3.59

5.3" Flat Long Nose Pliers

- Stainless steel
- Spring return
- Durable rubber handles
- 5.3" length w/ 1.4" plier nose
- Smooth jaws



Part No.	Description	1	10	50	100
195531	Flat long nose	\$6.85	\$6.07	\$4.80	\$3.49

Precision 5-Piece Stainless Steel Pliers Set



- Spring return
- Insulated handles

Includes:

One 3.5"L micro cutting nippers and one each 4"L micro round nose pliers, long nose pliers, flat nose pliers and bent nose pliers

Part No.	Description	Wt. (lbs.)	1	10	25
73121	5-piece set	0.6	\$18.49	\$16.75	\$14.99

*All Pliers — Enter Web Code TBJ

Diagonal Wire Cutters


- Jaws are designed for flush cutting
- Cuts component wire up to 1.2mm thick
- 0.5" cutting blade

35482: 4.3"L x 2.1"W

- Durable rubber handles
- Stainless steel

161411: 5.0"L x 1.8"W

- Also cuts 0.08mm fine wire
- Insulated handles

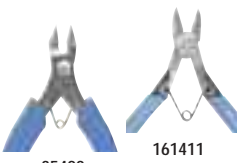

Part No.	Description	1	10	50
35482	4.3" cutter	\$7.35	\$6.60	\$6.02
161411	5.0" cutter	7.49	6.74	6.07

*Web Code: HAF

"F" Connector Compression Tool

Compresses RG-6 and RG-59 Snap-N-Seal type connectors.

- Length: 5"



Part No.	Product No.	1	5
261753	Compression tool	\$30.85	\$29.30

Xcelite Diagonal Cutters

*Web Code: HAF




Manufactured from the finest forged alloy steel with polished head and cushion comfort handles.

- Flush cutting edge
- Cutting edges machine ground and electronically hardened for extended life
- Forged alloy steel w/ polished head
- Handle coil springs for fast cutting action
- ESD safe cushion grips for max. comfort

Part No.	Mfr. Part No.	Description	1	5
217921	MS54J	4" oval head-flush	\$16.25	\$15.49
1536974	S475NJS	4" relieved head-flush	15.49	14.32
217904	MS549J	4" tapered head-flush	15.75	14.95
217867	MS545J	4" slim line tapered head-flush	15.25	14.49

Xcelite Cutters and Pliers

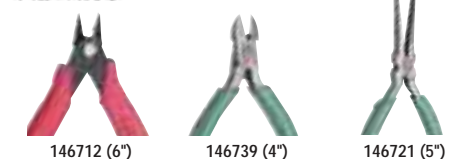

- Spring returns

146712: Micro series wire cutter – flush; 6"


146739: Diag. wire cutter – semi-flush; 4"

146721: Long needle nose pliers – flush; 5"

Part No.	Mfr. Part No.	1	5	25
146712	170M	\$5.89	\$5.49	\$5.15
146739	MS54V	16.75	15.95	15.25
146721	MN7776V	20.55	19.55	18.57

Xcelite Shearcutter/Pliers Set

- Improved handle grip for control and comfort
- Non-glare black finish carbon steel
- Size (plier): 5.6"L
- Size (shearcutter): 5.2"L

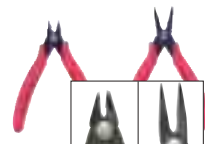

Part No.	Mfr. Part No.	1	5	50
152055	S2K	\$17.95	\$16.95	\$15.95

Jameco BenchPro Mini-Drill and Stand

This Mini Drill is excellent for drilling through circuit boards and protoboards. The drill comes with an array of drilling, grinding and sanding attachments. Drill stand is designed to function like a drill press.



Part No.	Description	Wt. (lbs.)	1	5	25
26702	GTT-103A drill	0.8	\$34.95	\$31.95	\$29.49
26711	GTT-104 stand	1.8	25.95	23.95	21.95

PC Board Drill Bits

- Shaft diameter: .125"
- Use for drilling holes in glass PC boards



Part No.	Size	Dia.	1	10	100
1919537	1/8	.125"	\$1.25	\$0.99	\$0.75
1919588	31	.120"	1.25	.99	.75
1919300	32	.116"	1.25	.99	.75
1919609	33	.113"	1.49	1.25	.99
1919553	35	.110"	1.49	1.25	.99
1919570	38	.102"	1.25	.99	.75
1919502	45	.082"	1.49	1.25	.99
1919596	46	.081"	1.49	1.25	.99
1919561	48	.076"	1.25	.99	.75
16580	59	.040"	1.75	1.49	.99
16619	75	.021"	1.75	1.49	.99

9-Piece Drill Bit Kit

- Variety of sizes: .014" to .126"
- Shank diameter: .125"
- Each kit will vary in contents of bit sizes



Part No.	Description	1	10	50
131676	9-piece drill bit kit	\$9.95	\$8.95	\$7.95

*Drill Bits — Enter Web Code NEJ

Jameco BenchPro 32-Piece Security Bit Set

These bits match the security fasteners commonly used in today's electronic products.

Includes: Torx bits: #6, #8 and #10; Tri-wing bits: #1, #2, #3 and #4; Security hex bits: 5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16" and 1/4"; Security Torx bits: T8, T10, T15, T20, T25, T27, T30, T35 and T40; Spanner bits: 4, 6, 8 and 10mm; Phillips bits: #1, #2, #3 and #4; and 60mm magnetic bit extension that fits 1/4" hex driver



Part No.	Description	1	10
223829	32-piece security bit set	\$12.99	\$11.99

Jameco BenchPro Pocket Screwdriver

Phillips & Flat head

- Size: 6"L
- Pen clip for pocket storage



*Web Code: CAQ

Part No.	Description	1	10	100
127271	Pocket screwdriver	\$1.95	\$1.59	\$1.35

Helping You Find What You Need

Can't find the product you're looking for call us at 1-800-831-4242.

*For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above

RoHS compliant product This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 161.