

AC-to-DC Regulated Switching Table-Top Power Supplies (Continued)

We are happy to change the power plug on any listed table-top power supply to a connector of your choice (see below) for just \$2.50 each. A 100 pc. minimum order applies.

Part Number	Manufacturer	Manufacturer Part No.	Output Volts (VDC)/ Current (A)	Output Connector ID x OD mm Female/Male; Polarity	Input VAC@Hz	Output Pwr (W)	LED Ind.	Size (L" x W" x H")	Cords (DC/AC)	Wt. (lbs.)	Agency Approvals	Pricing			
												1	10	50	100
3-Wire AC Input – Regulated Switching Table-Top – Triple Output															
190960	Mean Well	P25A13D-R1U	+5/2.5, +12/0.8, -12/0.3	5-pin DIN M	100-240@50-60	26	Yes	4.1 x 2.6 x 1.4	6'6"	1.1	CUL/TUV/CE	\$39.95	\$35.95	\$32.95	\$29.95
221702	Mean Well	P50A13D-R1BU	+5/4.0, +12/2.0, -12/0.5	5-pin DIN M	100-240@50-60	50	Yes	5.7 x 3.0 x 1.7	4'6"	1.5	UL/CUL/TUV/CE	49.95	44.95	40.95	36.95
237367	Mean Well	P50A14E-R1BU	+5/3.5; +15/1.2, -15/0.3	5-pin DIN M	100-240@47-63	42	Yes	5.8 x 3.0 x 1.7	4'6"	1.2	UL/CUL/TUV/CE	54.95	49.95	44.95	40.95

DC Power Plugs & Adapters

* Web Code: MFP

Part No.	Manufacturer	Product No.	Fig.	Description (Barrel) Plug ID x OD x L (mm)	Strain Relief ID x L (mm)	Pricing		
						1	10	100
Female Plugs								
71192	ValuePro	PP137	1	1.3 x 3.45 x 9.5	4.1 x 12 (black)	.79	.69	.65
191484	ValuePro	PP049W	1	2.1 x 5.5 x 9.0	4.6 x 12.5 (white)	.69	.59	.55
2004890	ValuePro	PP049S	1	2.1 x 5.5 x 9.5	4.5 x 12.5 (black)	.79	.69	.65
297617	Switchcraft	S760	3	2.1 x 5.5 x 9.5	5.5 x 25 (black)	2.95	2.49	2.25
28760	ValuePro	PP049	1	2.1 x 5.5 x 10 (P205)	4.1 x 12 (black)	.79	.69	.55
138587	ValuePro	PJ021R	2	2.1 x 5.5 x 12 (rt. angle)	2.8 x 11 (black)	.89	.79	.65
147329	ValuePro	PP049L	1	2.1 x 5.5 x 14 (P205L)	4.3 x 12 (black)	.89	.79	.65
190538	ValuePro	PP109S	1	2.5 x 5.5 x 9.5	5.0 x 13 (black)	.59	.55	.49
281877	Switchcraft	760	3	2.5 x 5.5 x 9.5	5.5 x 25 (black)	2.95	2.49	2.19
28768	ValuePro	PP109	1	2.5 x 5.5 x 10 (P206)	4.2 x 12 (black)	.79	.69	.59
147336	ValuePro	PP109L+	1	2.5 x 5.5 x 14 (P206L)	4.2 x 12 (black)	.79	.69	.59
168242	ValuePro	PP109N	3	2.5 x 5.5 x 14	3.9 x 22 (black)	.69	.59	.55
Male Plugs								
101135	ValuePro	PJ1025	4	— x 2.5 x 11 (P201)	4.3 x 13 (black)	.79	.69	.55
231176	ValuePro	AP-340	4	— x 3.5 x 14 (stereo)	4.3 x 13.5 (black)	.79	.69	.55
231167	ValuePro	AP-343	5	— x 3.5 x 14 (stereo)	4.4 x 13 (metal)	1.49	1.25	.99
231160	ValuePro	PJ1035	5	— x 3.5 x 14 (mono)	4.8 x 13.5 (metal)	1.49	1.25	.99
101152	ValuePro	PJ1035	4	— x 3.5 x 14.5 (P202)	4.0 x 13 (black)	.69	.59	.49

Female Power Plug Adapters

1953604	ValuePro	DCP2.1-DCJ2.5	6	2.1mm M to 2.5mm F (1.4"L)	—	1.49	1.25	.99
1953591	ValuePro	DCP2.5-DCJ2.1	6	2.5mm M to 2.1mm F (1.4"L)	—	1.49	1.25	.99

Male & Female Power Jacks

* Web Code: BAM

Part No.	Manufacturer	Product No.	Dimensions H x W x D (mm)	Type/ Mount	Circuit/ Terminal	Mating Plug (above)	Pricing		
							1	10	100
1.3 mm Male Jack									
101194	Various	PP024+	6.0 x 6.0 x 9.0	1/D	1/B	1.3 mm F	.59	.55	.45
2.1 mm Male Jacks									
101178	Various	PP014+	10.9 x 9.0 x 14.5	2/D	1/A	2.1 mm F	.39	.35	.29
137673	Various	PP013	10.9 x 9.0 x 14.5	3/D	4/A	2.1 mm F	.45	.39	.35
151590	Various	DPJ-021A	18.0 x 12.6 Dia.	4/C†	1/A	2.1 mm F	.89	.79	.69
151555	ValuePro	DPJ-026	21.0 x 8.0 Dia.	5/E	1/A	2.1 mm F	1.49	1.35	1.19
159611	Various	PJ1014A	57.5 x 12.6 Dia.	6/F	3/A	2.1 mm F	1.75	1.59	1.39
281851	Switchcraft	722A	15.1 x 7.5 Dia.	7/C	1/A	2.1 mm F	2.75	2.49	2.25
2.5 mm Male Jacks									
207714	Various	HEC0470	11.0 x 9.0 x 14.5	2/D	1/B	2.5 mm F	.75	.69	.59
101186	Various	PP014A+	11.0 x 9.0 x 14.5	2/D	1/A	2.5 mm F	.55	.49	.39
151563	Various	DPJ-026A	15.1 x 8.0 Dia.	5/E	1/A	2.5 mm F	1.49	1.35	1.19
159506	Various	PJ1015A	57.5 x 12.6 Dia.	6/F	3/A	2.5 mm F	1.75	1.59	1.39
202358	Various	HD2388	12.4 x 7.7 Dia.	8/C	3/A	2.5 mm F	1.19	.99	.89
281842	Switchcraft	712A	15.8 x 7.5 Dia.	7/C	1/A	2.5 mm F	2.49	2.25	1.95
1768329	Switchcraft	712RA	19.6 x 10.9 Dia.	9/D	1/B	2.5 mm F	3.49	3.25	2.95
297553	Switchcraft	PC712A	23.3 x 11.0 Dia.	10/D	1/A	2.5 mm F	2.95	2.65	2.35
297529	Switchcraft	L712A	23.3 x 11.0 Dia.	11/C	1/A	2.5 mm F	3.95	3.39	2.95
3.5 mm Female Jacks									
101143	ValuePro	PJ0352	10.0 x 10.0 x 18.5	12/E	2/A	3.5 mm M	.39	.35	.29
109496	ValuePro	PJ035PM	10.5 x 9.0 x 20.0	13/C	2/A	3.5 mm M	.55	.49	.45
165730	ValuePro	PJ0354	15.5 x 5.9 Dia.	14/C	3/A	3.5 mm M	.79	.69	.59

† Center offset

RoHS compliant product + This product is available in both RoHS and non-RoHS versions. Add an "R" before part number for RoHS version. Details on page 190.

 


Fig. 1 Strain Relief



Fig. 2



Fig. 3 Hard Plastic Strain Relief



Fig. 4 Strain Relief



Fig. 5 Metal Strain Relief



Fig. 6



Automobile Fused Power Plugs with Cords

• Accepts .25" x 1.25" fuse

115002: Screw assembly w/ strain relief



115002

124760: 3' cord w/ pigtail





124760

105064: 12' cord w/ pigtail

Part No.	Mfr.	Fuse	1	10	100
115002	ValuePro	5A/250VAC	\$2.25	\$1.99	\$1.79
124760	ValuePro	3A/250VAC	2.49	2.25	1.99
105064	Various	2A/250VAC	1.95	1.75	1.39

Terminals	Code
Solder eyelet	A
PC board	B


Mounting	Code
Panel	C
PCB	D
Panel & PCB	E
Cable	F

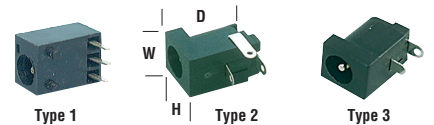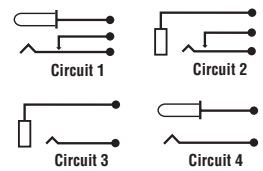

Type 1

Type 2

Type 3

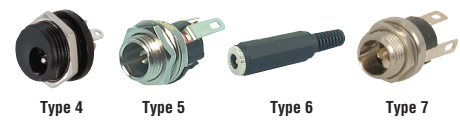

Type 4

Type 5

Type 6


Type 7



Type 8

Type 9

Type 10

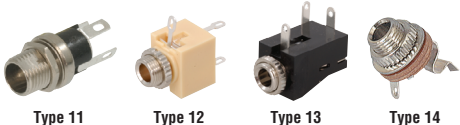

Type 11

Type 12

Type 13

Type 14