


Mounting Brackets & Accessories for Mean Well Enclosed Switching AC-to-DC Power Supplies

All brackets use metric screws: 2-F3 x 6, 2-F4 x 6, 2-T3 x 6, 2-T4 x 6 and 8-T4 x 6 (not included)

Part No.	Mfr. No.	For Models	1	10
222122	DRL-01	S-25/40, RS-25/35	\$1.75	\$1.49
222131	DRL-02	S-60/100F/150, D-60/120, SD-100/150, SP-75/100/150/200	2.49	2.25
222148	DRL-03	S-240/320, SP-320	2.95	2.75
222157	DRP-01	All Models	2.95	2.75
222165	DRP-02	S-25, SP-75/100/150/200	1.95	1.75
222173	DRP-03	All Models	2.25	1.95
222182	MHS012	S-320/350, SP-100/150/200/320	.99	.99
1952636	MHS013	PSP-500, SP-750, SE-600	1.25	.95
222199	MHS025	SP-500, PSP-600	1.95	1.75
248736	2094.0	DR, DRH, DRP, DRT, MDR	6.95	6.25

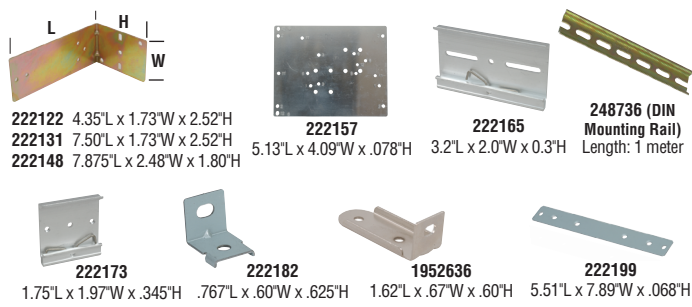

Mating Connector
103588 \$1.20/10
Spade Solderless Terminal

Crimp Tool
72996 \$22.49
Solderless Terminal Crimp Tool


Pricing & specs on page 90

LED Enclosed Power Supplies with Power Factor Correction

For Indoor and Outdoor Applications

- Suitable for LED lighting & moving sign application
- Short-circuit/overload/overvoltage/overtemperature protection
- UL1310 class 2 power unit
- 100% full-load burn-in test
- Universal AC input/full range
- Inrush current: 40A/230VAC
- Cooling by free air convection

- PLN Series** • Plastic case • Constant voltage and current • Working temperature: -30°C to 50°C • Two-year warranty
- CLG Series** • Metal case • Adjustable voltage and current • Working temperature: -30°C to 70°C • Three-year warranty

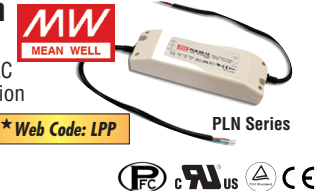

Jameco Part No.	Manufacturer	Mfr. Part No.	Output		Size (L" x W" x H")	Ripple & Noise (mV p-p)*	Load Reg. (±%)*	Line Reg. (±%)*	Certification	Pricing		
			Voltage @ Current (min-max)	Power						1	10	25
1954404	Mean Well	PLN-30-12	+12V @ 0-2.5A	30.0W	5.7 x 1.9 x 1.2	2000	10.0	3.0	UL/CUL/TUV/CE	\$44.95	\$39.95	\$36.95
1918833	Mean Well	PLN-100-12	+12V @ 0-5A	60.0W	7.9 x 2.8 x 1.4	150	2.0	1.0	UL/CUL/TUV/CE/PFC	84.95	76.95	72.95
1954877	Mean Well	CLG-150-12A	+12V @ 0-11A	132.0W	8.7 x 2.7 x 1.5	150	1.0	0.5	UL/TUV/CE	109.95	99.95	89.95
1918964	Mean Well	PLN-60-15	+15V @ 0-4A	60.0W	7.1 x 2.4 x 1.4	2400	10.0	4.0	UL/CUL/TUV/CE	64.95	58.95	54.95
1919001	Mean Well	CLG-60-15	+15V @ 0-4A	60.0W	6.8 x 2.4 x 1.5	2400	10.0	4.0	UL/CUL/TUV/CE	79.95	71.95	68.95
1918841	Mean Well	PLN-100-15	+15V @ 0-5A	75.0W	7.9 x 2.8 x 1.4	150	2.0	1.0	UL/CUL/TUV/CE/PFC	84.95	76.95	72.95
1585856	Mean Well	CLG-100-15	+15V @ 0-5A	75.0W	8.7 x 2.7 x 1.5	150	2.0	1.0	UL/CUL/TUV/CE/PFC	99.90	89.95	79.95
1585864	Mean Well	CLG-100-20	+20V @ 0-4.8A	96.0W	8.7 x 2.7 x 1.5	150	2.0	1.0	UL/CUL/TUV/CE/PFC	99.95	89.95	79.95
1954412	Mean Well	PLN-30-24	+24V @ 0-1.25A	30.0W	5.7 x 1.9 x 1.2	2600	10.0	3.0	UL/CUL/TUV/CE	44.95	39.95	36.95
1918868	Mean Well	PLN-100-24	+24V @ 0-4A	96.0W	7.9 x 2.8 x 1.4	150	2.0	1.0	UL/CUL/TUV/CE/PFC	74.95	68.95	62.95
1585872	Mean Well	CLG-100-24	+24V @ 0-4A	96.0W	8.7 x 2.7 x 1.5	150	2.0	1.0	UL/CUL/TUV/CE/PFC	99.95	89.95	79.95
1954885	Mean Well	CLG-150-24A	+24V @ 0-6.3A	150.0W	8.7 x 2.7 x 1.5	150	1.0	0.5	UL/TUV/CE	129.95	119.95	109.95
1585733	Mean Well	CLG-100-27	+27V @ 0-3.55A	96.0W	8.7 x 2.7 x 1.5	150	2.0	1.0	UL/CUL/TUV/CE/PFC	99.95	89.95	79.95
1585768	Mean Well	CLG-100-48	+48V @ 0-2A	96.0W	8.7 x 2.7 x 1.5	150	2.0	1.0	UL/CUL/TUV/CE/PFC	99.95	89.95	79.95

* Primary Output

Encapsulated Switching Power Supplies

* Web Code: ESP

PM-05/PM-10/PM-15/PM-20 Series:

- Universal AC input (85-264VAC @ 47Hz)
- Short-circuit, overload, overvoltage protection
- Ultra-miniature size
- UL/CUL/TUV/CE/CB
- Cooling by free air convection
- 100% full-load burn-in test
- Three-year warranty



Part No.	Manufacturer	Mfr. P/N	Output		Pins	Ripple & Noise (mVp-p)	Load Reg (±%)	Line Reg (±%)	Size (L" x W" x H")	Pricing		
			Volt. @ Curr. (min-max)	Power						1	10	25
1954527	Mean Well	PM-05-12	+12V @ 0-0.42A	5.04W	4	150	1.0	0.5	2.5 x 2.0 x 0.8	\$19.95	\$17.95	\$15.95
1954551	Mean Well	PM-10-12	+12V @ 0-0.85A	10.20W	4	150	1.0	0.5	2.8 x 2.0 x 0.9	21.95	19.95	17.95
1954586	Mean Well	PM-15-12	+12V @ 0-1.25A	15.00W	4	150	1.0	0.5	3.0 x 2.1 x 0.9	24.95	22.49	19.95
1954367	Mean Well	PM-20-12	+12V @ 0-1.80A	21.60W	6	150	1.0	0.5	3.7 x 2.2 x 0.9	27.95	25.95	23.95
1954535	Mean Well	PM-05-24	+24V @ 0-0.23A	5.52W	4	240	0.5	0.5	2.5 x 2.0 x 0.8	19.95	17.95	15.95
1954560	Mean Well	PM-10-24	+24V @ 0-0.42A	10.10W	4	240	0.5	0.5	2.8 x 2.0 x 0.9	21.95	19.95	17.95
1954594	Mean Well	PM-15-24	+24V @ 0-0.63A	15.10W	4	240	0.5	0.5	3.0 x 2.1 x 0.9	24.95	22.49	19.95
1954383	Mean Well	PM-20-24	+24V @ 0-0.92A	22.10W	6	240	0.5	0.5	3.7 x 2.2 x 0.9	27.95	25.95	23.95

Rackmount Power Supply


* Web Code: MCI

- AC Input active surge current limiting
- Forced air cooling by built-in DC fan
- Built-in remote sense function
- Short-circuit, overload, overvoltage, overtemperature protection
- Input voltage: 90-132VAC/180-264VAC switch selectable

Part No.	Mfr. Part No.	Power	Output (VDC @ A)	Ripple & Noise	Size(W x D x H)	1	10	25
673408	SE-600-48RM	600W	48 @ 12.5	150mVp-p max.	19.5" x 5.0" x 3.5"	\$269.95	\$249.95	\$229.95

Dual Adj. Regulated Power Supply Kit

- Adjustable positive/negative supplies ±5 to ±15VDC, 175mA-750mA per supply
- LED on indicator • 120VAC input • 48-piece kit
- PC board construction • Difficulty level: intermediate

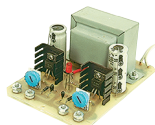

Part No.	Cross Ref. No.	Dimensions	Wt. (lbs.)	1	10
20626	JE215	5.1"L x 3.5"W x 2.0"H	2.1	\$24.95	\$22.49

We also carry
ATX Computer Power Supplies
See page 175

* For Complete Specs & Additional Product Listings Search www.Jameco.com/More and Enter Web Code Listed Above