


**JAMECO ValuePro**

## Binary Coded Decimal (BCD) Switches

- Contact resistance: 100mΩ max.
- Contacts: gold plated BE-CU alloy
- Continuous load: 1 amp max.
- Front snap-tab mounting with end plates

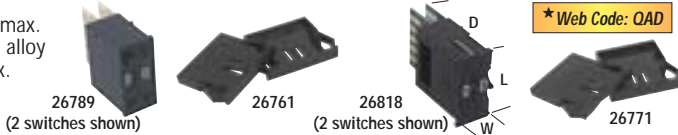


★ Web Code: QAD

Part No.	Product No.	Manufacturer	Description	Dimensions (L" x W" x D")	Character Height	Pricing		
						1	10	100
26789	GPF311221	ValuePro	10-position pushbutton	1.2 x 0.3 x 1.7	0.19"	\$4.49	\$4.45	\$3.95
26761	PF31E10	ValuePro	End plates for 26789	1.2 x 0.2 x 1.1	—	.95	.85	.75
26818	GTF311211	ValuePro	10-position thumbwheel	1.2 x 0.3 x 1.9	0.25"	4.75	4.19	3.75
26771	TF31E10	ValuePro	End plate for 26818 (2)	1.2 x 0.2 x 1.3	—	.95	.85	.75

**JAMECO ValuePro**

## Mini Pushbutton BCD Switch

- Operating temperature: -10°C to +65°C
- 28VDC @ 10A
- Break before make
- Switches snap together
- Positive logic ("0" all open output)
- Size L = 0.59", W = 0.30", S = 1"
- Character height: 0.12"

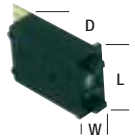


Part No.	Cross Ref.	Description	1	10	100
136558	MX061	10-position ...	\$2.95	\$2.65	\$2.39

**OMRON Honeywell**
 
## Miniature Basic Switches

★ Web Code: UEM

- 3 terminals: common; normally open; normally closed
- Size: 1.10"L x 0.40"W x 0.63"H



Part No.	Manufacturer	Mfr. Part No.	Actuator Type	Fig.	Contact Form	Contact Rating	Service Life (Mech./Elec.)	Terminal Type	Pricing		
									1	10	100
1945268	Zippy	VM-5	Long lever (2.00"L)	1	SPST	5A @ 125/250VAC	10M/1M	0.187" quick connect	\$1.19	\$0.95	\$0.75
187792	Omron	V-10G2-1C24K	Hinge lever (1.08"L)	2	SPDT-NC	0.1A @ 125VAC, 10A @ 250VAC	50M/300k	0.183" quick connect	2.49	2.25	1.95
187805	Omron	V-10G3-1C24K	Long hinge lever (2.01"L)	3	SPDT-NC	0.1A @ 125VAC, 10A @ 250VAC	50M/300k	0.183" quick connect	2.15	1.95	1.75
2076279	Honeywell	V3L-1465-D8	Lever actuator	4	SPDT	4A @ 125VAC	50M/300k	0.183" quick connect	1.59	1.35	1.09
2076244	Honeywell	V3-23-D8	Pin plunger	5	SPDT	5A @ 125VAC	50M/300k	0.183" quick connect	1.49	1.25	.95
617844	GC Electronics	35-880	Lever actuator	5	SPDT	10A @ 125VAC	10M/100k	0.187" quick connect	4.95	4.45	3.95
159572	Highly Electric	VS10N051C	Hinge roller (0.60"L)	6	SPDT-NC	10A @ 125VAC, 10A @ 250VAC	10M/100k	0.250" quick connect	2.95	2.65	2.39
159581	Highly Electric	VS10N021C2	Hinge lever (1.05"L)	2	SPDT-NC	10A @ 125VAC, 10A @ 250VAC	10M/100k	0.183" quick connect	2.49	2.25	1.95
483284	Cherry	D44CR1RD	Hinge lever (1.24"L)	7	SPDT	10A @ 125/250VAC	6k	0.187" quick connect	2.95	2.65	2.39
1917267	Honeywell	V7-2B17D8-201	Roller lever	6	SPDT	11A @ 125/250/277VAC	50M/300k	0.187" quick connect	3.49	3.15	2.85
1917099	Honeywell	V7-1C17D8	Pin plunger	5	SPDT	15.1A @ 125/250/277VAC	50M/300k	0.183" quick connect	2.95	2.65	2.39

## Subminiature Basic Switches

- Economical, subminiature basic switch offers long service life
- Free from overtravel restrictions, permits easy setting
- Lead spacing: A = 0.35"; B = 0.29"
- Dimensions: 0.78"L x 0.25"W x 0.40"H

★ Web Code: MBE



Part No.	Manufacturer	Product No.	Fig.	Actuator Type	Contact Form	Contact Rating	Service Life (Mech./Elec.)	Terminal Type	Pricing		
									1	10	100
187709	Omron	SS-5GL	1	Hinge lever (0.6"L)	SPDT-NC	5A @ 125VAC, 3A @ 250VAC	30M/200k	Solder	\$1.59	\$1.39	\$1.25
187733	Omron	SS-5GL2	2	Hinge roller (0.6"L)	SPDT-NC	5A @ 125VAC, 3A @ 250VAC	30M/200k	Solder	1.49	1.35	1.19
188867	Omron	D2F-LR	3	Hinge lever	SPDT-NC	3A @ 125VAC, 2A @ 30VDC	1M/30k	Solder	1.19	1.05	.95
159599	Highly Electric	SS0505A	2	Hinge roller (0.7"L)	SPDT-NC	5A @ 125VAC, 3A @ 250VAC	30M/200k	Solder	1.39	1.25	1.09

## Slide Switches

- Two mounting flanges
- Top actuation
- 6/6 nylon plastic housing
- Nylon actual
- Phenolic insulated



★ Web Code: LAP

Part No.	Manufacturer	Product No.	Fig.	Pins	Type	Dimensions (L" x W" x D")	Lead Spacing		Contact Rating (A @ VAC)	Housing Material	Lead Length	Actuator Height	Pricing		
							A"	B"					1	10	100
109171	ValuePro	G4050X-R	1	3	SPDT on-on	.22"L x .45"W x .23"D	—	.12	0.5A @ 50VDC	Plastic	.17"	.15"	\$0.35	\$0.29	\$0.25
204142	C&K	4102021ML0Y	2	3	SPDT on-on	.77"L x .40"W x .37"D	—	.19	2.0A @ 28VDC	Plastic	.19"	.17"	.29	.19	.15
202770	◆	74650-009	3	6	SPDT on-on	.35"L x .70"W x .30"D	.17	.20	0.1A @ 30VDC	Plastic	.16"	.32"	.29	.19	.15
2076210	CWI	GF126-1093	4	6	DPDT on-on	1.0"L x .41"W x .30"D	.19	.29	0.5A @ 125VDC	Metal	.25"	.20"	.69	.59	.45
161817	ValuePro	MS-306-R	4	6	SPDT on-on	.35"L x .14"W x .14"D	.10	.10	0.3A @ 6VDC	Plastic	.14"	.08"	.59	.49	.45
621325	GC Electronics	35-202-BU	4	3	SPDT on-on	.44"L x .22"W x .18"D	.14	—	0.3A @ 30VAC	Metal	.14"	.16"	1.79	1.59	1.39
549010	AlcoSwitch	1-1437575-4	1	3	SPDT on-on	.35"L x .13"W x .13"D	.10	.10	0.1A @ 30VAC	Plastic	.12"	.08"	2.95	2.65	2.39
588220	C&K	OS102011MA10N1	5	3	SPDT on-on	.34"L x .17"W x .15"D	—	.08	0.2A @ 30VDC	Metal	.11"	.16"	.39	.35	.29

**Switchcraft**

## Cord-Switch®

★ Web Code: CSH

**GG**

## Inline Cord Switch

- Maximum cable diameter: .375"
- Plastic insulation
- Copper alloy plated housing and switch bushing

- Contact form: SPST on-off
- Terminal: solder
- Contact rating: 6A @ 20VDC
- Black plastic body

Part No.	Mfr. Part No.	Type (momentary)	Button Color	1	10	50	Part No.	Mfr. Part No.	1	10	100
297502	ED903	SPDT off(on)	Red	\$12.95	\$11.65	\$10.49	621270	35-1851-BU	\$3.95	\$3.49	\$2.95

★ For Complete Specs & Additional Product Listings Search [www.Jameco.com/More](http://www.Jameco.com/More) and Enter Web Code Listed Above