

Barrier Terminal Strips and Blocks

- Standard and Metric
- Single, Dual, Tri-Barrier and Eurostrip Blocks
- Material: Polyamide 66 (UL94V-0)
- Pins: Tin plated brass
- Screws: M3.5 (metric) or 6-32 (standard)
- Operating Temp: -55°C to 95°C
- Wire Gauge: See web datasheet



Fig. 1



Fig. 2



Fig. 3




Fig. 4



Fig. 5



Fig. 6

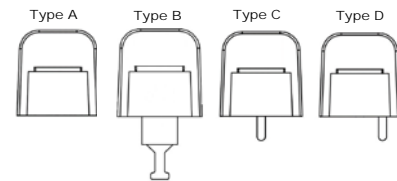

Jameco Part No.	Manufacturer Name	Manufacturer Part No.	Description	Top Termination	Bottom Termination	Pitch (inches)	Pitch (mm)	Number of Positions	Number of Rows	Max Voltage Rating	Max Current Rating	Fig.	Dimensions L x D x H (mm)	Price 1	Price 10
2272927	Eaton	A102203	Single Row Barrier Strip	Screw, 6-32	PC Pin, Offset, w/o Flange	0.325	8.26	3	1	250V	20A	1D	26.4 x 12.7 x 12.7	\$1.39	\$1.25
2272975	Eaton	A104204R26	Single Row Barrier Strip	Screw, 6-32	PC Pin, Offset, R/A, w/o Flange	0.325	8.26	4	1	250V	20A	1D	34.8 x 12.7 x 12.7	\$2.25	\$1.99
2272983	Eaton	A102204	Single Row Barrier Strip	Screw, 6-32	PC Pin, Offset, w/o Flange	0.325	8.26	4	1	250V	20A	1D	34.8 x 12.7 x 12.7	\$1.85	\$1.69
2275231	Jameco Valuepro	HI-201-02PH-S-D40	Single Row Barrier Strip	Screw, M3.5	PC Pin with Flange	0.375	9.53	2	1	250V	10A	2C	40.1 x 18 x 20	\$2.19	\$1.59
2275335	Jameco Valuepro	HI-202-02PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Insulated Solder Turret with Flange	0.375	9.53	2	1	250V	10A	2B	40.1 x 16.3 x 18.9	\$1.09	\$0.95
2275439	Jameco Valuepro	HI-201-02P	Single Row Barrier Strip	Screw, M3.5	PC Pin, w/o Flange	0.375	9.53	2	1	250V	10A	1C	21.1 x 18 x 20	\$1.35	\$0.95
2275175	Jameco Valuepro	HI-200-04PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	3	1	250V	10A	2A	49.6 x 16.5 x 20	\$2.39	\$1.59
2275239	Jameco Valuepro	HI-201-03PH-S-D40	Single Row Barrier Strip	Screw, M3.5	PC Pin with Flange	0.375	9.53	3	1	250V	10A	2C	49.6 x 18 x 20	\$2.59	\$1.99
2275287	Jameco Valuepro	HI-201-03P	Single Row Barrier Strip	Screw, M3.5	PC Pin, w/o Flange	0.375	9.53	3	1	250V	10A	1C	30.6 x 16.5 x 20	\$2.15	\$1.59
2275343	Jameco Valuepro	HI-202-03PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Insulated Solder Turret with Flange	0.375	9.53	3	1	250V	10A	2B	49.6 x 16.3 x 18.9	\$1.49	\$1.25
2277015	Molex	38720-6303	Single Row Barrier Strip	Screw, 6-32	PC Pin, w/o Flange	0.375	9.53	3	1	300V	15A	1C	30.7 x 15.7 x 16.8	\$2.25	\$1.75
2275183	Jameco Valuepro	HI-200-04PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	4	1	250V	10A	2A	59.1 x 16.5 x 20	\$2.69	\$1.89
2275247	Jameco Valuepro	HI-201-04PH-S-D40	Single Row Barrier Strip	Screw, M3.5	PC Pin with Flange	0.375	9.53	4	1	250V	10A	2C	59.1 x 18.0 x 20	\$2.69	\$2.05
2275295	Jameco Valuepro	HI-201-04P	Single Row Barrier Strip	Screw, M3.5	PC Pin, w/o Flange	0.375	9.53	4	1	250V	10A	1C	40.1 x 16.5 x 20	\$2.49	\$1.79
2275351	Jameco Valuepro	HI-202-04PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Insulated Solder Turret with Flange	0.375	9.53	4	1	250V	10A	2B	59.1 x 16.3 x 18.9	\$2.39	\$1.65
2275191	Jameco Valuepro	HI-200-05PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	5	1	250V	10A	2A	68.6 x 16.5 x 20	\$2.95	\$2.15
2275255	Jameco Valuepro	HI-201-05PH-S-D40	Single Row Barrier Strip	Screw, M3.5	PC Pin with Flange	0.375	9.53	5	1	250V	10A	2C	68.6 x 18.0 x 20	\$2.95	\$2.25
2275303	Jameco Valuepro	HI-201-05P	Single Row Barrier Strip	Screw, M3.5	PC Pin, w/o Flange	0.375	9.53	5	1	250V	10A	1C	49.6 x 16.5 x 20	\$2.59	\$1.95
2275359	Jameco Valuepro	HI-202-05PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Insulated Solder Turret with Flange	0.375	9.53	5	1	250V	10A	2B	68.6 x 16.3 x 18.9	\$3.79	\$2.79
797849	Molex	38720-6305	Single Row Barrier Strip	Screw, 6-32	PC Pin, w/o Flange	0.375	9.53	5	1	300V	15A	1C	49.8 x 15.7 x 16.8	\$2.49	\$2.25
2275199	Jameco Valuepro	HI-200-06PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	6	1	250V	10A	2A	78.1 x 16.5 x 20	\$3.49	\$2.39
2275263	Jameco Valuepro	HI-201-06PH-S-D40	Single Row Barrier Strip	Screw, M3.5	PC Pin with Flange	0.375	9.53	6	1	250V	10A	2C	78.1 x 18 x 20	\$3.39	\$2.49
2275311	Jameco Valuepro	HI-201-06P	Single Row Barrier Strip	Screw, M3.5	PC Pin, w/o Flange	0.375	9.53	6	1	250V	10A	1C	59.1 x 16.5 x 20	\$2.95	\$2.25
2275367	Jameco Valuepro	HI-202-06PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Insulated Solder Turret with Flange	0.375	9.53	6	1	250V	10A	2B	78.1 x 16.3 x 18.9	\$2.49	\$2.25
2273055	Magnum	A20220604	Single Row Barrier Strip	Screw, 6-32	PC Pin, w/o Flange	0.375	9.53	6	1	300V	30A	2C	58.6 x 16.5 x 19.3	\$2.95	\$2.59
2275207	Jameco Valuepro	HI-200-08PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	8	1	250V	10A	2A	97.1 x 16.5 x 20	\$4.49	\$3.59
2275271	Jameco Valuepro	HI-201-08PH-S-D40	Single Row Barrier Strip	Screw, M3.5	PC Pin with Flange	0.375	9.53	8	1	250V	10A	2C	97.1 x 18 x 20	\$3.89	\$2.99
2275383	Jameco Valuepro	HI-202-08PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Insulated Solder Turret with Flange	0.375	9.53	8	1	250V	10A	2B	97.1 x 16.3 x 18.9	\$4.09	\$2.89
2275447	Jameco Valuepro	HI-201-08P	Single Row Barrier Strip	Screw, M3.5	PC Pin, w/o Flange	0.375	9.53	8	1	250V	10A	1C	21.1 x 18 x 20	\$3.49	\$2.59
2272943	Eaton	A207108R42	Single Row Barrier Strip	Screw, 6-32	PC Pin Right Angle with Flange	0.375	9.53	8	1	300V	30A	2C	96.8 x 16.5 x 19.3	\$5.35	\$5.15
2275215	Jameco Valuepro	HI-200-10PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	10	1	250V	10A	2A	116.1 x 16.5 x 20	\$4.95	\$3.95
2275279	Jameco Valuepro	HI-201-10PH-S-D40	Single Row Barrier Strip	Screw, M3.5	PC Pin with Flange	0.375	9.53	10	1	250V	10A	2C	116.1 x 18 x 20	\$4.89	\$3.69
2275399	Jameco Valuepro	HI-202-10PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Insulated Solder Turret with Flange	0.375	9.53	10	1	250V	10A	2B	116.1 x 16.3 x 18.9	\$5.59	\$4.19
2275455	Jameco Valuepro	HI-201-10P	Single Row Barrier Strip	Screw, M3.5	PC Pin, w/o Flange	0.375	9.53	10	1	250V	10A	1C	21.1 x 18 x 20	\$4.95	\$3.79
2275223	Jameco Valuepro	HI-200-12PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	12	1	250V	10A	2A	135.1 x 16.5 x 20	\$5.49	\$4.49
2275407	Jameco Valuepro	HI-202-12PH-S-D40	Single Row Barrier Strip	Screw, M3.5	Insulated Solder Turret with Flange	0.375	9.53	12	1	250V	10A	2B	135.1 x 16.3 x 18.9	\$5.75	\$4.69
2275415	Jameco Valuepro	HI-201-12P	Single Row Barrier Strip	Screw, M3.5	PC Pin, w/o Flange	0.375	9.53	12	1	250V	10A	1C	116.1 x 18 x 20	\$5.95	\$4.89
2275423	Jameco Valuepro	HI-201-12PH-S-D40	Single Row Barrier Strip	Screw, M3.5	PC Pin with Flange	0.375	9.53	12	1	250V	10A	2C	116.1 x 18 x 20	\$5.29	\$4.79
2272959	Eaton	A303102	Single Row Barrier Strip	Screw, 6-32	Closed Bottom with Flange	0.437	11.1	2	1	600V	30A	2A	43.9 x 16.5 x 19.3	\$1.09	\$0.99
2272967	Eaton	A382207	Single Row Barrier Strip	Screw, 6-32	PC Pin, w/o Flange	0.437	11.1	7	1	600V	30A	1C	79.2 x 21.5 x 20.4	\$3.95	\$3.75
2277911	Dinkle	DT35-B01W-02	Tri-Barrier Strip	Screw, M3.5	PC Pin, Offset, w/o Flange	0.325	8.25	2	1	300V	20A	4D	17.8 x 15.2 x 12.7	\$1.25	\$1.09
2273031	TE Connectivity	4PCV-05-006	Tri-Barrier Strip	Screw, 6-32	PC Pin, Offset, w/o Flange	0.325	8.26	5	1	150V	20A	4D	33.0 x 15.2 x 12.7	\$2.95	\$2.69
2277895	TE Connectivity	4PCV-06-006	Tri-Barrier Strip	Screw, 6-32	PC Pin, Offset, w/o Flange	0.325	8.26	6	1	150V	20A	4D	41.28 x 15.24 x 12.7	\$1.95	\$1.75
2133616	Dinkle	DT35-B01W-06	Tri-Barrier Strip	Screw, M3.5	PC Pin, Offset, w/o Flange	0.325	8.26	6	1	300V	20A	4D	66 x 15.2 x 8	\$1.75	\$1.49
2277903	TE Connectivity	4PCV-08-006	Tri-Barrier Strip	Screw, 6-32	PC Pin, Offset, w/o Flange	0.325	8.26	8	1	150V	20A	4D	57.79 x 15.24 x 12.7	\$3.95	\$3.59
2133624	Dinkle	DT35-B01W-08	Tri-Barrier Strip	Screw, M3.5	PC Pin, Offset, w/o Flange	0.325	8.25	8	1	300V	20A	4D	82.5 x 15.2 x 8	\$2.95	\$2.59
2277919	Dinkle	DT35-B01W-09	Tri-Barrier Strip	Screw, M3.5	PC Pin, Offset, w/o Flange	0.325	8.25	9	1	300V	20A	4D	75.5 x 15.2 x 12.7	\$4.95	\$4.49
2276559	Cooper Industries	CB10111S1968	Tri-Barrier Strip	Screw, 6-32	Insulated Solder Turret with Flange	0.325	8.26	10	1	300V	15A	4B	84.3 x 15.2 x 13.2	\$4.95	\$4.49
2277927	Dinkle	DT35-B01W-10	Tri-Barrier Strip	Screw, M3.5	PC Pin, Offset, w/o Flange	0.325	8.25	10	1	300V	20A	4D	83.75 x 15.2 x 12.7	\$4.95	\$4.49
2277935	Dinkle	DT35-B01W-14	Tri-Barrier Strip	Screw, M3.5	PC Pin, Offset, w/o Flange	0.325	8.25	14	1	300V	20A	4D	116.75 x 15.2 x 12.7	\$6.95	\$6.25
2272951	TE Connectivity	6PCR-03	Tri-Barrier Strip	Screw, 6-32	PC Pin Right Angle w/o Flange	0.375	9.53	3	1	300V	25A	5C	30.1 x 16 x 17.8	\$1.09	\$0.99
2277087	TE Connectivity	6PCV-04	Tri-Barrier Strip	Screw, 6-32	PC Pin Right Angle w/o Flange	0.375	9.53	4	1	300V	25A	4D	39.6 x 17.8 x 15.9	\$2.29	\$1.79
2277079	TE Connectivity	6PCV-06	Tri-Barrier Strip	Screw, 6-32	PC Pin, Offset, w/o Flange	0.375	9.53	6	1	300V	25A	4D	58.7 x 17.8 x 15.9	\$3.95	\$3.59
2162628	Armdt	HB951-08P	Tri-Barrier Strip	Screw, M3.5	PC Pin, Offset, w/o Flange	0.375	9.53	8	1	250V	10A	4D	77.5 x 17.6 x 14.3	\$3.49	\$3.15
2273039	Eaton	CB20221107	Tri-Barrier Strip	Screw, 6-32	PC Pin, Offset, w/o Flange	0.375	9.53	11	1	300V	30A	4D	106.2 x 17.8 x 15.2	\$5.95	\$5.39
2272919	Eaton	CB20221207	Tri-Barrier Strip	Screw, 6-32	PC Pin, Offset, w/o Flange	0.375	9.53	12	1	300V	30A	4D	115.8 x 17.8 x 15.2	\$7.95	\$7.59
2277071	Molex	386608803	Tri-Barrier Strip	Screw, 6-32	PC Pin, Zig Zag, w/o Flange	0.500	12.7	3	1	600V	45A	4C/D	40.6 x 22.6 x 11.7	\$3.95	\$3.49
230973	Cinch Connectors	2-140	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.375	9.53	2	2	250VAC	15A	3A	35.7 x 22.2 x 28.6	\$2.25	\$1.95
2172682	Adam Technologies	TDA-02	Dual-Barrier Block	Screw, M3.5	Open Bottom	0.375	9.53	2	2	300V	10A	3A	36 x 19.5 x 11.9	\$1.95	\$1.75
2272831	Molex	38770-0102	Dual-Barrier Block	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	2	2	300V	15A	3A	35.7 x 18.3 x 11.2	\$1.95	\$1.49

Jameco Part No.	Manufacturer Name	Manufacturer Part No.	Description	Top Termination	Bottom Termination	Pitch (inches)	Pitch (mm)	Number of Positions	Number of Rows	Max Voltage Rating	Max Current Rating	Fig.	Dimensions L x D x H (mm)	Price 1	Price 10
2272863	Jameco Valuepro	GGE-10-2P	Dual-Barrier Block	Screw, M3.5	Open Bottom with Flange	0.375	9.53	2	2	600V	10A	3A	36 x 19.5 x 11.9	\$0.89	\$0.79
2272879	Jameco Valuepro	GGE-20-2P	Dual-Barrier Block	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	2	2	600V	20A	3A	36 x 19.5 x 11.9	\$1.09	\$0.99
69411	Molex	38770-0104	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.375	9.53	4	2	250V	15A	3A	54.7 x 11.2 x 22.4	\$2.95	\$2.39
230990	Cinch Connectors	4-140	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.375	9.53	4	2	250VAC	15A	3A	54.8 x 22.2 x 28.6	\$2.49	\$2.19
208857	Jameco Valuepro	GGE-10-4P-R	Dual-Barrier Block	Screw, M3.5	Open Bottom	0.375	9.53	4	2	600V	10A	3A	55 x 19.5 x 11.9	\$1.59	\$1.39
2272887	Jameco Valuepro	GGE-20-4P	Dual-Barrier Block	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	4	2	600V	20A	3A	55 x 19.5 x 11.9	\$1.95	\$1.75
2273047	Molex	5-140	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.375	9.53	5	2	250V	15A	5A	64.3 x 22.2 x 10.3	\$2.95	\$2.59
231010	Cinch Connectors	6-140	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.375	9.53	6	2	250VAC	15A	3A	73.8 x 22.2 x 28.6	\$3.25	\$2.95
2272839	Molex	38770-0106	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.375	9.53	6	2	300V	15A	3A	73.8 x 18.3 x 11.2	\$3.05	\$3.25
208865	Jameco Valuepro	GGE-10-6P-R	Dual-Barrier Block	Screw, M3.5	Open Bottom	0.375	9.53	6	2	600V	10A	3A	74 x 19.5 x 11.9	\$1.95	\$1.75
69454	Molex	38770-0108	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.375	9.53	8	2	250V	15A	3A	92.8 x 11.2 x 22.4	\$3.99	\$3.29
231036	Cinch Connectors	8-140	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.375	9.53	8	2	250VAC	15A	3A	92.9 x 22.2 x 28.6	\$4.25	\$3.79
2272871	Jameco Valuepro	GGE-10-8P	Dual-Barrier Block	Screw, M3.5	Open Bottom with Flange	0.375	9.53	8	2	600V	10A	3A	93 x 19.5 x 11.9	\$2.75	\$2.49
2272903	Jameco Valuepro	GGE-20-8P	Dual-Barrier Block	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	8	2	600V	20A	3A	93 x 19.5 x 11.9	\$2.95	\$2.75
231052	Cinch Connectors	10-140	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.375	9.53	10	2	250VAC	15A	3A	111.9 x 22.2 x 28.6	\$5.95	\$4.95
2272847	Molex	38770-0110	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.375	9.53	10	2	300V	15A	3A	111.9 x 18.3 x 11.2	\$4.49	\$3.59
208900	Jameco Valuepro	GGE-10-10P-R	Dual-Barrier Block	Screw, M3.5	Open Bottom	0.375	9.53	10	2	600V	10A	3A	112 x 19.5 x 11.9	\$2.95	\$2.75
2272911	Jameco Valuepro	GGE-20-10P	Dual-Barrier Block	Screw, M3.5	Closed Bottom with Flange	0.375	9.53	10	2	600V	20A	3A	112 x 19.5 x 11.9	\$3.25	\$2.95
231061	Cinch Connectors	12-140	Dual-Barrier Block	Screw, 6-32	Open Bottom	0.375	9.53	12	2	250VAC	15A	3A	131 x 22.2 x 28.6	\$6.95	\$5.95
2272855	Molex	38770-0112	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.375	9.53	12	2	300V	15A	3A	130.9 x 18.3 x 11.2	\$5.29	\$4.69
208882	Jameco Valuepro	GGE-10-12P-R	Dual-Barrier Block	Screw, M3.5	Open Bottom	0.375	9.53	12	2	600V	10A	3A	131 x 19.5 x 11.9	\$3.25	\$2.95
2273023	Cinch Connectors	20-140	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.375	9.53	20	2	250V	15A	5A	207.2 x 22.2 x 10.3	\$10.95	\$9.95
2278167	On Shore Technology	DB-95MNV-25	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.375	9.53	25	2	300V	20A	3A	254.7 x 21.8 x 13	\$9.95	\$8.95
207547	Jameco Valuepro	GGE-20-6P-R	Dual-Barrier Block	Screw, M3.5	Closed Bottom with Flange	0.429	10.9	6	2	600V	20A	3A	85.3 x 22 x 17	\$1.75	\$1.59
207572	Jameco Valuepro	GGE-20-12P-R	Dual-Barrier Block	Screw, M3.5	Open Bottom with Flange	0.429	10.9	12	2	600V	20A	3A	150.7 x 22 x 17	\$3.49	\$3.19
231351	Cinch Connectors	2-141	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.438	11.13	2	2	250VAC	20A	3A	41.3 x 28.6 x 33.3	\$1.95	\$1.75
2100021	Arndt	3-141	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.438	11.13	3	2	250V	20A	3A	52.4 x 22.2 x 12.7	\$2.95	\$2.49
231378	Cinch Connectors	4-141	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.438	11.13	4	2	250VAC	20A	3A	63.5 x 28.6 x 33.3	\$2.95	\$2.49
231394	Cinch Connectors	6-141	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.438	11.13	6	2	250VAC	20A	3A	85.7 x 28.6 x 33.3	\$3.95	\$3.35
231415	Cinch Connectors	8-141	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.438	11.13	8	2	250VAC	20A	3A	108 x 28.6 x 33.3	\$4.95	\$4.29
231431	Cinch Connectors	10-141	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.438	11.13	10	2	250VAC	20A	3A	130.2 x 28.6 x 33.3	\$5.95	\$5.29
231440	Cinch Connectors	12-141	Dual-Barrier Block	Screw, 6-32	Closed Bottom with Flange	0.438	11.13	12	2	250VAC	20A	3A	152.4 x 28.6 x 33.3	\$6.95	\$5.95
441210	Cinch Connectors	2-142	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.563	14.3	2	2	250V	30A	3A	53.2 x 27 x 15.9	\$2.95	\$2.39
440858	Cinch Connectors	4-142	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.563	14.3	4	2	250V	30A	3A	81.8 x 27 x 15.9	\$3.95	\$3.59
440874	Cinch Connectors	6-142	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.563	14.3	6	2	250V	30A	3A	110.3 x 27 x 15.9	\$6.95	\$6.29
440891	Cinch Connectors	8-142	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.563	14.3	8	2	250V	30A	3A	138.9 x 27 x 15.9	\$7.95	\$6.95
441130	Cinch Connectors	10-142	Dual-Barrier Block	Screw, 6-32	Open Bottom with Flange	0.563	14.3	10	2	250V	30A	3A	167.5 x 27 x 15.9	\$9.95	\$9.19
2275375	On Shore Technology	ES0800/02DSFB	Eurostyle Block	Screw	-	0.315	8	2	2	300V	15A	6	21.6 x 15.5 x 15.7	\$0.59	\$0.39
2275391	On Shore Technology	ES0800/03DSFB	Eurostyle Block	Screw	-	0.315	8	3	2	300V	15A	6	29.6 x 15.5 x 15.7	\$0.95	\$0.59
2275431	On Shore Technology	ES0800/04DSFB	Eurostyle Block	Screw	-	0.315	8	4	2	300V	15A	6	37.6 x 15.5 x 15.7	\$0.95	\$0.69
2275463	On Shore Technology	ES0800/06DSFB	Eurostyle Block	Screw	-	0.315	8	6	2	300V	15A	6	53.6 x 15.5 x 15.7	\$1.49	\$1.05
2275471	On Shore Technology	ES0800/08DSFB	Eurostyle Block	Screw	-	0.315	8	8	2	300V	15A	6	69.6 x 15.5 x 15.7	\$1.59	\$1.25
2275479	On Shore Technology	ES0800/10DSFB	Eurostyle Block	Screw	-	0.315	8	10	2	300V	15A	6	85.6 x 15.5 x 15.7	\$1.95	\$1.49
2259260	On Shore Technology	ES0800/12DSFB	Eurostyle Block	Screw	-	0.315	8	12	2	300V	15A	6	117.6 x 15.5 x 15.7	\$1.49	\$1.25
215011	Jameco Valuepro	PA7DS	Eurostyle Block	Screw	-	0.323	8.2	12	2	450V	17.5A	6	96.2 x 17 x 14.5	\$1.95	\$1.75
2275487	On Shore Technology	ES1000/02DSFB	Eurostyle Block	Screw	-	0.394	10	2	2	300V	20A	6	26.6 x 20.5 x 16	\$0.89	\$0.55
2275735	On Shore Technology	ES1000/03DSFB	Eurostyle Block	Screw	-	0.394	10	3	2	300V	20A	6	36.6 x 20.5 x 16	\$0.95	\$0.69
2275743	On Shore Technology	ES1000/04DSFB	Eurostyle Block	Screw	-	0.394	10	4	2	300V	20A	6	46.6 x 20.5 x 16	\$1.35	\$0.95
2275751	On Shore Technology	ES1000/06DSFB	Eurostyle Block	Screw	-	0.394	10	6	2	300V	20A	6	66.6 x 20.5 x 16	\$1.59	\$1.35
2275759	On Shore Technology	ES1000/08DSFB	Eurostyle Block	Screw	-	0.394	10	8	2	300V	20A	6	86.6 x 20.5 x 16	\$2.29	\$1.75
2275767	On Shore Technology	ES1000/10DSFB	Eurostyle Block	Screw	-	0.394	10	10	2	300V	20A	6	106.6 x 20.5 x 16	\$2.49	\$2.15
2120170	On Shore Technology	ES1000/12DS	Eurostyle Block	Screw	-	0.394	10	12	2	300V	20A	6	126.6 x 20.5 x 19	\$1.95	\$1.75
2275775	On Shore Technology	ES1000/12DSFB	Eurostyle Block	Screw	-	0.394	10	12	2	300V	20A	6	151.5 x 20.5 x 16	\$2.95	\$2.49
215029	Jameco Valuepro	PA9DS	Eurostyle Block	Screw	-	0.394	10	12	2	450V	24A	6	116.8 x 20.2 x 16.7	\$2.49	\$2.25
2275783	On Shore Technology	ES1200/02DSFB	Eurostyle Block	Screw	-	0.472	12	2	2	300V	30A	6	31.5 x 23.5 x 18.5	\$0.89	\$0.59
2275791	On Shore Technology	ES1200/03DSFB	Eurostyle Block	Screw	-	0.472	12	3	2	300V	30A	6	43.5 x 23.5 x 18.5	\$1.25	\$0.89
2275799	On Shore Technology	ES1200/04DSFB	Eurostyle Block	Screw	-	0.472	12	4	2	300V	30A	6	55.5 x 23.5 x 18.5	\$1.59	\$1.19
2275807	On Shore Technology	ES1200/06DSFB	Eurostyle Block	Screw	-	0.472	12	6	2	300V	30A	6	79.5 x 23.5 x 18.5	\$2.19	\$1.59
2275815	On Shore Technology	ES1200/08DSFB	Eurostyle Block	Screw	-	0.472	12	8	2	300V	30A	6	103.5 x 23.5 x 18.5	\$2.95	\$2.19
2275823	On Shore Technology	ES1200/10DSFB	Eurostyle Block	Screw	-	0.472	12	10	2	300V	30A	6	127.5 x 23.5 x 18.5	\$3.19	\$2.75
2275831	On Shore Technology	ES1200/12DSFB	Eurostyle Block	Screw	-	0.472	12	12	2	300V	30A	6	151.5 x 23.5 x 18.5	\$3.95	\$2.95
215037	Jameco Valuepro	PA12HDS	Eurostyle Block	Screw	-	0.472	12	12	2	450V	35A	6	141 x 23.8 x 19	\$3.25	\$2.95