





Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 102007

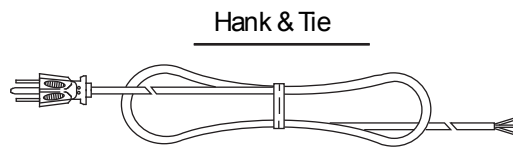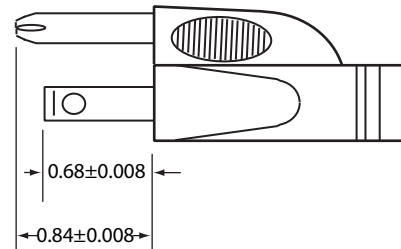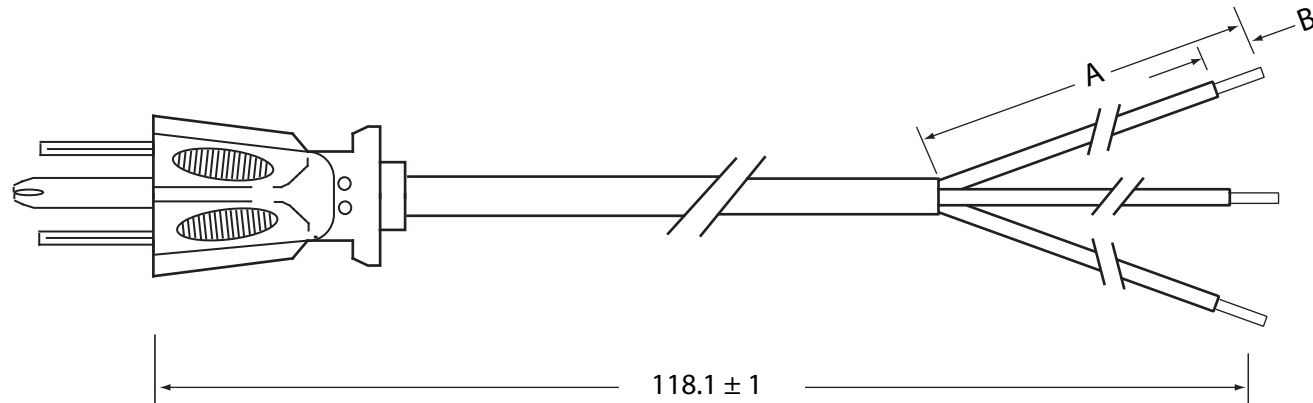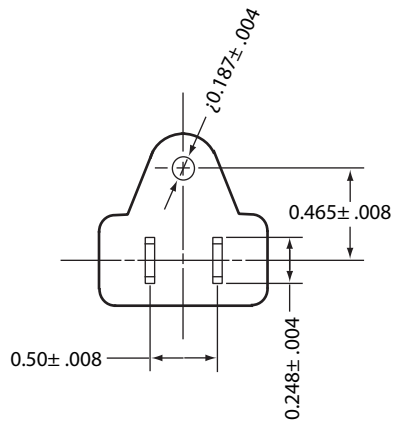

			X
			X

CONDUCTORS	A	B
LIVE (BROWN)	3	strip & twist 0.25
NEUTRAL (BLUE)	3	strip & twist 0.25
GROUND (GREEN/YELLOW)	3	strip & twist 0.25

RoHS Compliant since 2005	
PLUG TYPE	EL302 (NEMA 5-15P)
CONNECTOR	--
CABLE TYPE	SVT(CEE CODE)
COLOR	BLACK
# OF CONDUCTORS	3
WIRE SIZE	18 AWG
OVERALL LENGTH	118.1 INCHES LONG
OUTER DIAMETER	0.248"
TEMPERATURE	60°C
AMPERAGE RATING	10A
VOLTAGE RATING	125V

TOLERANCES ON DIMENSIONS UNLESS OTHERWISE SPECIFIED	
DO NOT SCALE DRAWING	SURFACE ROUGHNESS MAX 125
DECIMALS .XX ± .250	ANGLES ±
.XXX ± .100	



TUMBLER POWER CORDS

4241 BUSINESS CENTER DRIVE
 FREMONT, CA 94538
 Phone: (510)657-3002
 Fax: (510) 770-1933

DATE: 10/03/08	SHEET: 1 OF 1
----------------	---------------

PART NUMBER:	32V89.8SI
---------------------	------------------

MEASUREMENT IN: INCHES

NORTH AMERICA POWER CORD

APPROVAL: Jessica C.