

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242


The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 102331

BNC Coaxial Cables

BNC Plug to BNC Plug Coaxial Cables
 RG58, RG58A-Stranded, RG59, RG6
 75 and 50Ω – Nickel-Plated Connectors

205-521	3' RG59/U BNC-BNC Cable
205-523	3' RG58/U BNC-BNC Cable
205-525	6' RG59/U BNC-BNC Cable
205-527	6' RG58/U BNC-BNC Cable
205-528	10' RG58/U BNC-BNC Cable
205-529	12' RG59/U BNC-BNC Cable
205-530	15' RG58A/U BNC-BNC Cable
205-537	25' RG59/U BNC-BNC Cable
205-540	25' RG58/U BNC-BNC Cable
205-547	50' RG59/U BNC-BNC Cable
205-550	50' RG58/U BNC-BNC Cable
205-570	100' RG58/U BNC-BNC Cable

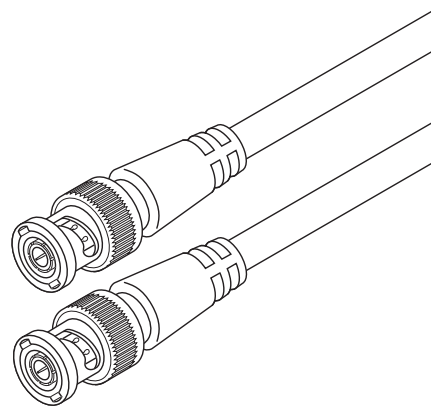

205-521	3' RG59
205-523	3' RG58
205-525	6' RG59
205-527	6' RG58
205-528	10' RG58
205-529	12' RG59
205-530	15' RG58A-Stranded
205-537	25' RG59
205-540	25' RG58
205-547	50' RG59
205-550	50' RG58
205-570	100' RG58

High-Grade BNC Cables

75Ω RG6/U UL Listed Professional BNC Cables
 Crimped Precision Machined Brass BNC Connectors
 Double Aluminum Foil Shield Plus
 60-67% Tinned-Copper Braid Shield
 0.193" nom. OD CPE Dielectric
 0.275" nom. OD Black PVC Jacket


205-580BK	3' RG6 BNC-BNC Cable – UL	◀ NEW
205-582BK	6' RG6 BNC-BNC Cable – UL	◀ NEW
205-586BK	12' RG6 BNC-BNC Cable – UL	◀ NEW
205-590BK	25' RG6 BNC-BNC Cable – UL	◀ NEW
205-592BK	50' RG6 BNC-BNC Cable – UL	◀ NEW
205-596BK	100' RG6 BNC-BNC Cable – UL	◀ NEW




UHF Coaxial Cables

UHF Plug to UHF Plug Coaxial Cables
 50Ω Low-Loss RG58/U or RG8x-Mini
 Fully Molded – Nickel-Plated Connectors

205-603	3' RG58/U UHF-UHF Cable
205-606	6' RG58/U UHF-UHF Cable
205-609	9' RG58/U UHF-UHF Cable
205-612	12' RG58/U UHF-UHF Cable
205-620	20' RG58/U UHF-UHF Cable
205-703	3' Mini-RG8x UHF-UHF Cable
205-706	6' Mini-RG8x UHF-UHF Cable
205-709	9' Mini-RG8x UHF-UHF Cable
205-712	12' Mini-RG8x UHF-UHF Cable
205-720	20' Mini-RG8x UHF-UHF Cable
205-750	50' Mini-RG8x UHF-UHF Cable

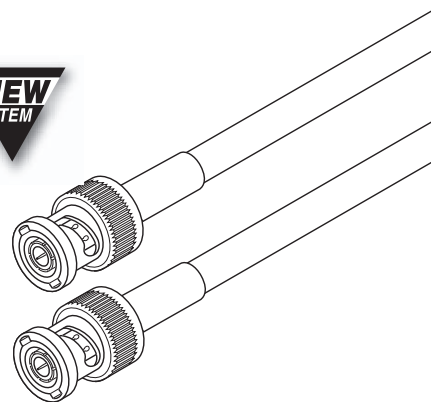

205-580BK	3' RG6
205-582BK	6' RG6
205-586BK	12' RG6
205-590BK	25' RG6
205-592BK	50' RG6
205-596BK	100' RG6

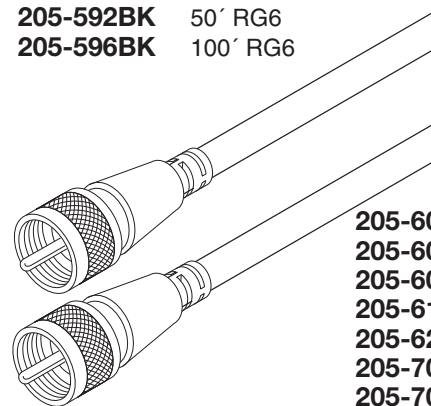

205-603	3' RG58/U
205-606	6' RG58/U
205-609	9' RG58/U
205-612	12' RG58/U
205-620	20' RG58/U
205-703	3' Mini-RG8x
205-706	6' Mini-RG8x
205-709	9' Mini-RG8x
205-712	12' Mini-RG8x
205-720	20' Mini-RG8x
205-750	50' Mini-RG8x