

Distributed by:

**JAMECO**<sup>®</sup>  
ELECTRONICS

**www.Jameco.com ♦ 1-800-831-4242**


The content and copyrights of the attached  
material are the property of its owner.

Jameco Part Number 102365

### BNC Coaxial Cables

BNC Plug to BNC Plug Coaxial Cables  
 RG58, RG58A-Stranded, RG59, RG6  
 75 and 50Ω – Nickel-Plated Connectors

<b>205-521</b>	3' RG59/U BNC-BNC Cable
<b>205-523</b>	3' RG58/U BNC-BNC Cable
<b>205-525</b>	6' RG59/U BNC-BNC Cable
<b>205-527</b>	6' RG58/U BNC-BNC Cable
<b>205-528</b>	10' RG58/U BNC-BNC Cable
<b>205-529</b>	12' RG59/U BNC-BNC Cable
<b>205-530</b>	15' RG58A/U BNC-BNC Cable
<b>205-537</b>	25' RG59/U BNC-BNC Cable
<b>205-540</b>	25' RG58/U BNC-BNC Cable
<b>205-547</b>	50' RG59/U BNC-BNC Cable
<b>205-550</b>	50' RG58/U BNC-BNC Cable
<b>205-570</b>	100' RG58/U BNC-BNC Cable

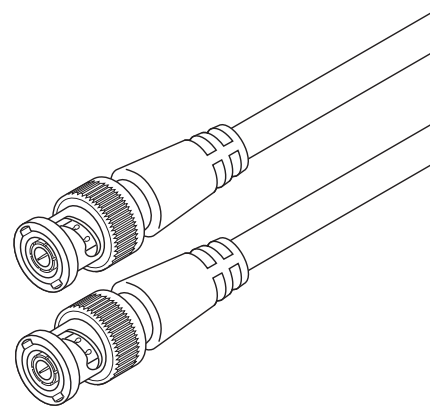

<b>205-521</b>	3' RG59
<b>205-523</b>	3' RG58
<b>205-525</b>	6' RG59
<b>205-527</b>	6' RG58
<b>205-528</b>	10' RG58
<b>205-529</b>	12' RG59
<b>205-530</b>	15' RG58A-Stranded
<b>205-537</b>	25' RG59
<b>205-540</b>	25' RG58
<b>205-547</b>	50' RG59
<b>205-550</b>	50' RG58
<b>205-570</b>	100' RG58

### High-Grade BNC Cables

75Ω RG6/U UL Listed Professional BNC Cables  
 Crimped Precision Machined Brass BNC Connectors  
 Double Aluminum Foil Shield Plus  
 60-67% Tinned-Copper Braid Shield  
 0.193" nom. OD CPE Dielectric  
 0.275" nom. OD Black PVC Jacket


<b>205-580BK</b>	3' RG6 BNC-BNC Cable – UL	◀ <b>NEW</b>
<b>205-582BK</b>	6' RG6 BNC-BNC Cable – UL	◀ <b>NEW</b>
<b>205-586BK</b>	12' RG6 BNC-BNC Cable – UL	◀ <b>NEW</b>
<b>205-590BK</b>	25' RG6 BNC-BNC Cable – UL	◀ <b>NEW</b>
<b>205-592BK</b>	50' RG6 BNC-BNC Cable – UL	◀ <b>NEW</b>
<b>205-596BK</b>	100' RG6 BNC-BNC Cable – UL	◀ <b>NEW</b>




### UHF Coaxial Cables

UHF Plug to UHF Plug Coaxial Cables  
 50Ω Low-Loss RG58/U or RG8x-Mini  
 Fully Molded – Nickel-Plated Connectors

<b>205-603</b>	3' RG58/U UHF-UHF Cable
<b>205-606</b>	6' RG58/U UHF-UHF Cable
<b>205-609</b>	9' RG58/U UHF-UHF Cable
<b>205-612</b>	12' RG58/U UHF-UHF Cable
<b>205-620</b>	20' RG58/U UHF-UHF Cable
<b>205-703</b>	3' Mini-RG8x UHF-UHF Cable
<b>205-706</b>	6' Mini-RG8x UHF-UHF Cable
<b>205-709</b>	9' Mini-RG8x UHF-UHF Cable
<b>205-712</b>	12' Mini-RG8x UHF-UHF Cable
<b>205-720</b>	20' Mini-RG8x UHF-UHF Cable
<b>205-750</b>	50' Mini-RG8x UHF-UHF Cable

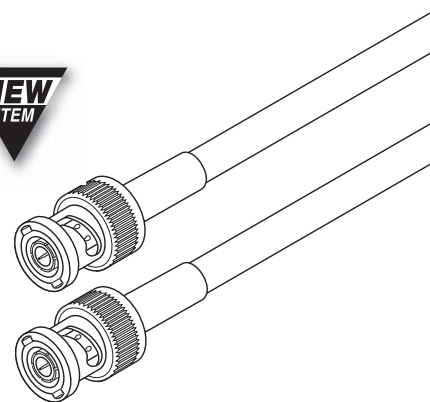

<b>205-580BK</b>	3' RG6
<b>205-582BK</b>	6' RG6
<b>205-586BK</b>	12' RG6
<b>205-590BK</b>	25' RG6
<b>205-592BK</b>	50' RG6
<b>205-596BK</b>	100' RG6

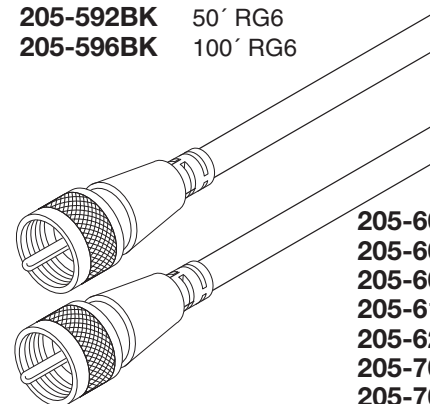

<b>205-603</b>	3' RG58/U
<b>205-606</b>	6' RG58/U
<b>205-609</b>	9' RG58/U
<b>205-612</b>	12' RG58/U
<b>205-620</b>	20' RG58/U
<b>205-703</b>	3' Mini-RG8x
<b>205-706</b>	6' Mini-RG8x
<b>205-709</b>	9' Mini-RG8x
<b>205-712</b>	12' Mini-RG8x
<b>205-720</b>	20' Mini-RG8x
<b>205-750</b>	50' Mini-RG8x