

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 104943

1008serie


D-SUB RIGHT ANGLE TYPE (7.2mm)

Specifications:



Contact Resistance: 30mΩmax. at DC 100mA
 Insulator Resistance: 1000MΩmin. at DC 500V
 Current Rating: 5 AMP

Dielectric Withstanding



Voltage: AC 1000V For 1 minute
 Operating Temperature: -55°C~+105°C
 Contact: Brass or Phosphor Bronze
 Housing: PBT & 30% Glass Fiber (UL 94V-0)

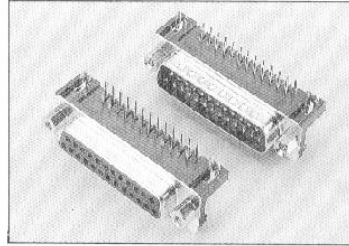

FEMALE

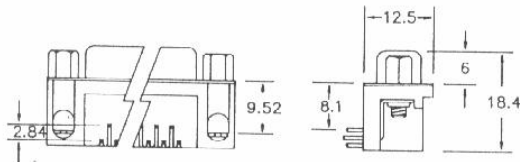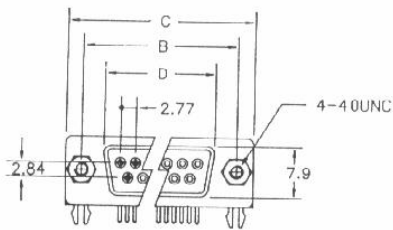

MALE

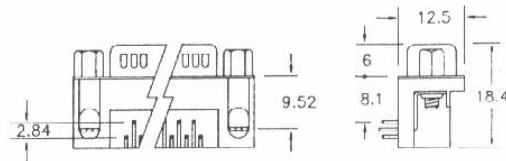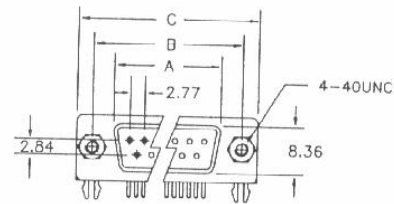

TOP WILLING CO., LTD.
 1FL., NO. 3, LANE 39, YU SHYH ROAD,
 WU-KU HSIANG, TAIPEI HSIEN, TAIWAN
 TEL: 2-2920757 FAX: 2-2941947

Dimension

Position	A	B	C	D
9	16.92	24.99	30.81	16.33
15	25.25	33.32	39.14	24.66
19		39.03	44.80	29.92
23		44.36	50.30	35.10
25	38.96	47.04	53.04	38.38
37	55.42	63.50	69.32	54.84
50	52.86	61.11	66.90	52.34