

 
Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 114770



F Series Connectors


Commercial Grade F Series Connectors
Suitable for Coaxial Networks Used in Video,
Data and Telephony Applications
Nickel- or Gold-Plated Brass/Zinc Construction

- 200-010** F Plug Crimp RG59 1/4" Ring
- 200-011** F Plug Crimp RG59 1/4" Ring – Gold
- 200-015** F Plug Crimp RG6 1/4" Ring
- 200-018** 1/4" Ring for 200-010 Connector
100 Count Bag
- 200-020** F Plug Crimp RG59 Attached Ring
- 200-025** F Plug Crimp RG6 Attached Ring
- 200-030** F Plug Crimp RG59 1/2" Barrel
- 200-031** F Plug Crimp RG59 1/2" Barrel – Gold
- 200-035** F Plug Crimp RG6 1/2" Barrel
- 200-036** F Plug Crimp RG6 1/2" Barrel – Gold
- 200-037** F Plug Crimp RG6 O-Ring Seal
2-Piece Die-Cast Construction
Anti-Corrosion Chromate Plating
- 200-038** F Plug Crimp RG6 Weatherproof
O-Ring Water Seal
Silicone-Gel Compound Seal
Precision Machined Brass
Anti-Corrosion Chromate Plating
- 200-039** F Plug Twist-On for RG6
- 200-040** F Plug Twist-On for RG59
- 200-041** F Plug Twist-On for RG59 – Gold
- 200-042** F-Quick Plug Crimp for RG59
- 200-043** F Plug Twist-On for RG6 – Gold

F Series Adapters

Commercial Grade F Series Adapters
Suitable for Coaxial Networks Used in
Video, Data and Telephony Applications
Nickel- or Gold-Plated Brass/Zinc Construction


- 200-045** RCA Jack to F Plug
- 200-050** F Coupler Jack-Jack
- 200-051** F Coupler Jack-Jack – Gold Plated
- 200-053** F Coupler Jack-Jack Panel Mount
with Mounting Nut and Washer
- 200-055** F Jack Panel Receptacle
- 200-056** 3/8" Nut-Washer for F Fittings
- 200-075** F Terminator 75Ω 5% 1/2W
- 200-100** F Coupler Plug-Plug
- 200-103** F Jack to F-Quick Plug
- 200-104** F Jack to F-Quick Plug – Gold Plated
- 200-107** F Angle Adapter Jack-Plug
- 200-108** BNC Jack to F Plug
- 200-117** F Jack to 3.5mm Mono Plug

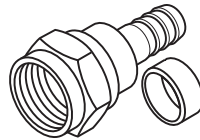


200-010 RG59 Nickel
200-011 RG59 Gold
200-015 RG6 Nickel




200-018 Price/100
RG59

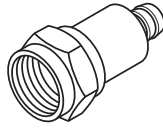


200-020 RG59
200-025 RG6

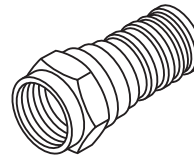

200-030 RG59 Nickel
200-031 RG59 Gold
200-035 RG6 Nickel
200-036 RG6 Gold

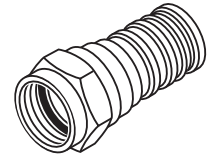


200-037 RG6

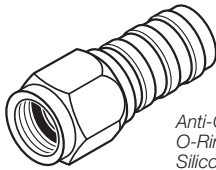


Anti-Corrosion Plating
O-Ring Seal
Silicone-Gel Seal


200-038 RG6 Weatherproof

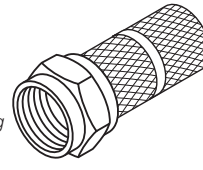


200-039 RG6 Nickel
200-040 RG59 Nickel
200-041 RG59 Gold
200-043 RG6 Gold

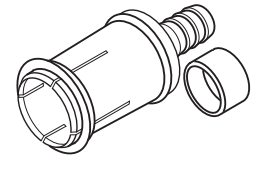


200-042 RG59

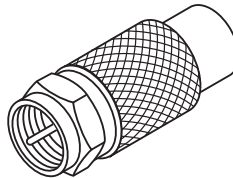


200-045

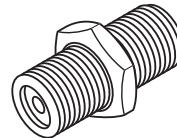


200-050 Nickel
200-051 Gold

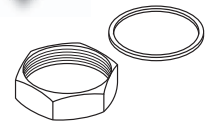


200-056

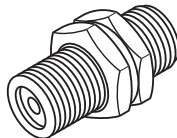


200-053 F81

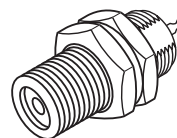


200-055

 


200-075 75Ω

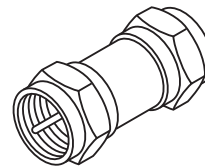


200-100 F71

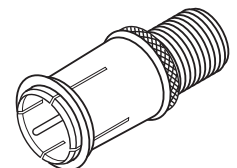


200-103 Nickel
200-104 Gold

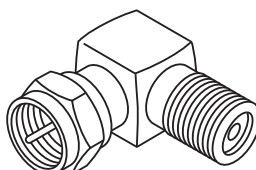

200-107

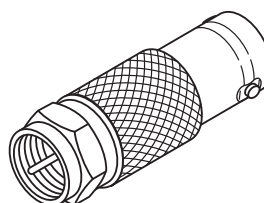

200-108

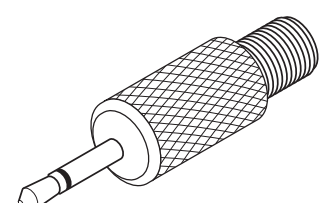

200-117