

 


Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242


The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 117911

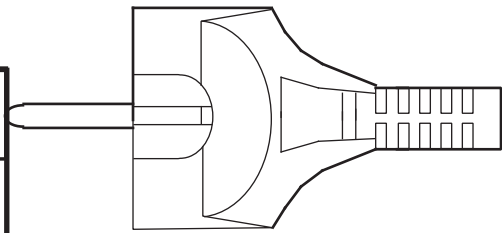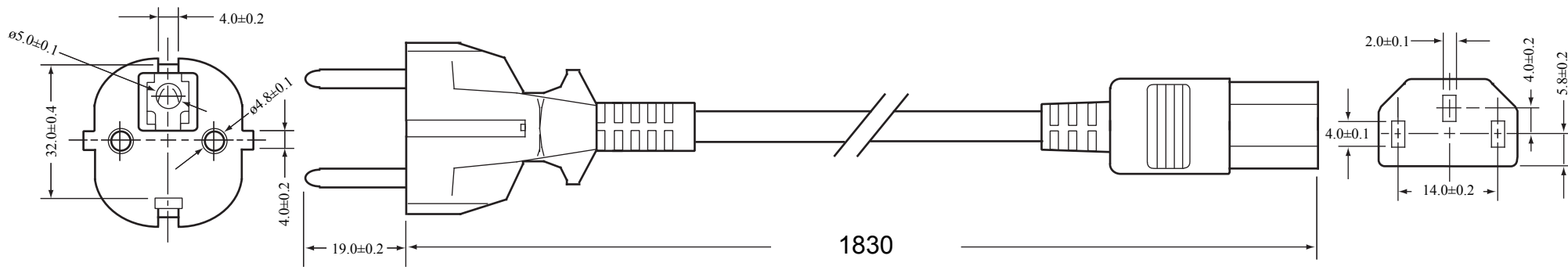

** RoHS Compliant **

 Hank & Tie



PLUG TYPE	EL 211 (CEE 7 VII)
CONNECTOR	EL 701 (EN 60320/C13)
CABLE TYPE	H05VV-F
COLOR	Black
# OF CONDUCTORS	3
WIRE SIZE	0.75mm sq.
OVERALL LENGTH	1830 mm (6 Feet)
OUTER DIAMETER	6.8 mm
TEMPERATURE	70°C
AMPERAGE RATING	6A
VOLTAGE RATING	250V

DATE: 08/01/05 SHEET: 1 OF 1

PART NUMBER: 2171H576

APPROVAL: Y.C.

SPECIFICATION CONTROL DRAWING

TUMBLER POWER CORDS

4241 BUSINESS CENTER DRIVE
 FREMONT, CA 94538
 Phone: (510)657-3002
 Fax: (510) 770-1933



TOLERANCES ON DIMENSIONS UNLESS OTHERWISE SPECIFIED	
DO NOT SCALE DRAWING	SURFACE ROUGHNESS MAX 125
DECIMALS .XX ± .50	ANGLES ±
.XXX ± .250	

MEASUREMENT IN: MM

EUROPEAN POWER CORDSET