

Distributed by:

JAMECO[®]
ELECTRONICS

www.Jameco.com ♦ 1-800-831-4242

The content and copyrights of the attached
material are the property of its owner.

Jameco Part Number 118594

BNC Series Connectors


Commercial Grade BNC Series Connectors
Suitable for Video and Headend Applications
Nickel-Plated Brass/Zinc Construction
Gold-Plated Contacts – Delrin Insulator

- 200-122** BNC Plug Twist-On for RG6 ◀ **NEW**
- 200-131** BNC Plug Crimp 2pc RG59
- 200-134** BNC Plug Crimp 2pc RG58
- 200-135** BNC Jack Crimp 2pc RG59/62
- 200-136** BNC Jack Crimp 2pc RG58
- 200-137** BNC Jack Crimp 2pc RG59 Plenum
- 200-138** BNC Plug Crimp 2pc RG59 Plenum
- 200-139** BNC Plug Crimp 2pc RG6
- 200-140** BNC Plug Crimp 3pc RG59 Plenum
- 200-141** BNC Plug Crimp 3pc RG6
- 200-142** BNC Plug Twist-On for RG59/62
- 200-143** BNC Plug Crimp 3pc RG59/62
- 200-144** BNC Plug Clamp for RG59/62
- 200-145** BNC Plug Crimp 3pc for RG58
- 200-146** BNC Plug Twist-On for RG58
- 200-147** BNC Plug Crimp 3pc RG58A/C
Includes PVC and Plenum Ferrules
- 200-148** BNC Jack Isolated Panel Mount
- 200-156** BNC Jack Panel – 1/8" Holes


BNC Series Adapters

Commercial Grade BNC Series Adapters
Suitable for Video and Headend Applications


- 200-130** F Jack to BNC Plug
- 200-132** UHF Jack to BNC Plug
- 200-133** BNC Coupler Plug-Plug
- 200-150** BNC Tee Adapter Jack-Jack-Jack
- 200-155** BNC Tee Adapter Jack-Plug-Jack
- 200-158** BNC Angle Adapter Jack-Plug
- 200-160** BNC Coupler Jack-Jack
- 200-165** BNC Coupler Jack-Jack Panel
- 200-173** RCA Jack to BNC Plug
- 200-174** BNC Terminator 50Ω 1% 1/2W
with 6" Brass Chain
- 200-175** BNC Terminator 50Ω 5% 1/2W
- 200-176** BNC Terminator 50Ω 1% 1/2W
- 200-177** BNC Terminator 75Ω 5% 1/2W
- 200-178** BNC Terminator 75Ω 1% 1/2W
- 200-179** BNC Terminator 93Ω 5% 1/2W
- 200-180** BNC Terminator 93Ω 1% 1/2W
- 200-834** Mini-UHF Jack to BNC Plug

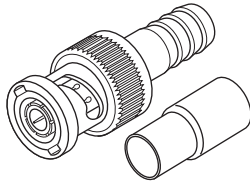


200-131 RG59
200-134 RG58
200-138 RG59/62 Plenum
200-139 RG6

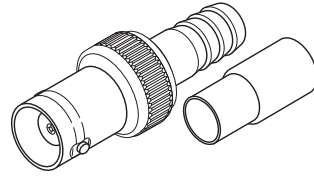


200-135 RG59/62
200-136 RG58
200-137 RG59/62/Plenum

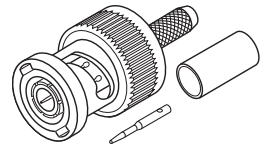



200-140 RG59/62 Plenum
200-141 RG6
200-143 RG59/62
200-145 RG58
200-147 RG58A/C 2-Ferr.

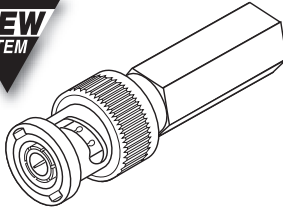


200-122 RG6
200-142 RG59/62
200-146 RG58

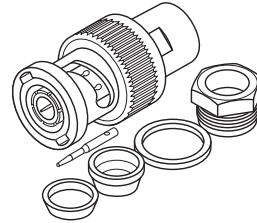


200-144 RG59/62 UG260/U **200-148**

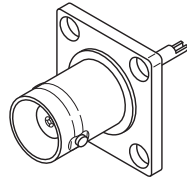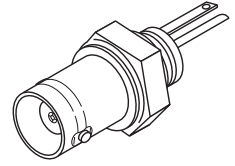


200-156

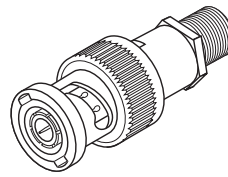


200-130

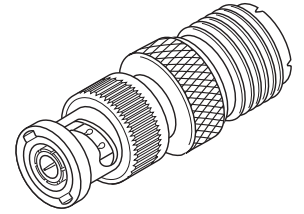


200-132 UG255A/U

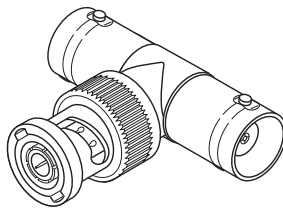


200-155 UG274B/U

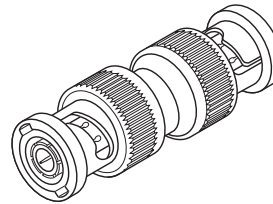


200-133 UG491B/U

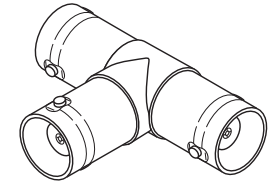


200-150

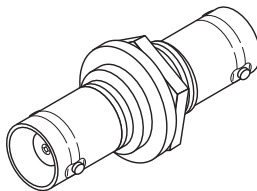


200-165 UG492A/U

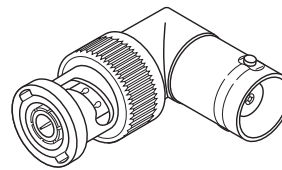


200-158 UG306B/U

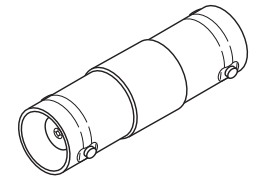


200-160 UG914/U

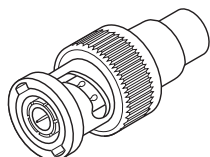

200-173

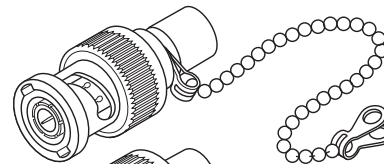

200-174 50Ω 1% Chain
200-175 50Ω 5%
200-176 50Ω 1%
200-177 75Ω 5%
200-178 75Ω 1%
200-179 93Ω 5%
200-180 93Ω 1%

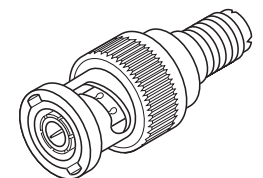

200-834