

Distributed by:



[www.Jameco.com](http://www.Jameco.com) ♦ 1-800-831-4242

The content and copyrights of the attached material are the property of its owner.

8

7

6

5

4

3

2

1

H

## Photoconductive Cells

**Epoxy Encapsulated**

**Small dimensions**

**Operating Temperature: -20°C ~ +70°C**

Applications:

Contrast control in TV sets  
Street light control  
Room light control  
Electronics toys  
Industrial controls


G

G

F

F

Epoxy on Leads  
3mm max.

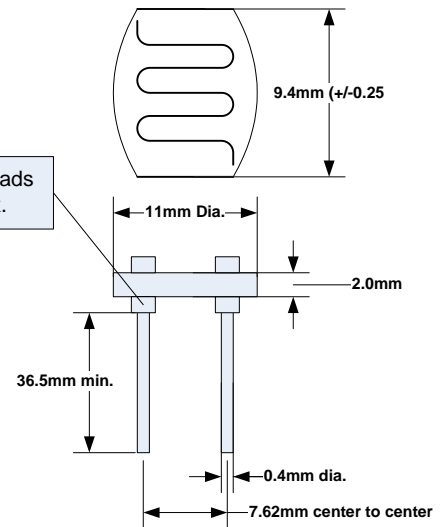

E

E

D

D

Type	SEN-5001	
Light Resistance	@ 2FC	6 - 29
(kohms)	@1FC	12 - 58
R05 min. (kohms)	500	
Spectral Response	550nm	
Pmax (mW)	250	
Vmax (V)	250	

C

C

B

B

A

A

**Model No.: SEN-5001**

## Photoconductive Cells

**Jameco Part Number 120299**

SIZE  
mm

FSCM NO

DWG NO

REV

SCALE

SHEET

1 OF 1

8

7

6

5

4

3

2

1