


 
# PIN EXTRACTOR FOR POLARIZED CONNECTORS

RAPIDLY KNOCK OUT MALE / FEMALE

INTER-LOCKING CRIMPING PINS

ROHS

HT-319

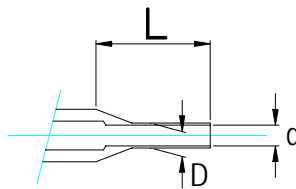

| HT-  | L     | $\varnothing$ D | $\varnothing$ d | $(D-d) / 2$ | REMARK        |
|------|-------|-----------------|-----------------|-------------|---------------|
| 319  | 12 mm | 3.94 mm         | 3.10 mm         | 0.42 mm     | INTER-LOCKING |
| 319A | 12 mm | 2.71 mm         | 2.15 mm         | 0.28 mm     |               |
| 319B | 12 mm | 4.12 mm         | 2.78 mm         | 0.67 mm     |               |
| 319C | 20 mm | 3.27 mm         | 2.65 mm         | 0.31 mm     | V.35 MALE     |
| 319D | 20 mm | 3.23 mm         | 2.87 mm         | 0.18 mm     | V.35 FEMALE   |

• SPECIAL SIZE ARE WELCOME

