


Hex Code Table		
✓ FCXXXX	Length (L)	
FC2098	1/8	
FC2099	3/16	
FC2100	1/4	
FC2101	5/16	
FC2102	3/8	
FC2103	7/16	
FC2104	1/2	
FC2105	9/16	
FC2106	5/8	
FC2107	11/16	
FC2108	3/4	
FC2109	13/16	
FC2110	7/8	
FC2111	15/16	
<b>FC2112</b>	<b>1</b>	
FC2113	1-1/16	
FC2114	1-1/8	
FC2115	1-3/16	
FC2116	1-1/4	
FC2117	1-5/16	
FC2118	1-3/8	
FC2119	1-7/16	
FC2120	1-1/2	
FC2121	1-9/16	
FC2122	1-5/8	
FC2123	1-11/16	
FC2124	1-3/4	
FC2125	1-13/16	
FC2126	1-7/8	
FC2127	1-15/16	
FC2128	2	
FC2129	2-1/8	
FC2130	2-1/4	
FC2131	2-3/8	
FC2132	2-1/2	
FC2133	2-5/8	
FC2134	2-3/4	
FC2135	2-7/8	
FC2136	3	
FC2137	3-1/4	
FC2138	3-1/2	
FC2139	3-3/4	
FC2140	4	
FC2141	4-1/4	
FC2142	4-1/2	
FC2143	4-3/4	
FC2144	5	
FC2145	5-1/4	
FC2146	5-1/2	
FC2147	5-3/4	
FC2148	6	

Jameco Part# 139205

# 1/4 Hex Female Standoff

Jameco Electronics

1-800-831-4242

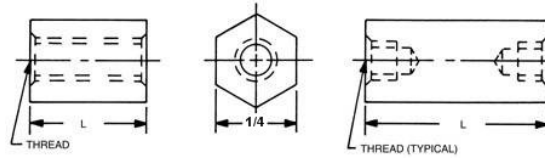

**Create a part number:**

Length	Thread	Material	Finish
FCXXXX	XXX	XX	XX
_____ - _____ - _____ - _____			

✓	Thread			
	Thread Code (XXX)	Tapped Thru		Longer Parts
		A, B, S	SS	Blind Tap Depth
	440	1	3/4	1/4
	632	1	1	3/8
	832	1	1	7/16
	1032	1-1/8	1	1/2

Aluminum (A), Brass (B), Steel (S), Stainless Steel (SS)

Material	
✓	Material Code (XX)
A	Aluminum
B	Brass
S	Steel
SS	Stainless Steel
N	Nylon

**Tolerances Unless otherwise Specified**  
 .xxx +/- .005  
 .xx +/- .010  
 Angular +/- 1 Degree  
 Linear +/- .005  
**Break all sharp edges**

✓ Compatible Finish	
A, B, S, SS	0 - Plain
B, S	5 - Nickel Plate (QQ-N-290)
A	6 - Iridite #14 Gold (MIL-C-5541E)
A	7 - Iridite Clear (MIL-C-5541E)
A	9 - Alodine 1200
B, S	12 - Zinc Clear (ASTM-B-633)
B, S	16 - Electro Tin (MIL-T-10727 TYPE 1)
SS	20 - Passivation (MIL-F-14072D)
A	22 - Clear Anodize (MIL-A-8625-TYPE2) (Sulphuric) Hot Water Seal (Clear)
A	24 - Black Anodize (MIL-A-8625)
B, S, SS	26 - Black Oxide
B, S	28 - Zinc Yellow (ASTM-B-633)

Jameco Electronics

1-800-831-4242