



## A Complete Line of Molded, Self-Adhesive, Polyurethane Bumpers

Available in  
**Clear, Black, Brown, Gray & White**

Manufacturing Bumpers is our only business, and we offer the Most Competitive Prices in the industry!

Our Bumpers are 100% Polyurethane. We use no plasticizers, oils or fillers which are widely used in our competitors' products.

We offer Bumpers with two different Pressure Sensitive Adhesives:

- An Aggressive Synthetic Rubber or
- A High Performance Acrylic to meet your specific requirements.

Custom shapes, sizes, colors and pad configurations are available upon request.

Bumpers are 'kiss-cut' on a protective release liner. Simply peel the bumper from the liner and apply anywhere protection is needed.

Our crystal Clear Bumpers are practically invisible when applied to colored or see-through surfaces such as glass or plastic.

Same Day Shipping of In-Stock Parts will meet critical deadlines to satisfy your needs and the needs of your customers.

### APPLICATIONS

- Cabinets
- Picture Frames
- Electronics
- Computers
- Circuit Boards
- Cutting Boards
- Automotive
- Medical
- Packaging
- Furniture
- POP Displays
- Building Materials
- DIY

### APPLIES QUICKLY & EASILY - WHEREVER PROTECTION IS NEEDED



Holds Cutting Boards firmly in place on all counter surfaces.

Acrylic Adhesive withstands the most extreme conditions of a dishwasher ...

RECOMMENDED PROFILES  
All profiles.  
Specify Acrylic Adhesive



... keeps Picture Frames stable, preventing them from marking and damaging walls ...

RECOMMENDED PROFILES  
Large Frames: BS-4, BS-8, BS-11, BS-15, BS-17, BS-19, BS-29, BS-37, BS-47, BS-57  
Small Frames: BS-1, BS-2, BS-3, BS-6, BS-12, BS-18, BS-22, BS-35



... dampens harsh sounds of slamming Cabinet Doors, Drawers and Lids ...

RECOMMENDED PROFILES  
For our New Softer Durometer, please specify with suffix -SD  
BS-1-SD, BS-12-SD  
Our Standard Line of Bumpers  
BS-1, BS-5, BS-7, BS-12, BS-27, BS-34, BS-40



... prevents Speakers, Electronics, and Computer Equipment from vibrating or sliding. Will not mar, scratch or stain tables ...

RECOMMENDED PROFILES  
BS-1, BS-2, BS-3, BS-4, BS-5, BS-7, BS-12, BS-18, BS-20, BS-22, BS-27, BS-32, BS-34, BS-35



... quiets Doorknobs, eliminating nicks and unsightly damage to walls behind doors.

RECOMMENDED PROFILE  
BS-30

**PHONE 800.541.2500**  
[www.bumperspecialties.com](http://www.bumperspecialties.com)

**FAX 800.220.2840**  
email: [bumper@snip.net](mailto:bumper@snip.net)

For more detailed information about Bumper Specialties' products, please contact a customer service representative.

# CYLINDRICAL

Product Number		Dimensions		Pieces
		Tolerance: ± .020" (0.5mm)		
<b>BS 1</b> <b>BS 1-SD*</b>		 .500"  .140"	12.7mm 3.5mm	200 Per Pad 5,000 Per Ctn
<b>BS 5</b>		 .500"  .060"	12.7mm 1.5mm	200 Per Pad 5,000 Per Ctn
<b>BS 6</b>		 .500"  .250"	12.7mm 6.4mm	200 Per Pad 5,000 Per Ctn
<b>BS 11</b>		 .650"  .400"	16.5mm 10.2mm	128 Per Pad 2,560 Per Ctn
<b>BS 18</b>		 .500"  .140"	12.7mm 3.5mm	200 Per Pad 5,000 Per Ctn
<b>BS 24</b>		 .810"  .120"	20.6mm 3.0mm	72 Per Pad 2,520 Per Ctn
<b>BS 34</b>		 .375"  .125"	9.5mm 3.2mm	300 Per Pad 6,000 Per Ctn
<b>BS 35</b>		 .375"  .190"	9.5mm 4.8mm	200 Per Pad 5,000 Per Ctn
<b>BS 41</b>		 .780"  .200"	19.8mm 5.1mm	84 Per Pad 3,360 Per Ctn
<b>BS 44</b>		 .750"  .160"	19.1mm 4.1mm	98 Per Pad 2,450 Per Ctn

# HEMISPHERICAL

Product Number		Dimensions		Pieces
		Tolerance: ± .020" (0.5mm)		
<b>BS 2</b>		 .440"  .200"	11.1mm 5.1mm	242 Per Pad 5,082 Per Ctn
<b>BS 7</b>		 .335"  .085"	8.5mm 2.2mm	450 Per Pad 5,400 Per Ctn
<b>BS 8</b>		 .700"  .380"	17.8mm 9.6mm	98 Per Pad 2,254 Per Ctn
<b>BS 12</b> <b>BS 12-SD*</b>		 .375"  .150"	9.5mm 3.8mm	200 Per Pad 5,000 Per Ctn
<b>BS 15</b>		 .620"  .310"	15.7mm 7.9mm	128 Per Pad 3,200 Per Ctn
<b>BS 22</b>		 .375"  .211"	9.5mm 5.4mm	300 Per Pad 6,000 Per Ctn
<b>BS 27</b>		 .312"  .085"	7.9mm 2.2mm	450 Per Pad 5,400 Per Ctn
<b>BS 39</b>		 .750"  .075"	19.1mm 1.9mm	84 Per Pad 5,040 Per Ctn
<b>BS 40</b>		 .250"  .062"	6.4mm 1.6mm	578 Per Pad 15,028 Per Ctn
<b>BS 37</b>		 .720"  .560"	18.3mm 14.2mm	1 Per Pad or 4 Per Pad 1,500 Per Ctn









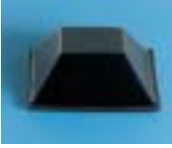






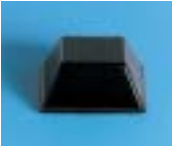







**Standard Colors:**  Clear  Black

Our most popular bumpers! Every bumper is available in Clear and Black. The crystal clear bumper is nearly invisible when used for translucent or see-through applications.

**Additional Colors :**  White  Brown  Gray

Most bumpers are stocked in every color and ready for shipment, however ... colors are inventoried based on popularity. Please call to confirm availability of white, brown and gray. There is no additional charge for clear or pigmented Bumpers.

# SQUARE

Product Number		Dimensions Tolerance: ± .020" (0.5mm)		Pieces
<b>BS 3</b>			.500" 12.7mm	200 Per Pad 5,000 Per Ctn
			.230" 5.8mm	
<b>BS 4</b>			.780" 19.8mm	1 Per Pad 2,000 Per Ctn
			.380" 9.7mm	
<b>BS 19</b>			.810" 20.6mm	98 Per Pad 2,646 Per Ctn
			.300" 7.6mm	
<b>BS 20</b>			.400" 10.2mm	242 Per Pad 5,082 Per Ctn
			.100" 2.5mm	
<b>BS 29</b>			.780" 19.8mm	98 Per Pad 2,940 Per Ctn
			.250" 6.4mm	
<b>BS 32</b>			.500" 12.7mm	200 Per Pad 5,000 Per Ctn
			.120" 3.0mm	
<b>BS 36</b>			1.000" 25.4mm	55 Per Pad 2,310 Per Ctn
			.180" 4.6mm	

# SPECIALTY

Product Number		Dimensions Tolerance: ± .020" (0.5mm)		Pieces
<b>BS 33</b> <b>BS 33-SD*</b>			.500" 12.7mm	200 Per Pad 5,000 Per Ctn
			.150" 3.8mm	
<b>BS 37</b>			.720" 18.3mm	1 Per Pad 1,000 Per Ctn
			.560" 14.2mm	
<b>BS 47</b>			.750" 19.1mm	1 or 4 Per Pad 2,646 Per Ctn
			.750" 19.1mm	
<b>BS 57</b>			.787" 20.0mm	1 or 4 Per Pad 1,000 Per Ctn
			.886" 22.5mm	
<b>BS 17</b>			.780" 19.8mm	98 Per Pad 2,940 Per Ctn
			.250" 6.4mm	
<b>BS 30</b>			1.810" 46.0mm	1 Per Pad 500 Per Ctn
			.600" 15.2mm	

### Custom Shapes & Colors

We are the only company that provides full engineering support to help you design a bumper to meet your particular needs! Our staff will meticulously assist your company with the completion of any project. A one-time charge (this differs with size) for tooling and set-up applies. Your final cost/m (m=thousand), will be consistent with our existing line of bumpers. The volume of polyurethane required for the custom shapes, difficulty of manufacturing, normal and customary waste are factors in pricing.

*You can be assured we are dedicated to providing you with the most competitive prices in the global marketplace!*

### Special Die-Cut Pads

Available die-cut in strips or smaller pads for a minimal cost/m and a one-time tool charge.

## FEATURES & GENERAL INFORMATION

- ✓ Superb Coefficient of Friction and Resistance to Skidding
- ✗ Contains **NO** Plasticizers, Oils or Fillers commonly used in our competitors' products
- ✓ UL Recognized Component
- ✓ Crack-Resistant and Resilient
- ✓ Easy 'Peel-Off' Application
- ✓ Non-Staining and Non-Marring
- ✓ Superior Abrasion Resistance
- ✓ Vibration and Shock Dampening

**Adhesive Systems** We offer both adhesives at the same low price!

**BSI-94** High Performance Acrylic Adhesive

**BSI-95** Aggressive Synthetic Rubber Adhesive

## Softer Durometer for Sound Dampening

A new softer durometer is offered in two of our standard profiles; BS 1-SD, BS 12-SD and BS 33-SD.

(The -SD suffix designates the softer durometer.) Please call for the availability of other profiles. Not for load bearing applications.

See technical information on our website at [www.bumperpecialties.com](http://www.bumperpecialties.com)

