


L Min (MM)	13
D (MM)	5
T (MM)	1.9
F (MM)	2.5
d (MM)	0.3
CAPACITANCE	0.1 $\mu$ F
TOLERANCE	$\pm$ 20%
VOLTAGE	50V
SIZE	5mm Dia.

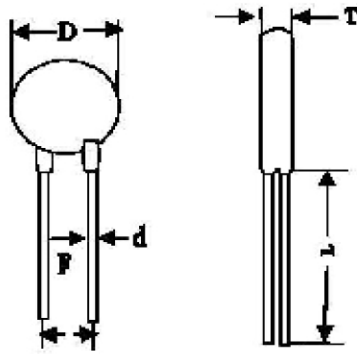

$L = \pm 1$   
 $F = \pm 0.8$   
 $d = \pm 0.05$   
 $D = \pm 1$   
 $T = \pm 1$

规格	Lmin (mm)	D (mm)	T (mm)	F (mm)	d (mm)	外观结构
50VDC-Y5V-104Z	13	5.0	1.9	2.5	0.3	
电容量	温度: 25 $^{\circ}$ C $\pm$ 2 $^{\circ}$ C		Manufacturer Part Number: DC.1/25 Jameco SKU: 15116			
	湿度: 50~60%		Z: $\pm$ 80 20%			
损耗角正切	电压: 0.1V $\pm$ 0.2Vrms		$\tan\delta \leq 2.5\%$			
	频率: 1 $\pm$ 0.2KHz					
耐电压	充电电流 $\leq 2\pi * f * c * u$		试验电压: 50VDC 或 100VDC			
	施加电压时间: 1min		在试验期间电容器应无击穿或飞弧			
绝缘电阻	测量电压: 50VDC		$IR \geq 1000M\Omega$			
	充电电流 $\leq 0.05A$					
	测量时间: 1min					